


Crimping Tools, Wire Strippers and Cable Cutters

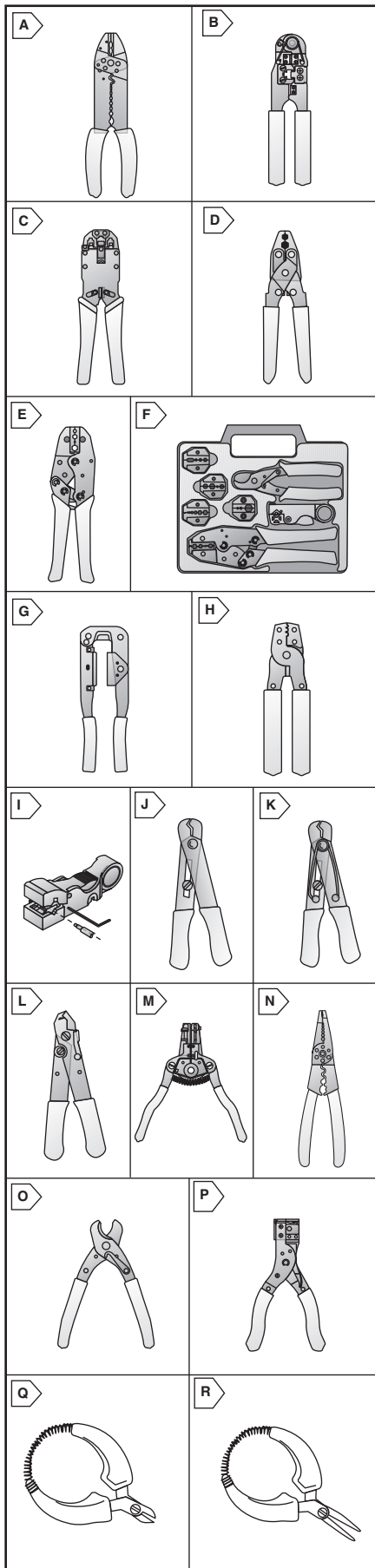

3M™ SOLDERLESS TERMINAL CRIMPING TOOL

- Crimps, cuts and strips
- Crimps both insulated and non-insulated solderless terminals

MOUSER STOCK NO.	Fig.	Description	Price Each
517-TH-440	A	Standard crimp for 22-10AWG	67.12
517-TH-450	A	Heavy duty crimp for 26-6 AWG	83.95

eagle plastic devices MODULAR CRIMPING TOOLS

3-Way Modular Crimping Tools

- Deluxe types with Safe Guide and closed lock for storage
- Cuts, strips, and crimps
- Hardened steel frame
- Black oxide finish
- Lightweight and durable

MOUSER STOCK NO.	Fig.	Description	Price Each
382-210C	B	For 8P8C modular plugs	21.48

Replacement Blades

MOUSER STOCK NO.	Fits	Price Each
382-20961	382-2194, 382-2196, 382-2198, 382-2094C, 382-2096C, & 382-210C	3.72

Professional Modular Crimping Tool

8" professional modular crimping tool cuts, strips, and crimps the more popular modular plugs. This tool is designed for crimping 8P8C, 6P6C, 6P4C, 6P2C, 4P4C, and 4P2C modular plugs with stranded flat wire.

MOUSER STOCK NO.	Fig.	Description	Price Each
382-2008	C	For 4, 6, and 8-position plugs	99.95

eagle plastic devices PARALLEL ACTION "F" CRIMPING TOOLS

MOUSER STOCK NO.	Fig.	Description	Price Each
382-0242	D	9" deluxe hex type for RG59 and aluminax RG6	8.55

eagle plastic devices COAX CRIMPING TOOL

- Crimps: RG6, 59, 62, 140, 210, Belden 8279, 55, 58, 141, 142, 223, 303, 400, fiber optic

MOUSER STOCK NO.	Fig.	Description	Price Each
382-301C	E	Ratchet hex tool for F, FNC, TNC, N, Teflon, Thinnest-PVC, and Fiber Optic connectors	28.95
382-0330	F	Coax tool kit, includes: (1 ea.) 382-301C Heavy Duty Professional Hex Crimp Tool, assortment of dies to work with the following types of coaxial cable: RG6, 8, 8X, 9, 11, 55, 58, 59, 62, 87A, 122, 140, 141, 142, 149, 165, 174, 178, 179, 180, 187, 188, 195, 210, 213, 214, 216, 223, 225, 303, 316, 400, Fiber Optic, Belden types 8218, 8279, and 9913, Coax stripper that works with RG58, 59, 62, 6, and 3C2V cable, Heavy duty 6-1/2" cable cutter that works with .16" to .413" cable	78.96

eagle plastic devices IDC CRIMPING PLIERS

- Easy to assemble flat cable onto IDC type connectors
- Crimping distance for connectors height from .236" to 1.06"

MOUSER STOCK NO.	Fig.	Description	Price Each
382-0214	G	9-1/2" long, steel frame	18.15

eagle plastic devices D-SUB CRIMPING TOOLS

MOUSER STOCK NO.	Fig.	Description	Price Each
382-0213	H	For computer pins and sockets D-sub 20-28 AWG wire	18.48

eagle plastic devices ROTARY CABLE STRIPPERS

- 3 blade models
- Comes with allen wrench adjustment tool
- No replacement cassettes needed

MOUSER STOCK NO.	Fig.	Description	Price Each
382-312A	I	Preset for stripping RG59/62/6	16.95
382-312B	I	Preset for stripping RG58/59/62	16.95

WIRE STRIPPERS AND CUTTERS

MOUSER STOCK NO.	Fig.	Description	Price Each
5876-100	J	Screw adjustment w/o spring 5"	8.23
5876-101S	K	Screw adjustment with spring 5"	9.49
5876-103S	L	Cam adjustment with spring 5-5/16"	13.97

STANDARD WIRE STRIPPERS

MOUSER STOCK NO.	Fig.	Description	Price Each
524-12-480	M	8-22 AWG Stripper	23.94

COOPER Hand Tools XCELITE WIRE STRIPPER & CUTTER

MOUSER STOCK NO.	Fig.	Description	Price Each
578-104CG	N	Stripper, Cutter, crimper and bolt cutter	28.59

eagle plastic devices CABLE CUTTER

- Hardened carbon steel
- Curved blade cuts wire .016" to .413"

MOUSER STOCK NO.	Fig.	Description	Price Each
382-0206	O	6-1/2" long, black oxide finish	8.37

eagle plastic devices CABLE TIE TOOL

- Accepts ties up to .07" thick
- Steel

MOUSER STOCK NO.	Fig.	Description	Price Each
382-2081	P	6-1/2" long, black oxide finish	12.40

eagle plastic devices PALM GRIP SERIES

- Precision, rust proof stainless steel
- Spring loaded with minimal travel
- Applications: PC boards, setting precise and small parts, assembling plastic hobby models, cutting small wires, fishing, and hundreds of other tasks

For quantities of 6 and up, call for quote.

MOUSER STOCK NO.	Fig.	Color	Description	Price Each
382-1017	Q	Red	Flush cutter	23.90
382-1018	R	Blue	Flat nose pliers (serrated)	19.97
382-1019	R	Tan	Flat nose pliers	19.57
382-1021	R	Green	Needle nose pliers	21.54
382-1022	R	Orange	Curved nose pliers	23.90

3M™ VINYL ELECTRICAL TAPE

Scotch™ Super 33+ Tape

Premium 7 mil, flame retardant, weather resistant tape. Resists temperature and moisture for splicing. Meets requirements of UL 510, CSA 22.2



RoHS Compliant

- 5yr shelf life

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Size	Price Each	
		1	10
517-33	3/4" x 66'	5.65	5.36

Scotch™ Super 88 Tape

Premium-grade heavy-duty 8.5 mil, flame retardant, cold and weather resistant tape with superior cold weather handling features. Meets UL 510, and CSA 22.2

- 5yr shelf life

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Size	Price Each	
		1	10
517-88	3/4" x 66'	6.80	6.46

© Copyright 2009 Mouser Electronics

© Copyright 2009 Mouser Electronics