 
 
 


Soldering Tools and Accessories

WAHL® ISO-TIP® SOLDER-PRO SERIES BUTANE POWERED SOLDERING IRONS

- Complete portability
- Convenient refills
- Multi-tool versatility


A	Solder-Pro 50 Features: <ul style="list-style-type: none"> • Cap with igniter • Up to 30 minute run time • Soldering temperatures: 410°F-750°F 
B	Solder-Pro 70 Features: <ul style="list-style-type: none"> • Cap with igniter • Up to 120 minute run time • Soldering temperatures: 410°F-850°F 
C	Solder-Pro 120 Features: <ul style="list-style-type: none"> • Automatic ignition • Up to 200 minute run time • Soldering temperatures: 410°F-1000°F • Torch temperature: 2400°F 

For quantities of 12 and up, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each
557-7971	A	Solder-Pro 50 No. 7971	25.50
557-7974	B	Solder-Pro 70 No. 7974	39.17
557-7977	C	Solder-Pro 120 No. 7977	61.07

WAHL® ISO-TIP® 7670 EZ CHANGE CORDLESS SOLDERING IRON

 The versatile EZ Change cordless soldering iron gives you extended soldering times (with a spare set of batteries); up to 125 electronics joints per charge. Includes industrial quality EZ charge iron, #7545 fine tip, (2) 400mAh (size C) rechargeable nickel cadmium batteries, tip protector, and instructions. (Optional battery charger sold separately.)




For quantities of 5 and up, call for quote.

557-7670 29.95

WAHL® ISO-TIP® 7800 ISO TIP "60" CORDLESS SOLDERING IRON

Fastest charging cordless soldering iron on the market. Solders up to 125 electronic joints per charge. Recharges fully in 1 hour. Cordless soldering iron, recharging stand with wall plug transformer, #7577 tip, #7545 tip, and instructions.

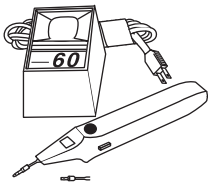

For quantities of 5 and up, call for quote.

557-7800 69.58

WAHL® ISO-TIP® 7700 CORDLESS SOLDERING IRON

Recharges completely in 3 to 4 1/2 hours. A partially discharged battery returns to full capacity in 1 to 2 hours. NiCd battery withstands high-rate charging without damage. Fully charged unit can make up to 125 electronic joints per charge. Recharging stand with wall plug transformer, #7545 tip, #7546 tip, & instructions.

For quantities of 5 and up, call for quote.

557-7700 50.95

7904 "POWER PRO" CORDLESS SOLDERING IRONS

High capacity cordless soldering iron using high efficiency tips, provides up to 30 minutes of continuous soldering time from a fully charged iron or intermittently over 200 solder joints.

- Complete recharge in 4 hours
- LED in recharge stand to indicate charging status
- Tip performance up to 900°F
- Easily replaceable battery and worklight

 


For quantities of 5 and up, call for quote.

557-7904 71.28

WAHL® ISO-TIP® SOLDER-IT SILVER BEARING SOLDER PASTE

- Works with a match, lighter, soldering iron or torch
- 5 times stronger than conventional solder
- Superior electrical conductivity
- Solders all metals



For quantities 24 and up, call for quote.

MOUSER STOCK NO.	Price Each
Mfr. Part Number	1 12
557-7459	5.03 4.29


WAHL® ISO-TIP® HI-EFFICIENCY SOLDERING TIPS

- All ISO-TIP replacement tips fit all ISO-TIP cordless irons
- Isolated tip, ground free, low voltage design eliminates electrical leaks and damage


- Intermittently 200 plus joints per charge
- Unique snap-in design
- Requires less power to heat tip
- Heats tip faster, approximately 5 seconds
- Longer soldering time per full battery charge, up to 30 minutes

For quantities of 5 and up, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each
557-7535-100	A	Regular tip	6.52
557-7545-100	B	Fine tip	6.52
557-7546-100	C	Heavy duty tip	8.35
557-7566-100	D	Micro tip	6.52
557-7577-100	E	Chisel tip	6.52
557-7579-100	F	Beveled tip	5.85

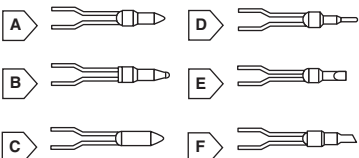

WAHL® ISO-TIP® TIPS FOR SOLDER-PRO SERIES

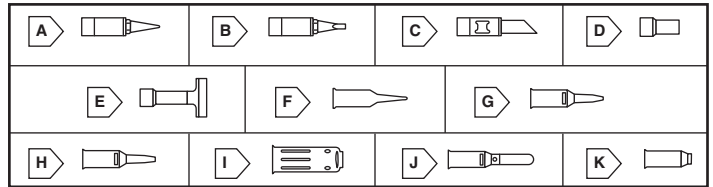

Tips for Solder-Pro 50 and 70 Series For quantities of 10 and up, call for quote.


MOUSER STOCK NO.	Fig.	Description	Price Each	
			1	5
557-7992	A	1mm conical tip	9.95	9.52
557-7992-001	B	2mm chisel tip	9.95	9.52
557-7992-002	C	Hot knife tip	9.95	9.52
557-7992-003	D	Torch tip	9.95	9.52
557-7992-004	E	Heat blower and deflector	9.95	9.52

Tips for Solder-Pro 120 Series For quantities of 10 and up, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each	
			1	5
557-7992-005	F	1.6mm conical tip	10.11	9.67
557-7992-006	G	2.4mm conical tip	10.10	9.67
557-7992-007	H	3.2mm chisel tip	9.95	9.52
557-7992-008	I	Torch tip	10.11	9.67
557-7992-009	J	Hot knife tip	10.11	9.67
557-7992-101	K	Heat blower	10.11	9.67

eagle PENCIL TYPE SOLDERING IRON

 For continuous use by industry and hobbyist. Balanced handle




- 120VAC
- 5/32" dia. tip
- 5 1/2 foot cord
- Replaceable tip
- Light weight

For quantities of 5 and up, call for quote.

MOUSER STOCK NO.	Description	Price Each
381-7394	35W solder iron	5.49
381-7396	Replacement tip	.89


eagle DESOLDERING TOOLS Anti-Static Desoldering Pump

- Rugged all-aluminum body
- Anti-static tip
- Disassembles easily for cleaning
- Dimensions: 7 5/8" (L) x 3/4" (Dia.)
- Replacement tip 384-1001

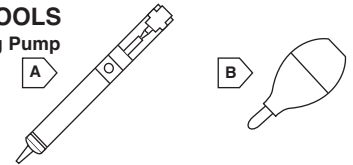

MOUSER STOCK NO.	Fig.	Description	Price Each	
			1	5
384-1000	A	Anti-static desoldering pump	6.25	5.63
384-1001	A	Replacement anti-static tip	1.72	1.55
384-1002	B	Desoldering bulb with tip	2.79	2.51
384-1004	B	Replacement Teflon tip for bulb	1.36	1.22


eagle SOLDERING AID SET

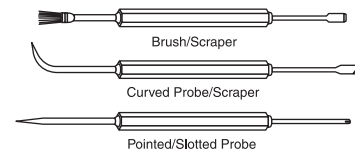

For quantities of 5 and up, call for quote.

MOUSER STOCK NO.	Description	Price Each
384-1017	Aluminum, spring-loaded clip-on heat sink, 2 1/2" long	.76
384-1018	4-pc. soldering aid set includes: clip-on heat sink brush/scraper, pointed/slotted probe, and curved probe/scraper	3.99

WAHL® ISO-TIP® PORTABLE HEAT GUN AND MINI TORCH

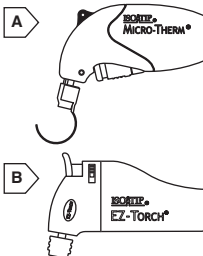

MicroTherm Heat Gun

- Portable and flameless heat
- Electronic ignition
- Temperatures up to 1200°F (650°C)
- For heat shrink tubing, activating adhesives and potting compounds.

EZ-Torch Portable Mini Torch

- Electronic ignition
- Runs approximately 20 minutes of continuous flame per cartridge
- Maximum temperature range: 1300°F-2375°F

For quantities of 10 and up, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each	
			1	5
557-7975	A	Micro Therm Heat Gun	28.91	27.47
557-7978	B	EZ-Torch Mini Torch	19.95	18.95
557-7978-300	-	Reusable butane refill - 2 pk.	3.19	3.03