


XICON Snap Mount Aluminum Electrolytic Capacitors

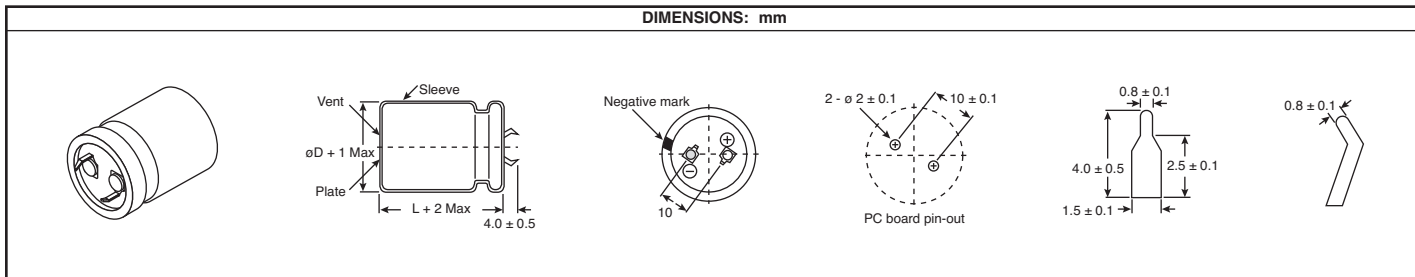

SNAP MOUNT ALUMINUM ELECTROLYTIC CAPACITORS

Specifications:

- Snap-in terminals solder directly to PC board saving process time
- Operating temp range: -40°C to $+85^{\circ}\text{C}$
- Leakage current: 0.2CV , or 1.5mA , whichever is smaller
- Load life test: 2000 hours



RoHS Compliant

RoHS Compliant

For quantities 1000 and up, call for quote.

MOUSER STOCK NO.	Xicon Part Number	Value (μF)	Voltage	Ripple Current (mA/rms)	Diameter	Length	Price Each			
							1	10	100	500
140-LS472M1E-2025-RC	LS472M1E-2025	4700	25	2310	20	25	1.42	1.07	.97	.75
140-LS103M1E-2240-RC	LS103M1E-2240	10000	25	3180	22	40	2.40	1.81	1.64	1.27
140-LS472M1V-2525-RC	LS472M1V-2525	4700	35	2420	25	25	2.01	1.52	1.37	1.07
140-LS103M1V-2250-RC	LS103M1V-2250	10000	35	3590	22	50	3.30	2.49	2.25	1.75
140-LS333M1V-3550-RC	LS333M1V-3550	33000	35	7020	35	50	9.92	7.48	6.59	5.26
140-LS472M1H-2530-RC	LS472M1H-2530	4700	50	3030	25	30	2.25	1.75	1.65	1.49
140-LS822M1H-2550-RC	LS822M1H-2550	8200	50	4370	25	50	3.50	2.73	2.58	2.33
140-LS103M1H-3530-RC	LS103M1H-3530	10000	50	4920	35	30	3.67	3.27	2.99	2.75
140-LS153M1H-3545-RC	LS153M1H-3545	15000	50	6440	35	45	5.18	4.90	3.32	3.25
140-LS472M1J-2250-RC	LS472M1J-2250	4700	63	3490	22	50	4.25	3.21	2.89	2.25
140-LS682M1J-3040-RC	LS682M1J-3040	6800	63	4410	30	40	5.80	4.38	3.95	3.07
140-LS103M1J-3045-RC	LS103M1J-3045	10000	63	5490	30	45	7.57	5.71	5.16	4.01
140-LS102M2A-2230-RC	LS102M2A-2230	1000	100	2120	22	30	2.83	2.32	1.62	1.32
140-LS221M2D-2225-RC	LS221M2D-2225	220	200	1180	22	25	2.19	1.79	1.25	1.02
140-LS271M2D-2225-RC	LS271M2D-2225	270	200	1300	22	25	2.25	1.88	1.29	1.09
140-LS331M2D-2525-RC	LS331M2D-2525	330	200	1430	25	25	2.51	2.06	1.44	1.17
140-LS471M2D-2235-RC	LS471M2D-2235	470	200	1880	22	35	2.87	2.35	1.65	1.34
140-LS681M2D-2535-RC	LS681M2D-2535	680	200	2360	25	35	4.02	3.30	2.31	1.88
140-LS102M2D-2545-RC	LS102M2D-2545	1000	200	3120	25	45	5.52	4.54	3.17	2.58
140-LS222M2D-3550-RC	LS222M2D-3550	2200	200	5000	35	50	7.25	5.82	4.18	3.90
140-LS680M2G-2225-RC	LS680M2G-2225	68	400	720	22	25	1.68	1.38	.96	.80
140-LS101M2G-2230-RC	LS101M2G-2230	100	400	940	22	30	2.60	2.13	1.49	1.24
140-LS181M2G-2530-RC	LS181M2G-2530	180	400	1370	25	30	3.64	2.98	2.09	1.73
140-LS221M2G-2540-RC	LS221M2G-2540	220	400	1620	25	40	4.18	3.43	2.40	1.99
140-LS471M2G-3050-RC	LS471M2G-3050	470	400	2400	30	50	7.49	6.59	4.99	4.05
140-LS680M2W-2225-RC	LS680M2W-2225	68	450	720	22	25	2.10	1.78	1.28	.96
140-LS101M2W-2235-RC	LS101M2W-2235	100	450	1000	22	35	2.77	2.34	1.68	1.26

Aluminum Caps, Can Xicon