


Audio Alarms and Audio/Video Connectors

 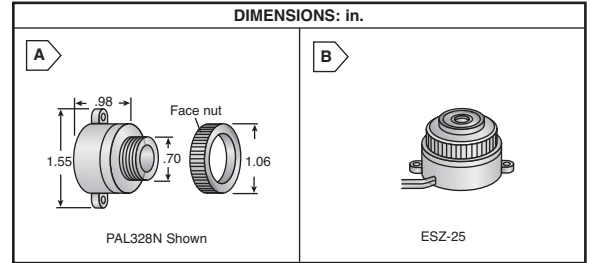


MOUSER STOCK NO.	Fig.	Description	Operating Voltage VDC		Sound Pressure dB (A) @ 2 ft.		Current Drain (mA)	Price Each			
			Min.	Max.	@ V Min.	@ V Max.		1	10	25	50
			*507-PAL328	A	W/out face nut	3.0		28.0	68	100	20
*507-PAL328N	A	W/face nut	3.0	28.0	68	100	20	9.40	8.93	8.46	7.99
507-ESZ-25S	B	Single tone	3.0	28.0	68	100	20	13.20	12.54	11.88	11.22
507-ESZ-25B	B	Dual tone	3.0	28.0	68	100	20	17.44	15.50	14.70	13.07




KOBICONN 3.5MM MONO PHONE JACK

- Specifications:**
- Mounting Hole: .25"
 - Closed Hex Nut
 - Chassis Mount



Schematic

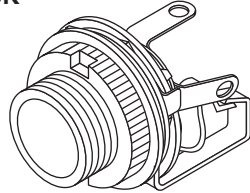


For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Description	Price Each		
		1	10	100
16PJ012	Hex dress nut, washer, N/C switch, chassis mount	1.43	1.10	1.00
16PJ011	Knurled nut, washer, N/C switch, chassis mount	1.43	1.10	1.00

KOBICONN CUSTOM MOLDING PLUGS

- Features:**
- Nickel plated brass contacts
 - Ideal for molding to your cable

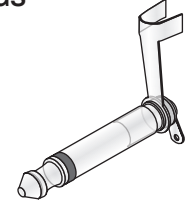

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Description	Price Each			
		1	10	100	500
17PP111	1/4" mono plug, high rel. 2 conductor	2.15	1.65	1.50	1.36
17PP112	1/4" stereo plug, high rel. 3 conductor	2.47	1.90	1.73	1.57