


Tools, Inspection Mirrors, Probes and Hooks

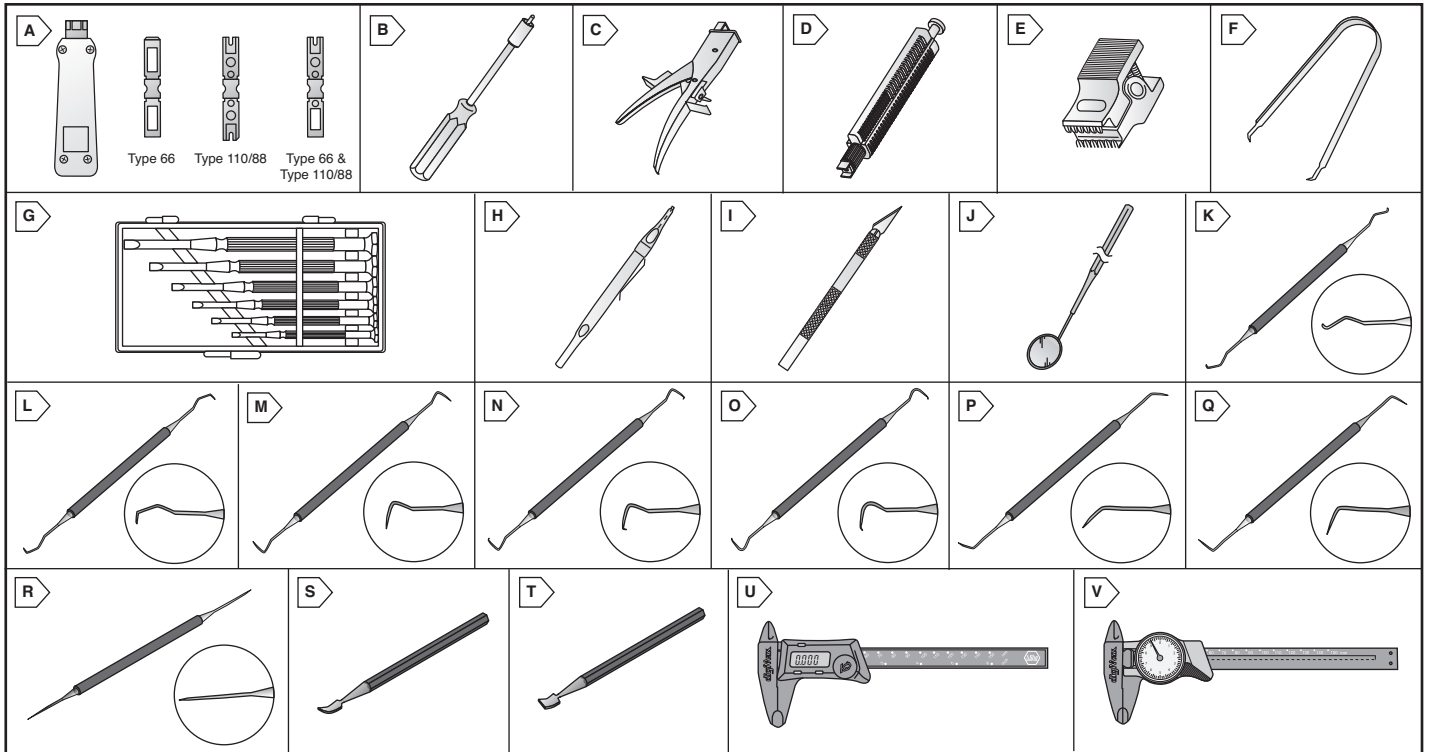

IMPACT AND PUNCH DOWN TOOL/BLADES

MOUSER STOCK NO.	Fig.	Description	Price Each	
			1	5
382-3240	A	Impact and punchdown tool	20.49	18.63
382-0014	A	Blade, type 66	10.20	9.18
382-0014B	A	Blade, type 110/88	10.20	9.18
382-0014C	A	Blade, type 66 and 110/88	10.20	9.18

KNURLED NUT TOOL

For tightening 4mm & 6mm slotted knurled nuts. • Blade Length: 3 inches • Total Length: 5 7/8 inches
 Stock Number: 16PJ100 (2.5mm) and • Accurately mates into knurled nut • Nickel plated finish
 16PJ011/135/137/138 (3.5mm) • Slots which are spaced 180° apart.

MOUSER STOCK NO.	Fig.	Knurled Nut Size (mm)	Price Each	
			1	5
382-0004	B	4	5.94	4.76
382-0006	B	6	7.25	5.80

DELUXE NIBBLING TOOL

For quantities of 6 and up, call for quote.

MOUSER STOCK NO.	GC/Waldom Part No.	Fig.	Description	Price Each	
				1	5
524-1806	12-1806-0000	C	Cuts metal and non-brittle plastic		13.94

ANTI-STATIC IC INSERTION TOOLS

For quantities of 10 and up, call for quote.

524-12-4116	12-4116	D	14 - 16 pin insertion tool	14.57
-------------	---------	---	----------------------------	-------

IC EXTRACTOR TOOLS

For quantities of 10 and up, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each
381C565	E	Spring clip / for use up to 16 pin	3.78
524-9227	F	IC spring steel extractor	3.22

PRECISION SCREWDRIVER SET

381-DK30	G	6 piece slotted set with clear-view plastic case Sizes (mm): .9, 1.2, 1.8, 2.3, 3.0, 3.5	16.95
----------	---	---	-------

TRIMMER POTENTIOMETER ADJUSTMENT TOOL

For quantities of 25 and up, call for quote.

MOUSER STOCK NO.	Spectrol Part No.	Fig.	Description	Price Each
594-8T000	8T000	H	Stainless steel blades, glass filled nylon	1.71

XCELITE KNIFE, BLADES, AND KNIFE SET

For quantities of 12 and up, call for quote.

MOUSER STOCK NO.	Xcelite Part No.	Fig.	Description	Price Each
578-XN100B	XN100B	I	Light duty knife	2.11
578-XNB103	XNB103	-	5 blade pack	2.14
578-XNS100	XNS100	-	Knife set, 10 assorted blades	10.19

INSPECTION MIRRORS

- Clean room quality
 - Magnifying, boilable, detachable
 - For visual checks and fault finding at inaccessible locations.
 - Natural finish, stainless steel
- For quantities of 6 and up, call for quote.

MOUSER STOCK NO.	Wiha Part No.	Fig.	Description	Mirror Size	Price Each	
					1	5
596-40410	40410	J	#0 IM - 185mm	10 mm	41.24	29.90
596-40414	40414	J	#1 IM - 200mm	14 mm	41.24	29.90
596-40420	40420	J	#3 IM - 205mm	20 mm	41.24	29.90
596-40426	40426	J	#6 IM - 215mm	26 mm	41.24	29.90
596-40430	40430	J	#8 IM - 215mm	30 mm	41.24	29.90

PROBES AND HOOKS

- Features for Probes:**
- For levering and removing components
 - For work on PCBs, modeling

- Features for Hooks:**
- Sharp hooks for cutting and marking
 - Surgical stainless steel
 - For work on PCBs
- For quantities of 6 and up, call for quote.

MOUSER STOCK NO.	Wiha Part No.	Fig.	Description	Price Each	
				1	5
Stainless steel, Polished finished Probes					
596-43222	43222	K	3220.2-06 170mm	25.40	24.12
596-43223	43223	L	3220.3-05 170mm	25.40	24.12
596-43224	43224	M	3220.4-16 170mm	25.40	24.12
596-43225	43225	N	3220.5-09 170mm	25.40	24.12
596-43226	43226	O	3220.6-10 170mm	25.40	24.12
596-43227	43227	P	3220.7-17 170mm	25.40	24.12
596-43228	43228	Q	3220.8-02 170mm	25.40	24.12
596-43229	43229	R	3220.9-09 170mm	25.40	24.12
Stainless steel, Natural finished Hooks					
596-43232	43232	S	3230.2-03 155mm	33.42	31.74
596-43236	43236	T	3230.6-60 155mm	33.42	31.74

DIGITAL CALIPER DIGIMAX

Non-metallic high-tech material with 60% fiber glass content. 5 digit digital display with 7.5mm numeral height for easy reading. For outside, inside, depth, and step measurements. Switches on automatically when used and switches off automatically after five minutes of non-use. Zero setting possible in every position for quick comparison measurements.

MOUSER STOCK NO.	Wiha Part No.	Fig.	Resolution	Range	Price Each	
					1	5
596-41101	41101	U	.0005" or .01mm	0-6" or 0-150mm	88.44	76.94

DIAL CALIPER DIALMAX- METRIC & INCH

Non-metallic high-tech material with 60% fiber glass content. For outside, inside, depth, and step measurements. Impact resistant dial can be recalibrated to zero.

Metric						
MOUSER STOCK NO.	Wiha Part No.	Fig.	Resolution	Range	1	5
596-41102	41102	V	.01mm	0-150mm	40.20	34.98
Inch						
596-41104	41104	V	.001"	0-6"	40.20	34.98