


Hardware

STAINLESS STEEL HARDWARE

High quality stainless steel fasteners available for your production needs and conveniently packaged 100 pieces to a bag.

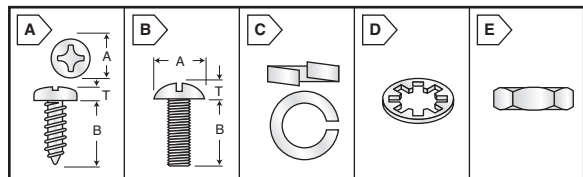

Phillips Pan Head Sheet Metal Screws

* Sold per pkg. of 100 only

MOUSER STOCK NO.	Fig.	Screw Size	Dimensions: in.			Price Per Pkg.			
			A	B	T	1	5	10	25
5721-4-3/8-SS	A	4	0.205	3/8	0.030	5.40	4.75	4.27	3.63
5721-4-1/2-SS	A	4	0.205	1/2	0.030	5.80	4.85	3.90	3.10
5721-4-3/4-SS	A	4	0.205	3/4	0.030	6.60	5.50	4.40	3.60
5721-6-3/8-SS	A	6	0.256	3/8	0.037	6.00	5.25	4.25	3.80
5721-6-1/2-SS	A	6	0.256	1/2	0.037	6.70	5.75	4.80	4.25
5721-6-3/4-SS	A	6	0.256	3/4	0.037	7.40	6.48	5.45	4.95
5721-8-3/8-SS	A	8	0.306	3/8	0.045	7.63	6.86	6.18	5.56
5721-8-1/2-SS	A	8	0.306	1/2	0.045	7.34	6.38	5.42	5.30
5721-8-3/4-SS	A	8	0.306	3/4	0.045	9.50	8.33	7.15	6.95
5721-10-3/8-SS	A	10	0.357	3/8	0.053	11.00	9.90	8.91	8.01
5721-10-1/2-SS	A	10	0.357	1/2	0.053	10.76	9.45	8.13	7.80
5721-10-3/4-SS	A	10	0.357	3/4	0.053	12.60	11.34	10.21	9.19

Round Head Machine Screws

* Sold per pkg. of 100 only

MOUSER STOCK NO.	Fig.	Screw Size	A	B	T	Price Per Pkg.			
						1	5	10	40.05
5721-256-1/4-SS	B	2-56	0.146	1/4	0.037	8.10	6.75	5.40	4.05
5721-256-3/8-SS	B	2-56	0.146	3/8	0.037	6.15	5.51	4.95	4.46
5721-256-1/2-SS	B	2-56	0.146	1/2	0.037	6.24	5.20	4.16	3.12
5721-440-1/4SS	B	4-40	0.193	1/4	0.044	4.80	4.05	3.30	2.80
5721-440-3/8-SS	B	4-40	0.193	3/8	0.044	4.90	4.20	3.45	2.85
5721-440-1/2-SS	B	4-40	0.193	1/2	0.044	5.00	4.25	3.50	3.25
5721-440-3/4-SS	B	4-40	0.193	3/4	0.044	6.97	6.00	5.03	4.75
5721-632-1/4SS	B	6-32	0.210	1/4	0.051	5.40	4.65	3.90	3.65
5721-632-3/8-SS	B	6-32	0.210	3/8	0.051	5.70	5.05	4.40	4.20
5721-632-1/2-SS	B	6-32	0.210	1/2	0.051	5.90	5.25	4.80	4.55
5721-632-3/4-SS	B	6-32	0.210	3/4	0.051	7.78	7.00	6.30	5.99
5721-832-1/4-SS	B	8-32	0.287	1/4	0.058	7.07	6.36	5.72	5.15
5721-832-3/8-SS	B	8-32	0.287	3/8	0.058	7.30	6.43	6.00	5.65
5721-832-1/2-SS	B	8-32	0.287	1/2	0.058	9.09	8.19	7.37	6.63
5721-832-3/4-SS	B	8-32	0.287	3/4	0.058	11.08	9.97	8.97	8.08
5721-1032-1/4-SS	B	10-32	0.334	1/4	0.065	10.86	9.77	8.79	7.92
5721-1032-3/8-SS	B	10-32	0.334	3/8	0.065	10.57	9.55	8.60	7.74
5721-1032-1/2-SS	B	10-32	0.334	1/2	0.065	12.54	11.29	10.16	9.15
5721-1032-3/4-SS	B	10-32	0.334	3/4	0.065	19.26	17.33	15.60	14.04

Lock Washers

* Sold per pkg. of 100 only

MOUSER STOCK NO.	Fig.	Style	Inside Dia.	Outside Dia.	Width	Price Per Pkg.		
						1	5	10
5721-LWS-4-SS	C	Split	0.114	0.209	0.040	2.94	2.45	1.96
5721-LWS-6-SS	C	Split	0.141	0.250	0.047	4.80	4.00	3.20
5721-LWS-8SS	C	Split	0.167	0.293	0.055	3.09	2.58	2.06
5721-LWS-10-SS	C	Split	0.193	0.334	0.062	3.39	2.83	2.26
5721-LWI-4-SS	D	Internal Tooth	0.114	0.255-265	0.040	4.80	4.00	3.20
5721-LWI6SS	D	Internal Tooth	0.141	0.275-285	0.047	4.95	4.13	3.30
5721-LWI-8-SS	D	Internal Tooth	0.167	0.325-336	0.055	5.55	4.63	3.70
5721-LWI-10-SS	D	Internal Tooth	0.193	0.370-381	0.062	5.85	4.88	3.90

Hex Nuts

* Sold per pkg. of 100 only

MOUSER STOCK NO.	Fig.	Flat Width	Corner Width	Thickness	Price Per Pkg.		
					1	5	10
5721-256-SS	E	3/16	0.205	0.057	4.80	4.00	3.20
5721-440-SS	E	1/4	0.275	0.087	4.99	4.23	3.46
5721-632-SS	E	5/16	0.344	0.102	5.18	4.89	4.40
5721-832-SS	E	11/32	0.378	0.117	5.96	5.36	4.83
5721-1032-SS	E	3/8	0.419	0.117	7.07	6.36	5.72

NICKEL

* Nickel-plated steel * Sold per box of 100 only

PLATED FLAT WASHERS

MOUSER STOCK NO.	Size	O.D. (In.)	Price Per Box		
			1	10	50
524-11-142C	4	9/32	3.33	2.98	2.45
524-11-146C	6	3/8	2.59	2.33	2.25
538-MW-403C	8	3/8	3.81	3.43	3.09
538-MW-404C	10	7/16	2.36	2.12	1.91

KEYSTONE PANEL NUTS

* For volume controls, switches, capacitors, tip jacks, etc.
* Material: brass, nickel plated

MOUSER STOCK NO.	Fig.	Type	Thread	Diameter	Thickness (In.)	Price Each	
						1	100
534-1448	A	Mounting	1/4-32	3/8 hex	3/32	.21	.13
534-1449	A	Mini control	1/4-32	5/16 hex	5/64	.16	.11
534-1456	A	Vol. control	3/8-32	1/2 hex	3/32	.25	.15
534-1458	A	Switch	15/32-32	9/16 hex	5/64	.30	.18
534-1459	B	Switch ring	15/32-32	5/8 knurl.	1/16	.49	.30

© Copyright 2009 Mouser Electronics


www.mouser.com



METRIC HARDWARE

Low profile metric nuts for switches, potentiometers, LED'S, plugs, and jacks.

DIMENSIONS: mm

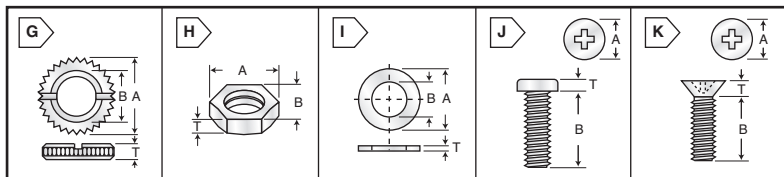

Star Washer

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Size (mm)	Style	Material	Plating	Price Each			
						1	100	1000	10000
481-0685	D	5	Internal tooth	Steel	Zinc	.16	.02	.02	.01
481-0686	D	6	Internal tooth	Steel	Zinc	.24	.03	.02	.02
481-0687	D	7	Internal tooth	Steel	Zinc	.32	.04	.03	.02
481-0688	D	8	Internal tooth	Steel	Zinc	.40	.05	.04	.03
481-0680	D	10	Internal tooth	Steel	Zinc	.56	.056	.05	.04
481-0682	D	12	Internal tooth	Steel	Zinc	.64	.07	.06	.05

Knurled Nuts

Please order in multiples of 100 For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Thread Size (mm)	Material	Plating	Dimensions: mm			Price Each			
					A	B	T	1	100	1000	10000
48KN004-GR	G	M4 x .50	Brass	Nickel	6	4	1.5	1.00	.10	.09	.08
48KN006	G	M6 x .50	Brass	Nickel	8	6	1.5	.70	.22	.20	.18
48KN007-GRX	G	M6 x .50	Brass	Nickel	8	6	2	.70	.16	.15	.13

Hex Nuts

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Thread Size	Material	Plating	A	B	T	Price Each			
								1	100	1000	10000
48AN006	H	M6 x 0.75	Steel	Zinc	9	8	2	.27	.04	.03	.02
48AN007	H	M7 x 0.75	Steel	Zinc	11	10	2	.30	.05	.039	.033
481-0007	H	M7 x 0.75	Steel	Nickel	11	10	2	.30	.03	.028	.025
481-0017F	H	M7 x 0.75	Steel	Zinc	11	10	2	1.00	.11	.099	.09
48AN008	H	M8 x 0.75	Steel	Zinc	12	11	2	.27	.027	.025	.023
48AN009	H	M9 x 0.75	Steel	Zinc	13.5	12	2	.27	.027	.025	.023
481-0009	H	M9 x 0.75	Steel	Nickel	13.5	12	2	.38	.054	.05	.045
481-0095-GR	H	M9.5 x 0.75	Steel	Nickel	15.3	13.4	2.2	.99	.31	.28	.25
481-9575	H	M9.5 x 0.75	Steel	Nickel	14.3	12.5	2.5	.68	.068	.052	.044
481-0010	H	M10 x 0.75	Steel	Zinc	16	14	2	.42	.05	.04	.04
48AN010	H	M10 x 1.00	Steel	Nickel	16	14	2	.42	.064	.06	.058
48AN012	H	M12 x .75	Steel	Nickel	16	14	2	.60	.072	.066	.06

† Special 7M nut. Inside diameter will fit over 1/4" round potentiometer shafts.

* Equivalent to 3/8 x 32 NBF

Flat Washers

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Thread Size (mm)	Material	Plating	Dimensions: mm			Price Each			
					A	B	T	1	100	1000	10000
48CW007	I	M7	Steel	Zinc	12	7	.5	.13	.035	.03	.028
48CW008	I	M8	Steel	Zinc	14	8	.5	.13	.035	.03	.025
48CW009	I	M9	Steel	Zinc	14	9	.5	.13	.035	.03	.025
48CW009.5	I	M9.5	Steel	Zinc	14	10	.5	.15	.017	.013	.012

Pan Head Phillips Screw

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Thread Size	Material	Plating	A	B	T	Price Each			
								1	100	1000	10000
481-S002F	J	M1.7 x 0.35	Steel	Nickel	3	4	1	.25	.033	.03	.027
48SM004	J	M2 x 0.40	Steel	Nickel	3.5	4	1.3	.16	.014	.013	.012
48SM006	J	M2 x 0.40	Steel	Nickel	3.5	4.7	1.3	.16	.014	.013	.012
48SM026	J	M2.6 x 0.45	Steel	Nickel	4	6	1.8	.12	.012	.011	.01
48SM030	J	M3 x 0.50	Steel	Nickel	5	6	2	.12	.012	.011	.01
481-0240	J	M2 x Self T.	Steel	Nickel	4	7.5	1	.36	.04	.03	.03
481-0264	J	M2.6 x 0.45	Steel	Nickel	4	4	1.8	.12	.012	.011	.01
481-0263	J	M3 x 0.50	Steel	Nickel	5	4	1.8	.12	.012	.011	.01
481-2680	J	M2.6 x Self T	Steel	Nickel	4.25	8	1.8	.36	.036	.033	.03

Flat Head Phillips Screw

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Thread Size	Material	Plating	A	B	T	1	100	1000	10000
48SS003	K	M2.5 x 0.45	Steel	Nickel	4	2.5	1.5	.12	.012	.011	.01

* Fits 163-5005 & 163-5006 † Fits 161-2103, 161-2104, 161-2105, 161-2106, 161-2108

SPEAKER MOUNTING CLIP

For panel mounting of speakers. Slotted mounting hole accepts a #4 screw (not included).

DIMENSIONS: in.