 


EAGLE PLASTIC DEVICES Nylon Panel Fasteners




KEY-HOLE CLIPS

The key-hole shaped interior allows the part to collapse more completely for easy assembly with finger pressure, and the tapered, bullet-style point slides into any hole easily. The angled panel lock section takes up slack in panels to provide for a tight assembly. The design allows for a relatively large clip diameter to hole size ratio, resulting in higher retention force. Parts can be tooled for a large variety of hole and panel variations.



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Dimensions: In.			Price Each		
	Head Diameter	Hole Size	Panel Thickness	1	100	1000
561-Y1250125	.250	.125	.125	.10	.08	.06
561-Y1250156	.250	.125	.156	.10	.05	.04
561-Y1250187	.250	.125	.188	.08	.06	.04
561-Y1250219	.250	.125	.219	.10	.05	.04
561-Y1560125	.313	.156	.125	.11	.07	.05
561-Y1870125	.313	.187	.125	.10	.07	.05

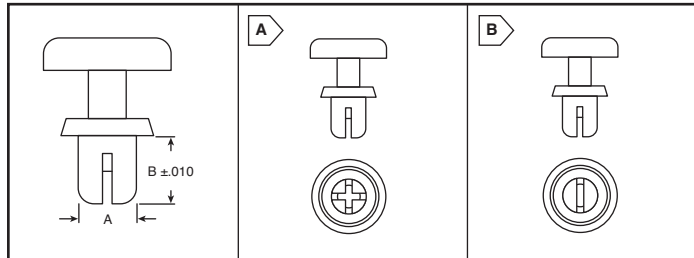

SNAP RIVETS


Nylon Snap Rivets are designed for assemblies requiring fast and economical fasteners that can be installed without tools. The 2 piece molded fastener comes assembled ready for use. The rivet is placed in the hole and the smooth, oversized head is pressed. The specially designed legs expand and firmly lock the components permanently in place. Snap rivets are molded in high dielectric (UL94V2) Nylon 6/6 making them ideal for electronic applications.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Dimensions: In.			Price Each		
		Panel Thickness	A	B	1	100	1000
561-SR12125	A	.035-.080	.100	.125	.12	.10	.10
561-SR12170	A	.078-.118	.102	.170	.21	.18	.11
561-SR12220	A	.125-.156	.102	.200	.14	.12	.10
561-SR0010	A	.050-.100	.118	.140	.11	.08	.06
561-SR13814	A	.047-.083	.135	.140	.21	.18	.11
561-SR13820	A	.106-.142	.135	.200	.21	.18	.11
561-SR13522	A	.118-.157	.135	.220	.21	.18	.11
561-SR13824	A	.146-.181	.135	.240	.21	.18	.11
561-SR13831	A	.217-.256	.135	.310	.21	.18	.11
561-SR15731	A	.148-.188	.157	.315	.14	.12	.10
561-SR15735	A	.256-.295	.157	.350	.21	.18	.11
561-SR240025	A	.062-.125	.240	.250	.13	.11	.10
561-SR16220	B	.134-.169	.100	.220	.21	.18	.11
561-SR12250	B	.142-.198	.100	.250	.21	.18	.11
561-SR18260	B	.157-.197	.118	.260	.21	.18	.11
561-SR18390	B	.295-.335	.118	.390	.21	.18	.11
561-SR0012	B	.122-.160	.122	.220	.09	.07	.05
561-SR0018	B	.100-.140	.160	.200	.09	.07	.04
561-SR0020	B	.144-.188	.166	.240	.14	.09	.07

RATCHETING ACTION RIVETS


Ratcheting action rivets feature a rigid design which provides an outstanding bond created by the action of the interlocking gripper teeth. With the larger head diameter, ratcheting action rivets make binding of soft materials a simple application.

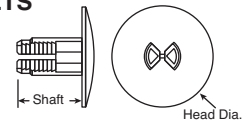

• Molded in black nylon 6/6.


For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Color	Dimensions: In.				Price Each		
		Head Diameter	Shank Length	Hole Size	Grip Range	1	100	1000
561-B3752N	Natural	.375	.219	.250	.235/.297	.10	.05	.04
561-B3753B	Black	.375	.344	.250	.346/.500	.10	.05	.04
561-B3753N	Natural	.375	.344	.250	.346/.500	.10	.05	.04
561-B4002N	Natural	.406	.219	.281	.235/.297	.25	.14	.09
561-B4003N	Natural	.406	.344	.281	.346/.500	.25	.15	.10
561-B6252N	Natural	.625	.219	.250	.235/.297	.10	.08	.06
561-B6253N	Natural	.625	.344	.250	.346/.500	.10	.05	.04
561-B7002N	Natural	.750	.219	.281	.235/.297	.26	.15	.10

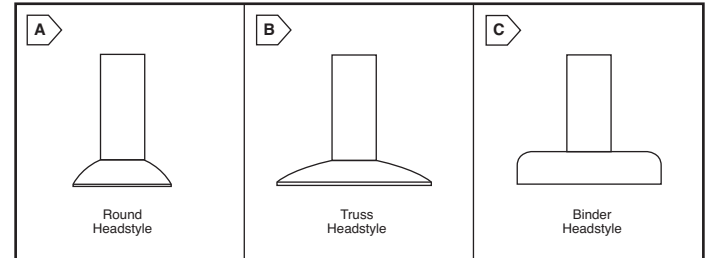

DRIVE RIVETS

 One-piece nylon blind rivets that offer a fast, economical, permanent, hand installed fastener that can be used in a wide variety of materials including sheet metal, plastic sheets, fiberglass, P.C. boards, and composition materials.



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Dimensions: In.			Price Each		
		Hole Size	Head Dia.	Panel Thickness	1	100	1000
561-PR9001	A	.130	.218	.031-.140	.25	.14	.09
561-PR6001	A	.160	.295	.062-.180	.10	.07	.05
561-PR2008	A	.187	.275	.031-.200	.25	.14	.09
561-PR3003	A	.187	.281	.078-.375	.25	.14	.09
561-PR01031	A	.187	.375	.156-.281	.25	.14	.09
561-PR01041	A	.187	.375	.062-.187	.25	.14	.09
561-PR1000	A	.218	.375	.093-.350	.25	.14	.09
561-PR01021	A	.226	.375	.125-.312	.25	.14	.09
561-PR8003	A	.250	.500	.109-.156	.27	.18	.12
561-PR01000	B	.218	.375	.187-.250	.25	.18	.12
561-PR1004	B	.187	.281	.062-.187	.25	.18	.12
561-PR1005	B	.226	.376	.125-.312	.10	.08	.06
561-PR4006	C	.187	.312	.078-.375	.26	.15	.10
561-PR4002	C	.250	.468	.156-.330	.26	.15	.10
561-PR4003	C	.250	.468	.093-.312	.26	.18	.12

Eagle Plastic Devices Hardware

