

ELPAC Medical Power Supplies



65 WATT MEDICAL POWER SUPPLIES

Specifications:

- Input Voltage: 85-264 VAC
- Input Mating Connector: AMP p/n 640250-3
- Output Mating Connector: AMP p/n 640250-6
- Mating Connector Contacts: AMP p/n 770476

Features:


- Wide Range AC Input
- High Efficiency
- LED Indicator
- Meets ECC Class B CISPR 11 Class BEMC per EN60601-1-2
- IEC 60601-1



For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Elpac Part No.	Fig.	DC Output Voltage	Output Current	Power	Dimensions: in.			Price Each			
						L	W	H	1	5	10	25
680-MS6512F	MS6512F	A	12V	5.4A	65W	5.0	2.99	1.15	54.92	50.35	46.47	43.15
680-MS6524F	MS6524F	A	24V	2.7A	65W	5.0	2.99	1.15	54.92	50.35	46.47	43.15

DIMENSIONS: in.

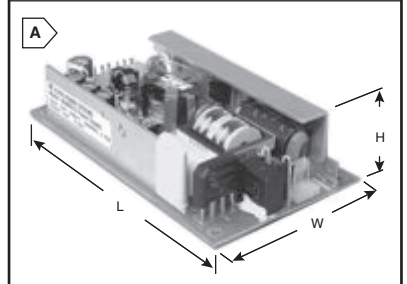

75 WATT MEDICAL POWER SUPPLIES

Specifications:

- Input Voltage: 90-264 VAC
- Input Mating Connector: AMP p/n 640250-5
- Output Mating Connector: AMP p/n 640250-9
- Mating Connector Contacts: AMP p/n 770476-1


Features:

- Wide Range AC Input, Fully Regulated Output
- Efficiency: 80% @ Full Load
- Meets FCC Class B, CISPR 11 Class B
- IEC 60601-1



For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Elpac Part No.	Fig.	DC Output Voltage	Output Current	Power	Dimensions: in.			Price Each			
						L	W	H	1	5	10	25
680-MSM7528	MSM7528	B	28V	2.7A	75W	5.750	3.400	1.663	55.89	52.18	50.65	47.85

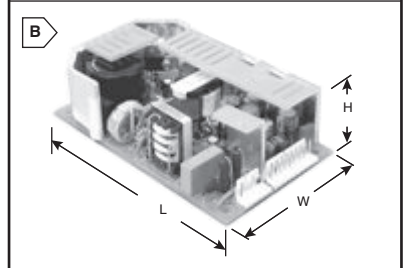

115 WATT MEDICAL POWER SUPPLIES

Specifications:

- Input Voltage: 85-264 VAC
- Input Mating Connector: AMP p/n 640250-5
- Signal Mating Connector: AMP p/n 640621-4
- Output Mating Connector: AMP p/n 640250-8
- Mating Connector Contacts: AMP p/n 770476-1

Features:

- Wide Range AC Input, Fully Regulated Output
- Efficiency: 74% @ Full Load
- Meets FCC Class B, CISPR 11 Class B
- IEC 60601-1



For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Elpac Part No.	Fig.	DC Output Voltage	† Output Current	Power	Dimensions: in.			Price Each			
						L	W	H	1	5	10	25
680-MSMP11512F	MSMP11512F	C	12V	6.7A	115W	5.25	3.30	1.50	115.07	109.25	104.00	100.50
680-MSMP11528F	MSMP11528F	C	28V	2.9A	115W	5.25	3.30	1.50	115.07	109.25	104.00	100.50

