

# BUD Open Racks and Accessories



## BUD OPEN RACKS

**Relay Racks:** There are two colors available, replace the ( ) in the part number with: **MG** for Metallic Gray or **BT** for Black Textured

### Table Top Racks

Chassis-type base holds heavy components for table mounting applications. Supporting angles provide strength, rigidity. Panel mounting rails tapped #10-32 on E.I.A. universal spacing. Standard 19" panel fits flush w/ front. Base is 20.38" x 12". Shipped knocked down.

MOUSER STOCK NO.	Bud Part No.	Height (In.)	Panel Space (In.)	Price Each
563-RR-1248-__	RR-1248__	24.00	21.00	118.47
563-RR-1249-__	RR-1249__	31.00	28.00	129.58

### RR-1263 Series Open Racks


Exceptionally strong structure made up of chassis-type base and supporting angles. Uprights, .11"; steel channels, 3" deep; top plate, 1.13" x 3.13". Rails tapped #10-32 on E.I.A. universal spacing. Base is 19.97" x 22" and drilled for 563-RC-7758 casters. Shipped knocked down in two (2) cartons, with all necessary assembly hardware.

MOUSER STOCK NO.	Bud Part No.	Height (In.)	Panel Space (In.)	Price Each
563-RR-1263-__	RR-1263__	35.63	31.50 x 19	181.88
563-RR-1363-__	RR-1363__	40.88	36.75 x 19	193.57
563-RR-1264-__	RR-1264__	70.63	66.50 x 19	261.70
563-RR-1364-__	RR-1364__	75.63	71.75 x 19	222.91
563-RR-1366-__	RR-1366__	81.13	77.00 x 19	228.29

### RR-1367 Series Open Racks

Extra-sturdy racks made of 14 and 12 gauge steel. 8" deep welded "U" member and triangular bracket hold uprights to base (12 GA). Panel mounting rails tapped #10-32 on E.I.A. universal spacing. Chassis type base, 20.88" x 26", drilled for 563-RC-7758 casters. Racks may be bolted together in Add-A-Rack fashion. Shipped knocked down in two (2) cartons, with all necessary assembly hardware.


MOUSER STOCK NO.	Bud Part No.	Height (In.)	Panel Space (In.)	Price Each
563-RR-1367-__	RR-1367__	64.63	61.25 x 19	397.75
563-RR-1368-__	RR-1368__	73.38	70.00 x 19	423.24
563-RR-1369-__	RR-1369__	80.38	77.00 x 19	437.29

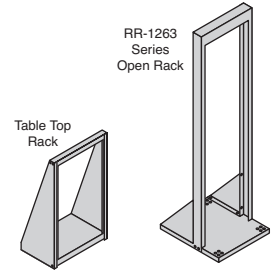

### Aluminum Open Racks - Natural Finish

Wide panel spaces. Panel mounting holes are #12-24 tapped on E.I.A. universal spacing on both the front and rear flanges. Finish: Natural or Black Textured. Shipped knocked down in one (1) carton, with all necessary assembly hardware.

MOUSER STOCK NO.	Bud Part No.	Height (In.)	Panel Space (In.)	Price Each
563-ARR-1272-NF	ARR-1272-NF	84.00	77.00 x 19	200.45
563-ARR-1276-NF	ARR-1276-NF	50.00	42.00 x 19	210.00
563-ARR-1294-NF	ARR-1294-NF	84.00	77.00 x 23	292.85

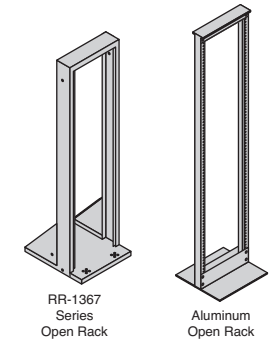

### Aluminum Open Racks - Black Textured

Wide panel spaces. Panel mounting holes are #12-24 tapped on E.I.A. universal spacing on both the front and rear flanges. Finish: Natural or Black Textured. Shipped knocked down in one (1) carton, with all necessary assembly hardware.

MOUSER STOCK NO.	Bud Part No.	Height (In.)	Panel Space (In.)	Price Each
563-ARR-1272-BT	ARR-1272-BT	84.00	77.00 x 19	217.10
563-ARR-1276-BT	ARR-1276-BT	50.00	42.00 x 19	230.00
563-ARR-1294-BT	ARR-1294-BT	84.00	77.00 x 23	350.00

## BUD HEAVY DUTY STEEL RACKS

 
### Design Features:

These heavy duty racks, an extension of the Bud RR-1265 Series, are available in 6', 7', and 9' heights and 19" and 23" wide panel spaces. Panel mounting holes are #12-24 tapped on E.I.A. universal spacing. Panel mounting holes are located on front flanges only.

### Features:

- Base Angles: .25" x 3.50" x 4.87"
- Top Angles: .12" x 2.09" x 1.56"
- Uprights: .18" x 3.00" x 1.28"
- Overall Width 20.37" for 19" rack, 24.37" for 23" rack
- Overall Depth 12.75 base, 3.00" upright, 6.12" top
- Finish: Black Texture (BT)

Racks are shipped knocked down in two (2) cartons, with all necessary assembly hardware included.



MOUSER STOCK NO.	Bud Part No.	Height (In.)	Panel Space (In.)	Price Each
563-RR-1265	RR-1265	72.25	66.50 x 19.00	294.22
563-RR-1269	RR-1269	82.75	77.00 x 19.00	308.96


## BUD OPEN RACK ASSEMBLY

### "Shipped Factory Direct"

### Includes:

- ARR-1272-BT Black aluminum rack with 19" x 77" usable panel space.
- Twelve CM-1196 cableway rings.
- One pair CM-1197 cableway covers.
- Six CM-1220 cable rings.
- All necessary assembly hardware.

Accepts all BUD open rack accessories.

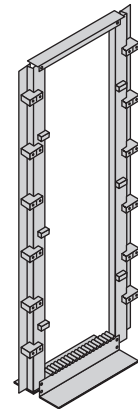

MOUSER STOCK NO.	Bud Part No.	Panel Space (In.)	Dimensions: in.		Price Each
			H	W	
563-DC-8035	DC-8035	19.00	84.00	26.25	529.05

## BUD ACCESSORIES FOR OPEN RACKS

MOUSER STOCK NO.	Bud Part No.	Description	Price Each
563-RC-7758	RC-7758	Casters, Heavy Duty	32.90
563-RC-7761	RC-7761	Casters with Brake	77.50
563-RC-7762	RC-7762	Casters without Brake	67.00
563-POS-194-S	POS-194-S	19" Rear Rack Mount Power Outlet Strip	53.55
563-POS-195-S	POS-195-S	19" Front Rack Mount Power Outlet Strip	57.75
563-SA-1719-GT	SA-1719-GT	16" Gray Shelf Assembly	93.75
563-SA-1719-RB	SA-1719-RB	16" Blue Shelf Assembly	93.75
563-SA-1720-GT	SA1720-GT	20" Gray Shelf Assembly	94.55
563-SA-1720-RB	SA1720-RB	20" Blue Shelf Assembly	94.55
563-SA-1278-BT	SA-1278-BT	16" x 17.62" Adjustable Shelf, Black	101.00
563-SA-1278-MG	SA-1278-MG	16" x 17.62" Adjustable Shelf, Gray	101.00
563-SA-1279-BT	SA-1279-BT	20" x 17.62" Adjustable Shelf, Black	108.90
563-SA-1279-MG	SA-1279-MG	20" x 17.62" Adjustable Shelf, Gray	108.90
563-SA-1378-BT	SA-1378-BT	16" x 21.62" Adjustable Shelf, Black	101.59
563-SA-1378-MG	SA-1378-MG	16" x 21.62" Adjustable Shelf, Gray	87.85
563-SA-1379-BT	SA-1379-BT	20" x 21.62" Adjustable Shelf, Black	96.80
563-SA-1379-MG	SA-1379-MG	20" x 21.62" Adjustable Shelf, Gray	96.80
563-SA-1796-BT	SA-1796-BT	19" Monitor Shelf, Black	101.83

MOUSER STOCK NO.	Bud Part No.	Description	Price Each
563-SA1796-MG	SA-1796-MG	19" Monitor Shelf, Black, Gray	101.83
563-SA-1798-BT	SA-1798-BT	23" Monitor Shelf, Black	108.55
563-SA-1798-MG	SA-1798-MG	23" Monitor Shelf, Gray	108.55
563-SA-1750-BT	SA-1750-BT	15" x 17.62" Equipment Shelf, Black	61.45
563-SA-1750-MG	SA-1750-MG	15" x 17.62" Equipment Shelf, Gray	61.45
563-SA-1752-BT	SA-1752-BT	20" x 17.62" Equipment Shelf, Black	73.50
563-SA-1752-MG	SA-1752-MG	20" x 17.62" Equipment Shelf, Gray	73.50
563-SA-1751-BT	SA-1751-BT	15" x 17.62" Vented Equipment Shelf, Black	67.15
563-SA-1751-MG	SA-1751-MG	15" x 17.62" Vented Equipment Shelf, Gray	67.15
563-SA-1753-BT	SA-1753-BT	20" x 17.62" Vented Equipment Shelf, Black	79.65
563-SA-1753-MG	SA-1753-MG	20" x 17.62" Vented Equipment Shelf, Gray	79.65
563-SA-1775-BT	SA-1775-BT	Stationary Keyboard Mouse Shelf, Black	71.50
563-SA-1775-MG	SA-1775-MG	Stationary Keyboard Mouse Shelf, Gray	71.50
563-KS1785BT	KS-1785-BT	19" Sliding Keyboard Mouse Shelf, Black	165.33
563-KS-1785-MG	KS-1785-MG	19" Sliding Keyboard Mouse Shelf, Gray	165.33
563-KS-1787-BT	KS-1787-BT	23" Sliding Keyboard Mouse Shelf, Black	174.87
563-KS-1787-MG	KS-1787-MG	23" Sliding Keyboard Mouse Shelf, Gray	181.58
563-KS-1788	KS-1788	Sliding Keyboard Shelf, Black	163.30