

Wiring Duct



This product is RoHS compliant.

PANELMAX™ DIN RAIL WIRING DUCT

Panduit® PanelMax™ DIN Rail Wiring Duct is an innovative wire management solution that maximizes space utilization within industrial enclosures, for flexibility in panel layout and reduced material and installation costs. The unique design raises components from the panel surface for easier component access and faster connections.

Features:

- Space saving design - up to 30% smaller footprint
- Increased design flexibility and component access
- DIN rail mounts directly to wiring duct with plastic thread cutting screws.
- Compatible with 35mm or 15mm DIN rail and many DIN rail mount components.

Specifications:


- Material: Lead-free PVC
- Mounting Method - Standard mounting holes
- Dual wiring channels
- Base, covers and DIN rail fasteners included
- Length - 6ft
- Color - Available in Lt. Gray (LG) or White (WH)



RoHS Compliant

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Panduit Part No.	Fig.	Description	External Dimen.: in.		Color	Price Per Each 6' Section		
				Width	Height		1	10	50
644-DRD22LG6	DRD22LG6	A	2" Height	6.25	2.15	Lt. Gray	110.00	101.00	
644-DRD22WH6	DRD22WH6	A	2" Height	6.25	2.15	White	110.00	101.00	
644-DRD33LG6	DRD33LG6	B	3" Height	7.25	3.16	Lt. Gray	165.95	152.50	
644-DRD33WH6	DRD33WH6	B	3" Height	7.25	3.16	White	165.95	152.50	
644-DRD44LG6	DRD44LG6	C	4" Height	8.25	4.16	Lt. Gray	216.50	200.00	
644-DRD44WH6	DRD44WH6	C	4" Height	8.25	4.16	White	216.50	200.00	

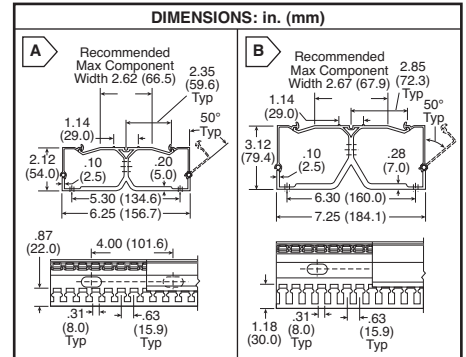

PANELMAX™ DIN RAIL WIRING DUCT ACCESSORIES

Replacement Covers

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Panduit Part No.	Fig.	Description	Color	Price Per Each 6' Section		
					1	10	20
644-DRDC2LG6	DRDC2LG6	D	2" Replacement Cover	Lt. Gray	12.50	11.53	10.64
644-DRDC2WH6	DRDC2WH6	D	2" Replacement Cover	White	12.50	11.53	10.64
644-DRDC3LG6	DRDC3LG6	D	3" Replacement Cover	Lt. Gray	19.10	17.54	16.19
644-DRDC3WH6	DRDC3WH6	D	3" Replacement Cover	White	19.10	17.54	16.19
644-DRDC4LG6	DRDC4LG6	D	4" Replacement Cover	Lt. Gray	23.10	21.22	19.58
644-DRDC4WH6	DRDC4WH6	D	4" Replacement Cover	White	23.10	21.22	19.58

Corner Strips

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Panduit Part No.	Fig.	Description	Color	Price Each		
					1	10	50
644-DRDCS2-X	DRDCS2-X	E	2" Corner Strip	Lt. Gray	4.02	3.68	3.45
644-DRDCS3-X	DRDCS3-X	E	3" Corner Strip	Lt. Gray	5.20	4.33	4.10
644-DRDCS4-X	DRDCS4-X	E	4" Corner Strip	Lt. Gray	5.56	5.10	4.90

Wire Retainers

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Panduit Part No.	Fig.	Description	Color	1	3.00	2.85
644-DRDWR2-X	DRDWR2-X	F	2" Wire Retainer	Black	3.16	3.00	2.85
644-DRDWR3-X	DRDWR3-X	F	3" Wire Retainer	Black	3.72	3.53	3.36
644-DRDWR4-X	DRDWR4-X	F	4" Wire Retainer	Black	4.38	4.16	3.95

Replacement DIN Rail Fasteners




For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Panduit Part No.	Fig.	Description	Price Each		
				1	100	500
644-DRDSF-C	DRDSF-C	G	Replacement DIN Rail Fasteners	.12	.10	.092

Notching Tool

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Panduit Part No.	Fig.	Description	Price Each	
				1	5
644-DNT-100	DNT-100	H	Notching tool for wiring duct	124.66	119.00

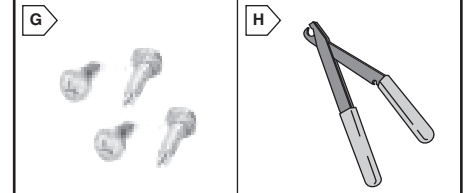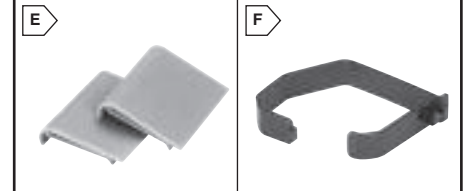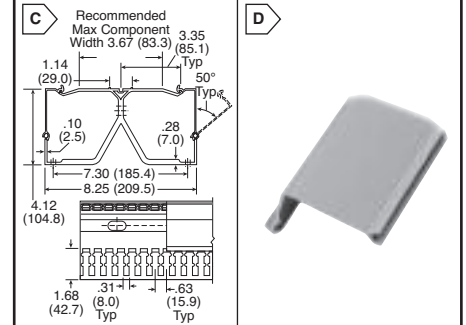

EAGLE PLASTIC DEVICES DIN RAIL CLIP

Attaches to standard Din #2 and #3 rails. Used to route wire and cables on equipment which uses Din Rails. The part snaps onto the din rail and is easily removable to allow reconfiguration of the wiring.



RoHS Compliant

- Material: Nylon 6/6
- Flammability Rating: UL94V2

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Dimensions: in.		Clip Width	Price Each		
	Length	Width		1	100	500
561-23001	3.35	0.625	0.312	.89	.82	.76

