

# WIREMOLD Surface Raceway Systems

**WIREMOLD**

legrand

## 2800/2900 SERIES UNIDUCT® NON-METALLIC RACEWAY

### Features:

- One-piece design
- Easy open and snap-close latch
- Durable, flexible hinge constriction
- Durable impact-resistant PVC
- Adhesive backing for quick installation
- Color: Ivory (field paintable)

### Uniduct® Latching Raceway

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Wiremold Part No.	Fig.	Description	Price Each			
				1	5	10	25
681-2800	2800	A	1/2" x 1" raceway, 6 foot length	10.20	9.42	9.00	8.74
681-2900	2900	B	3/4" x 1 1/2" raceway, 6 foot length	12.75	11.81	11.44	10.75
681-2900L8	2900L8	B	3/4" x 1 1/2" raceway, 8 foot length	17.06	15.75	15.28	14.62

### 2800 Series Raceway Fittings

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Wiremold Part No.	Description	Price Each			
			1	5	10	25
681-2806	2806	Cover clip	1.72	1.65	1.59	1.54
681-2810B	2810B	Blank end fitting	1.72	1.65	1.59	1.54
681-2811	2811	90° flat elbow	1.72	1.65	1.59	1.51
681-2815	2815	Tee	1.72	1.64	1.59	1.55
681-2817	2817	Internal elbow	1.72	1.64	1.55	1.46
681-2818	2818	External elbow	1.72	1.69	1.54	1.34
681-2886	2886	Drop ceiling connector	2.01	1.94	1.85	1.79

### 2900 Series Raceway Fittings

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Wiremold Part No.	Description	Price Each			
			1	5	10	25
681-2906	2906	Cover clip	1.89	1.83	1.75	1.68
681-2910B	2910B	Blank end fitting	1.82	1.76	1.69	1.54
681-2911	2911	90° flat elbow	1.82	1.76	1.69	1.61
681-2915	2915	Tee	1.82	1.76	1.69	1.61
681-2917	2917	Internal elbow	1.81	1.75	1.69	1.61
681-2918	2918	External elbow	1.82	1.76	1.67	1.59
681-2986	2986	Drop ceiling connector	2.01	1.95	1.89	1.81

### Device Boxes for 2800 and 2900

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Wiremold Part No.	Fig.	Description	Price Each			
				1	5	10	25
681-NM2048	NM2048	C	Deep device box	4.76	4.51	4.11	3.97
681-NM2044	NM2044	D	Extra deep device box	9.33	8.90	8.51	8.15
681-NM2048-2	NM2048-2	E	Two-gang deep device box	7.71	7.35	7.02	6.73
681-NM2044-2	NM2044-2	F	Two-gang extra deep device box	12.16	11.60	11.09	10.63
681-CM-MMB-291	CM-MMB-291	G	One insert multimedia box	4.42	4.09	3.76	3.43
681-CM-MMB-292	CM-MMB-292	H	Two insert multimedia box	5.93	5.65	5.24	4.94

## V500 SERIES ONE-PIECE SURFACE STEEL RACEWAY

### Features:

- Low-profile, unobtrusive appearance
- Ivory ScuffCoat finish
- Surface mounting
- Fittings have removable covers
- UL5 and ADA compliant

### One-Piece Raceway

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Wiremold Part No.	Fig.	Description	Price Each			
				1	5	10	25
681-V500-5	V500-5	I	3/4" x 1 7/32" raceway, 5 foot length	6.92	6.59	6.10	5.76

### Steel Raceway Fittings


For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Wiremold Part No.	Description	Price Each			
			1	5	10	25
681-V511	V511	90° flat elbow	1.90	1.86	1.80	1.76
681-V512	V512	45° flat elbow	4.92	4.68	4.34	4.10
681-V517	V517	Internal elbow	2.00	1.90	1.76	1.67
681-V518	V518	External elbow	1.85	1.76	1.63	1.54
681-V5715	V5715	Tee	3.85	3.67	3.40	3.21
681-V504	V504	Mounting strap	.30	.29	.26	.25
681-V506	V506	Connection cover	.42	.40	.37	.35

### Device Boxes

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Wiremold Part No.	Fig.	Description	Price Each			
				1	5	10	25
681-V5748	V5748	J	Device box	6.95	6.62	6.13	5.79
681-V5744	V5744	K	Extra deep device box	15.96	14.57	14.03	13.68
681-V5744S	V5744S	L	Deep switch and receptacle box	15.58	14.84	13.75	12.99

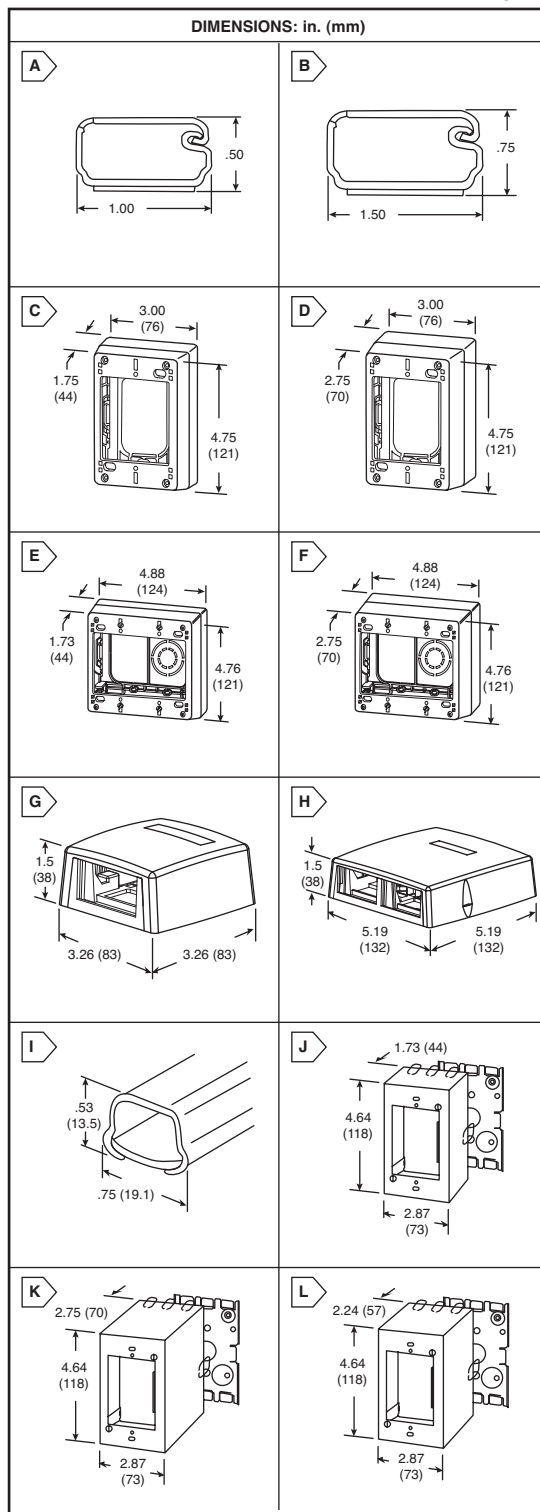

## PLUGMOLD™ STEEL PREWIRED MULTI OUTLET ASSEMBLIES

### Features:

- Ivory ScuffCoat finish
- Compact, low profile appearance
- Choose receptacle spacing
- 15A outlets
- Additional assemblies available - contact a Mouser Service Representative

For quantities of 50 and up, call for quote.

MOUSER STOCK NO.	Wiremold Part No.	Length	Number of Outlets	Outlet Center Distance	Price Each			
					1	5	10	25
681-V20GB512	V20GB512	5 foot	5	6 inch	40.26	39.85	36.01	35.75
681-V20GB506	V20GB506	5 foot	10	6 inch	66.45	64.35	63.97	59.99
681-V20GB618	V20GB618	6 foot	4	18 inch	39.84	38.56	37.26	35.19
681-V20GB612	V20GB612	6 foot	6	12 inch	59.97	57.23	52.36	48.99
681-V20GB606	V20GB606	6 foot	12	6 inch	79.89	76.66	71.99	65.23

