

CRYDOM Heatsinks and Assemblies

crydom

RoHS Compliant This product is RoHS compliant.



RoHS Compliant


CRYDOM H SERIES: HEATSINKS

Features:

- Suitable for 1 single or dual SSR
- Din Rail mounting
- Panel mounting
- 3 to 32 VDC input control voltage

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Ther Res	Dimensions: in.			Price Each		
Mfr.	Mfr. Part No.			W	L	H	1	10	25
558—HS351		A	3.5° C/W	1.78	3.2	1.78	8.33	7.94	7.58
558—HS301		B	3.0° C/W	1.78	3.2	1.58	15.83	15.09	14.40
558—HS271		C	2.7° C/W	1.78	3.2	2.96	10.00	9.53	9.09
558—HS251		D	2.5° C/W	2.31	1.98	1.51	10.00	9.53	9.09
558—HS202		E	2.0° C/W	3.55	3.2	1.58	23.33	22.24	21.21
558—HS201		F	2.0° C/W	1.78	3.2	3.15	22.50	21.44	20.46
558—HS172		G	1.7° C/W	2.31	3.95	1.51	15.83	15.09	14.40
558—HS151		H	1.5° C/W	1.78	3.2	3.74	24.17	23.03	21.97
558—HS122		I	1.2° C/W	3.54	3.2	3.15	30.00	28.59	27.27
558—HS103		J	1.0° C/W	5.2	3	2.37	53.33	50.83	48.49
558—HS072		K	0.7° C/W	4.75	5.5	2.63	31.67	30.18	28.79
558—HS053		L	0.5° C/W	6	6	3.5	31.67	30.18	28.79
558—HS501DR		M	5.0° C/W	1.75	3.15	0.6	11.67	11.12	10.61
558—HS351DR		N	3.5° C/W	1.78	3.2	1.78	13.33	12.71	12.12
558—HS301DR		O	3.0° C/W	1.78	3.2	1.58	20.83	19.85	18.94
558—HS271DR		C	2.7° C/W	1.78	3.2	2.96	15.00	14.30	13.64
558—HS202DR		P	2.0° C/W	3.55	3.2	1.58	31.67	30.18	28.79
558—HS201DR		F	2.0° C/W	1.78	3.2	3.15	27.50	26.21	25.00
558—HS151DR		H	1.5° C/W	1.78	3.2	3.74	29.17	27.80	26.52
558—HS122DR		I	1.2° C/W	3.54	3.2	3.15	38.33	36.53	34.85
558—HS103DR		J	1.0° C/W	5.2	3	2.37	65.00	61.95	59.10

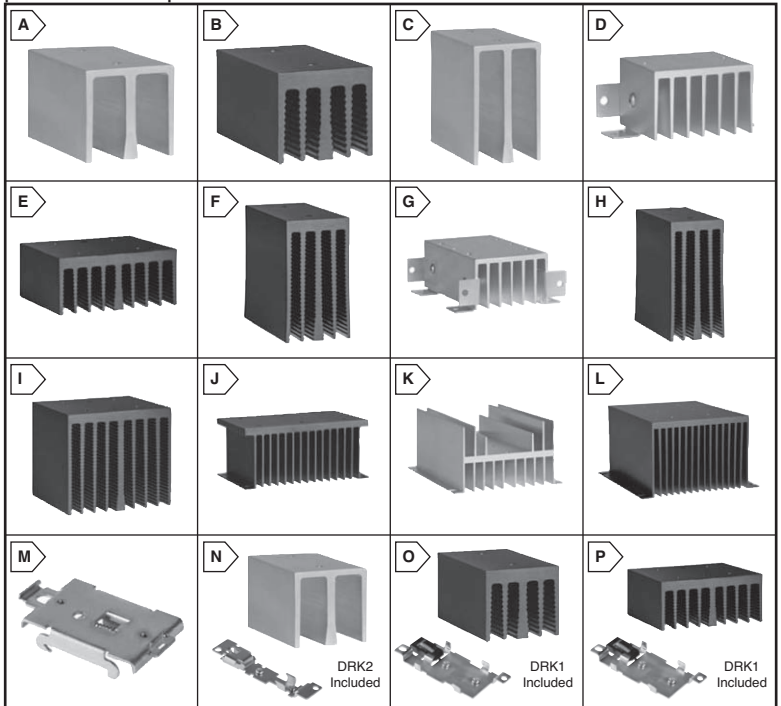


CRYDOM H SERIES: ASSEMBLIES



RoHS Compliant

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Operating Volt (Vrms)	Control Volt Rg (VDC)	Price Each		
Mfr.	Mfr. Part No.				1	10	25
558—HS501DR-D2425	Q	Q	24-280	3-32	50.66	48.27	46.05
558—HS501DR-HD6025	Q	Q	48-660	3-32	62.98	60.02	57.25
558—HS351DR-D2425	R	R	24-280	3-32	52.49	50.02	47.72
558—HS351DR-HD6025	R	R	48-660	3-32	71.16	67.27	62.22
558—HS301DR-D2425	S	S	24-280	3-32	60.74	57.88	55.22
558—HS301DR-HD6025	S	S	48-660	3-32	73.06	69.62	66.42
558—HS271DR-D2425	T	T	24-280	3-32	54.32	51.77	49.39
558—HS271DR-HD6025	T	T	48-660	3-32	66.64	63.51	60.59
558—HS251-D2450	U	U	24-280	3-32	57.93	55.21	52.67
558—HS251-HD6050	U	U	48-660	3-32	70.02	66.72	63.65
558—HS202DR-D2450	V	V	24-280	3-32	79.02	75.30	71.84
558—HS202DR-HD6050	V	V	48-660	3-32	91.10	86.82	82.82
558—HS201DR-D2450	W	W	24-280	3-32	74.43	70.93	67.67
558—HS201DR-HD6050	W	W	48-660	3-32	86.52	82.45	78.66
558—HS201DRCC2425W3U	W	W	24-280	3-32	110.92	105.00	100.84
558—HS172-D2450	X	X	24-280	3-32	61.60	58.70	56.00
558—HS172-HD6050	X	X	48-660	3-32	73.68	70.22	66.99
558—HS151DR-D2450	Y	Y	24-280	3-32	76.27	72.68	69.34
558—HS151DR-HD6050	Y	Y	48-660	3-32	88.35	84.20	80.32
558—HS151DRCC2425W3U	Y	Y	24-280	4-32	116.08	110.63	105.54
558—HS122DR-D2450	Z	Z	24-280	3-32	86.35	82.29	78.51
558—HS122DR-HD6050	Z	Z	48-660	3-32	98.43	93.81	89.49
558—HS122DRCC2450W3U	Z	Z	24-280	4-32	135.67	129.28	123.34
558—HS103DR-D2490	AA	AA	24-280	3-32	149.20	142.18	135.64
558—HS103DR-HD6090	AA	AA	48-660	3-32	162.64	154.99	147.86
558—HS103-D53TP25D	AA	AA	48-530	3-32	223.10	212.61	202.83
558—HS072-D2490	BB	BB	24-280	3-32	112.53	107.24	102.31
558—HS072-HD6090	BB	BB	48-660	3-32	125.97	120.15	114.53
558—HS053-D24125	CC	CC	24-280	3-32	184.71	176.03	167.93
558—HS053-HD60125	CC	CC	48-660	3-32	199.12	189.76	181.03
558—HS053-D53TP50D	CC	CC	48-530	3-32	261.23	248.95	237.50

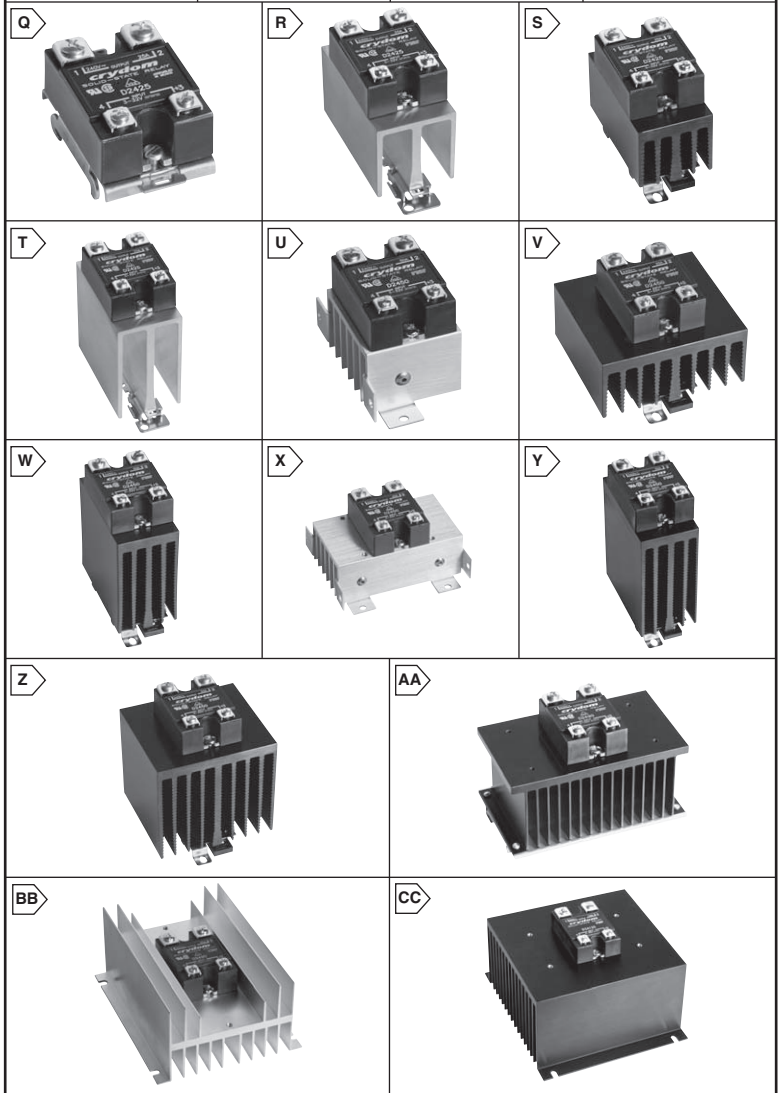

CRYDOM H SERIES: ACCESSORIES



RoHS Compliant

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Description	Price Each		
Mfr.	Mfr. Part No.		1	10	25
558—DRK1		Din Bracket Kit (45mm)	7.50	7.15	6.82
558—DRK2		Din Bracket Kit (22.5mm)	5.50	4.81	4.40
558—HK1		2 SSR Mounting Hardware Kit 8-32x3/8	.50	.48	.45
558—HK2		1 ground screw 10-32x 3/8 and 2 bracket, screws 6-32x1/4	.83	.79	.76
558—TRM6		Copper Lug Terminal	2.20	2.08	1.92

NEW FROM CRYDOM

NEW FROM CRYDOM

NEW FROM CRYDOM

Crydom

Heat Sinks

NEW FROM CRYDOM

NEW FROM CRYDOM

NEW FROM CRYDOM

NEW FROM CRYDOM

NEW FROM CRYDOM