


FAIRCHILD Zener Diodes

Products may be RoHS compliant.
Check mouser.com for RoHS status.

FAIRCHILD
SEMICONDUCTOR

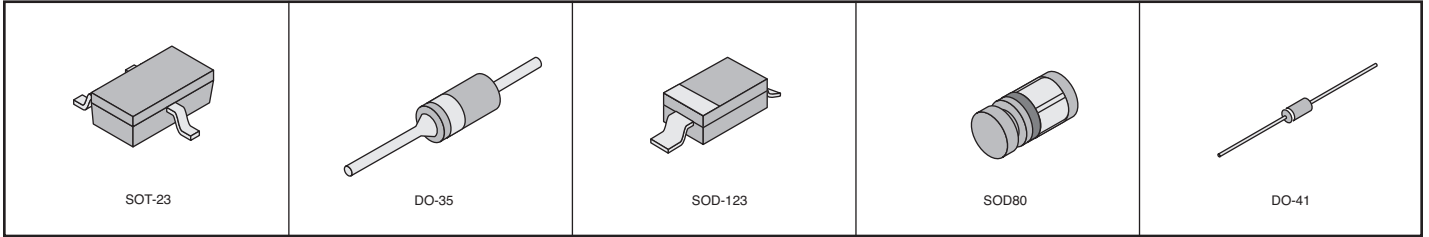

◆ Surface Mount Device

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.		Package	PD (W)	VZ (V)	Price Each	
Mfr.	Mfr. Part Number				1	25
◆	512—MMBZ5223B	SOT-23	.35	2.7	.05	.047
◆	512—BZX84C3V3	SOT-23	.35	3.3	.08	.06
◆	512—MMBZ5226B	SOT-23	.35	3.3	.06	.05
◆	512—BZX84C3V6	SOT-23	.35	3.6	.05	.047
◆	512—MMBZ5227B	SOT-23	.35	3.6	.05	.047
◆	512—BZX84C4V3	SOT-23	.35	4.3	.05	.047
◆	512—MMBZ5229B	SOT-23	.35	4.3	.06	.05
◆	512—BZX84C4V7	SOT-23	.35	4.7	.07	.038
◆	512—MMBZ5230B	SOT-23	.35	4.7	.06	.05
◆	512—BZX84C5V1	SOT-23	.35	5.1	.07	.038
◆	512—MMBZ5231B	SOT-23	.35	5.1	.06	.05
◆	512—MMBZ5235B	SOT-23	.35	5.6	.07	.038
◆	512—MMBZ5232B	SOT-23	.35	5.6	.08	.05
◆	512—MMBZ5233B	SOT-23	.35	6	.06	.05
◆	512—BZX84C6V2	SOT-23	.35	6.2	.07	.038
◆	512—MMBZ5234B	SOT-23	.35	6.2	.06	.05
◆	512—BZX84C6V8	SOT-23	.35	6.8	.10	.07
◆	512—MMBZ5235B	SOT-23	.35	6.8	.06	.057
◆	512—BZX84C7V5	SOT-23	.35	7.5	.06	.057
◆	512—MMBZ5236B	SOT-23	.35	7.5	.06	.057
◆	512—BZX84C8V2	SOT-23	.35	8.2	.06	.057
◆	512—MMBZ5237B	SOT-23	.35	8.2	.06	.057
◆	512—BZX84C9V1	SOT-23	.35	9.1	.09	.066
◆	512—MMBZ5239B	SOT-23	.35	9.1	.06	.057
◆	512—BZX84C10	SOT-23	.35	10	.06	.057
◆	512—MMBZ5240B	SOT-23	.35	10	.06	.057
◆	512—BZX84C11	SOT-23	.35	11	.09	.066
◆	512—MMBZ5241B	SOT-23	.35	11	.06	.057
◆	512—BZX84C12	SOT-23	.35	12	.09	.066
◆	512—MMBZ5242B	SOT-23	.35	12	.09	.066
◆	512—BZX84C13	SOT-23	.35	13	.06	.057
◆	512—MMBZ5243B	SOT-23	.35	13	.06	.057
◆	512—MMBZ5244B	SOT-23	.35	14	.06	.057
◆	512—BZX84C15	SOT-23	.35	15	.09	.066
◆	512—MMBZ5245B	SOT-23	.35	15	.06	.057
◆	512—BZX84C16	SOT-23	.35	16	.06	.057
◆	512—MMBZ5246B	SOT-23	.35	16	.06	.057
◆	512—MMBZ5247B	SOT-23	.35	17	.06	.057
◆	512—BZX84C18	SOT-23	.35	18	.06	.057
◆	512—MMBZ5248B	SOT-23	.35	18	.06	.057
◆	512—BZX84C20	SOT-23	.35	20	.09	.066
◆	512—MMBZ5250B	SOT-23	.35	20	.06	.057
◆	512—BZX84C22	SOT-23	.35	22	.06	.057
◆	512—MMBZ5251B	SOT-23	.35	22	.06	.057
◆	512—BZX84C24	SOT-23	.35	24	.06	.057
◆	512—MMBZ5252B	SOT-23	.35	24	.06	.057
◆	512—MMBZ5254B	SOT-23	.35	27	.06	.057
◆	512—MMBZ5255B	SOT-23	.35	28	.06	.057
◆	512—BZX84C30	SOT-23	.35	30	.08	.066
◆	512—BZX84C33	SOT-23	.35	33	.06	.057
◆	512—MMBZ5257B	SOT-23	.35	33	.06	.057
◆	512—1N4370A	DO-35	.50	2.4	.04	.038
◆	512—1N5221B	DO-35	.50	2.4	.06	.047
◆	512—1N5221BT50R	DO-35	.50	2.4	.07	.04
◆	512—1N5985B	DO-35	.50	2.4	.04	.038
◆	512—BZX55C2V4	DO-35	.50	2.4	.04	.038
◆	512—1N5222B	DO-35	.50	2.5	.06	.047
◆	512—1N4371A	DO-35	.50	2.7	.04	.038
◆	512—1N5223B	DO-35	.50	2.7	.06	.047
◆	512—1N5986B	DO-35	.50	2.7	.04	.038
◆	512—BZX55C2V7	DO-35	.50	2.7	.04	.038
◆	512—BZX79C2V7	DO-35	.50	2.7	.04	.038
◆	512—1N5224B	DO-35	.50	2.8	.04	.028
◆	512—1N4372A	DO-35	.50	3	.04	.038
◆	512—1N5225B	DO-35	.50	3	.06	.047
◆	512—1N5987B	DO-35	.50	3	.04	.038
◆	512—BZX55C3V0	DO-35	.50	3	.04	.038
◆	512—1N5226B	DO-35	.50	3.3	.06	.047
◆	512—1N746A	DO-35	.50	3.3	.04	.028

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.		Package	PD (W)	VZ (V)	Price Each	
Mfr.	Mfr. Part Number				1	25
◆	512—BZX55C3V3	DO-35	.50	3.3	.04	.038
◆	512—BZX79C3V3	DO-35	.50	3.3	.04	.038
◆	512—MMSZ468A	SOD-123	.50	3.3	.06	.05
◆	512—MMSZ5226B	SOD-123	.50	3.3	.06	.05
◆	512—1N5227B	DO-35	.50	3.6	.06	.047
◆	512—1N5227BTR	DO-35	.50	3.6	.04	.036
◆	512—1N747A	DO-35	.50	3.6	.04	.028
◆	512—BZX55C3V6	DO-35	.50	3.6	.04	.038
◆	512—MMSZ5227B	SOD-123	.50	3.6	.06	.05
◆	512—1N5228B	DO-35	.50	3.9	.06	.047
◆	512—1N748A	DO-35	.50	3.9	.04	.028
◆	512—BZX55C3V9	DO-35	.50	3.9	.04	.038
◆	512—BZX79C3V9	DO-35	.50	3.9	.02	.016
◆	512—MMSZ4686	SOD-123	.50	3.9	.06	.05
◆	512—MMSZ5228B	SOD-123	.50	3.9	.06	.05
◆	512—1N5229B	DO-35	.50	4.3	.04	.028
◆	512—1N5229B_T50A	DO-35	.50	4.3	.04	.028
◆	512—1N5229BTR	DO-35	.50	4.3	.06	.038
◆	512—1N5991B	DO-35	.50	4.3	.04	.038
◆	512—1N749A	DO-35	.50	4.3	.04	.028
◆	512—MMSZ5229B	SOD-123	.50	4.3	.06	.05
◆	512—1N5230B	DO-35	.50	4.7	.06	.047
◆	512—1N5230BTR	DO-35	.50	4.7	.07	.04
◆	512—1N5230B_T26A	DO-35	.50	4.7	.04	.028
◆	512—1N750A	DO-35	.50	4.7	.04	.028
◆	512—BZX55C4V7	DO-35	.50	4.7	.04	.038
◆	512—BZX79C4V7	DO-35	.50	4.7	.04	.038
◆	512—MMSZ4688	SOD-123	.50	4.7	.06	.05
◆	512—MMSZ5230B	SOD-123	.50	4.7	.06	.05
◆	512—1N5248BTR	DO-35	.50	4.8	.07	.05
◆	512—1N5231B	DO-35	.50	5.1	.06	.047
◆	512—1N5243B	DO-35	.50	5.1	.07	.04
◆	512—1N5993B	DO-35	.50	5.1	.04	.038
◆	512—1N751A	DO-35	.50	5.1	.06	.047
◆	512—1N751ATR	DO-35	.50	5.1	.07	.04
◆	512—BZX55C5V1	DO-35	.50	5.1	.04	.038
◆	512—1N5230B	DO-35	.50	5.1	.06	.047
◆	512—MMSZ4689	SOD-123	.50	5.1	.06	.05
◆	512—MMSZ5231B	SOD-123	.50	5.1	.06	.05
◆	512—FLZ5V1B	SOD-80	.50	5.1	.08	.06
◆	512—1N5231C	DO-35	.50	5.2	.06	.047
◆	512—1N5232B	DO-35	.50	5.6	.06	.047
◆	512—1N5232BTR	DO-35	.50	5.6	.07	.04
◆	512—1N752A	DO-35	.50	5.6	.06	.047
◆	512—BZX55C5V6	DO-35	.50	5.6	.05	.047
◆	512—BZX79C5V6	DO-35	.50	5.6	.04	.038
◆	512—MMSZ5232B	SOD-123	.50	5.6	.06	.05
◆	512—FLZ5V6B	SOD-80	.50	5.6	.08	.06
◆	512—1N5233B	DO-35	.50	6	.04	.028
◆	512—MMSZ5233B	SOD-123	.50	6	.06	.05
◆	512—1N5234B	DO-35	.50	6.2	.06	.047
◆	512—1N5234BTR	DO-35	.50	6.2	.04	.036
◆	512—1N5995B	DO-35	.50	6.2	.04	.038
◆	512—1N753A	DO-35	.50	6.2	.06	.047
◆	512—1N753ATR	DO-35	.50	6.2	.07	.05
◆	512—BZX79C6V2	DO-35	.50	6.2	.04	.038
◆	512—MMSZ5234B	SOD-123	.50	6.2	.06	.05
◆	512—1N5235B	DO-35	.50	6.8	.06	.047
◆	512—1N5235BTR	DO-35	.50	6.8	.07	.04
◆	512—1N754A	DO-35	.50	6.8	.04	.028
◆	512—BZX79C6V8	DO-35	.50	6.8	.02	.016
◆	512—MMSZ5235B	SOD-123	.50	6.8	.06	.057
◆	512—FLZ6V8B	SOD-80	.50	6.8	.08	.06
◆	512—1N5235B	DO-35	.50	7.5	.04	.028
◆	512—1N755A	DO-35	.50	7.5	.04	.028
◆	512—BZX55C7V5	DO-35	.50	7.5	.02	.016
◆	512—BZX79C7V5	DO-35	.50	7.5	.04	.038
◆	512—MMSZ5236B	SOD-123	.50	7.5	.06	.057
◆	512—1N5237B	DO-35	.50	8.2	.04	.028

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.		Package	PD (W)	VZ (V)	Price Each	
Mfr.	Mfr. Part Number				1	25
◆	512—1N5998B	DO-35	.50	8.2	.04	.038
◆	512—1N756A	DO-35	.50	8.2	.04	.028
◆	512—BZX79C8V2	DO-35	.50	8.2	.04	.038
◆	512—MMSZ5237B	SOD-123	.50	8.2	.06	.057
◆	512—1N5238B	DO-35	.50	8.7	.04	.028
◆	512—1N5238BTR	DO-35	.50	8.7	.04	.036
◆	512—MMSZ5238B	SOD-123	.50	8.7	.06	.057
◆	512—1N5239B	DO-35	.50	9.1	.06	.047
◆	512—1N757A	DO-35	.50	9.1	.04	.028
◆	512—BZX55C9V1	DO-35	.50	9.1	.04	.038
◆	512—MMSZ5239B	SOD-123	.50	9.1	.06	.057
◆	512—1N5240B	DO-35	.50	10	.06	.047
◆	512—1N5240BTR	DO-35	.50	10	.07	.04
◆	512—1N5240BT50R	DO-35	.50	10	.04	.036
◆	512—1N758A	DO-35	.50	10	.04	.028
◆	512—BZX55C10	DO-35	.50	10	.04	.038
◆	512—MMSZ5240B	SOD-123	.50	10	.12	.076
◆	512—1N5241B	DO-35	.50	11	.04	.028
◆	512—1N5241BTR	DO-35	.50	11	.04	.036
◆	512—BZX79C11	DO-35	.50	11	.04	.038
◆	512—MMSZ5241B	SOD-123	.50	11	.06	.057
◆	512—1N5242B	DO-35	.50	12	.06	.047
◆	512—1N5242BTR	DO-35	.50	12	.07	.04
◆	512—1N759A	DO-35	.50	12	.04	.028
◆	512—BZX55C12	DO-35	.50	12	.06	.047
◆	512—BZX79C12	DO-35	.50	12	.04	.038
◆	512—MMSZ5242B	SOD-123	.50	12	.12	.076
◆	512—1N5243B	DO-35	.50	13	.06	.047
◆	512—BZX55C13	DO-35	.50	13	.04	.038
◆	512—MMSZ5243B	SOD-123	.50	13	.06	.057
◆	512—1N5244B	DO-35	.50	14	.06	.047
◆	512—1N5245B	DO-35	.50	15	.06	.047
◆	512—BZX55C15	DO-35	.50	15	.04	.038
◆	512—BZX79C15	DO-35	.50	15	.04	.038
◆	512—MMSZ470					