


COOPER / BUSSMANN Fuses

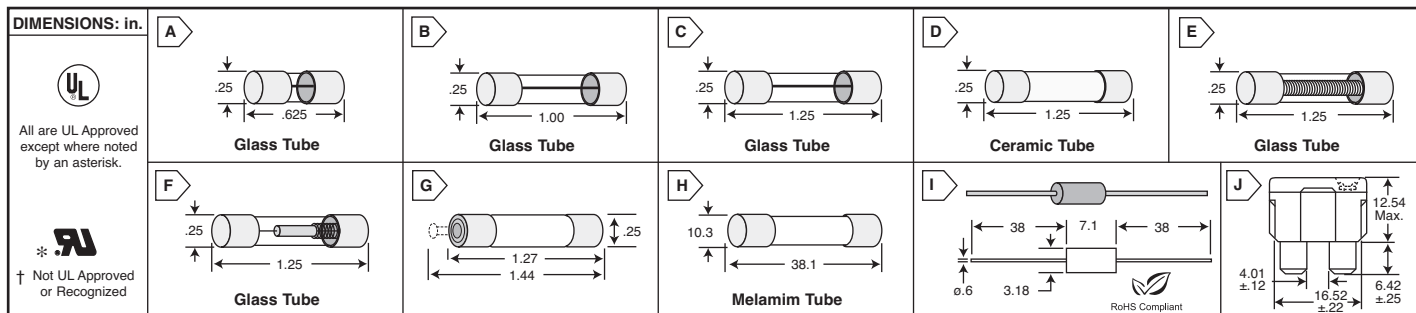

1/4" X 5/8" FUSES

AGA Series Fast Acting Fuses

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Amp (A)	Volt (V)	Price Each		
				1	25	50
504-AGA-1/4	A	1/4	125	3.46	3.29	3.11
504-AGA-3/8	A	3/8	125	3.29	3.11	3.07
504-AGA-1/2	A	1/2	125	2.76	2.62	2.48
504-AGA-3/4	A	3/4	125	2.00	1.98	1.89
504-AGA-1	A	1	125	1.41	1.34	1.27
504-AGA-1-1/2	A	1 1/2	125	1.41	1.34	1.27
504-AGA-2	A	2	125	1.40	1.12	1.01
504-AGA-2-1/2	A	2 1/2	125	1.41	1.34	1.27
504-AGA-3	A	3	125	1.70	1.62	1.52
504-AGA-5	A	5	125	1.07	1.02	.96
504-AGA-6	A	6	32	1.07	1.02	.96
504-AGA-7	A	7	32	1.07	1.02	.96
504-AGA-7-1/2	A	7 1/2	32	1.07	1.02	.96
504-AGA-10	A	10	32	1.07	1.02	.96
504-AGA-15	A	15	32	1.07	1.02	.96
504-AGA-20	A	20	32	1.07	1.02	.96
504-AGA-25	A	25	32	1.07	1.02	.96
504-AGA-30	A	30	32	1.02	.96	.91

1/4" X 1-1/4" FUSES (CONT.)

ABC Series Fast Acting Fuses

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Amp (A)	Volt (V)	Price Each		
				1	25	50
504-ABC-2	D	2	250	.92	.73	.67
504-ABC-3	D	3	250	.83	.67	.65
504-ABC-5	D	5	250	.79	.63	.60
504-ABC-6	D	6	250	.79	.63	.60
504-ABC-8	D	8	250	.79	.63	.60
504-ABC-10	D	10	250	.85	.81	.77
504-ABC-12	D	12	250	.85	.81	.77
504-ABC-15	D	15	250	.82	.78	.74
*504-ABC-20	D	20	250	1.15	.92	.89
*504-ABC-25	D	25	125	1.15	.92	.89
†504-ABC-30	D	30	125	1.55	1.49	1.39

1/4" X 1-1/4" FUSES (CONT.)

MDA Series Time Delay Fuses

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Amp (A)	Volt (V)	Price Each		
				1	25	50
504-MDA-1	D	1	250	1.95	1.56	1.40
504-MDA-2	D	2	250	1.95	1.56	1.40
504-MDA-2-1/2	D	2 1/2	250	1.85	1.76	1.67
504-MDA-3	D	3	250	1.37	1.31	1.24
504-MDA-4	D	4	250	1.37	1.31	1.24
504-MDA-5	D	5	250	1.37	1.31	1.24
504-MDA-6-1/4	D	6 1/4	250	1.37	1.31	1.24
504-MDA-7	D	7	250	1.85	1.76	1.67
504-MDA-8	D	8	250	1.37	1.31	1.24
504-MDA-10	D	10	250	1.34	1.27	1.21
504-MDA-12	D	12	250	1.37	1.31	1.24
†504-MDA-15	D	15	250	1.34	1.27	1.21
†504-MDA-20	D	20	250	1.37	1.31	1.24
†504-MDA-30	D	30	250	1.37	1.31	1.24

1/4" X 1" FUSES

AGX Series Fast Acting Fuses

* For instruments, electronic and small appliance circuits

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Amp (A)	Volt (V)	Price Each		
				1	25	50
504-AGX-1/16	B	1/16	250	4.25	3.88	3.55
504-AGX-1/8	B	1/8	250	2.73	2.70	2.67
504-AGX-3/8	B	3/8	250	1.10	1.07	1.04
504-AGX-1/4	B	1/4	250	1.10	1.07	1.04
504-AGX-1/2	B	1/2	250	.87	.84	.818
504-AGX-1	B	1	250	.60	.57	.55
504-AGX1-1/2	B	1 1/2	250	.60	.57	.55
504-AGX-2	B	2	250	.60	.57	.55
504-AGX-3	B	3	125	.58	.531	.482
504-AGX-4	B	4	125	.65	.62	.592
504-AGX-5	B	5	125	.65	.62	.592
504-AGX10	B	10	32	.42	.383	.348
504-AGX-15	B	15	32	.39	.378	.356
504-AGX-20	B	20	32	.39	.378	.356

MDL Series Time Delay Fuses

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Amp (A)	Volt (V)	Price Each		
				1	25	50
†504-MDL-1/16	E	1/16	250	2.28	2.17	2.05
†504-MDL-1/10	E	1/10	250	1.83	1.74	1.65
504-MDL-3/16	E	3/16	250	2.46	2.34	2.21
504-MDL-15/100	E	15/100	250	2.31	2.28	2.25
504-MDL-1/8	E	1/8	250	1.83	1.74	1.65
504-MDL-2/10	E	2/10	250	2.46	2.34	2.21
504-MDL-1/4	E	1/4	250	1.10	1.05	.99
504-MDL-3/10	E	3/10	250	1.10	1.05	.99
504-MDL-4/10	E	4/10	250	1.49	1.42	1.34
504-MDL-3/8	E	3/8	250	1.49	1.42	1.34
504-MDL-8/10	E	8/10	250	1.08	1.03	.97
504-MDL-1/2	E	1/2	250	1.04	.83	.75
504-MDL-6/10	E	6/10	250	1.04	.83	.75
504-MDL-3/4	E	3/4	250	1.04	.83	.75
504-MDL-1	E	1	250	1.13	.90	.81
504-MDL-1-2/10	E	1 2/10	250	1.08	1.03	.97
504-MDL-1-1/4	E	1 1/4	250	.80	.76	.72
504-MDL-1-1/2	E	1 1/2	250	.78	.74	.70
504-MDL-1-6/10	E	1 6/10	250	1.08	1.03	.97
504-MDL-1-8/10	E	1 8/10	250	1.08	1.03	.97
504-MDL-2	E	2	250	.76	.72	.69
504-MDL-2-1/4	E	2 1/4	250	1.08	1.03	.97
504-MDL-2-1/2	E	2 1/2	250	.80	.76	.72
504-MDL-3	E	3	250	.78	.74	.70
504-MDL-3-2/10	E	3 2/10	250	.80	.76	.72
504-MDL-3-1/2	E	3 1/2	250	.80	.76	.72
504-MDL-4	E	4	250	.80	.76	.72
504-MDL-5	E	5	250	.78	.74	.70
504-MDL-6	E	6	250	.80	.76	.72
504-MDL-6-1/4	E	6 1/4	250	.80	.76	.72
504-MDL-7	E	7	250	.80	.76	.72
504-MDL-8	E	8	250	.80	.76	.72
*504-MDL-10	E	10	32	1.18	1.12	1.06
504-MDL-12A	E	12	32	1.16	1.10	1.04
*504-MDL-15	E	15	32	1.18	1.12	1.06
*504-MDL-20	E	20	32	1.18	1.12	1.06
*504-MDL-25	E	25	32	1.59	1.51	1.43
*504-MDL-30	E	30	32	1.64	1.60	1.55

GLD Series Fast Acting, Pin-Indicating/ Non Timing Delay Fuse

MOUSER STOCK NO.	Fig.	Amp (A)	Volt (V)	Price Each		
				1	25	50
504-GLD-1/2A	G	1/2	125	7.92	7.52	7.13
504-GLD-1	G	1	125	6.09	5.91	5.73
504-GLD-1-1/2	G	1 1/2	125	6.09	5.91	5.73
504-GLD2	G	2	125	6.09	5.91	5.73
504-GLD-3	G	3	125	6.09	5.91	5.73
504-GLD-4	G	4	125	6.09	5.91	5.73
504-GLD-5	G	5	125	6.09	5.91	5.73
504-GLD-10	G	10	125	8.14	7.96	7.78
504-GLD-12.0	G	12	125	9.20	8.74	8.28
504-GLD-15	G	15	125	9.20	8.74	8.28

13/32" X 1 1/2" FUSES

KTK Series Limitron® Fast-Acting Midget Fuses

MOUSER STOCK NO.	Fig.	Amp (A)	Volt (V)	Price Each		
				1	25	50
504-KTK1/2	H	1/2	600	17.57	17.09	15.37
504-KTK-1	H	1	600	18.70	17.77	16.83
504-KTK3	H	3	600	18.70	17.77	16.83
504-KTK-5	H	5	600	18.70	17.77	16.83
504-KTK-10	H	10	600	19.88	19.90	14.31
504-KTK-15	H	15	600	18.80	15.90	14.31
504-KTK-20	H	20	600	19.96	15.97	14.36
504-KTK-25	H	25	600	19.96	15.97	14.36
504-KTK-30	H	30	600	19.96	15.97	14.36

MCRW SERIES FUSES

Fast Acting Axial Lead Fuses

* Subminiature size • Automatic insertion
• Hermetically sealed

RoHS Compliant

MOUSER STOCK NO.	Fig.	Amp (A)	Volt (V)	Price Each		
				1	25	50
*504-MCRW-125MA	I	1/8	125	.59	.47	.42
*504-MCRW-250MA	I	1/4	125	.59	.47	.42
*504-MCRW-500MA	I	1/2	125	.59	.47	.42
*504-MCRW-1A	I	1	125	.59	.47	.42
*504-MCRW-1-1/2A	I	1 1/2	125	.59	.47	.42
*504-MCRW-2A	I	2	125	.59	.47	.42
*504-MCRW-3A	I	3	125	.59	.47	.42
*504-MCRW-4A	I	4	125	.59	.47	.42
*504-MCRW-5A	I	5	125	.59	.47	.42
*504-MCRW-10A	I	10	125	.59	.47	.42

ATC SERIES FUSES

Blade Type, Fast Acting Fuses

MOUSER STOCK NO.	Fig.	Amp (A)	Volt (V)	Color	Price Each		
					1	25	50
504-ATC-1	J	1	32	Black	1.22	1.16	1.10
504-ATC-2	J	2	32	Gray	1.22	1.15	1.04
504-ATC-3	J	3	32	Violet	.52	.49	.47
504-ATC-4	J	4	32	Pink	.52	.49	.47
504-ATC-5	J	5	32	Tan	.52	.49	.47
504-ATC-7-1/2	J	7.5	32	Brown	.52	.49	.47
504-ATC-10	J	10	32	Red	.52	.49	.47
504-ATC-15	J	15	32	Blue	.52	.49	.47
504-ATC-20	J	20	32	Yellow	.52	.49	.47
504-ATC-25	J	25	32	Clear	.52	.49	.47
504-ATC-30	J	30	32	Green	.52	.49	.47
504-ATC-35	J	35	32	Blade	.86	.81	.77
504-ATC-40	J	40	32	Amber	.52	.49	.47

MDQ SERIES Dual Element Time Delay Fuses

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Amp (A)	Volt (V)	Price Each		
				1	25	50
504-MDQ-2	F	2	250	3.62	3.44	3.26
504-MDQ-3	F	3	250	3.62	3.44	3.26
504-MDQ-4	F	4	250	3.62	3.44	3.26
504-MDQ-5	F	5	250	3.09	3.04	2.99
504-MDQ-6	F	6	250	3.62	3.44	3.26