


LITTELFUSE Fuse Clips, Holders and Blocks



Products may be RoHS compliant.
Check mouser.com for RoHS status.

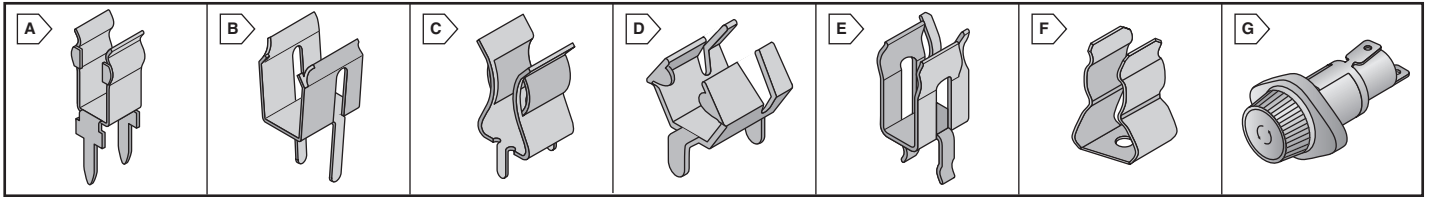

FUSE CLIPS



RoHS Compliant

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Mount Method	Fuse Type	Fuse Mounting	Price Each			
						1	10	100	250
576-01000054H	100054	A	PC	3AG/3AB	Cartridge	.19	.18	.17	.16
576-01000056H	100056	A	PC	3AG/3AB	Cartridge	.16	.15	.14	.13
576-01010001H	101001	A	Rivet/Eyelet	3AG/3AB	Cartridge	.15	.14	.135	.13
576-01010002H	101002	A	Rivet/Eyelet	3AG/3AB	Cartridge	.15	.14	.135	.13
576-01210002H	121002	A	Rivet/Eyelet	3AG/3AB	Cartridge	1.10	1.04	.99	.93
576-01000058H	100058	B	PC	3AG/3AB	Axial/Radial	.15	.145	.14	.13
576-01020071H	102071	C	PC	3AG/3AB	Cartridge	.15	.14	.135	.13
576-01020074H	102074	C	PC	3AG/3AB	Cartridge	.15	.14	.135	.13
576-01220083H	122083	C	PC	3AG/3AB	Cartridge	.44	.41	.39	.37
576-01220088H	122088	C	PC	3AG/3AB	Cartridge	.36	.34	.32	.31
576-01250001H	125001	F	PC	3AG/3AB	Cartridge	.94	.89	.84	.80
576-01020080H	102080	D	Rivet/Eyelet	NEC	Cartridge	.15	.14	.13	.12
576-01220090H	122090	D	Rivet/Eyelet	NEC	Cartridge	.40	.38	.36	.34
576-01270001H	127001	D	Rivet/Eyelet	NEC	Cartridge	2.60	2.47	2.34	2.21
576-01110501H	111501	E	PC	5x20mm	Axial/Radial	.15	.14	.135	.13
576-01110506H	111506	E	PC	5x20mm	Axial/Radial	.28	.27	.25	.24
576-01070002H	107002	F	Rivet/Eyelet	NEC	Cartridge	.59	.56	.53	.50

571 SERIES PANEL MOUNT FUSE HOLDERS



RoHS Compliant

For quantities of 500 and up, call for quote.

Specifications:

- 4000V dielectric strength
- Black Thermoplastic
- Rejection Feature
- Fuse Diameter 13/32"

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Type	Amp Rating	Voltage Rating	Fuse Mounting	Price Each			
							1	10	100	250
576-05710007L	571007	G	Standard	30	600	1 13/32" - 1 1/2"	5.82	5.53	5.24	4.95
576-05710007LXP	571007P	G	Watertight	30	600	1 13/32" - 1 1/2"	6.63	6.30	5.97	5.64
576-05710008L	571008	G	Standard	30	600	1 13/32" - 1 1/2"	5.82	5.53	5.24	4.95
576-05710008LXP	571008P	G	Watertight	30	600	1 13/32" - 1 1/2"	7.04	6.69	6.34	5.99
576-05710027L	571027	G	Standard	20	600	1 5/18" - 1 3/8"	6.37	6.05	5.73	5.42
576-05710027LXP	571027P	G	Watertight	20	600	1 5/18" - 1 3/8"	7.56	7.18	6.80	6.42
576-05710028L	571028	G	Standard	20	600	1 5/18" - 1 3/8"	5.82	5.53	5.24	4.95
576-05710028LXP	571028P	G	Watertight	20	600	1 5/18" - 1 3/8"	7.04	6.69	6.34	5.99
576-057100CCL	5710CC	G	Standard	30	600	1 1/2"	7.31	6.95	6.58	6.22
576-057100CCLXP	5710CCP	G	Watertight	30	600	1 1/2"	8.51	8.08	7.66	7.23
576-05710RCCL	571RCC	G	Standard	30	600	1 1/2"	7.31	6.95	6.58	6.22
576-05710RCCLXP	571RCCP	G	Watertight	30	600	1 1/2"	8.51	8.08	7.66	7.23

CLASS T FUSE BLOCKS



E14721

LR73091

Features:

- Bases are molded phenolic. To provide a low resistance connection and long-range reliability, steel reinforcing springs are supplied as standard. Larger blocks employ an integral heat sink for maximum heat dissipation.

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	No. of poles.	Amp Rating	Connector Type	Price Each			
					1	10	100	250
300V								
576-LT300302CR	LT30030-2CR	2	30	Box Lug	35.66	33.88	32.09	30.31
576-LT300302SR	LT30030-2SR	2	30	Screw	28.40	26.98	25.56	24.14
576-LT300303CR	LT30030-3CR	3	30	Box Lug	43.21	40.67	38.13	36.86
576-LT300602CR	LT30060-2CR	2	60	Box Lug	34.24	32.53	30.82	29.10
576-LT300603CR	LT30060-3CR	3	60	Box Lug	39.70	37.36	35.03	33.86
576-LT300604CR	LT30060-4CR	4	60	Box Lug	53.07	49.95	46.83	45.27
576-LT301001C	LT30100-1C	1	100	Box Lug	36.74	34.58	32.42	31.34
576-LT301002C	LT30100-2C	2	100	Box Lug	58.22	55.31	52.01	50.13
576-LT301003C	LT30100-3C	3	100	Box Lug	104.98	98.80	92.63	89.54
576-LT302001C	LT30200-1C	1	200	Box Lug	99.21	93.38	87.54	84.62
576-LT304001C	LT30400-1C	1	400	Box Lug	115.43	112.13	108.83	105.54
576-LT306001C	LT30600-1C	1	600	Box Lug	232.32	218.66	204.99	198.16
600V								
576-LT600301CR	LT60030-1CR	1	30	Box Lug	14.07	13.43	12.79	12.15
576-LT600301SR	LT60030-1SR	1	30	Screw	16.56	15.73	14.90	14.08
576-LT600302CR	LT60030-2CR	2	30	Box Lug	38.42	36.50	34.58	32.66
576-LT600302SR	LT60030-2SR	2	30	Screw	29.14	27.68	26.23	24.77
576-LT600303CR	LT60030-3CR	3	30	Box Lug	40.72	38.32	35.93	34.73
576-LT600303SR	LT60030-3SR	3	30	Screw	39.48	37.51	35.53	33.56
576-LT600601CR	LT60060-1CR	1	60	Box Lug	18.42	17.50	16.58	15.66
576-LT600602CR	LT60060-2CR	2	60	Box Lug	38.92	36.97	35.03	33.08
576-LT600603CR	LT60060-3CR	3	60	Box Lug	41.99	39.52	37.05	35.82
576-LT601001C	LT60100-1C	1	100	Box Lug	50.86	47.87	44.88	43.38
576-LT601002C	LT60100-2C	2	100	Box Lug	110.21	103.73	97.25	94.00
576-LT601003C	LT60100-3C	3	100	Box Lug	131.72	123.97	116.22	112.35
576-LT602001C	LT60200-1C	1	200	Box Lug	105.01	98.83	92.66	89.57
576-LT604001C	LT60400-1C	1	400	Box Lug	151.61	142.69	133.77	129.31
576-LT606001C	LT60600-1C	1	600	Box Lug	275.04	258.86	242.69	234.60

