

ALPS Metal Shaft Potentiometers


ALPS

ALPS 9MM SIZE METAL SHAFT SNAP-IN POTENTIOMETERS

RK09L Series

Features:

- Shaft Type: Flat

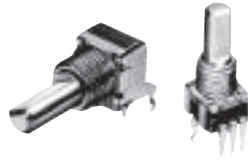


For quantities of 500 and up, call for quote.

MOUSER STOCK NO.		Length of Shaft	Total Resistance	Resistance Taper	Price Each			
Mfr.	Mfr. Part No.				1	25	50	100
Single-Unit Horizontal								
688	RK09L1120A2S	15mm	10kΩ	15A	.90	.83	.75	.60
688	RK09L1120036	15mm	10kΩ	1B	.98	.90	.82	.66
Single-Unit Vertical								
688	RK09L1140A5P	15mm	50kΩ	1B	3.10	2.55	2.35	2.00
688	RK09L114001T	20mm	10kΩ	1B	1.07	.98	.89	.71
688	RK09L1140A6S	25mm	5kΩ	1B	.75	.69	.63	.50
Dual-Unit Horizontal								
688	RK09L12B0A31	15mm	50kΩ	15A	1.60	1.45	1.25	1.10
Dual-Unit Vertical								
688	RK09L12D0A1T	20mm	10kΩ	15A	1.12	1.02	.93	.74

ALPS 9MM SIZE METAL SHAFT MULTI-GANGED POTENTIOMETERS

 RK097/RK098 Series



For quantities of 500 and up, call for quote.

MOUSER STOCK NO.		Length of Shaft	Total Resistance	Resistance Taper	Price Each			
Mfr.	Mfr. Part No.				1	25	50	100
Single-Unit Horizontal								
688	RK097111080J	15mm	10kΩ	15A	1.26	1.16	1.05	.84
688	RK0971110909	15mm	20kΩ	1B	1.26	1.16	1.05	.84
688	RK097111050B	15mm	50kΩ	15A	1.26	1.16	1.05	.84
688	RK0971110D7Z	15mm	50kΩ	1B	1.33	1.22	1.11	.89
688	RK097111020N	15mm	50kΩ	1B	1.26	1.16	1.05	.84
688	RK0971110D88	20mm	10kΩ	1B	1.33	1.22	1.11	.89
688	RK097111091M	25mm	10kΩ	15A	1.26	1.16	1.05	.84
688	RK0971110D57	25mm	10kΩ	1B	1.26	1.16	1.05	.84
688	RK0971111Z0P	15mm	20kΩ	15A	2.16	1.98	1.80	1.44
688	RK09711110AL	20mm	10kΩ	15A	2.16	1.98	1.80	1.44
688	RK09711110EL	20mm	10kΩ	1B	2.16	1.98	1.80	1.44
688	RK097111202P	25mm	10kΩ	15A	3.06	2.80	2.55	2.04
688	RK097111202Q	25mm	10kΩ	1B	3.06	2.80	2.55	2.04
688	RK0971114D0B	15mm	10kΩ	3B	2.22	2.04	1.85	1.48
688	RK0971214Z06	20mm	10kΩ	1B	2.64	2.42	2.20	1.76
688	RK0971224Z01	20mm	10kΩ	15A	3.00	2.75	2.50	2.00
688	RK0971114Z07	20mm	10kΩ	1B	2.45	2.24	2.04	1.63
688	RK0971114Z04	25mm	10kΩ	1B	2.45	2.24	2.04	1.63
688	RK097111T065	25mm	10kΩ	1B	1.98	1.82	1.65	1.32
688	RK097111T064	25mm	100kΩ	15A	1.98	1.82	1.65	1.32
688	RK097111TD2M	25mm	10kΩ	1B	2.05	1.88	1.71	1.37
Dual-Unit Horizontal								
688	RK0971210D97	20mm	100kΩ	1B	1.73	1.58	1.44	1.15
688	RK09712200MC	15mm	10kΩ	15A	1.80	1.65	1.50	1.20
688	RK09712200MY	15mm	10kΩ	3B	1.80	1.65	1.50	1.20
688	RK09712200FS	20mm	50kΩ	15A	1.80	1.65	1.50	1.20
688	RK0971221Z05	15mm	10kΩ	3B	2.80	2.57	2.33	1.87
688	RK097121200C	15mm	10kΩ	15A	3.59	3.29	2.99	2.39
688	RK097121TD57	25mm	10kΩ	1B	2.83	2.42	2.02	1.81
688	RK097122T017	25mm	10kΩ	15A	2.42	2.22	2.02	1.62

ALPS COMPACT REFLOW TYPE SLIDE POTENTIOMETER

RS06U Series

Features:

- Resistance Taper: Linear (B)



For quantities of 500 and up, call for quote.

MOUSER STOCK NO.		Travel	Length of Lever	Total Resistance	Price Each			
Mfr.	Mfr. Part No.				1	25	50	100
Single-Unit Horizontal								
688	RS06U11Z001	6mm	1.05mm	30kΩ	1.50	1.38	1.25	1.00

ALPS ILLUMINATED TYPE SLIDE POTENTIOMETERS (SINGLE-UNIT TYPE)

RS602 Series

Features:

- LED Color: Green



For quantities of 500 and up, call for quote.


MOUSER STOCK NO.		Travel	Length of Lever	Total Resistance	Price Each			
Mfr.	Mfr. Part No.				1	25	50	100
Single-Unit Vertical								
688	RS602111LA02	60mm	15mm	10kΩ	3.33	3.06	2.78	2.22
688	RS602113LA05	60mm	15mm	10kΩ	3.11	2.83	2.54	2.26

ALPS 16MM SIZE METAL SHAFT POTENTIOMETERS

RK163 Series

Features:

 - Shaft Types: Flat and Slotted



For quantities of 500 and up, call for quote.

MOUSER STOCK NO.		Length of Shaft	Total Resistance	Resistance Taper	Price Each			
Mfr.	Mfr. Part No.				1	25	50	100
Single-Unit Horizontal								
688	RK271111001T	25mm	100kΩ	15A	6.92	6.30	5.67	5.04
688	RK2711120026	25mm	100kΩ	15A	7.33	6.66	5.99	5.33
Dual-Unit Horizontal								
688	RK27112A00AK	20mm	100kΩ	15A	11.71	10.64	9.58	8.51
688	RK27112A00CC	25mm	100kΩ	15A	11.71	10.64	9.58	8.51
688	RK27112A0A16	20mm	100kΩ	15A	11.71	10.64	9.58	8.51

ALPS 16MM SIZE METAL SHAFT POTENTIOMETERS

RK163 Series

Features:

- Shaft Types: Flat and Knurled



For quantities of 500 and up, call for quote.

MOUSER STOCK NO.		Length of Shaft	Total Resistance	Resistance Taper	Price Each			
Mfr.	Mfr. Part No.				1	25	50	100
Single-Unit Horizontal								
688	RK1631110TBK	15mm	10kΩ	1B	1.62	1.49	1.35	1.08
688	RK1631110TT3	20mm	10kΩ	15A	1.62	1.49	1.35	1.08
688	RK1631110TNP	20mm	10kΩ	1B	1.62	1.49	1.35	1.08
Dual-Unit Horizontal								
688	RK1631210AX9	15mm	10kΩ	1B	2.59	2.37	2.16	1.73
688	RK16312A0B85	20mm	10kΩ	15A	2.66	2.44	2.22	1.77

ALPS 9MM SIZE INSULATED SHAFT LONG-LIFE POTENTIOMETER

Features:

- Shaft Types: Flat



For quantities of 500 and up, call for quote.

MOUSER STOCK NO.		Length of Shaft	Total Resistance	Resistance Taper	Price Each			
Mfr.	Mfr. Part No.				1	25	50	100
Single-Unit Horizontal								
688	RK09Y11L0001	15mm	10kΩ	15A	.61	.56	.51	.41

ALPS 16MM/27MM SIZE MOTOR-DRIVEN POTENTIOMETERS

Features:

- Shaft Types: Flat



For quantities of 500 and up, call for quote.

MOUSER STOCK NO.		Length of Shaft	Total Resistance	Resistance Taper	Price Each			
Mfr.	Mfr. Part No.				1	25	50	100
Single-Unit								
688	RK16812MG099	25mm	100k	3B	8.00	7.00	6.25	5.50
688	RK16814MG02R	25mm	20k	15A	6.88	6.26	5.63	5.01
Dual-Unit								
688	RK27112MC030	25mm	100k	15A	18.00	16.37	14.73	13.09
6 Ganged-Unit								
688	RK16816MGA04	25mm	100k	3B	9.91	9.01	8.11	7.21