

VISHAY / SFERNICE Multi-Turn Trimmers

VISHAY SFERNICE T63 SERIES: 1/4" 15-TURN, SQUARE, CERMET TRIMMERS

Specifications:

- Tolerance: ±10%
- Oper. temp. range: -55°C to +155°C
- Rated voltage: 250VD
- Rotation: 15 turns ±5
- Power rating: .25W @ 85°C
- Temperature coefficient: ±70ppm/°C
- Screwdriver slot: .02" x .02"

For quantities 500 and up, call for quote.

MOUSER STOCK NO.	Fig.	Table of Values (Ω)	Price Each				
			1	25	50	100	200
72-T63YB-Value	A	10, 20, 50, 100, 200, 500, 1K, 2K, 5K, 10K, 20K, 25K, 50K, 100K, 200K, 250K, 500K, 1M	2.89	2.41	1.93	1.74	1.67
72-T63XB-Value	B		3.01	2.43	1.94	1.78	1.68
72-T63ZB-Value	C		3.14	2.53	2.02	1.86	1.75

VISHAY SFERNICE TS63 SERIES: 1/4" 13-TURN SMD, SQUARE, CERMET TRIMMERS

Specifications:

- Tolerance: ±10%
- Oper. temp. range: -55°C to +155°C
- Rated voltage: 250VD
- Rotation: 13 turns ±2
- Power rating: .25W @ 85°C
- Temperature coefficient: ±100ppm/°C, 10Ω-50Ω 0/+200ppm
- Screwdriver slot: .02" x .02"

◆ Surface Mount Device

For quantities 500 and up, call for quote.

MOUSER STOCK NO.	Fig.	Table of Values (Ω)	Price Each				
			1	25	50	100	200
72-TS63Y-Value	D	10, 20, 50, 100, 200, 500, 1K, 2K, 5K, 10K, 20K, 25K, 50K, 100K, 200K, 250K, 500K, 1M, 2M	3.28	2.64	2.11	1.94	1.83

VISHAY SFERNICE T18 SERIES: 3/4" 15-TURN, RECTANGULAR, HORIZONTAL ADJUST, CERMET TRIMMERS

Specifications:

- Tolerance: ±10%
- Oper. temp. range: -55°C to +155°C
- Rated voltage: 250VDC
- Rotation: 15 turns ±1
- Power rating: .75W @ 70°C
- Temperature coefficient: ±70ppm/°C
- Screwdriver slot: .024" x .024"

For quantities 500 and up, call for quote.

MOUSER STOCK NO.	Fig.	Table of Values (Ω)	Price Each				
			1	25	50	100	200
72-T18-Value	E	100, 200, 500, 1K, 2K, 5K, 10K, 20K, 25K, 50K, 100K, 200K, 500K, 1M, 2M	1.19	.96	.77	.704	.663

VISHAY SFERNICE T93 SERIES: 3/8" 19-TURN, SQUARE, CERMET TRIMMERS


Specifications:

- Tolerance: ±10%
- Rated voltage: 250VDC
- Operating temperature range: -55°C to +155°C
- Rotation: 19 turns ±2
- Power rating: .50W @ 85°C
- Temperature coefficient: ±70ppm/°C
- Screwdriver slot: .024" x .024"

For quantities 500 and up, call for quote.

MOUSER STOCK NO.	Fig.	Table of Values (Ω)	Price Each				
			1	25	50	100	200
72-T93XA-Value	F	10, 20, 50, 100, 200, 500, 1K, 2K, 5K, 10K, 20K, 25K, 50K, 100K, 200K, 250K, 500K, 1M, 2M	1.51	1.21	.97	.89	.84
72-T93XB-Value	G		1.32	1.06	.85	.78	.73
72-T93YA-Value	H		1.51	1.21	.97	.89	.84
72-T93YB-Value	I		1.32	1.06	.85	.78	.73

VISHAY SFERNICE T93 SERIES: 3/8" 19-TURN, SQUARE TRIMMER KITS

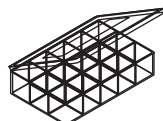

RoHS Compliant



LEAD-FREE

MOUSER STOCK NO.	Kit Contains 90 Pieces	Price Each
370-T93XA-KIT	10 each: 1K, 5K, 10K; 5 each: 10, 50, 100, 500, 2K,	99.95
370-T93YB-KIT	20K, 50K, 100K, 200K,	99.95
370-T93Z-KIT	500K, 1M, 2M	99.95

DIMENSIONS: in.

A

B

Screwdriver slot .02x.02

C

D

E

F

G

H

I

Multi-Turn Trimmers

Vishay