


RoHS Compliant This product is RoHS compliant.

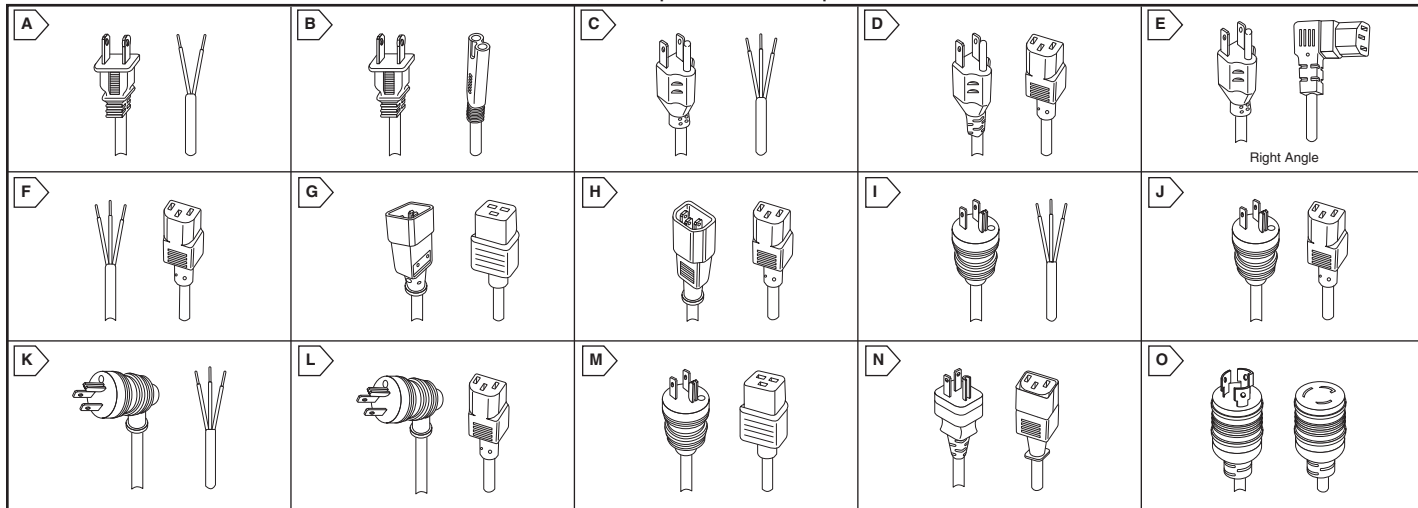

NORTH AMERICAN POWER CORDS

2 Conductor Power Cords

All cords have CEE Color Code (Brown/Blue/Green/Yellow), with 60°C temperature rating unless marked as below:

† North American Color Code (Black/White/Green)
Temperature Rating: 105°C VW-1

MOUSER STOCK NO.	Qualtek Part No.	Fig.	"L"	Cordage	No. of Cond. AWG	Amps 125V	Nema Plug	Conn.	Price Each		
									1	10	25
562-221001-01	221001-01	A	6'0"	SPT-1 †	2 x 18	10	1-15	-	1.62	1.55	1.50
562-221002-01	221002-01	A	9'0"	SPT-1 †	2 x 18	10	1-15	-	2.48	2.30	2.20
562-223020-01	223020-01	B	6'0"	SPT-2 † #	2 x 18	7	1-15	C7	2.10	1.95	1.88
562-223021-01	223021-01	B	8'0"	SPT-2 † #	2 x 18	7	1-15	C7	2.52	2.35	2.10

3 Conductor Power Cords - Unshielded

All cords have CEE Color Code (Brown/Blue/Green/Yellow), with 60°C temperature rating unless marked as below:

† North American Color Code (Black/White/Green)
Temperature Rating: 105°C VW-1

Features:
• Black: -01
• Gray: -06

MOUSER STOCK NO.	Qualtek Part No.	Fig.	"L"	Cordage	No. of Cond. AWG	Amps 125V	Nema Plug	Conn.	Price Each		
									1	10	25
562-211011-01	211011-01	C	6'0"	SVT †	3 x 18	10@125	5-15	-	2.42	2.25	2.09
562-211011-06	211011-06	C	6'0"	SVT †	3 x 18	10@125	5-15	-	3.28	3.05	2.83
562-211012-06	211012-06	C	8'0"	SVT †	3 x 18	10@125	5-15	-	4.26	4.00	3.75
562-211017-06	211017-06	C	6'0"	SVT †	3 x 18	10@125	5-15	-	5.70	5.30	4.93
562-21101806	211018-06	C	8'0"	SJT †	3 x 18	10@125	5-15	-	3.64	3.40	3.23
562-311010-01	311010-01	C	9'10"	SVT	3 x 18	10@125	5-15	-	4.85	4.50	4.00
562-311016-01	311016-01	C	9'10"	SJT	3 x 18	10@125	5-15	-	4.65	4.28	3.93
562-311007-01	311007-01	C	6'7"	SJT	3 x 18	10@125	5-15	-	3.20	2.88	2.72
562-311013-01	311013-01	C	6'6"	SVT	3 x 18	10@125	5-15	-	5.00	4.51	4.21
562-311019-01	311019-01	C	6'6"	SJT	3 x 16	13@125	5-15	-	6.45	5.83	5.28
562-311022-01	311022-01	C	9'8"	SJT	3 x 16	13@125	5-15	-	9.65	8.70	7.88
562-311027-01	311027-01	C	9'10"	SJT	3 x 14	15@125	5-15	-	9.65	8.69	8.42
562-212004-01	212004-01	D	7'6"	SVT †	3 x 18	10@125	5-15	C13	4.50	4.25	4.04
562-212013-01	212013-01	D	7'6"	SJT †	3 x 16	13@125	5-15	C13	6.11	5.86	5.67
562-312003-01	312003-01	D	7'6"	SVT	3 x 18	10@125	5-15	C13	4.05	3.88	3.75
562-312007-01	312007-01	D	6'7"	SJT	3 x 18	10@125	5-15	C13	5.50	5.00	4.75
562-312008-01	312008-01	D	7'6"	SJT	3 x 18	10@125	5-15	C13	5.30	5.00	4.67
562-312010-01	312010-01	D	9'10"	SJT	3 x 18	10@125	5-15	C13	6.45	6.12	6.00
562-312011-01	312011-01	D	6'6"	SJT	3 x 16	13@125	5-15	C13	7.40	6.65	6.16
562-312014-01	312014-01	D	9'10"	SJT	3 x 16	13@125	5-15	C13	7.00	6.75	6.50
562-312019-01	312019-01	D	9'10"	SJT	3 x 14	15@125	5-15	C13	11.50	10.92	10.55
562-312021-01	312021-01	D	7'6"	SVT #	3 x 18	10@125	5-15	C13	4.50	4.27	4.06
562-313001-01	313001-01	E	7'6"	SVT	3 x 18	10@125	5-15	C13	4.70	4.48	4.16
562-313003-01	313003-01	E	6'7"	SVT	3 x 18	10@125	5-15	C13	4.00	3.65	3.33
562-313006-01	313006-01	E	6'6"	SJT	3 x 18	10@125	5-15	C13	5.85	5.36	4.93
562-313011-01	313011-01	E	7'6"	SJT	3 x 16	13@125	5-15	C13	7.45	7.08	6.69
562-313014-01	313014-01	E	9'10"	SJT	3 x 16	13@125	5-15	C13	7.32	6.61	6.10
562-315005-01	315005-01	F	6'6"	SJT	3 x 16	10@125	-	C13	4.90	4.57	4.24
562-315008-01	315008-01	F	9'10"	SJT	3 x 18	10@125	-	C13	4.80	4.56	4.41

3 Conductor Power Cords - Unshielded (CONT.)

MOUSER STOCK NO.	Qualtek Part No.	Fig.	"L"	Cordage	No. of Cond. AWG	Amps V	Nema Plug	Conn.	Price Each		
									1	10	25
562-331010-01	331010-01	G	9'10"	SJT	3 x 14	15@250	C20	C19	12.00	11.60	11.20
562-318002-01	318002-01	H	3'3"	SVT	3 x 18	10@125	C14	C13	3.44	3.33	3.01
562-318005-01	318005-01	H	3'3"	SJT	3 x 18	10@125	C14	C13	3.35	3.20	2.96
562-318007-01	318007-01	H	3'3"	SJT	3 x 16	13@125	C14	C13	3.25	3.10	3.02

Hospital Grade - Unshielded

Features:
• With North American Color Code (Black/White/Green)
• Cordage: SJT
• Temperature rating: 60°C

* Hospital Grade Clear Plug
** Hospital Grade Gray Plug
†† Hospital Grade Black Plug
† Right Angle Plug

MOUSER STOCK NO.	Qualtek Part No.	Fig.	"L"	Cordage Color	No. of Cond. AWG	Amps 125V	Nema Plug	Conn.	Price Each		
									1	10	25
* 562-232002-06	232002-06	I	8'0"	Gray	3 x 18	10	5-15	-	6.30	5.98	5.85
* 562-232003-06	232003-06	I	10'0"	Gray	3 x 18	10	5-15	-	6.75	6.41	6.25
** 562-232010-06	232010-06	I	8'0"	Gray	3 x 18	10	5-15	-	5.67	5.37	5.11
** 562-232011-06	232011-06	I	10'0"	Gray	3 x 18	10	5-15	-	7.45	7.15	6.70
** 562-233002-06	233002-06	J	8'0"	Gray	3 x 18	10	5-15	C13	4.68	4.51	4.30
** 562-233003-06	233003-06	J	10'0"	Gray	3 x 18	10	5-15	C13	9.00	8.55	8.12
** 562-233008-06	233008-06	J	8'0"	Gray	3 x 18	10	5-15	C13	6.62	6.29	6.00
** 562-233009-06	233009-06	J	10'0"	Gray	3 x 18	10	5-15	C13	6.95	6.60	6.27
†† 562-242003-06	242003-06	K	10'0"	Gray	3 x 18	10	5-15	-	5.72	5.54	5.16
† 562-243003-06	243003-06	L	10'0"	Gray	3 x 18	10	5-15	C13	12.50	11.35	10.78
** 562-233080-06	233080-06	M	10'0"	Gray	3 x 12	20	5-15	C19	18.27	17.44	16.61
** 562-233081-06	233081-06	N	10'0"	Gray	3 x 12	20	5-20	C19	18.27	17.44	16.61
** 562-233082-06	233082-06	M	10'0"	Gray	3 x 14	15	5-15	C19	13.99	13.35	12.72
** 562-233056-06	233056-06	J	10'0"	Gray	3 x 16	13	5-15	C13	8.97	8.56	8.15
** 562-233057-01	233057-01	J	10'0"	Black	3 x 16	13	5-15	C13	9.07	8.67	8.25
†† 562-233058-01	233058-01	J	10'0"	Black	3 x 16	13	5-15	C13	8.97	8.56	8.15

Twist Lock Power Cord - Unshielded

Features:
• With North American Color Code (Black/White/Green)
• Cordage: SJT
• Temperature rating: 60°C

MOUSER STOCK NO.	Qualtek Part No.	Fig.	"L"	Cordage Color	No. of Cond. AWG	Amps 125V	Plug	Conn.	Price Each		
									1	10	25
562-250069-01	250069-01	O	10'0"	Black	3 x 16	13	L5-15P	L5-15R	13.65	13.03	12.41

Universal Jumper Cords

Features:
• Cordage: SJT/H05VV-F • CEE Color Code • Temperature rating: 60°C


MOUSER STOCK NO.	Qualtek Part No.	Fig.	"L"	Cordage Color	No. of Cond. AWG	Amps 250V	Plug	Conn.	Price Each		
									1	10	25
562-319002	319002-T01	H	3'3"	Black	3 x 18/3 x 1.0mm ²	10.0	C14	C13	4.40	4.25	3.83
562-319004	319004-T01	H	8'2"	Black	3 x 18/3 x 1.0mm ²	10.0	C14	C13	6.29	6.00	5.62

SAFETY RETAINER CLIPS

Helps prevent accidental removal of detachable power cordsets from IEC 320-C14 Power Inlets and IEC 320-C13 Outlets.

Kit contains: 1 stainless steel clip; 2 threaded posts; 2 threaded nuts; 2 washers

MOUSER STOCK NO.	Qualtek Part No.	Description	Price Each		
			1	10	25
562-730B-01	730B-00/00	Used on power cord Fig. D, F, and H in conjunction with a screw mount IEC power inlet	2.49	2.22	2.04
562-730B-05	730B-00/05	Used on power cord Fig. D, F, and H in conjunction with a screw mount IEC power inlet	2.10	1.85	1.66
562-731B-00	731B-00/00	Used on power cord Fig. J or L in conjunction with a screw mount IEC power inlet	3.25	2.90	2.73
562-732B-00	732B-00/00	Used on power cord Fig. H in conjunction with a screw mount IEC power inlet	3.18	2.95	2.75

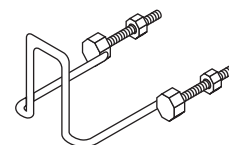

For quantities of 50 and up, call for quote.