


CORCOM Power Entry Modules

RoHS Compliant This product is RoHS compliant.

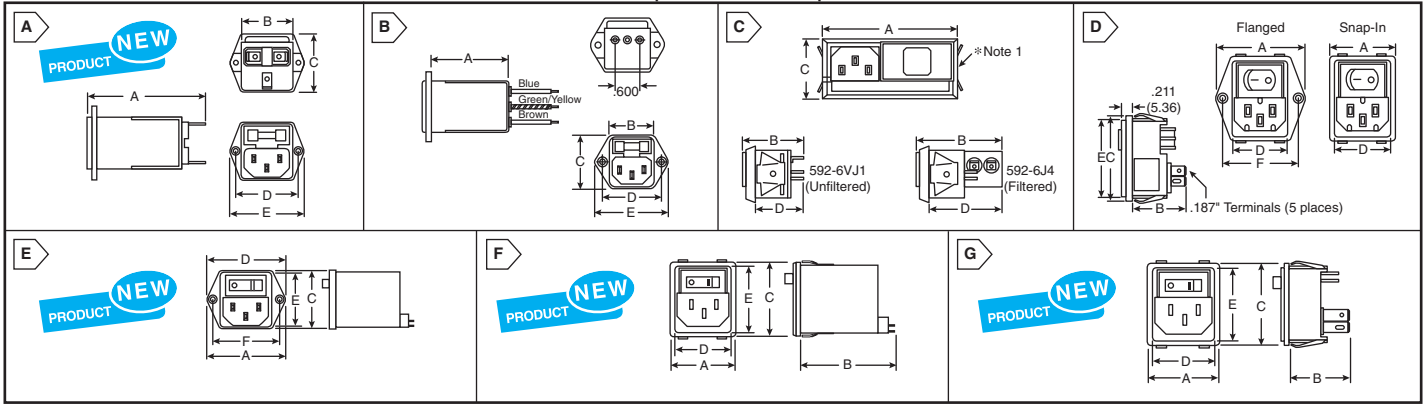

POWER-ENTRY MODULES WITH METRIC FUSE HOLDERS (GG SERIES)

• 5 x 20mm fuse not included

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Amps	No. of Fuse Holders	Dimensions: in. (mm)					Price Each			
Mfr.	Mfr. Part No.				A	B	C	D	E	1	10	25	50
592-1EGG1-2	A	1	2	1.66 (51.10)	1.13 (28.70)	1.29 (32.77)	1.41 (33.30)	1.76 (44.70)	15.36	14.09	13.00	12.08	
592-6EGG1-1	A	6	1	1.66 (51.10)	1.13 (28.70)	1.29 (32.77)	1.41 (33.30)	1.76 (44.70)	10.80	10.00	9.15	8.50	
592-6EGG1-2	A	6	2	1.66 (51.10)	1.13 (28.70)	1.29 (32.77)	1.41 (33.30)	1.76 (44.70)	14.20	13.25	12.21	11.27	
592-6EGG8-2	B	6	2	2.02 (51.10)	1.13 (28.70)	1.29 (32.80)	1.42 (36.00)	1.76 (44.70)	20.40	17.30	15.95	14.90	
592-10EGG1-1	A	10	1	2.15 (54.61)	1.13 (28.70)	1.29 (32.76)	1.42 (36.06)	1.76 (44.70)	14.24	13.59	12.46	11.40	
592-10EGG1-2	A	10	2	2.15 (54.61)	1.13 (28.70)	1.29 (32.76)	1.42 (36.06)	1.76 (44.70)	14.64	13.98	12.81	11.72	

J SERIES - VOLTAGE SELECTING AND FUSED CONNECTOR

6 Amps; 120 - 250 Volts AC; 50-60 Hz

• 5 x 20mm fuse not included

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Amps	Filtered	Dimensions: in. (mm)				Price Each			
Mfr.	Mfr. Part No.				A (Max.)	B1 (Max.)	C (Max.)	D (±.008)	1	10	25	50
592-6VJ1	C	6	No	2.68 (68.10)	1.52 (38.60)	1.17 (29.70)	1.23 (31.20)	14.32	13.01	11.83	10.76	
592-6J4	C	6	Yes	2.75 (69.90)	1.87 (47.50)	1.17 (29.70)	1.58 (40.10)	25.32	23.22	21.43	19.90	

C SERIES - POWER ENTRY MODULE WITH IEC CONNECTOR

* Pre-Connected Terminals

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Amps	Mount Type	Filtered	Dimensions: in. (mm)					Price Each			
Mfr.	Mfr. Part No.					A (Max.)	B (Max.)	C (Max.)	D	E	F	1	10	25
592-3CFE1	D	3	Flange	Yes	1.74 (44.20)	2.53 (64.26)	1.62 (41.17)	1.12 (28.50)	1.54 (39.12)	1.42 (36.00)	19.30	18.95	17.25	16.30
592-3CFS1	D	3	Snap-in	Yes	1.23 (31.24)	2.53 (64.26)	1.62 (41.17)	1.12 (28.50)	1.54 (39.12)	---	18.35	16.80	15.50	14.35
592-6CFE1	D	6	Flange	Yes	1.74 (44.20)	2.53 (64.26)	1.62 (41.17)	1.12 (28.50)	1.54 (39.12)	1.42 (36.00)	17.74	16.40	15.15	14.05
592-6CFS1	D	6	Snap-in	Yes	1.23 (31.24)	2.53 (64.26)	1.62 (41.17)	1.12 (28.50)	1.54 (39.12)	---	17.10	15.65	14.45	13.40
592-10CE1	D	10	Flange	No	1.74 (44.20)	0.97 (24.64)	1.62 (41.17)	1.06 (26.92)	1.54 (39.12)	1.42 (36.00)	6.15	5.67	5.20	4.87
592-10CFE1	D	10	Flange	Yes	1.74 (44.20)	2.53 (64.26)	1.62 (41.17)	1.12 (28.50)	1.54 (39.12)	1.42 (36.00)	19.45	17.80	16.45	15.30
592-10CFS1	D	10	Snap-in	Yes	1.23 (31.24)	2.53 (64.26)	1.62 (41.17)	1.12 (28.50)	1.54 (39.12)	---	19.00	17.40	16.10	14.90
592-10CE1	D	10	Snap-in	No	1.23 (31.24)	0.97 (24.64)	1.62 (41.17)	1.06 (26.92)	1.54 (39.12)	---	6.17	5.60	5.15	4.80
592-15CS1	D	15	Snap-in	No	1.23 (31.24)	0.97 (24.64)	1.62 (41.17)	1.06 (26.92)	1.54 (39.12)	---	6.38	5.83	5.41	5.03
592-15CBS1	D	15	Snap-in	No	1.23 (31.24)	0.97 (24.64)	1.62 (41.17)	1.06 (26.92)	1.54 (39.12)	---	7.49	6.80	6.24	5.87
592-15CE1	D	15	Flange	No	1.74 (44.20)	0.97 (24.64)	1.62 (41.17)	1.06 (26.92)	1.54 (39.12)	1.42 (36.00)	6.38	5.83	5.41	5.03
*592-15CBE1	D	15	Flange	No	1.74 (44.20)	0.97 (24.64)	1.62 (41.17)	1.06 (26.92)	1.54 (39.12)	1.42 (36.00)	7.49	6.80	6.24	5.87

CU SERIES

Specifications:

- Filling the need for smaller versions of Corcom's Switched inlet filters.
- Compact 1U height (1 3/4")
- Provides complete shielding, shrouded quick connect terminals and basic filtering for 1A-15A applications

* Pre-Connected Terminals

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Amps	Mount Type	Filtered	Dimensions: in. (mm)					Price Each			
Mfr.	Mfr. Part No.					A (Max.)	B (Max.)	C (Max.)	D	E	F	1	10	25
592-1CUFS1	F	1	Snap-In	Yes	1.20 (30.60)	1.80 (45.00)	1.34 (34.10)	1.11 (28.10)	1.26 (32.00)	---	20.28	18.41	16.88	15.89
592-1CUFF1	E	1	Flange	Yes	1.70 (43.10)	1.80 (45.00)	1.34 (34.10)	1.21 (30.80)	1.35 (34.30)	1.45 (36.80)	20.28	18.41	16.88	15.89
592-1CUFE1	E	1	Flange	Yes	1.73 (43.90)	1.75 (44.50)	1.34 (34.10)	1.11 (28.10)	1.26 (31.90)	1.45 (36.80)	20.28	18.41	16.88	15.89
592-3CUFS1	F	3	Snap-In	Yes	1.20 (30.60)	1.80 (45.00)	1.34 (34.10)	1.11 (28.10)	1.26 (32.00)	---	20.28	18.41	16.88	15.89
592-3CUFF1	E	3	Flange	Yes	1.70 (43.10)	1.80 (45.00)	1.34 (34.10)	1.21 (30.80)	1.35 (34.30)	1.45 (36.80)	20.33	18.46	16.92	15.94
592-3CUFE1	E	3	Flange	Yes	1.73 (43.90)	1.75 (44.50)	1.34 (34.10)	1.11 (28.10)	1.26 (31.90)	1.45 (36.80)	20.00	18.16	16.65	15.67
592-6CUFS1	F	6	Snap-In	Yes	1.20 (30.60)	1.80 (45.00)	1.34 (34.10)	1.11 (28.10)	1.26 (32.00)	---	20.20	18.35	16.82	15.83
592-6CUFF1	E	6	Flange	Yes	1.70 (43.10)	1.80 (45.00)	1.34 (34.10)	1.21 (30.80)	1.35 (34.30)	1.45 (36.80)	20.33	18.46	16.92	15.94
592-6CUFE1	E	6	Flange	Yes	1.73 (43.90)	1.75 (44.50)	1.34 (34.10)	1.11 (28.10)	1.26 (31.90)	1.45 (36.80)	20.28	18.41	16.88	15.89
592-10CUFS1	F	10	Snap-In	Yes	1.20 (30.60)	1.80 (45.00)	1.34 (34.10)	1.11 (28.10)	1.26 (32.00)	---	20.28	18.41	16.88	15.89
592-10CUFF1	E	10	Flange	Yes	1.70 (43.10)	1.80 (45.00)	1.34 (34.10)	1.21 (30.80)	1.35 (34.30)	1.45 (36.80)	20.33	18.46	16.92	15.94
592-10CUFE1	E	10	Flange	Yes	1.73 (43.90)	1.75 (44.50)	1.34 (34.10)	1.11 (28.10)	1.26 (31.90)	1.45 (36.80)	20.28	18.41	16.88	15.89
592-15CUS1	E	15	Flange	No	1.20 (30.60)	0.97 (24.60)	1.34 (34.10)	1.04 (26.40)	1.26 (32.00)	---	6.85	6.22	5.70	5.37
592-15CUFS1	F	15	Snap-In	Yes	1.20 (30.60)	1.80 (45.00)	1.34 (34.10)	1.11 (28.10)	1.26 (32.00)	---	21.89	19.87	18.22	17.15
592-15CUFF1	E	15	Flange	Yes	1.70 (43.10)	1.80 (45.00)	1.34 (34.10)	1.21 (30.80)	1.35 (34.30)	1.45 (36.80)	21.96	19.94	18.28	17.21
592-15CUFE1	E	15	Flange	Yes	1.73 (43.90)	1.75 (44.50)	1.34 (34.10)	1.11 (28.10)	1.26 (31.90)	1.45 (36.80)	21.89	19.87	18.22	17.15
592-15CUE1	G	15	Snap-In	No	1.73 (43.90)	0.96 (24.60)	1.34 (34.10)	1.06 (26.90)	1.09 (27.60)	---	6.85	6.22	5.70	5.37
592-15CBS1	F	15	Snap-In	No	1.20 (30.60)	0.97 (24.60)	1.34 (34.10)	1.04 (26.40)	1.26 (32.00)	---	7.75	7.04	6.45	6.08
*592-15CUBE1	E	15	Flange	No	1.73 (43.90)	0.96 (24.60)	1.34 (34.10)	1.06 (26.90)	1.09 (27.60)	1.45 (36.80)	7.75	7.04	6.45	6.08
592-15CU1S1	G	15	Snap-In	No	1.20 (30.60)	0.97 (24.60)	1.34 (34.10)	1.05 (26.70)	1.24 (31.60)	---	6.36	5.78	5.30	4.99
592-15CU1BS1	F	15	Snap-In	No	1.20 (30.60)	0.97 (24.60)	1.34 (34.10)	1.05 (26.70)	1.24 (31.60)	---	7.75	7.04	6.45	6.08
592-15CU10S1	G	15	Snap-In	No	1.20 (30.60)	0.97 (24.60)	1.34 (34.10)	1.05 (26.70)	1.24 (31.60)	---	6.36	5.78	5.30	4.99
592-15CU10BS1	F	15	Snap-In	No	1.20 (30.60)	0.97 (24.60)	1.34 (34.10)	1.05 (26.70)	1.24 (31.60)	---	7.75	7.04	6.45	6.08