

# POMONA RF Connectors and Adapters



## Pomona BNC WITHIN SERIES ADAPTERS

• Nickel plated brass For quantities of 100 and up, call for quote.

MOUSER STOCK NO.		Fig.	Description	Insulation	Price Each		
Mfr.	Mfr. Part No.				1	25	50
565—3847		A	BNC Jack/Jack Hermetically sealed 50Ω	PTFE	19.20	18.27	17.33
565—3534		B	BNC Jack/Plug Right Angle 50Ω	PTFE	8.60	8.17	7.76
565—3283		C	BNC Jack/Jack 50Ω	PTFE	5.25	4.97	4.75
565—3284		D	BNC Jack/Jack/Jack 50Ω	PTFE	15.35	14.53	13.89

## Pomona BETWEEN SERIES ADAPTERS AND KITS

• Nickel plating For quantities of 100 and up, call for quote.

MOUSER STOCK NO.		Fig.	Description	Insulation	Price Each		
Mfr.	Mfr. Part No.				1	25	50
<b>Adapters</b>							
565—1269		E	BNC Jack to double stacking banana plug	ABS	7.42	7.24	6.88
565—1270		F	BNC Plug to double stacking banana plug	ABS	10.50	9.98	9.48
565—1452		G	BNC Jack to stackable binding posts	ABS	11.34	10.78	10.23
565—1296		H	BNC Plug to stackable binding posts	ABS	13.70	13.05	12.40
<b>Kits</b>							
565—5748		I	Maxi Universal coaxial RF adapter kit	-	265.65	252.63	240.00
565—5698		I	Universal Adapter Kit	-	178.55	169.62	161.14
565—6254		I	7/16 Din Adapter Kit	-	524.74	499.75	474.76

## Pomona BNC TERMINATIONS, ATTENUATORS, AND WITHIN SERIES ADAPTERS

• Nickel plating For quantities of 100 and up, call for quote.

MOUSER STOCK NO.		Fig.	Description	Price Each		
Mfr.	Mfr. Part No.			1	25	50
<b>Terminations</b>						
565—4119-50		J	BNC Feed-Thru Termination, 50Ω	34.87	33.13	31.47
565—4119-75		K	BNC Feed-Thru Termination, 75Ω	57.50	54.76	52.02
565—5297		J	BNC plug to jack with DC-blocking Series Cap, 1000pF, 600V	29.65	28.24	26.83
<b>Adapters</b>						
565—3846		L	BNC jack to BNC jack, 50Ω	16.70	15.85	15.04
565—3533		M	BNC plug to BNC plug, 50Ω	3.14	2.98	2.83
565—4896		N	BNC Plug/Jack/Jack, 50Ω	13.59	12.94	12.29
565—6700		O	BNC Jack/Plug/Jack, In-line space saving, 50Ω	15.42	14.66	13.91
565—6701		P	BNC Jack/Plug/Jack, Right angle space saving, 50Ω	17.99	17.13	16.27
565—3285		Q	BNC Jack/Plug/Jack, Standard, 50Ω	5.99	5.70	5.41
<b>Attenuators</b>						
565—4108-		R	BNC 50Ω Attenuator	71.00	67.62	64.24

\* (select dB) -3DB, -6DB, -10DB, -14DB, -20DB

## Pomona SMA 50 OHM WITHIN SERIES ADAPTERS & TERMINATORS

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.		Fig.	Description	Insulation	Price Each		
Mfr.	Mfr. Part No.				1	25	50
<b>Adapters</b>							
565—4283		S	SMA plug to SMA plug, gold plated	Teflon	9.23	8.78	8.33
565—4284		T	SMA jack to SMA jack, gold plated	Teflon	9.30	8.86	8.42
565—4282		U	SMA jack to SMA plug, Right Angle, gold plated	Teflon	10.97	10.45	9.93
<b>Terminators</b>							
565—4286		V	SMA Terminator plug, 50Ω, gold plated	Teflon	42.79	40.75	38.71
565—5088		W	SMA Shorting Cap, gold plated	-	19.59	18.66	17.73

## Pomona COAXIAL BETWEEN SERIES ADAPTERS


For quantities of 100 and up, call for quote.

MOUSER STOCK NO.		Fig.	Description	Insulation	Price Each		
Mfr.	Mfr. Part No.				1	25	50
<b>SMA to BNC</b>							
565—4288		X	SMA plug to BNC plug, gold plated	Teflon	9.95	9.48	9.01
565—4289		Y	SMA jack to BNC plug, gold plated	Teflon	8.71	8.28	7.86
565—4290		Z	SMA plug to BNC jack, gold plated	Teflon	8.75	8.56	8.13
565—4291		AA	SMA jack to BNC jack, gold plated	Teflon	7.97	7.57	7.19
<b>SMA to TNC</b>							
565—4292		BB	SMA Plug to TNC Plug, gold plated	PTFE	10.37	9.88	9.39
565—4293		CC	SMA Jack to TNC Plug, gold plated	PTFE	21.37	20.35	19.33
565—4294		DD	SMA Plug to BNC jack, gold plated	PTFE	9.59	9.13	8.67
565—4295		EE	SMA Jack to TNC Plug, gold plated	PTFE	21.08	20.08	19.08
<b>SMA to Type N</b>							
565—4296		FF	SMA Plug to type N Plug, gold plated	PTFE	15.31	14.58	13.85
565—4297		GG	SMA Jack to type N Plug, gold plated	PTFE	17.30	16.46	15.61
565—4298		HH	SMA Plug to type N Jack, gold plated	PTFE	17.45	16.62	15.79
565—4299		II	SMA Jack to type N Jack, gold plated	PTFE	17.45	16.62	15.79
565—5300		JJ	BNC Jack to Plug Triax, nickel plated brass	PTFE	33.46	32.88	30.32

## Pomona AUDIO/VIDEO ADAPTERS

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.		Fig.	Description	Insulation	Price Each		
Mfr.	Mfr. Part No.				1	25	50
565—4054		KK	BNC plug to phono jack, nickel plating	-	17.36	16.47	15.69
565—5319		LL	BNC female to phono plug	-	6.72	6.38	6.06

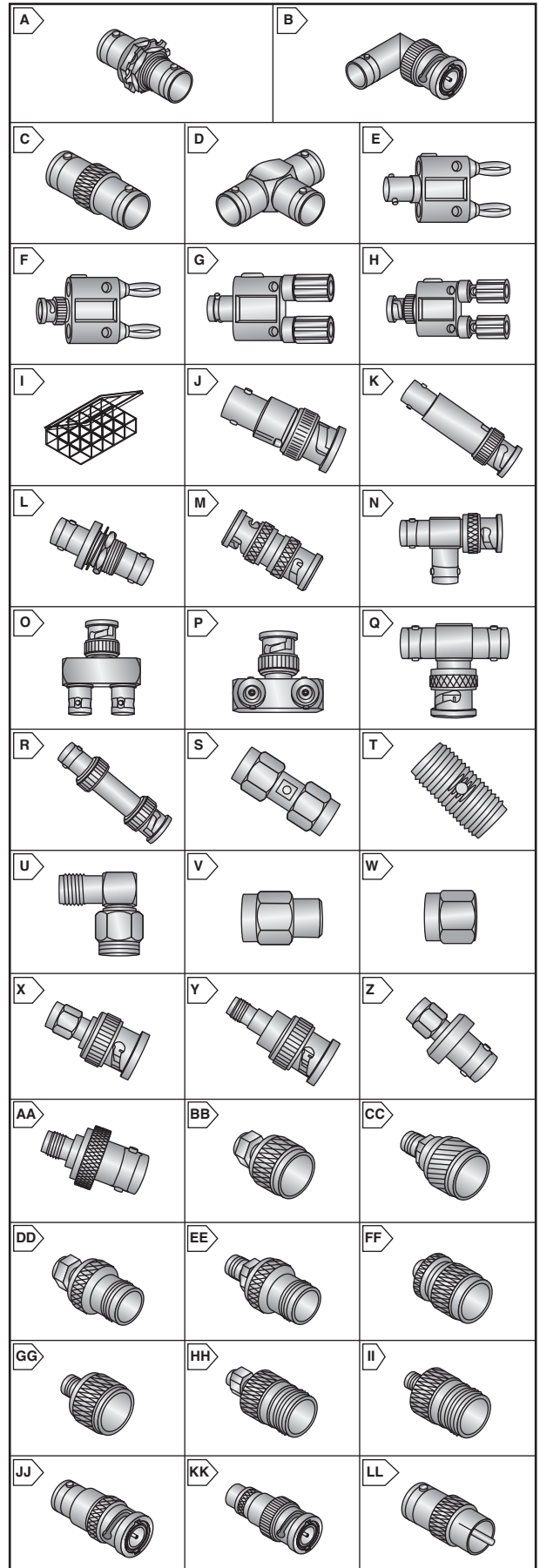

RF Connectors Pomona