


MILL-MAX Spring Loaded Connectors and Contacts



RoHS compliant This product is RoHS compliant.

DIMENSIONS: in. ("A" represents Initial Height, "B" represents Full Stroke)

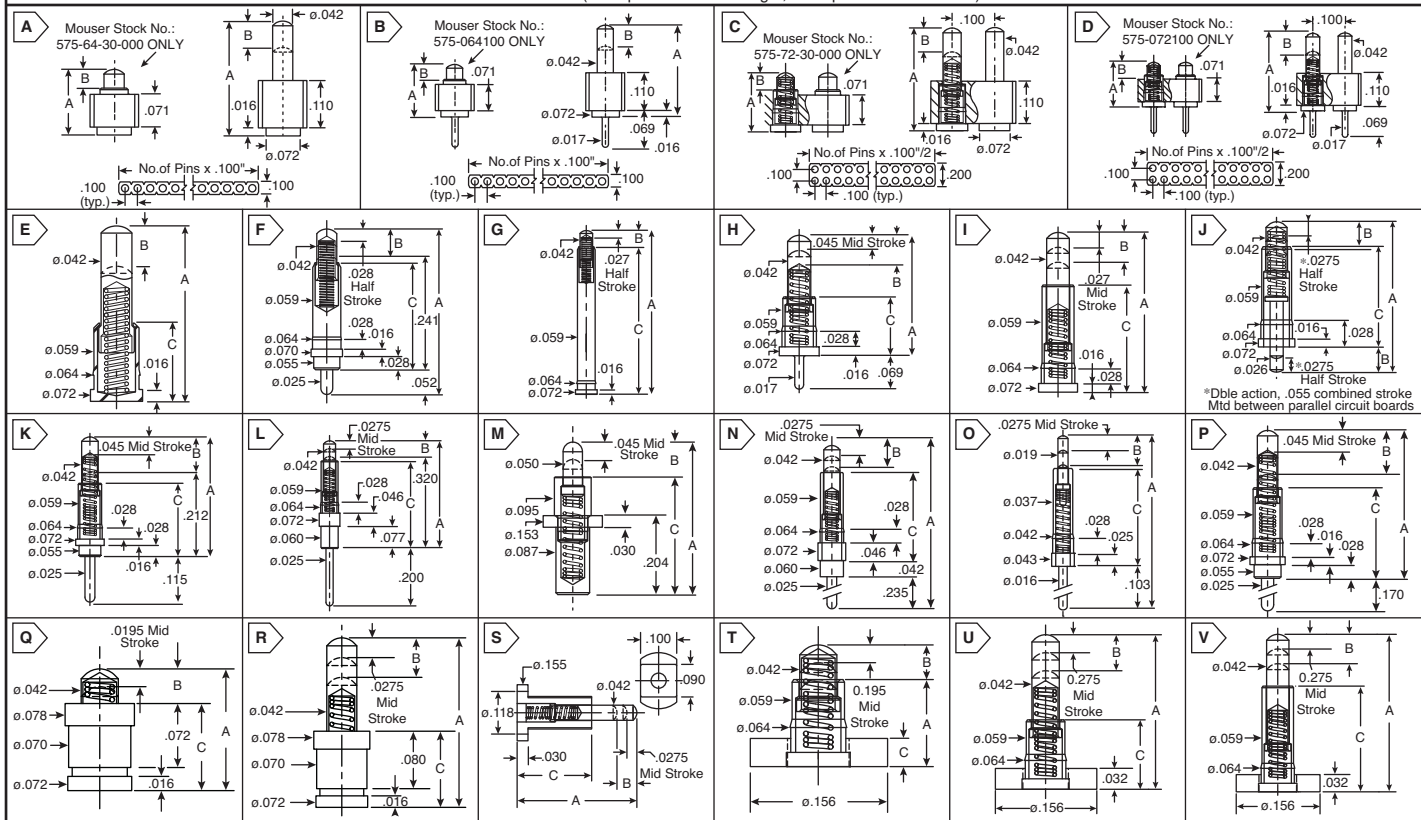

Sockets

.100" SPRING LOADED SURFACE MOUNT CONNECTORS

For quantities of 25 and up, call for quote.

MOUSER STOCK NO.	Mill-Max Part No.	Fig.	Contact	Dimensions: in.			Price Each		
				Initial Ht. A	Stroke B		1	5	10
Single Row									
575-64-30-000	811-22-064-30-000101	A	64	.137	.039		23.58	23.00	21.82
575-64-30-001	811-22-064-30-001101	A	64	.177	.055		23.05	22.48	21.32
575-64-30-002	811-22-064-30-002101	A	64	.197	.055		23.12	22.55	21.38
575-64-30-003	811-22-064-30-003101	A	64	.217	.055		23.19	22.61	21.44
575-64-30-004	811-22-064-30-004101	A	64	.236	.055		23.56	22.97	21.78
575-064100	821-22-064-10-000101	B	64	.137	.039		28.88	26.14	24.75
575-064101	821-22-064-10-001101	B	64	.177	.055		25.38	22.96	21.76
575-064102	821-22-064-10-002101	B	64	.197	.055		25.40	22.98	21.78
575-064103	821-22-064-10-003101	B	64	.217	.055		25.51	23.08	21.86
575-064104	821-22-064-10-004101	B	64	.236	.055		25.91	23.44	22.20

For quantities of 25 and up, call for quote.

MOUSER STOCK NO.	Mill-Max Part No.	Fig.	Contact	Dimensions: in.			Price Each		
				Initial Ht. A	Stroke B		1	5	10
Double Row									
575-72-30-000	813-22-072-30-000101	C	72	.137	.039		26.23	25.57	24.26
575-72-30-001	813-22-072-30-001101	C	72	.177	.055		25.63	24.99	23.70
575-72-30-002	813-22-072-30-002101	C	72	.197	.055		25.71	25.06	23.78
575-72-30-003	813-22-072-30-003101	C	72	.217	.055		25.79	25.14	23.85
575-72-30-004	813-22-072-30-004101	C	72	.236	.055		26.20	25.55	24.23
575-072100	823-22-072-10-000101	D	72	.137	.039		32.18	29.12	27.58
575-072101	823-22-072-10-001101	D	72	.177	.055		40.35	33.62	26.89
575-072102	823-22-072-10-002101	D	72	.197	.055		28.26	25.56	24.23
575-072103	823-22-072-10-003101	D	72	.217	.055		28.38	25.67	24.33
575-072104	823-22-072-10-004101	D	72	.236	.055		28.83	26.08	24.71

DISCRETE SPRING LOADED CONTACTS

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Mill-Max Part No.	Fig.	Dimensions: in.			Price Each			
			A	B	C	1	10	100	200
575-900011	0900-0-00-00-00-00-11-0	E	.137	.039	.098	.47	.40	.34	.30
575-900011	0900-1-00-00-00-00-11-0	E	.177	.055	.106	.46	.39	.33	.29
575-900211	0900-2-00-00-00-00-11-0	E	.197	.055	.106	.46	.39	.33	.29
575-900311	0900-3-00-00-00-00-11-0	E	.217	.055	.106	.46	.40	.33	.29
575-900411	0900-4-00-00-00-00-11-0	E	.236	.055	.106	.47	.41	.34	.30
575-901011	0901-0-00-00-00-00-11-0	F	.348	.055	.226	.59	.51	.42	.37
575-905011	0905-0-00-00-00-00-11-0	G	.638	.055	.638	1.05	.90	.75	.68
575-906015	0906-0-15-20-76-14-11-0	H	.137	.039	.098	.58	.49	.41	.37
575-906115	0906-1-15-20-75-14-11-0	H	.177	.055	.106	.49	.41	.35	.31
575-906215	0906-2-15-20-75-14-11-0	H	.197	.055	.106	.49	.41	.35	.31
575-906315	0906-3-15-20-75-14-11-0	H	.217	.055	.106	.49	.42	.35	.31
575-906415	0906-4-15-20-75-14-11-0	H	.236	.055	.106	.50	.42	.36	.32
575-907011	0907-0-15-20-75-14-11-0	I	.255	.055	.198	.54	.45	.38	.34
575-907111	0907-1-15-20-75-14-11-0	I	.275	.055	.198	.54	.45	.38	.34
575-907211	0907-2-15-20-75-14-11-0	I	.295	.055	.198	.55	.46	.39	.35
575-907311	0907-3-15-20-75-14-11-0	I	.315	.055	.198	.57	.48	.40	.36
575-907411	0907-4-15-20-75-14-11-0	I	.335	.055	.198	.72	.61	.51	.46
575-907511	0907-5-15-20-75-14-11-0	I	.350	.055	.198	.73	.62	.52	.47
575-907611	0907-6-15-20-75-14-11-0	I	.370	.055	.198	.74	.57	.52	.47
575-907711	0907-7-15-20-75-14-11-0	I	.390	.055	.198	.74	.62	.52	.47
575-907811	0907-8-15-20-75-14-11-0	I	.410	.055	.198	.75	.63	.53	.48
575-907911	0907-9-15-20-75-14-11-0	I	.430	.055	.198	.75	.63	.53	.48
575-980011	0980-0-15-20-75-14-11-0	J	.298	.050	.198	.80	.68	.56	.51
575-914015	0914-0-15-20-77-14-11-0	K	.302	.090	.185	.73	.61	.51	.47
575-922015	0922-0-15-20-75-14-11-0	L	.375	.055	.305	.80	.69	.57	.52



For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Mill-Max Part No.	Fig.	Dimensions: in.			Price Each			
			A	B	C	1	10	100	200
575-950152	0850-0-15-20-83-14-11-0	M	.395	.090	.304	1.64	1.13	.91	.85
575-929152	0929-0-15-20-75-14-11-0	N	.575	.055	.228	.88	.78	.64	.59
575-950152	0950-0-15-20-71-14-11-0	O	.351	.055	.186	1.13	1.01	.83	.75
575-932152	0932-0-15-20-77-14-11-0	P	.472	.090	.185	.69	.61	.50	.45
575-910076	0910-0-57-20-76-14-11-0	Q	.137	.039	.098	1.01	.91	.86	.81
575-910175	0910-1-57-20-75-14-11-0	R	.177	.055	.106	1.00	.90	.85	.80
575-910275	0910-2-57-20-75-14-11-0	R	.197	.055	.106	1.00	.90	.85	.80
575-910375	0910-3-57-20-75-14-11-0	R	.217	.055	.106	1.00	.90	.85	.80
575-910475	0910-4-57-20-75-14-11-0	R	.236	.055	.106	1.01	.91	.86	.81
575-967075	0967-0-15-20-75-14-11-0	S	.331	.055	.206	.71	.64	.61	.57
575-990076	0990-0-50-20-76-14-11-0	T	.098	.039	.032	.49	.44	.42	.39
575-990175	0990-1-50-20-75-14-11-0	U	.177	.055	.106	.49	.44	.42	.39
575-990275	0990-2-50-20-75-14-11-0	U	.197	.055	.106	.49	.44	.42	.39
575-990375	0990-3-50-20-75-14-11-0	U	.217	.055	.106	.49	.44	.42	.39
575-990475	0990-4-50-20-75-14-11-0	U	.236	.055	.106	.49	.44	.42	.39
575-990775	0997-0-50-20-75-14-11-0	V	.255	.055	.198	.55	.49	.47	.44
575-997175	0997-1-50-20-75-14-11-0	V	.275	.055	.198	.55	.49	.47	.44
575-997275	0997-2-50-20-75-14-11-0	V	.295	.055	.198	.55	.49	.47	.44
575-997375	0997-3-50-20-75-14-11-0	V	.315	.055	.198	.56	.51	.48	.45
575-997475	0997-4-50-20-75-14-11-0	V	.335	.055	.198	.56	.51	.48	.45
575-997575	0997-5-50-20-75-14-11-0	V	.350	.055	.198	.56	.51	.48	.45
575-997675	0997-6-50-20-75-14-11-0	V	.370	.055	.198	.56	.51	.48	.45
575-997775	0997-7-50-20-75-14-11-0	V	.390	.055	.198	.58	.52	.49	.46
575-997875	0997-8-50-20-75-14-11-0	V	.410	.055	.198	.58	.52	.49	.46
575-997975	0997-9-50-20-75-14-11-0	V	.430	.055	.198	.58	.52	.49	.46

