


# AVAGO Transceivers

Products may be RoHS compliant.  
Check mouser.com for RoHS status.

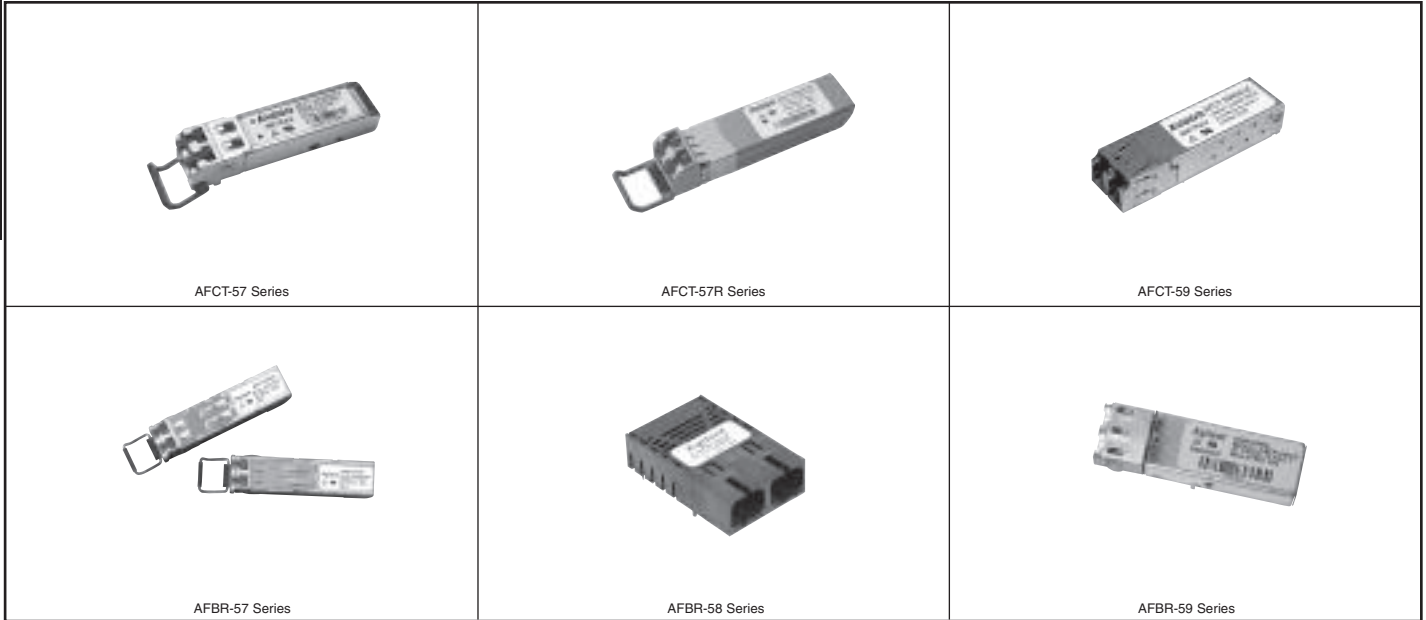

Avago Technologies is the world's leading provider of fiber optic transmitters, receivers and transceivers for Networking and Storage solutions. Avago Technologies offers unmatched quality with high-volume, low-cost manufacturing techniques.

## Fiber Optic Transceivers

Avago Technologies portfolio of optical transceivers include ATM/SONET, Ethernet, Storage, Parallel and WDM Transceivers

Avago Technologies is the leading supplier of fiber optic transceivers, with manufacturing and testing procedures that produce the industry's most reliable devices. Avago's broad portfolio of Ethernet, SONET and Fibre Channel transceivers supports all speeds and includes transmitters and receivers for industrial and automotive applications. The company's support and order fulfillment organizations provide unmatched service and delivery worldwide.

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Avago Part No.	Pkg.	Protocol Support	Media Type	Data Rate (Max.)	Reach	Operating Wavelength	Transmitter	Price Each			
									1	25	100	500
<a href="#">630-AFBR-5103TZ</a>	AFBR-5103TZ	1x9	Ethernet	Multi-mode	100 Mb/s	2km	1310nm	LED	38.00	31.35	28.50	26.60
<a href="#">630-AFBR-5103Z</a>	AFBR-5103Z	1x9	Ethernet	Multi-mode	100 Mb/s	2km	1310nm	LED	38.00	31.35	28.50	26.60
<a href="#">630-AFBR-5803AZ</a>	AFBR-5803AZ	1x9	Ethernet	Multi-mode	100 Mb/s	2km	1310nm	LED	33.00	27.23	24.75	23.10
<a href="#">630-AFBR-5803TZ</a>	AFBR-5803TZ	1x9	Ethernet	Multi-mode	100 Mb/s	2km	1310nm	LED	30.00	24.75	22.50	21.00
<a href="#">630-AFBR-5803Z</a>	AFBR-5803Z	1x9	Ethernet	Multi-mode	100 Mb/s	2km	1310nm	LED	30.00	24.75	22.50	21.00
<a href="#">630-AFBR-5205Z</a>	AFBR-5205Z	1x9	SONET / SDH	Multi-mode	155 Mb/s	2km	1310nm	LED	38.00	31.35	28.50	26.60
<a href="#">630-AFBR-5805Z</a>	AFBR-5805Z	1x9	SONET / SDH	Multi-mode	155 Mb/s	2km	1310nm	LED	30.00	24.75	22.50	21.00
<a href="#">630-AFCT-5805AZ</a>	AFCT-5805AZ	1x9	SONET / SDH	Single-mode	155 Mb/s	15km	1310nm	FP Laser	112.12	92.50	84.09	78.48
<a href="#">630-AFCT-5805BZ</a>	AFCT-5805BZ	1x9	SONET / SDH	Single-mode	155 Mb/s	15km	1310nm	FP Laser	102.38	84.46	76.79	71.67
<a href="#">630-AFBR-5601Z</a>	AFBR-5601Z	GBIC	Ethernet	Multi-mode	1 Gb/s	550m	850nm	VCSEL	70.00	57.75	52.50	49.00
<a href="#">630-AFCT-5611Z</a>	AFCT-5611Z	GBIC	Ethernet	Single-mode	1 Gb/s	10km	1310nm	FP Laser	184.00	151.80	138.00	128.80
<a href="#">630-AFBR-5903AZ</a>	AFBR-5903AZ	SFF	Ethernet	Multi-mode	100 Mb/s	2km	1310nm	LED	58.00	47.85	43.50	40.60
<a href="#">630-AFBR-5903EZ</a>	AFBR-5903EZ	SFF	Ethernet	Multi-mode	100 Mb/s	2km	1310nm	LED	52.00	42.90	39.00	36.40
<a href="#">630-AFBR-5903Z</a>	AFBR-5903Z	SFF	Ethernet	Multi-mode	100 Mb/s	2km	1310nm	LED	47.40	39.11	35.55	33.18
<a href="#">630-HFBR-5912EZ</a>	HFBR-5912EZ	SFF	Ethernet	Multi-mode	1 Gb/s	550m	850nm	VCSEL	96.00	79.20	72.00	67.20
<a href="#">630-HFBR-5961ALZ</a>	HFBR-5961ALZ	SFF	Ethernet	Multi-mode	100 Mb/s	2km	1310nm	LED	61.60	50.82	46.20	43.12
<a href="#">630-AFBR-5921ALZ</a>	AFBR-5921ALZ	SFF	Fibre Channel	Multi-mode	2.125 Gb/s	300m	850nm	VCSEL	47.00	38.78	35.25	32.90
<a href="#">630-AFCT-5961TLZ</a>	AFCT-5961TLZ	SFF	SONET / SDH	Single-mode	155 Mb/s	15km	1310nm	FP Laser	138.00	113.85	103.50	96.60
<a href="#">630-ABCU-5710RZ</a>	ABCU-5710RZ	SFP	Ethernet	Copper	1 Gb/s	100m	- - -	- - -	102.00	84.15	76.50	71.40
<a href="#">630-AFBR-5710PZ</a>	AFBR-5710PZ	SFP	Ethernet	Multi-mode	1 Gb/s	550m	850nm	VCSEL	47.00	38.78	35.25	32.90
<a href="#">630-AFBR-5715LZ</a>	AFBR-5715LZ	SFP	Ethernet	Multi-mode	1 Gb/s	550m	850nm	VCSEL	49.00	40.43	36.75	34.30
<a href="#">630-AFBR-5715PZ</a>	AFBR-5715PZ	SFP	Ethernet	Multi-mode	1 Gb/s	550m	850nm	VCSEL	49.00	40.43	36.75	34.30
<a href="#">630-AFCT-5710PZ</a>	AFCT-5710PZ	SFP	Ethernet	Single-mode	1 Gb/s	10km	1310nm	FP Laser	96.00	79.20	72.00	67.20
<a href="#">630-AFCT-5715PZ</a>	AFCT-5715PZ	SFP	Ethernet	Single-mode	1 Gb/s	10km	1310nm	FP Laser	100.00	82.50	75.00	70.00
<a href="#">630-AFBR-57R5AEZ</a>	AFBR-57R5AEZ	SFP	Fibre Channel	Multi-mode	4.25 Gb/s	150m	850nm	VCSEL	54.50	44.96	40.88	38.15
<a href="#">630-AFBR-57R5APZ</a>	AFBR-57R5APZ	SFP	Fibre Channel	Multi-mode	4.25 Gb/s	150m	850nm	VCSEL	54.50	44.96	40.88	38.15
<a href="#">630-AFBR-57R6AEZ</a>	AFBR-57R6AEZ	SFP	Fibre Channel	Multi-mode	4.25 Gb/s	150m	850nm	VCSEL	57.00	47.03	42.75	39.90
<a href="#">630-AFCT-57R5APZ</a>	AFCT-57R5APZ	SFP	Fibre Channel	Single-mode	4.25 Gb/s	4km	1310nm	Various	200.00	165.00	150.00	140.00
<a href="#">630-AFCT-57R5ATPZ</a>	AFCT-57R5ATPZ	SFP	Fibre Channel	Single-mode	4.25 Gb/s	4km	1310nm	Various	360.00	297.00	270.00	252.00
<a href="#">630-AFCT-5750PZ</a>	AFCT-5750PZ	SFP	SONET / SDH	Single-mode	622 Mb/s	2km, 15km	1310nm	FP Laser	114.00	94.05	85.50	79.80
<a href="#">630-AFCT-5755PZ</a>	AFCT-5755PZ	SFP	SONET / SDH	Single-mode	622 Mb/s	2km, 15km	1310nm	FP Laser	114.00	94.05	85.50	79.80
<a href="#">630-AFCT-5760PZ</a>	AFCT-5760PZ	SFP	SONET / SDH	Single-mode	155 Mb/s	2km, 15km, 40km	1310nm	Various	96.00	79.20	72.00	67.20
<a href="#">630-AFCT-5760TPZ</a>	AFCT-5760TPZ	SFP	SONET / SDH	Single-mode	155 Mb/s	2km, 15km, 40km	1310nm	Various	114.00	94.05	85.50	79.80
<a href="#">630-AFBR-720XPZ</a>	AFBR-720XPZ	XFP	Ethernet	Multi-mode	10.5 Gb/s	300m	850nm	VCSEL	450.00	371.25	337.50	315.00

