


ALCOSWITCH Knobs

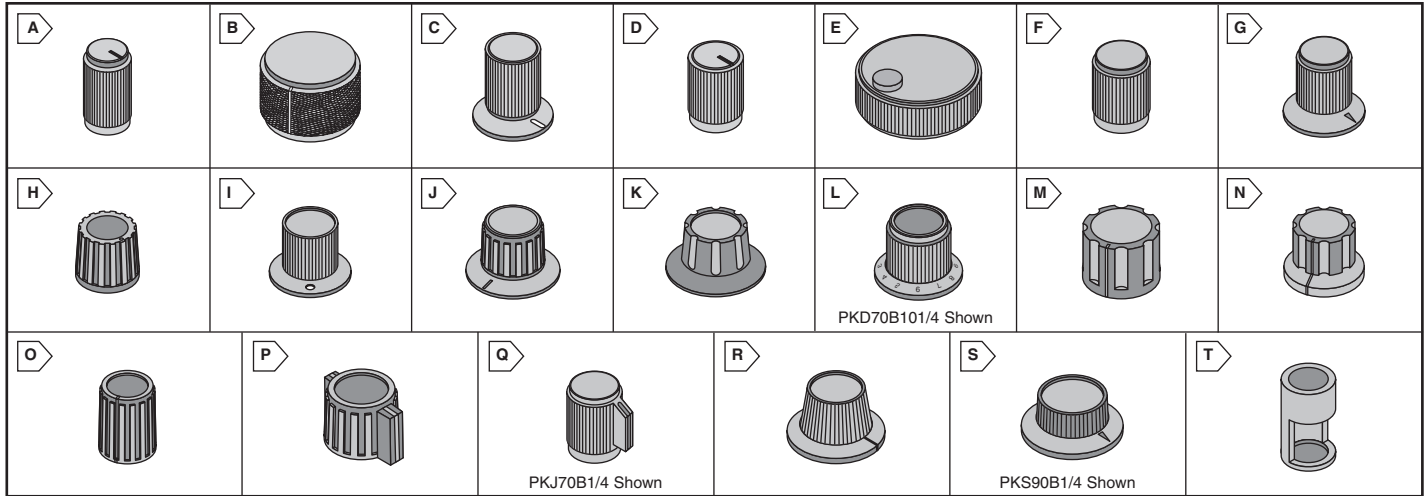

K SERIES MACHINED ALUMINUM CONTROL KNOBS

Specifications:

- Made of machined aluminum alloy stock
- Finish is gloss anodize
- Set screws: steel, type 303, hex head, cup point
- * Parts are Black body with Natural skirt and top.

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Tyco Electronics Part Number	Alcoswitch Part Number	Fig.	Shaft Size	Knurl Type	Knob Color	Description	Diameter: in. (mm)	Height: in. (mm)	Price Each			
										1	10	25	50
506-KB500B1/4	3-1437621-8	KB500B1/4	A	1/4"	Straight	Black	Top line indicator	.500 (12.7)	.787 (20.0)	6.43	5.86	5.52	5.07
506-KB500B1/8	3-1437621-9	KB500B1/8	A	1/8"	Straight	Black	Top line indicator	.500 (12.7)	.787 (20.0)	9.26	8.45	7.96	7.31
506-KD500B1/4	7-1437621-2	KD500B1/4	B	1/4"	Diamond	Black	Side indicator line	.500 (12.7)	.630 (16.0)	6.68	6.01	5.46	5.01
506-KD700B1/4	7-1437621-5	KD700B1/4	B	1/4"	Diamond	Black	Side indicator line	.750 (19.1)	.630 (16.0)	6.68	6.01	5.46	5.01
506-KD1250A-1/4	6-1437621-8	KD1250A1/4	B	1/4"	Diamond	Black	Side indicator line	1.25 (31.8)	.750 (19.1)	16.36	14.92	14.05	12.92
506-KFS400B1/8	8-1437621-6	KFS400B1/8	C	1/8"	Straight	Black	Indicator dot on skirt	.380 (9.65)	.500 (12.7)	8.78	8.01	7.54	6.94
506-KLN1250B1/4	9-1437621-5	KLN1250B1/4	D	1/4"	Straight	Natural	Top and side indicator	1.25 (31.8)	.591 (15.0)	13.51	12.32	11.61	10.66
506-KLN500A1/8	9-1437621-7	KLN500A1/8	D	1/8"	Straight	Black	Top and side indicator	.500 (12.7)	.625 (15.9)	7.52	6.86	6.46	5.94
506-KLN500B1/8	9-1437621-9	KLN500B1/8	D	1/8"	Straight	Natural	Top and side indicator	.500 (12.7)	.625 (15.9)	7.77	7.41	6.98	6.41
506-KLN700A-1/4	1437622-2	KLN700A1/4	D	1/4"	Straight	Black	Top and side indicator	.740 (18.8)	.625 (15.9)	8.72	7.95	7.49	6.88
506-KLN700B1/4	1437622-3	KLN700B1/4	D	1/4"	Straight	Black	Top and side indicator	.740 (18.8)	.625 (15.9)	8.72	7.95	7.49	6.88
506-KLN900B1/4	1437622-7	KLN900B1/4	D	1/4"	Straight	Natural	Top and side indicator	.937 (23.8)	.625 (15.9)	10.37	9.46	8.98	7.94
506-KN1751AS1/4	3-1437622-5	KN1751AS1/4	E	1/4"	Straight	Black	Fingertip spinner	1.75 (44.5)	.620 (15.8)	25.88	23.60	22.24	20.43
506-KN1751BS1/4	3-1437622-8	KN1751BS1/4	E	1/4"	Straight	Black	Fingertip spinner	1.75 (44.5)	.620 (15.8)	25.88	23.60	22.24	20.43
506-KN500A1/4	4-1437622-2	KN500A1/4	F	1/4"	Straight	Natural	Side indicator line	.500 (12.7)	.625 (15.9)	6.20	5.50	5.19	4.75
506-KN500B-1/4	4-1437622-6	KN500B1/4	F	1/4"	Straight	Black	Side indicator line	.500 (12.7)	.625 (15.9)	7.21	6.57	6.19	5.69
506-KN500B1/8	4-1437622-7	KN500B1/8	F	1/8"	Straight	Black	Side indicator line	.500 (12.7)	.625 (15.9)	7.21	6.57	6.19	5.69
506-KN700B1/4	6-1437622	KN700B1/4	F	1/4"	Straight	Black	Side indicator line	.750 (19.1)	.625 (15.9)	9.12	8.32	7.84	7.20
506-KN1250B1/4	2-1437622-7	KN1250B1/4	F	1/4"	Straight	Black	Side indicator line	1.25 (31.8)	.625 (15.9)	13.50	12.61	12.00	11.13
506-KNS501BA1/8	7-1437622-7	KNS501BA1/8	G	1/8"	Straight	Black *	Arrowhead indicator on skirt	.500 (12.7)	.625 (15.9)	10.94	10.42	9.82	9.02
506-KNS701BA1/4	8-1437622	KNS701BA1/4	G	1/4"	Straight	Black *	Arrowhead indicator on skirt	.750 (19.1)	.625 (15.9)	12.92	11.78	11.10	10.20

P SERIES MOLDED PHENOLIC KNOBS

Specifications:

- Made of general purpose phenolic (thermoset)
- Finish is gloss
- Insert is made of Cu alloy
- Set screws: steel, hex head, cup point
- Inlays and skirts are aluminum alloy, spun finish
- Wh. = White; Blk. = Black

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Tyco Electronics Part Number	Alcoswitch Part Number	Fig.	Shaft Size	Knurl Type	Description	Diameter: in. (mm)	Height: in. (mm)	Price Each			
									1	10	25	50
506-PK1100B1/4	1437624-3	PK1100B1/4	H	1/4"	Serrated	Wh. indicator on top & spun alum. inlay	.700 (17.8)	.530 (13.5)	2.23	1.98	1.80	1.73
506-PK50B1/4	1437624-6	PK50B1/4	I	1/4"	Straight	Wh. dot indicator on skirt & spun alum. inlay	.748 (19.0)	.550 (14.0)	2.14	1.89	1.72	1.65
506-PK50B1/8	1437624-7	PK50B1/8	I	1/8"	Straight	Wh. dot indicator on skirt & spun alum. inlay	.748 (19.0)	.550 (14.0)	1.75	1.54	1.40	1.35
506-PK70B1/4	1437624-8	PK70B1/4	I	1/4"	Straight	Wh. dot indicator on skirt & spun alum. inlay	.984 (25.0)	.590 (15.0)	2.88	2.69	2.45	2.35
506-PK90B-1/4	1437624-9	PK90B1/4	I	1/4"	Straight	Wh. dot indicator on skirt & spun alum. inlay	1.25 (31.8)	.595 (15.1)	2.83	2.69	2.45	2.35
506-PKA50B1/4	1-1437624-0	PKA50B1/4	J	1/4"	Ribbed	Wh. line indicator on skirt & spun alum. inlay	.795 (20.2)	.590 (15.0)	1.66	1.47	1.34	1.28
506-PKA50B1/8	1-1437624-1	PKA50B1/8	J	1/8"	Ribbed	Wh. line indicator on skirt & spun alum. inlay	.795 (20.2)	.590 (15.0)	1.66	1.47	1.34	1.28
506-PKA70B1/4	1-1437624-5	PKA70B1/4	J	1/4"	Ribbed	Wh. line indicator on skirt & spun alum. inlay	.980 (24.9)	.750 (19.1)	3.29	2.91	2.65	2.54
506-PKA90B1/4	1-1437624-7	PKA90B1/4	J	1/4"	Ribbed	Wh. line indicator on skirt & spun alum. inlay	1.375 (34.9)	.840 (21.3)	4.37	3.97	3.79	3.41
506-PKB90B1/4	2-1437624-4	PKB90B1/4	K	1/4"	Fluted	Wh. line indicator on skirt & spun alum. inlay	1.50 (38.1)	.820 (20.8)	5.43	4.81	4.57	4.23
506-PKD70B1/4	PKD70B1/4	PKD70B1/4	L	1/4"	Straight	Black arrow indicator on skirt & spun alum. inlay	1.02 (25.9)	.610 (15.5)	2.77	2.60	2.54	2.32
506-PKD70B101/4	3-1437624-2	PKD70B101/4	L	1/4"	Straight	0-10 numerals on skirt & spun alum. inlay	1.02 (25.9)	.610 (15.5)	2.64	2.33	2.12	2.03
506-PKE60B1/4	4-1437624-3	PKE60B1/4	M	1/4"	Fluted	Line indicator on side & spun alum. inlay	.626 (15.9)	.472 (12.0)	3.10	2.80	2.65	2.54
506-PKE90-B	4-1437624-5	PKE90B1/4	M	1/4"	Fluted	Line indicator on side & spun alum. inlay	.890 (22.6)	.512 (13.0)	3.47	3.08	2.80	2.68
506-PKES120B1/4	4-1437624-6	PKES120B1/4	N	1/4"	Fluted	Skirt and wh. indicator line & spun alum. inlay	1.30 (32.9)	.628 (16.0)	3.47	3.08	2.80	2.68
506-PKES60B1/4	5-1437624-0	PKES60B1/4	N	1/4"	Fluted	Skirt and wh. indicator line & spun alum. inlay	.748 (19.0)	.470 (11.9)	2.07	1.83	1.66	1.59
506-PKES60B1/8	5-1437624-1	PKES60B1/8	N	1/8"	Fluted	Skirt and wh. indicator line & spun alum. inlay	.748 (19.0)	.470 (11.9)	2.07	1.83	1.66	1.59
506-PKES90B1/4	5-1437624-3	PKES90B1/4	N	1/4"	Fluted	Skirt and wh. indicator line & spun alum. inlay	1.01 (25.7)	.570 (14.5)	2.39	2.12	1.92	1.84
506-PKG40B1/8	5-1437624-9	PKG40B1/8	O	1/8"	Ribbed	Wh. indicator line & spun alum. inlay	.437 (11.1)	.472 (12.0)	1.57	1.39	1.26	1.21
506-PKG50B1/4	6-1437624	PKG50B1/4	O	1/4"	Ribbed	Wh. indicator line & spun alum. inlay	.551 (14.0)	.512 (13.0)	2.66	2.39	2.17	2.08
506-PKG50B1/8	6-1437624-1	PKG50B1/8	O	1/8"	Ribbed	Wh. indicator line & spun alum. inlay	.551 (14.0)	.512 (13.0)	2.70	2.39	2.17	2.08
506-PKG70B1/8	6-1437624-8	PKG70B1/8	O	1/8"	Ribbed	Wh. indicator line & spun alum. inlay	.740 (18.8)	.559 (14.2)	4.48	4.29	4.11	3.95
506-PKGP-70B-1/4	7-1437624-2	PKGP70B1/4	P	1/4"	Ribbed	Bar pointer, wh. indicator line, & spun alum. inlay	.740 (18.8)	.460 (11.7)	4.99	4.42	4.02	3.86
506-PKJ70B1/4	7-1437624-7	PKJ70B1/4	Q	1/4"	Straight	Bar pointer, wh. indicator line, & spun alum. inlay	.760 (19.3)	.555 (14.1)	3.25	2.79	2.62	2.51
506-PKJ750B1/8	7-1437624-9	PKJ750B1/8	Q	1/8"	Straight	Bar pointer, wh. indicator line, & alum. spin plate	.515 (13.1)	.585 (14.9)	3.18	2.81	2.56	2.46
506-PKS1106B1/4	9-1437624-7	PKS1106B1/4	R	1/4"	Straight	Blk. line indicator on alum. skirt, spun alum. inlay	1.17 (29.6)	.670 (17.0)	5.14	4.89	4.45	4.27
506-PKS1105B101/4	9-1437624-6	PKS1105B101/4	R	1/4"	Straight	Blk. numbers 0-9 on alum. skirt, spun alum. inlay	1.17 (29.6)	.670 (17.0)	5.25	4.89	4.45	4.27
506-PKS90B1/4	1437625-5	PKS90B1/4	S	1/4"	Straight	Blk. arrow indicator on alum. skirt, spun alum. inlay	1.42 (36.1)	.596 (15.1)	3.87	3.68	3.35	3.21
506-PKS90B101/4	1437625-6	PKS90B101/4	S	1/4"	Straight	Blk. numbers 1-10 on alum. skirt, spun alum. inlay	1.42 (36.1)	.596 (15.1)	6.11	5.41	4.92	4.72

ADAPTER

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Tyco Electronics Part Number	Alcoswitch Part Number	Fig.	Description	Diameter: in. (mm)	Height: in. (mm)	Price Each			
							1	10	25	50
506-KR104	1825620-1	KR104	T	Shaft hole adapter, 1/4" to 1/8"	---	---	.85	.77	.73	.67

Alcoswitch

Knobs