


Bumpers and Grommets



This product is RoHS compliant.

3M™ BUMPON PROTECTIVE PRODUCTS

Bump Protective Products are self-sticking polyurethane bumpers that serve as high performance cushions, feet, spacers, and protectors. No need for screws, glue, rivets, or holes of any kind!

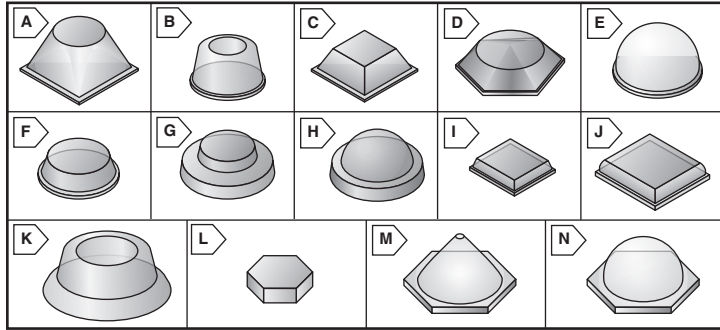


Specifications:

- Non-marring
- Non-slip
- Crack resistant

Note: all dimensions are height x width (inches)

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Fig.	Description	Size	Color	Price Per Indiv. Bumpom			
					1	25	100	500
517-SJ-5514BK	A	Square Base Cone	.52x.81	Black	.66	.56	.50	.47
517-SJ-5514GY	A	Square Base Cone	.52x.81	Gray	.66	.56	.50	.47
517-SJ-5514WH	A	Square Base Cone	.52x.81	White	.66	.56	.50	.47
517-SJ-5009BK	B	Circle Depressed	.40x.88	Black	.59	.48	.41	.34
517-SJ-5009BR	B	Circle Depressed	.40x.88	Brown	.59	.48	.41	.34
517-SJ-5009GY	B	Circle Depressed	.40x.88	Gray	.59	.48	.41	.34
517-SJ-5009WH	B	Circle Depressed	.40x.88	White	.59	.48	.41	.34
517-SJ-5023BK	C	Tapered Square	.30x.81	Black	.33	.25	.20	.15
517-SJ-5023BR	C	Tapered Square	.30x.81	Brown	.33	.25	.20	.15
517-SJ-5023GY	C	Tapered Square	.30x.81	Gray	.33	.25	.20	.15
517-SJ-5023WH	C	Tapered Square	.30x.81	White	.33	.25	.20	.15
517-SJ-5508-BK	C	Tapered Square	.12x.50	Black	.19	.12	.11	.10
517-SJ5508BR	C	Tapered Square	.12x.50	Brown	.19	.12	.11	.10
517-SJ5508GY	C	Tapered Square	.12x.50	Gray	.19	.12	.11	.10
517-SJ5508WH	C	Tapered Square	.12x.50	White	.19	.12	.11	.10
517-SJ5518BK	C	Tapered Square	.23x.50	Black	.25	.22	.20	.16
517-SJ5518BR	C	Tapered Square	.23x.50	Brown	.25	.22	.20	.16
517-SJ5518GY	C	Tapered Square	.23x.50	Gray	.25	.22	.20	.16
517-SJ5518WH	C	Tapered Square	.23x.50	White	.25	.22	.20	.16
517-SJ5523BK	C	Tapered Square	.30x.81	Black	.28	.24	.22	.20
517-SJ5523BR	C	Tapered Square	.30x.81	Gray	.28	.24	.22	.20
517-SJ5523WH	C	Tapered Square	.30x.81	White	.28	.24	.22	.20
517-SJ-5077BK	D	Hexagon	.16x.65	Black	.25	.13	.11	.10
517-SJ-5027BK	E	Hemisphere	.31x.63	Black	.39	.29	.26	.24
517-SJ-5027BR	E	Hemisphere	.31x.63	Brown	.39	.29	.26	.24
517-SJ-5027GY	E	Hemisphere	.31x.63	Gray	.39	.29	.26	.24
517-SJ-5027WH	E	Hemisphere	.31x.63	White	.39	.29	.26	.24
517-SJ-5017BK	E	Large Hemisphere	.38x.75	Black	.48	.37	.34	.31
517-SJ-5017BR	E	Large Hemisphere	.38x.75	Brown	.48	.37	.34	.31
517-SJ-5017GY	E	Large Hemisphere	.38x.75	Gray	.48	.37	.34	.31
517-SJ-5017WH	E	Large Hemisphere	.38x.75	White	.48	.37	.34	.31
517-SJ-5306CL	E	Hemisphere	.15x.375	Clear	.19	.12	.11	.10
517-SJ-5406WH	E	Hemisphere	.15x.375	White	.20	.13	.12	.11
517-SJ-5303CL	E	Small Hemisphere	.20x.44	Clear	.19	.12	.11	.10
517-SJ-5003BK	E	Small Hemisphere	.20x.44	Black	.18	.11	.10	.09
517-SJ-5003BR	E	Small Hemisphere	.20x.44	Brown	.18	.11	.10	.09
517-SJ-5003GY	E	Small Hemisphere	.20x.44	Gray	.18	.11	.10	.09
517-SJ-5003WH	E	Small Hemisphere	.20x.44	White	.18	.11	.10	.09
517-SJ-5412WH	E	Hemisphere	.14x.50	White	.19	.12	.11	.10
517-SJ-6506CL	E	Hemisphere	.15x.375	Clear	.18	.11	.10	.09
517-SJ-5302CL	E	Small Hemisphere	.085x.312	Clear	.18	.11	.10	.09
517-SJ-5744BK	F	Cylindrical	.16x.75	Black	.27	.20	.18	.16
517-SJ5001BK	F	Cylindrical	.14x.50	Black	.21	.18	.15	.13
517-SJ-5012BK	F	Cylindrical	.14x.50	Black	.19	.15	.11	.09
517-SJ-5012BR	F	Cylindrical	.14x.50	Brown	.19	.15	.11	.09
517-SJ-5012GY	F	Cylindrical	.14x.50	Gray	.19	.15	.11	.09
517-SJ-5012WH	F	Cylindrical	.14x.50	White	.19	.15	.11	.09
517-SJ-5312CL	F	Cylindrical	.14x.50	Clear	.19	.15	.11	.09
517-SJ-6512CL	F	Cylindrical	.14x.50	Clear	.18	.14	.10	.08
517-SJ-6115BK	G	Top Hat	.187x.625	Black	.25	.20	.18	.17
517-SJ-6125BK	H	Top Hat	.25x.625	Black	.25	.20	.18	.17
517-SJ-5008BK	I	Tapered Square	.12x.50	Black	.17	.13	.10	.08
517-SJ-5008GY	I	Tapered Square	.12x.50	Gray	.17	.13	.10	.08
517-SJ-5008WH	I	Tapered Square	.12x.50	White	.17	.13	.10	.08
517-SJ-5018BK	I	Tapered Square	.23x.50	Black	.21	.20	.18	.16
517-SJ-5018BR	I	Tapered Square	.23x.50	Brown	.21	.20	.18	.16
517-SJ-5018GY	I	Tapered Square	.23x.50	Gray	.21	.20	.18	.16
517-SJ-5018WH	I	Tapered Square	.23x.50	White	.21	.20	.18	.16
517-SJ-5007BK	I	Tapered Square	.10x.40	Black	.17	.13	.10	.08
517-SJ-5705BK	J	Square	.24x1.25	Black	1.28	.85	.64	.50
517-SJ-5532BK	K	Circle Depressed	.66x1.88	Black	2.38	2.10	1.89	1.70
517-SJ-5532BR	K	Circle Depressed	.66x1.88	Brown	2.38	2.10	1.89	1.70
517-SJ-5532GY	K	Circle Depressed	.66x1.88	Gray	2.38	2.10	1.89	1.70
517-SJ-5532WH	K	Circle Depressed	.66x1.88	White	2.38	2.10	1.89	1.70
517-SJ-5201BR	L	Hexagon	.125x.433	Brown	.12	.10	.07	.05
517-SJ-5202BR	L	Hexagon	.063x.433	Brown	.12	.10	.06	.05
517-SJ-6553CL	M	Hexagonal Cone	.12x.433	Clear	.13	.11	.10	.09
517-SJ-6561CL	N	Hex Base Hemisphere	.15x.433	Clear	.15	.12	.09	.09

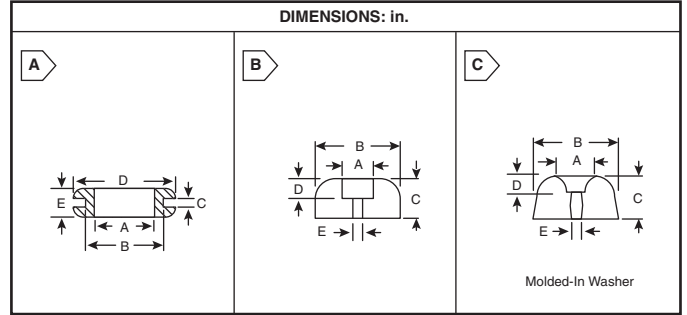

BUMPERS AND GROMMETS

Rubber Grommets

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Dimensions (In.)					Price Each		
		A	B	C	D	E	1	1000	2500
534-730	A	.125	.187	.062	.312	.187	.12	.09	.07
534-733	A	.125	.250	.062	.343	.187	.11	.09	.05
534-734	A	.125	.437	.062	.625	.187	.89	.47	.43
534-735	A	.125	.375	.093	.500	.312	.36	.17	.16
534-736	A	.187	.312	.062	.437	.218	.11	.07	.05
534-731	A	.187	.312	.062	.437	.218	.14	.07	.05
534-737	A	.187	.281	.093	.437	.218	.28	.13	.123
534-738	A	.250	.437	.062	.625	.187	.23	.13	.12
534-739	A	.250	.375	.062	.562	.250	.17	.07	.06
534-740	A	.250	.375	.093	.500	.250	.21	.13	.11
534-741	A	.312	.562	.062	.812	.312	.39	.24	.221
534-742	A	.312	.437	.062	.625	.281	.16	.10	.09
534-743	A	.312	.437	.093	.625	.312	.24	.15	.13
534-744	A	.375	.625	.062	.875	.312	.51	.26	.24
534-745	A	.375	.500	.062	.625	.250	.16	.08	.07
534-732	A	.437	.562	.062	.750	.250	.20	.12	.09
534-746	A	.437	.687	.062	.937	.312	.58	.29	.282
534-747	A	.500	.812	.062	1.062	.312	.48	.30	.27
534-749	A	.500	.750	.093	.968	.281	.31	.11	.10
534-750	A	.562	.812	.062	1.062	.312	.69	.36	.33
534-752	A	.625	.875	.062	1.125	.312	.32	.20	.192
534-753	A	.625	1.250	.062	1.500	.250	1.02	.54	.50
534-755	A	.750	1.062	.062	1.375	.375	1.05	.55	.51
534-756	A	.750	1.437	.062	1.812	.375	2.06	1.34	1.24
534-757	A	.875	1.250	.062	1.625	.437	1.58	.80	.78

Rubber Bumpers

For quantities greater than listed, call for quote.


MOUSER STOCK NO.	Fig.	Screw Size	Dimensions (In.)					Price Each		
			A	B	C	D	E	1	100	1000
534-720	B	4	.25	.50	.25	.187	.125	.14	.11	.08
534-721	B	4	.25	.625	.312	.187	.125	.35	.21	.14
534-722	B	4	.25	.718	.437	.218	.125	.80	.40	.22
534-723	C	8	.375	.937	.375	.187	.187	.77	.41	.21

RUBBER GROMMETS

Designed for insulating sharp edged holes to protect electrical cables and tubing.


For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Dimensions: in.					Price Each		
		A	B	C	D	E	1	1000	2500
5167-208	A	9/32	1/16	9/16	1/4	3/8	.08	.06	.05
5167-211	A	3/16	1/16	7/16	1/4	5/16	.07	.05	.04
5167-159	B	1/4	1/16	5/8	3/8	7/16	.12	.08	.07
5167-210	A	3/8	1/16	5/8	1/4	1/2	.08	.06	.05

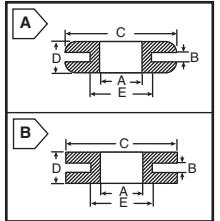

BUMPERS

Available in black or gray.
Replace the () in the part number with:
B for Black or G for Medium Gray

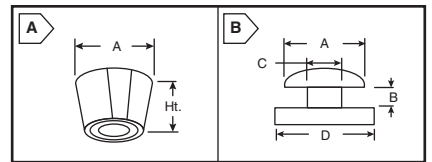

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Dimensions: in.				Screw Size	Price Each	
		A	B	C	D		1	100
Vinyl								
5162-F4	A	.562	.375	----	----	4	.36	.31
5162-F6	A	.750	.437	----	----	6	.37	.32
5162-F8	A	.937	.625	----	----	8	.57	.46
5162-SF6	A	.687	.250	----	----	6	.34	.28
5162-SF8	A	.875	.312	----	----	8	.40	.35
5162-SF10	A	1.062	.437	----	----	10	.62	.46
Rubber								
5167-202	B	5/16	3/64	1/4	7/16	----	.09	.06