

BUD Cabinet Racks and Accessories




BUD ECONOMIZER™ CABINET RACK

"Shipped Factory Direct"

High quality, low cost. 19" panel width in both ventilated (side and doors feature ventilating louvers) and non-ventilated versions. 24" panel width also available. Welded frame has 14-gauge steel vertical rails and 16-gauge steel top and bottom, with uniquely designed, 16-gauge steel rail supports. Furnished complete with removable sides, rear door, and one pair of fully adjustable panel mounting rails (some accessories require two pairs of rails). Side panels are 20-gauge steel, and removable from outside for easy access. Panel mounting rails are 12-gauge steel. Bottom is pierced for casters with one 9.56" square hole and four 1.11" knockouts for cable access.

Three colors available, replace () in the part number with: **S** for Sand Textured, **RB** for Royal Blue, or **BT** for Black Textured

Ventilated			Non-Ventilated			Dimensions: in.		Panel Space (In.)
MOUSER STOCK NO.	Bud Part No.	Price Each	MOUSER STOCK NO.	Bud Part No.	Price Each	H	D	
563-ER-16602-	ER-16602-	745.09	563-ER-16502-	ER-16502-	659.43	47.31	18.50	42.00
563-ER-16603-	ER-16603-	767.89	563-ER-16503-	ER-16503-	725.39	57.81	18.50	52.50
563-ER-16604-	ER-16604-	826.67	563-ER-16504-	ER-16504-	778.61	66.56	18.50	61.25
563-ER-16605-	ER-16605-	871.94	563-ER-16505-	ER-16505-	825.02	75.31	18.50	70.00
563-ER-16606-	ER-16606-	902.46	563-ER-16506-	ER-16506-	860.24	84.06	18.50	78.75
563-ER-16612-	ER-16612-	795.11	563-ER-16512-	ER-16512-	746.59	47.31	25.50	42.00
563-ER-16613-	ER-16613-	826.96	563-ER-16513-	ER-16513-	779.21	57.81	25.50	52.50
563-ER-16614-	ER-16614-	898.79	563-ER-16514-	ER-16514-	852.29	66.56	25.50	61.25
563-ER-16615-	ER-16615-	935.76	563-ER-16515-	ER-16515-	890.04	75.31	25.50	70.00
563-ER-16616-	ER-16616-	986.87	563-ER-16516-	ER-16516-	941.91	84.06	25.50	78.75
563-ER-16622-	ER-16622-	842.24	563-ER-16522-	ER-16522-	779.44	47.31	30.75	42.00
563-ER-16623-	ER-16623-	878.39	563-ER-16523-	ER-16523-	815.56	57.81	30.75	52.50
563-ER-16624-	ER-16624-	973.14	563-ER-16524-	ER-16524-	910.29	66.56	30.75	61.25
563-ER-16625-	ER-16625-	995.94	563-ER-16525-	ER-16525-	933.14	75.31	30.75	70.00
563-ER-16626-	ER-16626-	1082.52	563-ER-16526-	ER-16526-	1016.86	84.06	30.75	78.75

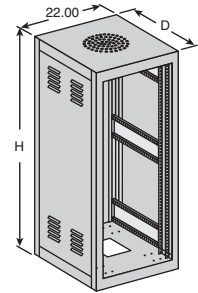

DIMENSIONS: in.

BUD ECONOMIZER STEEL DOORS

"Shipped Factory Direct"

Material: • 20 gauge steel

There are three colors available,

replace the () in the part number with: **S** for Sand Textured, **BT** for Black Textured or **RB** for Royal Blue Textured

Ventilated			Non-Ventilated			Height (In.)
MOUSER STOCK NO.	Bud Part No.	Price Each	MOUSER STOCK NO.	Bud Part No.	Price Each	
563-ER-16592-	ER-16592-	222.98	563-ER-16532-	ER-16532-	199.75	41.94
563-ER-16593-	ER-16593-	237.38	563-ER-16533-	ER-16533-	214.15	52.44
563-ER-16594-	ER-16594-	265.13	563-ER-16534-	ER-16534-	241.98	61.19
563-ER-16595-	ER-16595-	279.15	563-ER-16535-	ER-16535-	255.85	69.94
563-ER-16596-	ER-16596-	288.15	563-ER-16536-	ER-16536-	264.93	78.69

BUD ECONOGLAS DOORS

"Shipped Factory Direct"

For Series 2000, Series 60, LPR, Classic II, and Economizer Upright Cabinet Racks.

Design Features:

- Aluminum frame door with gasketed, .18" thick Smoke Gray Plastic insert.
- Can be used in place of a normal steel door. Comes standard with keylock.

MOUSER STOCK NO.	Bud Part No.	Height (In.)	Price Each
563-V9763L	V-9763-L	41.94	190.20
563-V9764-L	V-9764-L	52.44	244.95
563-V9765-L	V-9765-L	61.19	245.90
563-V9766-L	V-9766-L	69.94	252.75
563-V9767-L	V-9767-L	78.69	307.55


BUD SERVER RACKS

"Shipped Factory Direct"

Design Features:

- Extra deep 36" and 43" cabinets accept most manufacturer's servers.
- Front Econoglas door is ventilated.
- Cable access in both top and bottom of cabinet
- Perforated side panels, 36% open, and rear door, 27% open, provide for maximum air flow.
- Comes with internal grounding studs.
- Comes complete with two pairs of fully-adjustable universal spacing mounting rails that accept #12-24 and #M-6 cage nuts.
- Ventilated top can be used with optional exhaust fans (Bud FN-1282)

MOUSER STOCK NO.	Bud Part No.	Panel Space (In.)	Dimensions: in. H x W x D	Max. Clear Inside Depth	Price Each
563-DC-8105	DC-8105	78.75 x 19.00	84.06 x 24 x 35.43	33.94	2192.93
563-DC-8110	DC-8110	78.75 x 19.00	84.06 x 24 x 41.82	41.82	2279.31

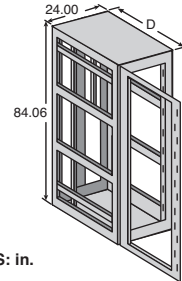

DIMENSIONS: in.

BUD ACCESSORIES FOR ECONOMIZER AND SERVER CABINET RACKS

MOUSER STOCK NO.	Description	For Cabinet Rack		Price Each
		Economizer	Server Rack	
563-FN-1282	10" Cabinet Fan	•	•	134.70
563-FN-1280	4.5" Muffin Fan	•	•	37.50
563-FN-1170-WH	White Fan Tray	•	•	176.63
563-FN-1170-MG	Gray Fan Tray	•	•	176.65
563-B-60	3.50" Blower	•	•	470.66
563-RL-7767	Levelers, Nylon	•	•	4.60
563-RL-7771	Levelers, Rubber	•	•	5.00
563-RC-7758	Castors, 200 # (pair)	•	•	32.90
563-RC-7761	Castors, 240 # with Brake (pair)	•	•	77.50
563-RC-7762	Castors, 240 # without Brake (pair)	•	•	67.00

Sliding Mechanisms

MOUSER STOCK NO.	Description	Economizer	Server Rack	Price Each
563-AS-5000-A	2-piece, 12" Slide Length (pair)	•	•	25.45
563-AS-5001-A	2-piece, 16" Slide Length (pair)	•	•	33.50
563-AS-5002-A	2-piece, 20" Slide Length (pair)	•	•	35.09
563-AS-5004-A	2-piece, 26" Slide Length (pair)	•	•	38.75
563-AS-5042-A	3-piece, 20" Slide Length (pair)	•	•	76.00
563-BAS-5106	Slide Brackets (mounting bracket kit)	•	•	25.56

Panel Mounting Rails

MOUSER STOCK NO.	Description	Economizer	Server Rack	Price Each
563-PMR-9448	Fits 21.00" Panel Space (pair)	•	•	60.30
563-PMR-2331	Fits 24.50" Panel Space (pair)	•	•	51.20
563-PMR-9449	Fits 31.50" Panel Space (pair)	•	•	68.65
563-PMR-9450	Fits 42.00" Panel Space (pair)	•	•	74.40
563-PMR-9451	Fits 52.50" Panel Space (pair)	•	•	82.45
563-PMR-9452	Fits 61.25" Panel Space (pair)	•	•	92.20
563-PMR-9453	Fits 71.00" Panel Space (pair)	•	•	100.80
563-PMR-9454	Fits 78.75" Panel Space (pair)	•	•	106.85
563-PMR9483	L-Shaped Fits 70.00" (pkg. of 4)	•	•	169.35
563-PMR-9484	L-Shaped Fits 78.75" (pkg. of 4)	•	•	179.30
563-7346	Screws for Rails	•	•	.10

Power Outlet Strips See Accessory Pages for a complete listing of Power Outlet Strips

MOUSER STOCK NO.	Description	Economizer	Server Rack	Price Each
563-POS-194-S	19" Rear Rack Mount	•	•	53.55
563-POS-195-S	19" Front Rack Mount	•	•	57.75

Stationary Shelves See Accessory Pages for a complete listing of Stationary Shelves

MOUSER STOCK NO.	Description	For Cabinet Rack		Price Each
		Economizer	Server Rack	
563-SA-1719-GT	16" Gray	•	•	93.75
563-SA-1720-RB	20" Blue	•	•	94.55
563-SA-1278-BT	16" x 17.62" Black, Adjustable	•	•	101.00
563-SA-1279-MG	20" x 17.62" Gray, Adjustable	•	•	108.90
563-SA-1378-BT	16" x 21.62" Black, Adjustable	•	•	101.59
563-SA-1379-MG	20" x 21.62" Gray, Adjustable	•	•	96.80
563-SH-2383	Vented 19" x 17"	•	•	59.50
563-SH-2381	Non-Vented 19" x 24"	•	•	72.29
563-SA-1750-BT	19" Non-Vented Black, 15" x 17.62"	•	•	61.45
563-SA-1751-MG	19" Vented Gray, 15" x 17.62"	•	•	67.15
563-SA-1775-BT	Keyboard Mouse Shelf	•	•	71.50

Sliding Shelves

MOUSER STOCK NO.	Description	For Cabinet Rack		Price Each
		Economizer	Server Rack	
563-SH-2391	Vented 19" x 17"	•	•	102.45
563-SH-2393	Vented 19" x 24"	•	•	115.25
563-SH-2388	Non-Vented 19" x 20.5"	•	•	107.90
563-SH-2390	Non-Vented 19" x 29.25"	•	•	122.50
563-KS1785BT	19" Keyboard/ Mouse, Black	•	•	165.33
563-KS-1787-MG	23" Keyboard/ Mouse, Gray	•	•	181.58
563-KS-1788	Keyboard Shelf	•	•	163.30
563-60-2361-BT	19" Desktop	•	•	160.83

Drawers

MOUSER STOCK NO.	Description	Economizer	Server Rack	Price Each
563-DD-2363BT	19" Desktop, Black	•	•	251.80
563-DD-2363-MG	19" Desktop, Gray	•	•	251.80
563-D-1722-WH	19" White, 16.18" Deep	•	•	248.35
563-D-1722-BT	19" Black, 16.18" Deep	•	•	248.35
563-D-1722-MG	19" Gray, 16.18" Deep	•	•	248.35
563-D-1723-WH	19" White, 19.18" Deep	•	•	257.85
563-D-1723-BT	19" Black, 19.18" Deep	•	•	257.85
563-D-1723-MG	19" Gray, 19.18" Deep	•	•	257.85