


# APC UPS Systems

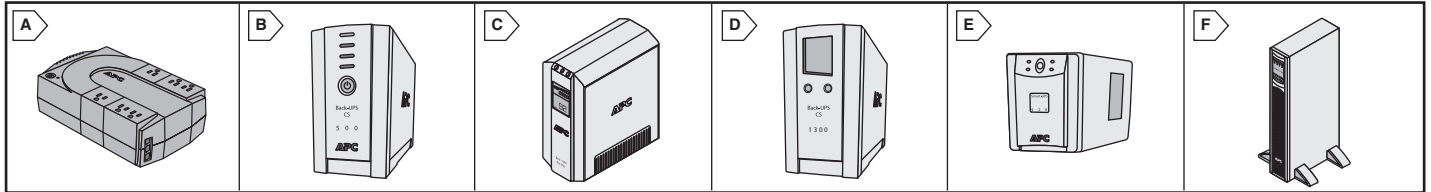

## APC BACK-UPS

Back up power solutions from desktop to datacenter to custom-built industrial UPS system

- Input / Output Volts = 120V / 120V
- Input Plug - NEMA 5-15P
- SMT2200 - NEMA 5-20P
- SMT3000 - NEMA L5-30P



For quantities of 2 and up, call for quote.

MOUSER STOCK NO.	APC Part No.	Fig.	No. of Outlets	Model	Dimensions: H x W x D in.	Output Power Capacity	Recommended Replacement Battery	Backup Time Half/Full Load	Price Each
679-BE350G	BE350G	A	6	Back-UPS ES	3.50 x 6.25 x 11.00	350VA / 200W	RBC35	9.7min. / 2.3 min.	53.20
679-BE450G	BE450G	A	8	Back-UPS ES	3.50 x 7.00 x 12.00	450VA / 257W	- - -	11.6min / 2.5 min.	64.40
679-BE550G	BE550G	A	8	Back-UPS ES	3.50 x 7.00 x 12.00	550VA / 330W	APCRBC110	13.5min / 3.3 min.	70.70
679-BE750G	BE750G	A	10	Back-UPS ES	3.48 x 7.09 x 13.49	725VA / 450W	RBC17	11.3min. / 2.3 min.	105.00
679-BK350	BK350	B	6	Back-UPS CS	6.50 x 3.60 x 11.20	350VA / 210W	RBC2	18.1min / 4.7 min.	88.20
679-BK500	BK500	B	6	Back-UPS CS	6.50 x 3.60 x 11.20	500VA / 300W	RBC2	13.9min. / 3.4 min.	131.18
679-BR700G	BR700G	C	6	Power-Saving Back-UPS RS	7.48 x 3.58 x 12.20	700VA / 450W	RBC17	12.0min. / 3.0 min.	130.00
679-BR1200	BR1200	B	8	Back-UPS RS	14.60 x 3.40 x 13.10	1200VA / 780W	RBC33	17.4min. / 6.2 min.	209.44
679-BR1500	BR1500	B	8	Back-UPS RS	14.60 x 3.40 x 13.10	1500VA / 865W	RBC33	15.4min. / 5.1 min.	255.08
679-BR1500LCD	BR1500LCD	D	8	Back-UPS RS	8.75 x 5.25 x 14.00	1500VA / 865W	APCRBC109	13.4min / 3.3 min.	238.14
679-SC420	SC420	E	4	Smart-UPS SC	6.60 x 4.70 x 14.50	420VA / 260W	RBC2	13.5min. / 5.5 min.	133.00
679-SC620	SC620	E	4	Smart-UPS SC	6.60 x 4.70 x 14.50	620VA / 390W	RBC48	15.7min. / 5.5 min.	201.60
679-SMT750	SMT750	C	6	Power-Saving Smart-UPS	6.30 x 5.40 x 14.10	750VA / 500W	RBC48	15.9min. / 4.6 min.	320.00
679-SMT1000	SMT1000	C	8	Power-Saving Smart-UPS	8.50 x 6.70 x 17.30	1000VA / 670W	RBC6	20.6min. / 6.1 min.	459.00
679-SMT1500	SMT1500	C	8	Power-Saving Smart-UPS	8.50 x 6.70 x 17.30	1440VA / 980W	RBC7	23.9min. / 6.7 min.	559.00
679-SMT2200	SMT2200	C	*10	Power-Saving Smart-UPS	17.00 x 7.70 x 21.50	2200VA / 1980W	RBC55	24.0min. / 7.0 min.	965.25
679-SMT3000	SMT3000	C	*10	Power-Saving Smart-UPS	17.00 x 7.70 x 21.50	3000VA / 2700W	RBC55	14.0min. / 6.0 min.	1224.78
679-SMX750	SMX750	F	8	Power-Saving Smart-UPS	17.00 x 3.50 x 19.30	750VA / 500W	APCRBC116	24.0min. / 12.0 min.	490.00
679-SMX1000	SMX1000	F	8	Power-Saving Smart-UPS	17.00 x 3.50 x 19.30	1000VA / 800W	APCRBC116	20.0min. / 8.0 min.	600.00
679-SMX1500RM2U	SMX1500RM2U	F	8	Power-Saving Smart-UPS	3.50 x 17.00 x 19.30	1500VA / 1200W	APCRBC115	14.0min. / 5.0 min.	779.00



\*10 Output Connections: (8) NEMA 5-12R & (2) NEMA 5-20R

## APC UPS REPLACEMENT BATTERY CARTRIDGES

For quantities of 2 and up, call for quote.

• Other options available, contact a Mouser Representative

MOUSER STOCK NO.	APC Part No.	Replaces Batteries in Models	Price Each
679-RBC2	RBC2	BK200, BK250B, BK280B, BK280, BP280, BP280PNP, BP280C, BP280S, BK300 BK350, BK400, BK400B, BP420S, SU420NET, BK500, BE500U, BK500M BK650MC, BP650C, BP650PNP, BP650S, SU620NET BP1000, SUVS1000, SU1000, SUA1000, SU1000NET SU700XL, SU1000XL, BP1400, SU1400, SUA1500	41.10
679-RBC4	RBC4		65.76
679-RBC6	RBC6		157.55
679-RBC7	RBC7		183.58

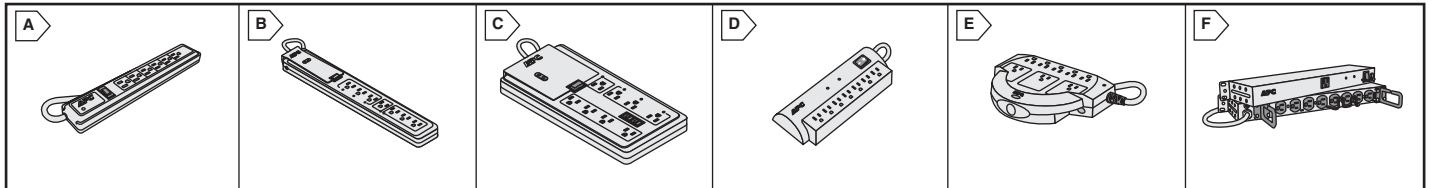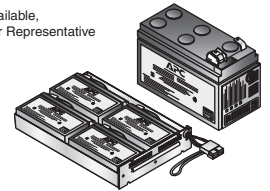

## APC SURGE PROTECTION AND CONDITIONING

Safeguard your equipment from everyday power surges, lightning strikes and other power anomalies



For quantities of 2 and up, call for quote.

MOUSER STOCK NO.	APC Part No.	Fig.	No. of Outlets	Category	Description	Price Each
679-P7T	P7T	A	7	Basic Surge Protectors - A	420joules, data line protection, 6' cord, black	14.00
679-P7GB	P7GB	B	7	Power-Saving Essential SurgeArrest	1020joules, "power-saving" outlets, data line protection, 4' cord, white	24.99
679-P8GT	P8GT	C	8	Power-Saving Home/Office SurgeArrest	w/ phone protection	29.99
679-PER7	PER7	D	7	SurgeArrest Personal	420joules, beige	11.90
679-PRO7	PRO7	D	7	SurgeArrest Professional	320joules, beige	22.79
679-PRO7T	PRO7T	D	7	SurgeArrest Professional	320joules, data line protection, beige	27.93
679-PRO8	PRO8	E	8	SurgeArrest Professional	320joules, beige	24.99
679-NET7	NET7	D	7	SurgeArrest Network	480joules, beige	24.99
679-NET8N	NET8N	E	8	SurgeArrest Network	480joules, 10base-T token ring protection, beige	39.69
679-NET9RMBLK	NET9RMBLK	F	9	SurgeArrest Rack Mountable	480joules, horizontal or vertical mount, beige	98.00

## APC LINE-R-HIGH PERFORMANCE POWER CONDITIONING

## APC PROTECTNET DATA LINE PROTECTORS



For quantities of 2 and up, call for quote.



For quantities of 2 and up, call for quote.

MOUSER STOCK NO.	APC Part No.	Description	Price Each	MOUSER STOCK NO.	APC Part No.	Description	Price Each
679-LE600	LE600	600VA, 4NEMA 5-15R	43.37	679-PNET1GB	PNET1GB	RJ45 10/100/1000 Base-T ethernet prot.	23.52
679-LE1200	LE1200	1200VA, 4 NEMA 5-15R	54.03	679-PTEL2	PTEL2	RJ45 modem/fax/DSL protection	22.05
				679-PV	PV	Cable modem/DSS cont. box/cable/VCR	22.40

© Copyright 2010 Mouser Electronics

© Copyright 2010 Mouser Electronics