

TRIPP LITE Power Protection Solutions



TRIPP LITE DIGITAL UPS SYSTEMS

- Features:**
- Rotatable LCD Status Screen
 - 8 outlets safeguard an entire computer or home entertainment center
 - Power button offers convenient, one-touch power control
 - Up to \$250,000 Ultimate Lifetime Insurance



RoHS Compliant

This product is RoHS compliant.



For quantities of 2 and up, call for quote.

MOUSER STOCK NO.	Tripp Lite Part Number	VA/W	Outlets	Comm. Ports	1/2 Load Runtime	Price Each
545-OMNI650LCD	OMNI650LCD	650/350	8	1 USB	15 min.	132.00
545-SMART1500LCD	SMART1500LCD	1500/900	8	1 USB	17 min.	286.81

TRIPP LITE MEDICAL-GRADE ISOLATION TRANSFORMERS

- Features:**
- UL-60601-1 listed for use in patient care areas
 - Full isolation protects medical equipment and computers
 - Hospital-grade (HG) plug and receptacles
 - Faraday shielding reduces cumulative leakage current to less than 300mA



RoHS Compliant



 
MOUSER STOCK NO.	Tripp Lite Part Number	Output Capacity	Outlets	Price Each
545-IS250HG	IS250HG	250W	2	203.00
545-IS500HG	IS500HG	500W	4	297.00
545-IS1800HG	IS1800HG	1800W	6	675.00

TRIPP LITE INTERNET OFFICE® DESKTOP AND TOWER STANDBY UPS SYSTEMS

- Features:**
- Reliable battery backup plus AC line and phone/DSL surge suppression
 - Up to 8 outlets (4 UPS/surge, 4 surge-only) protect an entire setup, including printers and other heavy-draw devices
 - Communication port and FREE PowerAlert software (web download) enable unattended system shutdown
 - Up to \$150,000 Ultimate Lifetime Insurance



RoHS Compliant



For quantities of 2 and up, call for quote.

MOUSER STOCK NO.	Tripp Lite Part Number	VA/W	Outlets	Comm. Ports	1/2 Load Runtime	Price Each
Desktop Models						
545-INTERNET350U	INTERNET350U	350/180	8+tel/DSL	1 USB	12 min.	48.00
545-INTERNET550U	INTERNET550U	550/300	8+tel/DSL	1 USB	10 min.	73.00

TRIPP LITE BC SERIES TOWER STANDBY UPS SYSTEMS

- Features:**
- Basic standby battery backup for personal computers
 - BCPRO models include a USB port that works with FREE PowerAlert software (web download) for unattended shutdown
 - Up to \$200,000 Ultimate Lifetime Insurance



RoHS Compliant



For quantities of 2 and up, call for quote.

MOUSER STOCK NO.	Tripp Lite Part Number	VA/W	Outlets	Comm. Ports	1/2 Load Runtime	Price Each
BC Personal® UPS Systems						
545-300	BCPERS300	300/175	3	--	17 min.	96.46
BC Pro® UPS Systems						
545-600	BCPRO600	600/345	6 + tel/DSL	1 USB	19 min.	143.87

TRIPP LITE VS SERIES TOWER LINE-INTERACTIVE UPS SYSTEMS

- Features:**
- Up to 8 outlets (6 UPS/surge, 2 surge-only) protect an entire computer setup, including printers and heavy-draw devices
 - Automatic voltage regulation ensures connected equipment receives constant, 120V computer-grade power
 - Built-in tel/DSL or tel/DSL/Ethernet jacks
 - USB port and FREE PowerAlert software (web download) provide unattended system shutdown
 - Extended runtime capability (OMNIVS1500XL only)
 - \$200,000 Ultimate Lifetime Insurance



RoHS Compliant



For quantities of 2 and up, call for quote.


MOUSER STOCK NO.	Tripp Lite Part Number	VA/W	Outlets	Comm. Ports	1/2 Load Runtime	Price Each
545-OMNIVS800	OMNIVS800	800/475	7+tel/DSL	1 USB	19 min.	140.00

TRIPP LITE PRECISION-REGULATED DC POWER SUPPLIES

- Features:**
- Provide DC power to security, diagnostic, and electronic equipment
 - Convert 120V AC to 13.8V DC (±0.5V)
 - Provide excellent regulation of output voltage
 - Ideal for use with ham and CB radios, test benches, tape players and amplifiers
 - Compact footprint, metal housing and lighted on/off switch



RoHS Compliant

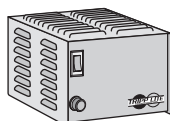

For quantities of 2 and up, call for quote.

MOUSER STOCK NO.	Tripp Lite Part Number	Description	Price Each
545-PR3	PR3	3 amp capacity	38.00
545-PR4.5	PR4.5	4.5 amp capacity	48.23
545-PR7	PR7	7 amp capacity	60.00
545-PR10	PR10	10 amp capacity	90.00
545-PR20	PR20	20 amp capacity	152.00
545-PR30	PR30	30 amp capacity	204.00
545-PR50	PR50	50 amp capacity	292.00
545-PR60	PR60	60 amp capacity	343.00

TRIPP LITE POWERVERTER® ULTRA-COMPACT INVERTERS

- Features:**
- Provide mobile power support by converting DC vehicle battery power to 120V, 60Hz AC power
 - Delivery peak surge output (up to 200% of continuous rating) instantaneously to handle equipment start-up
 - Easy connection: lighter plug (PV150, PV375) or user-supplied cables (all other models)
 - Clean, quiet operation—superior to gas generators



RoHS Compliant



For quantities of 2 and up, call for quote.


MOUSER STOCK NO.	Tripp Lite Part Number	Input	Regular/Peak Output Wattage	Outlets	Price Each
Portable Models					
545-PV150	PV150	12VDC	150/300	1	39.23
545-PV375	PV375	12VDC	375/600	2	64.00
545-PV700HF	PV700HF	12VDC	700/1400	3	120.50
Permanent-Mount Models					
545-PV1000HF	PV1000HF	12VDC	1000/2000	4	277.01

TRIPP LITE POWERVERTER® INVERTER/CHARGERS

- Features:**
- Permanent-mount or mobile uninterruptible power for equipment
 - Provide AC power while utility power is available and charge user-supplied DC batteries at the same time
 - Switch to frequency controlled AC power drawn from attached batteries when no AC power is available
 - Advanced, modified sine wave output, frequency control and output voltage regulation for sensitive equipment
 - Ideal AC power for RVs, boats, solar panels and any other large load equipment



RoHS Compliant

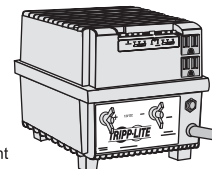

For quantities of 2 and up, call for quote.

MOUSER STOCK NO.	Tripp Lite Part Number	Input	Regular/Peak Output Wattage	Outlets	Price Each
545-APS1250	APS1250	12VDC	1250/2500	2	616.00

TRIPP LITE LINE CONDITIONERS

- Features:**
- Automatic Voltage Regulation (AVR) corrects (brownouts) and high voltage conditions
 - Diagnostic LEDs signal power problems before equipment is put at risk
 - Built-in surge and line noise protection
 - Rackmount and wallmount models available
 - \$25,000 Ultimate Lifetime Insurance



RoHS Compliant



For quantities of 2 and up, call for quote.

MOUSER STOCK NO.	Tripp Lite Part Number	Watts	Description	Outlets	Price Each
545-LS606M	LS606M	600	High/low voltage reg.	6	117.21
545-LC1200	LC1200	1200	Premium surge protection	4	162.42
545-LC1800	LC1800	1800	Premium surge protection	6	225.22
545-LR2000	LR2000	2000	Premium surge protection	6	369.46
545-LC2400	LC2400	2400	Premium surge protection	6	326.51
545-LCR2400	LCR2400	2400	Rackmount(3U) surge protection	14	442.04

TRIPP LITE NETWORK SURGE SUPPRESSORS

- Features:**
- The industry's most complete line of network cable protection
 - Lifetime product warranty



RoHS Compliant



For quantities of 2 and up, call for quote.

MOUSER STOCK NO.	Tripp Lite Part No.	Description	Price Each
545-DNET1	DNET1	RJ45 100BaseT, 10BaseT, token ring, RS232, AS400/Sys 3x protector for NICs	20.96
545-DB9	DB9	Serial DB9 RS-232 protector (pins 1-9) for any male or female 9 pin port	17.34
545-DTEL-2	DTEL2	RJ11/45 two line dial-up protector, ideal for modems, faxes, answering machines	25.13