


Consumer and Sealed Lead-Acid Battery Finder

NON-RECHARGEABLE

*Pack of 4 †Pack of 2

Size	Volt	mAh	Chemistry	MOUSER STOCK NO.	Manufacturer	Price Each
AAAA	1.5	550	Alkaline	525-E96	Energizer	1.24
AAA	1.5	300	Zinc Chloride	639-HD-AAA	Golden Power	.25
AAA	1.5	NR	Alkaline	573-24A	GP	.40
AAA	1.5	1,100	Carbon Zinc	525-1212SW-4	Eveready	*2.07
AAA	1.5	1,100	Alkaline	613-PC2400	Duracell Procell	.75
AAA	1.5	1,150	Alkaline	613-MN2400	Duracell	1.18
AAA	1.5	1,250	Alkaline	525-EN92	Energizer Industrial	.82
AAA	1.5	1,250	Alkaline	525-E92	Energizer	1.94
AAA	1.5	NR	Alkaline	613-MX2400	Duracell M3 Ultra	1.52
AAA	1.5	1,250	Lithium	525-L92BP-2	Energizer	† 7.19
AA	1.5	540	Carbon Zinc	525-1215SW-4	Eveready	*2.07
AA	1.5	570	Zinc Chloride	639-HD-AA	Golden Power	.27
AA	1.5	NR	Alkaline	573-15A	GP	.40
AA	1.5	2,450	Alkaline	613-PC1500	Duracell Procell	.70
AA	1.5	2,850	Alkaline	525-EN91	Energizer Industrial	.82
AA	1.5	2,850	Alkaline	525-E91	Energizer	1.89
AA	1.5	2,850	Alkaline	613-MN1500	Duracell	1.88
AA	1.5	NR	Alkaline	613-MX1500	Duracell M3 Ultra	1.52
AA	1.5	2,900	Lithium	525-L91BP-2	Energizer	† 7.19
C	1.5	1,600	Carbon Zinc	639-HD-C	Golden Power	.58
C	1.5	NR	Alkaline	573-14A	GP	1.17
C	1.5	7,100	Alkaline	613-PC1400	Duracell Procell	1.36
C	1.5	7,800	Alkaline	613-MN1400	Duracell	2.83
C	1.5	8,350	Alkaline	525-EN93	Energizer Industrial	1.14
C	1.5	8,350	Alkaline	525-E93	Energizer	2.51
D	1.5	3,300	Carbon Zinc	639-HD-D	Golden Power	.82
D	1.5	8,000	Carbon Zinc	525-1250-2	Eveready	1.67
D	1.5	14,000	Alkaline	613-PC1300	Duracell Procell	*1.68
D	1.5	NR	Alkaline	573-13A	GP	1.54
D	1.5	15,000	Alkaline	613-MN1300	Duracell	2.27
D	1.5	18,000	Alkaline	525-EN95	Energizer Industrial	1.28
D	1.5	18,000	Alkaline	525-E95	Energizer	2.51
N	1.5	NR	Alkaline	573-910A	GP	.65
N	1.5	1,000	Alkaline	525-E90	Energizer	1.42
9V	9	209	Carbon Zinc	639-GP-9V	Golden Power	.86
9V	9	228	Carbon Zinc	639-HD-9V	Golden Power	1.56
9V	9	NR	Alkaline	573-1604A	GP	1.90
9V	9	565	Alkaline	613-PC1604	Duracell Procell	2.33
9V	9	580	Alkaline	613-MN1604	Duracell	3.38
9V	9	625	Alkaline	525-EN22	Energizer Industrial	2.19
9V	9	625	Alkaline	525-522	Energizer	2.40
9V	9	1,200	Lithium	5169-U9VL-FP	Ultralife	6.53
9V	9	1,200	Lithium	5169-U9VL-J	Ultralife	7.41
Lantern	6	12,000	Carbon Zinc	525-1209	Eveready	3.79
Lantern	6	13,000	Alkaline	613-MN908	Duracell	13.51
---	12	55	Alkaline	573-23A	GP	.88
---	2	18	Alkaline	573-25A	GP	.88
---	12	18	Alkaline	573-27A	GP	.88

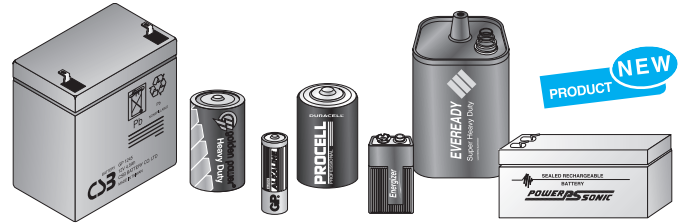

SEALED LEAD-ACID (RECHARGEABLE)

** Negative = .187" Faston, Positive = .250" Faston

Volt	Nominal Capacity @ 20 Hr. Rate A.H.	Terminal Type	MOUSER STOCK NO.	Manufacturer	Price Each
4	4.5	.250" Faston	547-PS-445	Power Sonic	15.73
4	9.0	.250" Faston	547-PS-490	Power Sonic	19.63
6	0.5	Wire Leads	547-PS-605	Power Sonic	22.97
6	1.0	.187" Faston	547-PS-610	Power Sonic	15.00
6	1.2	.187" Faston	547-PS-612H	Power Sonic	9.63
6	1.3	.187" Faston	632-GH613	CSB	6.64
6	1.3	.187" Faston	658-LCR061R3P	Panasonic	15.87
6	3.3	.187" Faston	632-GH633	CSB	10.44
6	3.4	.187" Faston	547-PS-630	Power Sonic	15.94
6	3.4	.187" Faston	658-LCR063R4PU	Panasonic	26.45
6	4.5	.187" Faston	632-GH645	CSB	7.58
6	4.5	.187" Faston	632-GP645	CSB	11.66
6	4.5	.187" Faston	547-PS-640	Power Sonic	10.26
6	4.5	.187" Faston	658-LCR064R5P	Panasonic	15.84
6	5.0	.187" Faston	547-PS650LF	Power Sonic	22.87
6	5.0	Spring	547-PS-650LS	Power Sonic	22.87
6	6.5	**	547-PS-665	Power Sonic	22.53
6	7.0	.187" Faston	547-PS-670	Power Sonic	16.18
6	7.2	.187" Faston	658-LCR067R2P	Panasonic	23.66
6	7.2	.250" Faston	658-LCR067R2P1	Panasonic	23.66
6	7.2	.187" Faston	632-GP672	CSB	15.12
6	8.0	.187" Faston	547-PS-682	Power Sonic	21.89
6	12.0	.187" Faston	547-PS-6100	Power Sonic	23.96
6	12.0	.187" Faston	632-GH6120	CSB	18.96
6	12.0	.187" Faston	632-GP6120	CSB	20.66
6	12.0	.187" Faston	658-LCR0612P	Panasonic	27.41
6	12.0	.250" Faston	658-LCR0612P1	Panasonic	27.41
6	12.0	.250" Faston	632-GP6120F2	CSB	20.66
6	12.0	**	547-PS-6120	Power Sonic	25.62
6	20.0	Nut and bolt	547-PS-6200	Power Sonic	64.72
6	36.0	.250" Faston	547-PS-6360	Power Sonic	69.98
12	0.8	Mate-N-Lok	547-PS-1208	Power Sonic	21.22
12	1.2	.187" Faston	547-PS-1212	Power Sonic	18.99
12	1.3	.187" Faston	632-GH1213	CSB	10.72
12	1.3	.187" Faston	658-LCR121R3PU	Panasonic	32.56
12	2.5	.187" Faston	547-PS-1220	Power Sonic	31.00
12	2.2	.187" Faston	632-GH1222	CSB	13.36
12	2.2	.187" Faston	632-GP1222	CSB	16.54
12	2.2	.187" Faston	658-LCR122R2PU	Panasonic	34.21
12	2.9	.187" Faston	547-PS1229	Power Sonic	31.01
12	3.4	.187" Faston	547-PS-1230	Power Sonic	27.77
12	3.4	.187" Faston	632-GH1234	CSB	14.52
12	3.4	.187" Faston	658-LCR123R4PU	Panasonic	44.97
12	4.5	.187" Faston	632-GP1245	CSB	18.82
12	5.0	.187" Faston	547-PS1250F1	Power Sonic	21.62
12	5.0	.250" Faston	547-PS1250F2	Power Sonic	21.62
12	7.0	.187" Faston	632-GH1270	CSB	20.70
12	7.0	.187" Faston	547-PS-1270	Power Sonic	19.65
12	7.2	.187" Faston	632-GP1272	CSB	23.08
12	7.2	.250" Faston	632-GP1272F2	CSB	22.02
12	7.2	.187" Faston	658-LCR127R2P	Panasonic	39.26
12	7.2	.250" Faston	658-LCR127R2P1	Panasonic	39.26
12	8.0	.187" Faston	547-PS-1282	Power Sonic	49.56
12	9.0	.250" Faston	547-PS-650LS	Power Sonic	31.61
12	12.0	.250" Faston	547-PS-12100	Power Sonic	44.30
12	12.0	.250" Faston	632-GP12120F2	CSB	39.74
12	12.0	.250" Faston	547-PS-12120	Power Sonic	42.96
12	17.0	Nut and bolt	658-LCRD1217P	Panasonic	93.35
12	17.0	Nut and bolt	632-GP12170	CSB	57.56
12	17.0	Nut and bolt	632-EVX12170	CSB	60.30
12	17.5	Nut and bolt	547-PS-12180	Power Sonic	65.35
12	18.0	.250" Faston	547-PS-12180F	Power Sonic	79.31
12	26.0	Nut and bolt	632-EVX12260	CSB	85.84
12	26.0	.250" Faston	547-PS-12260	Power Sonic	100.23
12	26.0	Nut and bolt	632-GP12260	CSB	84.44
12	28.0	Nut and bolt	658-LCX1228P	Panasonic	143.30
12	28.0	Nut and bolt	547-PS12280	Power Sonic	125.01
12	33.0	Nut and bolt	658-LCLA1233P	Panasonic	139.86
12	34.0	Nut and bolt	632-EVX12340	CSB	96.58
12	35.0	Nut and bolt	547-PS-12350	Power Sonic	115.54
12	40.0	Nut and bolt	632-GP12400	CSB	126.96
12	75.0	Nut and bolt	547-PS-12750	Power Sonic	246.18
12	100.0	Nut and bolt	547-PS121000	Power Sonic	289.85

RECHARGEABLE

*Pack of 4 †Pack of 2

Size	Volt	mAh	Chemistry	MOUSER STOCK NO.	Manufacturer	Price Each
AAA	1.2	250	Nickel-Cadmium	547-PS-AAA	Power Sonic	2.06
AAA	1.2	250	Nickel-Cadmium	639-N250AAA	Sanyo	3.42
AAA	1.2	750	Nickel Metal Hydride	639-HR-4U	Sanyo	2.70
AAA	1.2	750	Nickel Metal Hydride	525-NH12BP-4	Energizer	*15.77
AA	1.2	600	Nickel-Cadmium	547-PS-AA	Power Sonic	2.08
AA	1.2	600	Nickel-Cadmium	573-60AAK	GP	2.40
AA	1.2	700	Nickel-Cadmium	639-N700AAC	Sanyo	2.94
AA	1.2	900	Nickel-Cadmium	639-KR900AAEC	Sanyo	3.08
AA	1.2	1,000	Nickel-Cadmium	573-100AAK	GP	4.72
AA	1.2	1,100	Nickel-Cadmium	639-KR1100AAU	Sanyo	3.61
AA	1.2	1,600	Nickel Metal Hydride	573-GP160AA	GP	3.81
AA	1.2	1,650	Nickel Metal Hydride	639-HR-3U	Sanyo	4.33
AA	1.2	1,800	Nickel Metal Hydride	573-GP180AAHC	GP	4.84
AA	1.2	2,100	Nickel Metal Hydride	525-NH15BP-4	Energizer	*15.77
C	1.2	2,200	Nickel Metal Hydride	525-NH35BP-2	Energizer	11.51
D	1.2	2,200	Nickel Metal Hydride	525-NH50BP-2	Energizer	† 11.51
D	1.2	4,000	Nickel-Cadmium	547-PS-DL	Power Sonic	† 11.58
D	1.2	4,400	Nickel-Cadmium	639-KR4400D	Sanyo	† 13.09
N	1.2	1,500	Nickel-Cadmium	639-N150N	Sanyo	2.35
9V	7.2	150	Nickel Metal Hydride	525-NH22NBP	Energizer	11.51
9V	8.4	150	Nickel Metal Hydride	573-GP17R8H	GP	9.38
9V	8.4	150	Nickel Metal Hydride	672-05522	Varta	14.84

Please also see our offering of Battery Holders, Chargers, Computer, and Specialty Batteries