


## FLUKE 718 PRESSURE CALIBRATOR

The Fluke 718 Pressure Calibrator is a complete, self-contained calibration solution.

### Features:

- Built-in pressure / vacuum hand pump, with vernier and bleed valve
- New switch test function captures set, reset and dead band
- Pressure measurement to 0.05% of full span, using an internal pressure sensor
- Pressure measurements to 10,000 PSI, 700 bar using any of the Fluke 700Pxx Pressure Modules
- Current measurement with 0.025% accuracy and 0.001 mA resolution
- Wide range of selectable measurement units for pressure
- 24 volt loop power supply
- Min-Max Hold and damp functions
- 1/8 inch NPT female pressure fitting
- Simple, push-button user interface
- Compact size and weight
- 3 year warranty

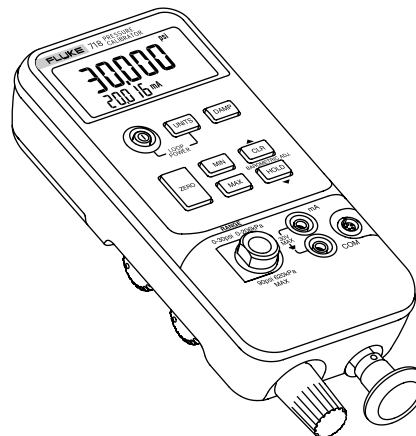


MOUSER STOCK NO.	Fluke Part No.	Description	Price Each
<a href="#">676-718</a>	718 10U	Pressure Calibrator 100 PSIG	1995.00
<a href="#">676-718-30</a>	718 30US	Pressure Calibrator 30 PSIG	1995.00
<b>Accessories</b>			
<a href="#">676-TL220</a>	TL220	SureGrip Industrial Test Lead Set	59.10
<a href="#">676-AC72</a>	AC72	Alligator Clip Set	13.25
<a href="#">676-TL71</a>	TL71	Test Lead Set	21.65
<a href="#">676-AC220</a>	AC220	SureGrip Alligator Clips	30.10
<a href="#">676-C789</a>	C789	Meter and Accessory Case	101.65

## FLUKE 725 MULTIFUNCTION PROCESS CALIBRATOR

The Fluke Multifunction Process Calibrators are powerful, yet easy-to-use field calibrators. Use the measure and source functions to test and calibrate almost any process parameter.

### Features:

- Small, streamlined shape makes it easy to carry
- Rugged, reliable design stands up to field use
- Easy to read measure/source screen lets you view input and output simultaneously
- Measure volts, mA, RTDs, thermocouples, frequency and ohms to test sensors and transmitters
- Source/simulate volts, mA, thermocouples, RTDs, frequency, ohms, and pressure to calibrate transmitters
- Measure/source pressure using any of 29 Fluke 700Pxx Pressure Modules
- Source mA with simultaneous pressure measurement to conduct valve and I/P tests
- Support flow meter testing with frequency and CPM functions
- Perform fast linearity tests with auto-step and auto-ramp features
- Power transmitters during test using loop supply with simultaneous mA measurement
- Store frequently used test setups for later use
- Backlight lets you work in poor light
- Large battery capacity of four AA cells
- 3 Year Warranty

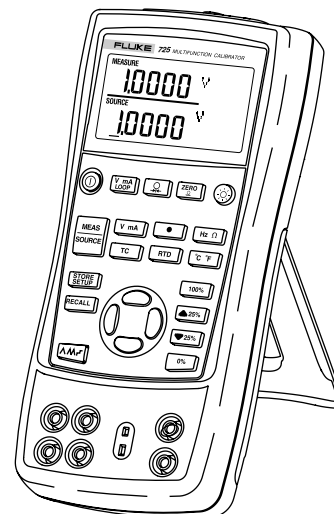

MOUSER STOCK NO.	Fluke Part No.	Description	Price Each
<a href="#">676-725</a>	FLUKE 725	Multifunction Process Calibrator	2095.00
<b>Accessories</b>			
<a href="#">676-TL220</a>	TL220	SureGrip Industrial Test Lead Set	59.10
<a href="#">676-AC72</a>	AC72	Alligator Clip Set	13.25
<a href="#">676-TL71</a>	TL71	Test Lead Set	21.65
<a href="#">676-AC220</a>	AC220	SureGrip Alligator Clips	30.10
<a href="#">676-TL238</a>	TL238	Test Lead Set for High Energy Environments	58.45
<a href="#">676-C125</a>	C125	Soft Meter Case	32.00
<a href="#">676-TPAK</a>	TPAK	ToolPak, Meter Hanging Kit	33.15
<a href="#">676-I1010</a>	I1010	AC/DC Current Clamp (1000 A)	316.40
<a href="#">676-I410</a>	I410	AC/DC Current Clamp (400 A)	194.65

## FLUKE PRESSURE MODULES FOR CALIBRATORS

### Features:

- Display pressure readings in any of 10 different pressure units you specify in the calibrator setup
- Rugged urethane molded case protects the module from rough handling and harsh conditions
- Internal temperature compensation from 0°C to 50°C for full-accuracy performance
- Includes NIST-traceable calibration certificate
- Module can be calibrated locally using the Fluke 700PCK Pressure Calibration Kit, a PC, and a precision pressure source
- One year warranty

MOUSER STOCK NO.	Fluke Part No.	Description	Price Each
<a href="#">676-700P06</a>	700P06	Pressure Module, 0-100 PSIG	1112.00
<a href="#">676-700P07</a>	700P07	Pressure Module, 0-500 PSIG	1112.00
<a href="#">676-700P27</a>	700P27	Pressure Module, 300 PSIG	1112.00
<a href="#">676-700P08</a>	700P08	Pressure Module, 0-30PSIA	1112.00
<a href="#">676-700P09</a>	700P09	Pressure Module, 0-100PSIA	1112.00
<a href="#">676-700PA5</a>	700PA5	Pressure Module, 0-1000 PSIG	1282.00
<a href="#">676-700PA6</a>	700PA6	Pressure Module, 1500PSIG	1282.00

