



## G3 CLEANERS, DEFLUXERS, AND CONTACT CLEANERS

G3 is by far the best HCFC-141b replacement on the market. No other non-flammable precision cleaner can match G3's price/performance. G3 has 32% better cleaning ability than HCFC-141b, making G3 products the ideal choices for electronic cleaning.

- Non-ozone depleting
- Non-flammable
- Safe on most plastics
- Rapidly evaporating
- Patented formula
- Ideal for Lead-Free processes



### Blue Shower® G3™ Cleaner /Degreaser

This innovative, non-flammable blend is designed for precision cleaning of polar and non-polar soils including hand and solder oils, greases, silicones, fluxes, and other similar contaminants. Blue Shower® G3™ is effective in cleaning electronic equipment, machinery, metal parts, and other general cleaning applications.

For quantities 24 and up, call for quote.

MOUSER STOCK NO.		Size	Price Each	
Mfr.	Mfr. Part No.		1	5
577	1630-16S	16 oz. Aerosol	23.86	22.87
577	1630-10S	10 oz. Aerosol	18.96	16.33

### Contact Cleaner G3™

This non-flammable, precision blend is the optimal choice for removing oils, greases, silicones, dirt, and grime from all types of switches, relays, contact pads, and other electrical connections.

For quantities 24 and up, call for quote.

MOUSER STOCK NO.		Size	Price Each	
Mfr.	Mfr. Part No.		1	5
577	1632-16S	16 oz. Aerosol	23.87	21.85
577	1632-10S	10 oz. Aerosol	17.24	16.33

### Flux Remover G3™

Non-flammable defluxer designed specifically for removing R, RA, RMA, and SA type flux residues after high temperature reflow. This flux remover can also be used as an all-purpose cleaner to remove light oils, silicones, waxes, greases, and other similar contaminants often found in electronics manufacturing.



LEAD-FREE

For quantities 24 and up, call for quote.

MOUSER STOCK NO.		Size	Price Each	
Mfr.	Mfr. Part No.		1	5
577	1631-16S	16 oz. aerosol	22.85	20.10
577	1631-5S	5 oz. w/ brush attach.	15.16	13.75
577	1631-10S	10 oz. Aerosol	18.01	16.53

### No Clean Flux Remover G3™

Designed specifically for removing R, RA, RMA, and SA type flux residues after high temperature reflow. Can be used as an all-purpose cleaner to remove light oils, silicones, waxes, greases, and similar contaminants often found in electronics manufacturing.



LEAD-FREE

For quantities 24 and up, call for quote.

MOUSER STOCK NO.		Size	Price Each	
Mfr.	Mfr. Part No.		1	5
577	1634-12S	12 oz. aerosol	21.65	19.99



RoHS Compliant

This product is RoHS compliant.

## ECO-LINE™ CLEANERS AND DEFLUXERS

Unique blend of hydrocarbons offers new, viable alternatives to CFC cleaning w/out depleting the ozone. Excellent cleaning ability, rapid evaporation, safe on plastic, ideal for lead-free applications, and is low cost.

### Contact Cleaner

Contains a hexane mixture. Ideal for switches, relays, contact pads, and other places of electrical connections.

- Ozone depleting factor: 0
- Rapid evaporation

For quantities 24 and up, call for quote.

MOUSER STOCK NO.		Fig.	Size	Price Each	
Mfr.	Mfr. Part No.			1	5
577	1622-10S	A	10 oz. aerosol	12.10	11.00
577	1622-13S	A	13 oz aerosol	13.88	13.03

### Ecoline Blue Shower Maintenance Cleaner

A blend of isopropanol and ethanol. Designed for cleaning electronic and electrical equipment, machinery, and metal parts.

- Ozone depleting factor: 0
- Rapid evaporation
- Safe on most plastics

For quantities 24 and up, call for quote.

MOUSER STOCK NO.		Fig.	Size	Price Each	
Mfr.	Mfr. Part No.			1	5
577	1620-10S	A	10 oz. aerosol	12.94	11.50




## AK225 CLEANERS AND DEFLUXERS

### No-Clean Flux Remover

Non-flammable, rapidly evaporating AK 225 blend designed for the removal of No-clean flux and white residue. Aggressively removes grease, oil, and soils from contacts, PCBs, connectors, and relays.

For quantities 24 and up, call for quote.

MOUSER STOCK NO.		Fig.	Size	Price Each	
Mfr.	Mfr. Part No.			1	5
577	1660-6S	B	6 oz. aerosol, w/ brush attach.	18.67	17.62

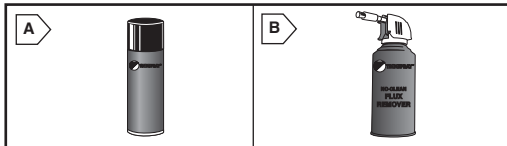

## AK225 CLEANERS AND DEFLUXERS (CONT.)

AK225 solvents are premium cleaners, combining powerful solvency with superior plastics, elastomers, and metals compatibility. EPA regulations restrict the sale of HCFC's to commercial users who can provide proof of their commercial status.

### Asahiklin AK225, Maintenance Cleaner

- 100% HCFC-225
- Non-flammable
- Safe on most plastics
- Rapid evaporation

For quantities of 24 and up, call for quote.

MOUSER STOCK NO.		Fig.	Size	Price Each	
Mfr.	Mfr. Part No.			1	5
577	1663-8S	A	8 oz aerosol	21.04	18.81
577	1663-18S	A	18 oz. aerosol	40.08	35.81

### Flux Remover AMS

Mixture of AK225 and methanol. Superior flux removal for type R, RMA, RA, and synthetic fluxes.

- Non-flammable
- Rapid evaporation
- Ozone depleting factor: .03
- Safe on most plastics

For quantities of 24 and up, call for quote.

MOUSER STOCK NO.		Fig.	Size	Price Each	
Mfr.	Mfr. Part No.			1	5
577	1665-8S	A	8 oz. aerosol	20.40	17.65
577	1665-18S	A	8 oz. aerosol	37.76	34.00

### Blue Shower II, Degreaser/Defluxer

The standard for precision cleaning of polar and non-polar soils.

- Non-flammable
- Ozone depleting factor: .03
- Rapid evaporation
- Safe on most plastics

For quantities of 24 and up, call for quote.

MOUSER STOCK NO.		Fig.	Size	Price Each	
Mfr.	Mfr. Part No.			1	5
577	1667-8S	A	8 oz. aerosol	19.18	18.02
577	1667-18S	A	18 oz. aerosol	37.03	33.08

### Contact Cleaner II

The choice solvent for precision cleaning and degreasing of electrical contacts.

- Non-flammable
- Ozone depleting factor: .03
- Rapid evaporation

For quantities of 24 and up, call for quote.

MOUSER STOCK NO.		Fig.	Size	Price Each	
Mfr.	Mfr. Part No.			1	5
577	1668-8S	A	8 oz. aerosol	19.92	19.02
577	1668-18S	A	18 oz. aerosol	38.12	32.75



## DESOLDERING FINE BRAID

### No-Clean Features:

- Prevents ionic residue
- Recommended for lead-free processes
- Cleanest no-clean wick in the industry
- Meets MIL Spec MIL-F-14256F



LEAD-FREE

### No Clean Wick • 5 Foot Spools

MOUSER STOCK NO.		Color Code	Width (in.)	Price Each	
Mfr.	Mfr. Part No.			1	10
577	1815-5F	Yellow	0.055	3.86	3.67
577	1816-5F	Green	0.075	3.84	3.56
577	1817-5F	Blue	0.098	4.16	3.90
577	1818-5F	Brown	0.13	4.60	4.38

• 10 Foot Spools

MOUSER STOCK NO.		Price Each	
Mfr.	Mfr. Part No.	1	10
577	1815-10F	6.53	5.60
577	1816-10F	6.81	6.30
577	1817-10F	7.35	6.82

### No Clean Wick w/ Static Dissipative Bobbin

- 5 Foot Spools

MOUSER STOCK NO.		Color Code	Width (in.)	Price Each	
Mfr.	Mfr. Part No.			1	10
577	1820-5F	White	0.035	3.31	2.99
577	1821-5F	Yellow	0.055	3.52	2.97
577	1822-5F	Green	0.075	3.70	3.12
577	1823-5F	Blue	0.098	4.00	3.38
577	1824-5F	Brown	0.13	4.57	3.81
577	1825-5F	Red	0.193	5.19	4.28

• 10 Foot Spools

MOUSER STOCK NO.		Price Each	
Mfr.	Mfr. Part No.	1	10
577	1820-10F	6.50	5.30
577	1821-10F	6.41	5.39
577	1822-10F	6.56	5.46
577	1823-10F	7.15	5.89

- 100% pure copper w/ advanced braid design
- Vacuum sealed to prevent oxidation

### Pro-Wick Features:

- Fast wicking action
- Meets MIL Spec MIL-F-14256F, NASA NHB5300.4, NPC200-4, SP5002

### Pro-Wick

- 5 Foot Spools

MOUSER STOCK NO.		Color Code	Width (in.)	Price Each	
Mfr.	Mfr. Part No.			1	10
577	1803-5F	Green	0.075	3.07	2.85
577	1804-5F	Blue	0.098	3.38	3.13
577	1805-5F	Brown	0.13	3.85	3.56
577	1806-5F	Red	0.193	4.17	3.97

• 10 Foot Spools

MOUSER STOCK NO.		Price Each	
Mfr.	Mfr. Part No.	1	10
577	1802-10F	5.42	5.02
577	1803-10F	5.52	5.11
577	1804-10F	6.03	5.59

### Pro-Wick w/ Static Dissipative Bobbin

- 5 Foot Spools

MOUSER STOCK NO.		Color Code	Width (in.)	Price Each	
Mfr.	Mfr. Part No.			1	10
577	1808-5F	White	0.035	2.88	2.39
577	1809-5F	Yellow	0.055	2.88	2.39
577	1810-5F	Green	0.075	2.96	2.84
577	1811-5F	Blue	0.098	3.28	3.11
577	1812-5F	Brown	0.13	3.75	3.10
577	1813-5F	Red	0.193	4.16	3.99

• 10 Foot Spools

MOUSER STOCK NO.		Price Each	
Mfr.	Mfr. Part No.	1	10
577	1808-10F	5.19	5.00
577	1809-10F	5.22	5.03
577	1810-10F	5.31	5.12
577	1811-10F	5.87	4.84