


# Audio Alarms and Audio/Video Connectors

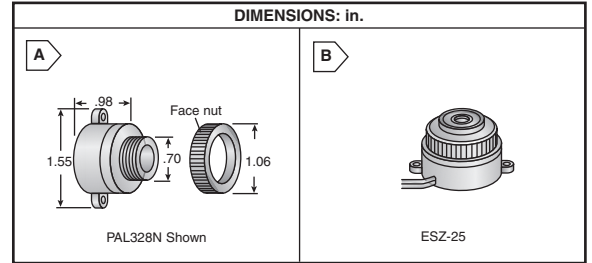

MOUSER STOCK NO.	Fig.	Description	Operating Voltage VDC		Sound Pressure dB (A) @ 2 ft.		Current Drain (mA)	Price Each			
			Min.	Max.	@ V Min.	@ V Max.		1	10	25	50
*507-PAL328	A	W/out face nut	3.0	28.0	68	100	20	8.00	7.60	7.20	6.98
*507-PAL328N	A	W/face nut	3.0	28.0	68	100	20	9.40	8.93	8.46	7.99
507-ESZ-25S	B	Single tone	3.0	28.0	68	100	20	13.20	12.54	11.88	11.22
507-ESZ-25B	B	Dual tone	3.0	28.0	68	100	20	17.44	15.50	14.70	13.07



## KOBICONN 3.5MM MONO PHONE JACK

- Specifications:**
- Mounting Hole: .25"
  - Closed Hex Nut
  - Chassis Mount

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Description	Price Each		
		1	10	100
16PJ012	Hex dress nut, washer, N/C switch, chassis mount	1.43	1.10	1.00
16PJ011	Knurled nut, washer, N/C switch, chassis mount	1.43	1.10	1.00

