

# Fast Acting and Slow Blow Fuses





## SINGLE BLOW SURFACE MOUNT FUSES

RoHS Compliant This product is RoHS compliant.

- Features:**
- Single blow fuse for over current protection
  - UL certified
  - Surface mount packaging for automated assembly
  - RoHS compliant and halogen free



Case Size	DIMENSIONS: mm			
	L	W	H	a
0402	1.0 ±0.1	0.52 ±0.05	0.35 ±0.05	0.25 ±0.1
0603	1.6 ±0.1	0.8 ±0.1	0.45 ±0.1	0.35 ±0.2
1206	3.2 ±0.1	1.55 ±0.1	0.6 ±0.1	0.5 ±0.2

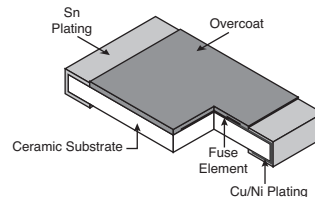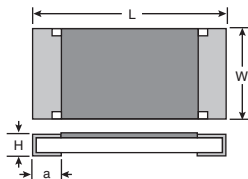

### Fast Acting Fuses

For quantities greater than listed, call for quote.

 
MOUSER STOCK NO.	Bourns Part No.	Rated Current (Amps)	Rated Voltage	Package Size	Price Each				Reel Qty.	Price Per Piece
					1	10	100	250		
652-SF-0402F050-2	SF-0402F050-2	0.5A	24V	0402	.68	.43	.32	.30	10000	.25
652-SF-0402F200-2	SF-0402F200-2	2.0A	24V	0402	.68	.43	.32	.30	10000	.25
652-SF-0603F050-2	SF-0603F050-2	0.5A	50V	0603	.57	.36	.27	.25	5000	.21
652-SF-0603F100-2	SF-0603F100-2	1.0A	32V	0603	.57	.36	.27	.25	5000	.21
652-SF-0603F150-2	SF-0603F150-2	1.5A	32V	0603	.57	.36	.27	.25	5000	.21
652-SF-0603F200-2	SF-0603F200-2	2.0A	32V	0603	.57	.36	.27	.25	5000	.21
652-SF-0603F250-2	SF-0603F250-2	2.5A	24V	0603	.57	.36	.27	.247	5000	.21
652-SF-0603F300-2	SF-0603F300-2	3.0A	24V	0603	.57	.36	.27	.25	5000	.21
652-SF-0603F315-2	SF-0603F315-2	3.15A	24V	0603	.57	.36	.27	.25	5000	.21
652-SF-0603F500-2	SF-0603F500-2	5.0A	32V	0603	.57	.36	.27	.25	5000	.21
652-SF-1206F050-2	SF-1206F050-2	0.5A	63V	1206	.65	.41	.31	.28	5000	.24
652-SF-1206F080-2	SF-1206F080-2	0.8A	63V	1206	.65	.41	.31	.28	5000	.24
652-SF-1206F100-2	SF-1206F100-2	1.0A	63V	1206	.65	.408	.306	.28	5000	.24
652-SF-1206F125-2	SF-1206F125-2	1.25A	63V	1206	.65	.41	.31	.28	5000	.24
652-SF-1206F150-2	SF-1206F150-2	1.5A	63V	1206	.65	.41	.31	.28	5000	.24
652-SF-1206F200-2	SF-1206F200-2	2.0A	63V	1206	.65	.41	.31	.28	5000	.24
652-SF-1206F250-2	SF-1206F250-2	2.5A	32V	1206	.65	.41	.31	.28	5000	.24
652-SF-1206F300-2	SF-1206F300-2	3.0A	32V	1206	.65	.41	.31	.28	5000	.24
652-SF-1206F400-2	SF-1206F400-2	4.0A	24V	1206	.65	.41	.31	.28	5000	.24
652-SF-1206F500-2	SF-1206F500-2	5.0A	24V	1206	.65	.41	.31	.28	5000	.24
652-SF-1206F700-2	SF-1206F700-2	7.0A	24V	1206	.65	.41	.31	.28	5000	.24

### Slow Blow Fuses

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bourns Part No.	Rated Current (Amps)	Rated Voltage	Package Size	Price Each				Reel Qty.	Price Per Piece
					1	10	100	250		
652-SF-0402S200-2	SF-0402S200-2	2.0A	24V	0402	.70	.45	.34	.32	10000	.27
652-SF-0603S125-2	SF-0603S125-2	1.25A	32V	0603	.61	.38	.29	.27	5000	.23
652-SF-0603S160-2	SF-0603S160-2	1.6A	32V	0603	.61	.38	.288	.264	5000	.23
652-SF-0603S200-2	SF-0603S200-2	2.0A	32V	0603	.61	.38	.29	.27	5000	.23
652-SF-0603S250-2	SF-0603S250-2	2.5A	32V	0603	.61	.38	.29	.27	5000	.23
652-SF-0603S300-2	SF-0603S300-2	3.0A	32V	0603	.61	.38	.29	.27	5000	.23
652-SF-1206S050-2	SF-1206S050-2	0.5A	63V	1206	.68	.43	.32	.30	5000	.26
652-SF-1206S100-2	SF-1206S100-2	1.0A	63V	1206	.68	.43	.32	.30	5000	.26
652-SF-1206S150-2	SF-1206S150-2	1.5A	63V	1206	.68	.43	.32	.30	5000	.26
652-SF-1206S200-2	SF-1206S200-2	2.0A	63V	1206	.68	.43	.32	.30	5000	.26
652-SF-1206S250-2	SF-1206S250-2	2.5A	32V	1206	.68	.43	.32	.30	5000	.26
652-SF-1206S300-2	SF-1206S300-2	3.0A	32V	1206	.68	.43	.32	.30	5000	.26
652-SF-1206S400-2	SF-1206S400-2	4.0A	24V	1206	.68	.43	.32	.30	5000	.26
652-SF-1206S500-2	SF-1206S500-2	5.0A	24V	1206	.68	.43	.32	.30	5000	.26
652-SF-1206S700-2	SF-1206S700-2	7.0A	24V	1206	.68	.43	.32	.30	5000	.26

### Littelfuse 209 SERIES 2AG, SLO-BLO (TIME-LAG) FUSES



For quantities of 250 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Amp Rating	Voltage Rating	Price Each		
				1	10	100
576-Q209.500MXEP	0209.500MXEP	0.5	350	.50	.48	.45
576-Q209.750MXEP	0209.750MXEP	0.75	350	.50	.48	.45
576-Q209001.MXEP	0209001.MXEP	1	350	.50	.48	.45


### Littelfuse 208 SERIES 2AG, FAST-ACTING FUSES



 For quantities of 250 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Amp Rating	Voltage Rating	Price Each		
				1	10	100
576-0208002.MXEP	0208002.MXEP	2	350	.35	.34	.32
576-0208003.MXEP	0208003.MXEP	3	350	.35	.34	.32
576-0208004.MXEP	0208004.MXEP	4	350	.35	.34	.32
576-0208005.MXEP	0208005.MXEP	5	350	.35	.34	.32
576-0208007.MXEP	0208007.MXEP	7	350	.35	.34	.32

### Littelfuse 875 AND 877 SERIES SLO-BLO 3.6X10MM PIGTAIL FUSES



- Features:**
- Slo-Blo ceramic body fuse in compact package
  - Single pigtail axial
  - Lead format

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Amp Rating	Voltage Rating	Price Each			
				1	10	100	250
<b>875 Series</b>							
576-0875.100MXEP	0875.100MXEP	0.1	250	1.72	1.63	1.55	1.46
576-0875.125MXEP	0875.125MXEP	0.125	250	1.72	1.63	1.55	1.46
576-0875.200MXEP	0875.200MXEP	0.2	250	1.72	1.63	1.55	1.46
576-0875.250MXEP	0875.250MXEP	0.25	250	1.72	1.63	1.55	1.46
576-0875.300MXEP	0875.300MXEP	0.3	250	1.72	1.63	1.55	1.46
576-0875.400MXEP	0875.400MXEP	0.4	250	1.72	1.63	1.55	1.46
576-0875.500MXEP	0875.500MXEP	0.5	250	1.37	1.30	1.23	1.16
576-0875.600MXEP	0875.600MXEP	0.6	250	1.37	1.30	1.23	1.16
576-0875.800MXEP	0875.800MXEP	0.8	250	1.37	1.30	1.23	1.16
576-0875001.MXEP	0875001.MXEP	1	250	1.29	1.22	1.16	1.09
576-0875002.MXEP	0875002.MXEP	2	250	1.29	1.22	1.16	1.09
576-0875003.MXEP	0875003.MXEP	3	250	1.29	1.22	1.16	1.09
576-0875004.MXEP	0875004.MXEP	4	250	1.29	1.22	1.16	1.09
576-0875005.MXEP	0875005.MXEP	5	250	1.29	1.22	1.16	1.09
576-087501.5MXEP	087501.5MXEP	1.5	250	1.29	1.22	1.16	1.09
576-087501.6MXEP	087501.6MXEP	1.6	250	1.29	1.22	1.16	1.09
576-087502.5MXEP	087502.5MXEP	2.5	250	1.29	1.22	1.16	1.09
<b>877 Series</b>							
576-0877002.MXEP	0877002.MXEP	2	250	.89	.85	.80	.76
576-0877004.MXEP	0877004.MXEP	4	250	.89	.85	.80	.76
576-087706.3MXEP	087706.3MXEP	6.3	250	.89	.85	.80	.76
576-08773.15MXEP	08773.15MXEP	3.15	250	.89	.85	.80	.76