


LITTELFUSE Fuses



Products may be RoHS compliant. Check mouser.com for RoHS status.

DIMENSIONS: mm (in.)

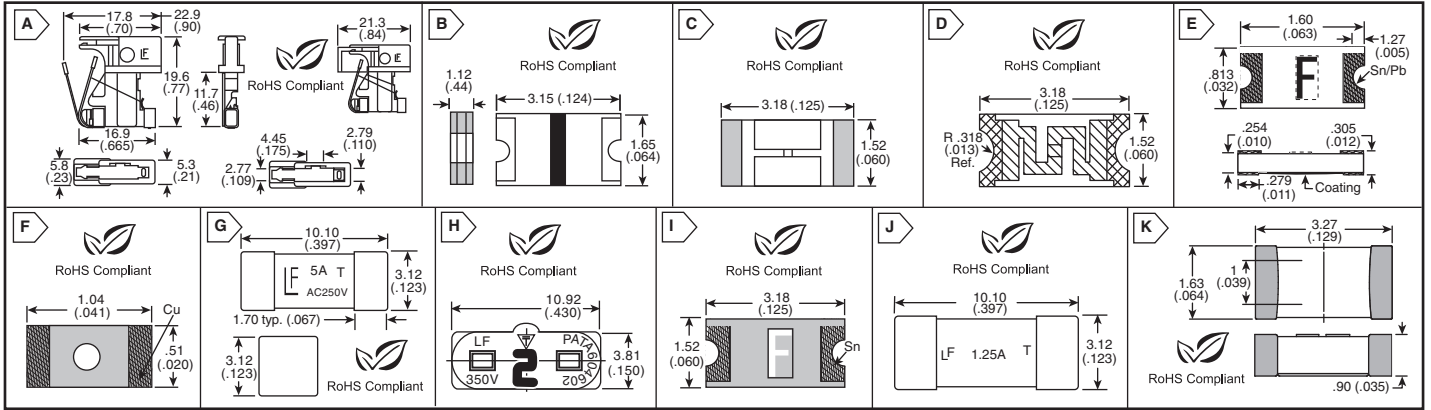

Littelfuse Fuses & Fuse Holders

481 SERIES INDICATING / ALARM FAST-ACTING FUSES

Specifications:

- Indicator flag: color-coded to indicate amp rating
- Body: black phenolic with UL 94V0 flammability rating
- Contacts: bright alloy-plated beryllium copper
- Voltage rating: 125VAC, 60VDC

For telecommunications equipment and similar applications.

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0481.180H	481.180	A	0.18	125	1.77	1.68	1.59	1.50
576-0481.250H	481.250	A	0.25	125	1.77	1.68	1.59	1.50
576-0481.500H	481.500	A	0.5	125	1.77	1.68	1.59	1.50
576-0481.750H	481.750	A	0.75	125	1.77	1.68	1.59	1.50
576-0481001.H	481001	A	1	125	1.77	1.68	1.59	1.50
576-04811.33H	4811.33	A	1.33	125	1.77	1.68	1.59	1.50
576-048101.5H	48101.5	A	1.5	125	1.77	1.68	1.59	1.50
576-0481002.H	481002	A	2	125	1.77	1.68	1.59	1.50
576-0481003.H	481003	A	3	125	1.77	1.68	1.59	1.50
576-048103.5H	48103.5	A	3.5	125	1.77	1.68	1.59	1.50
576-0481004.H	481004	A	4	125	1.77	1.68	1.59	1.50
576-0481005.H	481005	A	5	125	1.77	1.68	1.59	1.50
576-048107.5H	48107.5	A	7.5	125	1.77	1.68	1.59	1.50
576-0481010.H	481010	A	10	125	1.77	1.68	1.59	1.50
576-0481015.H	481015	A	15	125	1.77	1.68	1.59	1.50
576-0481020.H	481020	A	20	125	2.95	2.80	2.66	2.51

SLIMLINE™ 1206 FUSE

1206L Series Resettable PTC's

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	25	100	250
576-1206L020YR	1206L020	B	0.2	15	.28	.27	.25	.24
576-1206L025YR	1206L025	B	0.25	15	.28	.27	.25	.24
576-1206L035YR	1206L035	B	0.35	6	.28	.27	.25	.24
576-1206L050YR	1206L050	B	0.5	6	.27	.26	.25	.23
576-1206L075WR	1206L075	B	0.75	6	.28	.26	.25	.24
576-1206L110WR	1206L110	B	1.1	6	.41	.40	.389	.36
576-1206L150PR	1206L150	B	1.5	6	.29	.28	.27	.25
576-1206L160PR	1206L160	B	1.6	6	.45	.43	.41	.38

429 Series Very Fast Acting Surface Mount Fuses

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	25	100	250
576-0429007.WRML	429007	C	7	24	.46	.42	.40	.38

SLO-BLO® Fuses

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0468.500NR	468.500	D	0.5	63	.65	.61	.58	.54
576-0468001.NR	468001.NR	D	1	63	.65	.61	.58	.54

433 Series- Very Fast Acting

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.*	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0433.250NR	433.250	E	0.25	125	.75	.70	.65	.60
576-0433.800NR	433.800	E	0.8	63	.75	.70	.65	.60
576-0433004.NR	433004	E	4	24	.69	.64	.59	.55
576-0433005.NR	433005	E	5	24	.69	.64	.59	.55

* Dimensions larger than shown, by factor of two.

435 Series Lead Free VFA Surface Mount Fuses

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	50	100	500
576-0435.250KR	435.250	F	0.25	24	.71	.68	.65	.62
576-0435.500KR	435.500	F	0.5	24	.71	.68	.65	.62
576-0435002.KR	435002	F	2	24	.65	.61	.58	.54

443 Series Fuse



For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	50	100	500
576-0443.500DR	0443.500DR	G	0.5	250	1.58	1.44	1.21	.96
576-0443.750DR	0443.750DR	G	0.75	250	1.58	1.44	1.21	.96
576-0443001.DR	0443001.DR	G	1	250	1.58	1.44	1.21	.96
576-0443002.DR	0443002.DR	G	2	250	1.58	1.44	1.21	.96
576-0443003.DR	0443003.DR	G	3	250	1.58	1.44	1.21	.96
576-0443004.DR	0443004.DR	G	4	250	1.58	1.44	1.21	.96
576-0443005.DR	0443005.DR	G	5	250	1.58	1.44	1.21	.96
576-044301.5DR	044301.5DR	G	1.5	250	1.58	1.44	1.21	.96
576-044302.5DR	044302.5DR	G	2.5	250	1.58	1.44	1.21	.96
576-044303.5DR	044303.5DR	G	3.5	250	1.58	1.44	1.21	.96

446 Series Fast Acting Surface Mount Fuses

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	50	100	500
576-0446002.ZR	446002	H	2	350	.53	.50	.476	.452
576-0446003.ZR	446003	H	3	350	.62	.59	.55	.52
576-044607.5ZR	44607.5	H	7.5	350	.53	.50	.476	.452
576-0446010.ZR	446010	H	10	350	.62	.59	.55	.52

466 Series VFA Surface Mount Fuses

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	50	100	500
576-0466.125NR	466.125	I	0.125	125	.46	.42	.40	.38
576-0466.500NR	466.500	I	0.5	63	.46	.42	.40	.38
576-0466.750NR	466.750	I	0.75	63	.46	.42	.40	.38
576-0466002.NR	466002	I	2	63	.46	.42	.40	.38
576-046602.5NR	46602.5	I	2.5	32	.46	.42	.40	.38
576-0466003.NR	466003	I	3	32	.46	.42	.40	.38
576-0466004.NR	466004	I	4	24	.46	.42	.40	.38
576-0466005.NR	466005	I	5	24	.46	.42	.40	.38

461 Series NANO TELELINK Surface Mount Fuses

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	50	100	500
576-0461.500ER	461.500	J	0.5	600	.98	.93	.89	.84
576-04611.25ER	4611.25	J	1.25	600	.98	.93	.89	.84
576-0461002.ER	461002	J	2	600	.98	.93	.89	.84

467 Series VFA Surface Mount Fuses

For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	50	100	500
576-0467.500NR	467.500	E	.5	32	.58	.53	.50	.48
576-0467001.NR	467001	E	1	32	.58	.53	.50	.48
576-046701.5NR	46701.5	E	1.5	32	.58	.53	.50	.48
576-0467002.NR	467002	E	2	32	.58	.53	.50	.48
576-0467003.NR	467003	E	3	32	.58	.53	.50	.48
576-0467005.NR	467005	E	5	32	.58	.53	.50	.48

469 SERIES - 1206 SLO-BLO® FUSE



For quantities of 1000 and up, call for quote.

MOUSER STOCK NO.	Littelfuse Part No.	Fig.	Amp (A)	Volts (V)	Price Each			
					1	10	100	250
576-0469001.WR	0469001.WR	K	1	63	.45	.42	.401	.381
576-0469002.WR	0469002.WR	K	2	63	.45	.42	.401	.381
576-0469003.WR	0469003.WR	K	3	32	.45	.42	.401	.381
576-0469004.WR	0469004.WR	K	4	32	.45	.42	.401	.381
576-0469005.WR	0469005.WR	K	5	32	.45	.42	.401	.381
576-0469006.WR	0469006.WR	K	6	24	.45	.42	.401	.381
576-0469007.WR	0469007.WR	K	7	24	.45	.42	.401	.381
576-0469008.WR	0469008.WR	K	8	24	.45	.42	.401	.381
576-046901.5WR	046901.5WR	K	1.5	63	.45	.42	.401	.381
576-046902.5WR	046902.5WR	K	2.5	32	.45	.42	.401	.381
576-046903.5WR	046903.5WR	K	3.5	32	.45	.42	.401	.381
576-04691.25WR	04691.25WR	K	1.25	63	.45	.42	.401	.381