


AMP Tools and Accessories

JACKNACK TELECOMMUNICATIONS CABLE PREPERATION TOOL

- Cable Jack Stripper
- Cable Filler Sheer
- Jacknack Clamp
- Wire Placement Tool



MOUSER STOCK NO.	Fig.	Description	Price Each
571-2119000-1	A	Cable Preparation Tool for Unshielded Twisted Pair Cable (Cat. 3-6)	32.00

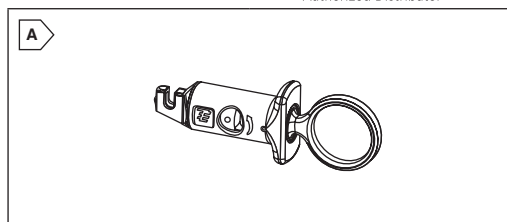


TOOLS FOR PCB CONNECTORS AND PIN AND SOCKET CONNECTORS

Pro Crimper III Hand Tool

- Field repair / prototyping
- Ratchet control
- Brush / bellmouth control
- Precision crimp height control


MOUSER STOCK NO.	Fig.	Description	Price Each
571-908721	B	.093" Pin and Socket cont. 24-18 AWG	201.43
571-908711	B	.093" Pin and Socket cont. 20-14 AWG	201.43
571-908701	B	.062" Pin and Socket cont. 30-24 AWG	186.35
571-908691	B	.062" Pin and Socket cont. 24-18 AWG	210.53
571-585141	B	Miniature rectangular connectors	201.43
571-905741	B	Commercial Mate-N-Lok® 24-18 AWG	201.43
571-905751	B	Commercial Mate-N-Lok® 20-14 AWG	201.43
571-905481	B	Universal Mate-N-Lok® 24-18 AWG	127.34
571-905461	B	Universal Mate-N-Lok® 20-14 AWG	127.34
571-584951	B	"Series 1" CPC size 16 contacts	138.00
571-584482	B	"Series 2" CPC size 20 contacts	201.43
571-3549401	B	Pro-Crimper III frame	46.16
571-584231	B	Die set for solderless terminals	57.90

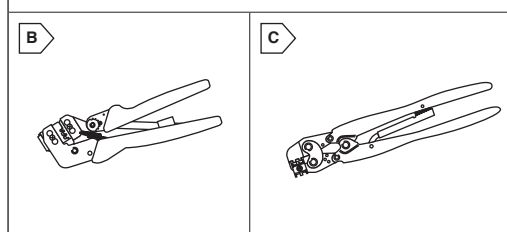

Certi-Crimp Crimping Tool

- Field repair / prototyping
- Ratchet control
- Brush / bellmouth control
- Precision crimp height control

MOUSER STOCK NO.	Fig.	Description	Price Each
571-903822	C	"Series 3" CPC type XII 12-16 AWG	836.59
571-903841	C	"Series 3" CPC type XII 8-10 AWG	836.59

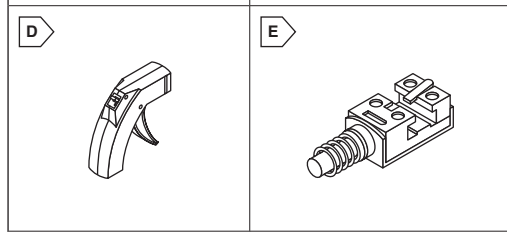


TOOLS FOR MTA SERIES

Pistol Grip Hand Tool

MOUSER STOCK NO.	Fig.	Description	Price Each
571-580741	D	Pistol Grip Hand Tool for MTA Series	61.20


Interchangeable Head for Pistol Grip Hand Tool

MOUSER STOCK NO.	Fig.	Description	Price Each
571-58246-1	E	MTA .100 Series	122.85
571-582471	E	MTA .156 Series	122.85

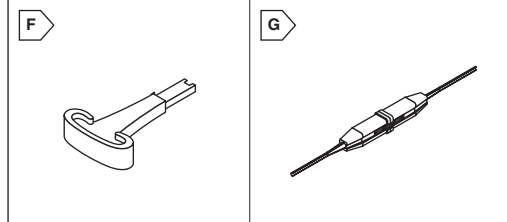


"T" Handle Maintenance Tool

MOUSER STOCK NO.	Fig.	Description	Price Each
571-598031	F	For MTA .100 Series	18.30
571-598041	F	For MTA .156 Series	18.30

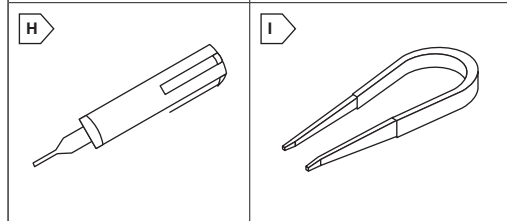

CONTACT INSERTION/EXTRACTION TOOLS

MOUSER STOCK NO.	Fig.	Description	Price Each
571-910672	G	Insertion/extraction, size 20, 22 contacts	5.54
571-3188311	H	Extraction, .062 Pin and Socket	190.76
571-1804030-1	H	Extraction, Universal Mate-N-Lok®	37.17
571-4558301	I	Insertion, Universal Mate-N-Lok® and MR	17.06
571-4656441	J	Extraction, Commercial Mate-N-Lok®	12.80
571-305183	K	Extraction, size 16 CPC contacts	13.13
571-912851	L	Insertion/extraction, size 20, 22 contacts	14.65
571-910193	M	Extraction, type XII series 3 CPC contacts	212.89
571-911241	N	Extraction, type XII series 4 CPC contacts	48.84

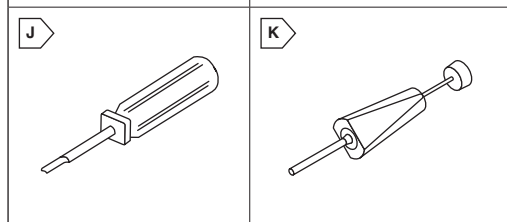

TOOLS FOR MODULAR PLUGS

"Category 5" High Performance Crimp Tool


- For use with modular plugs
- Cuts, strips, and terminates cable
- All plug sizes, except 10-position are accommodated using interchangeable die sets

MOUSER STOCK NO.	Fig.	Description	Price Each
571-32316520	O	8-position modular crimp tool with die	121.50

Professional Hand Tools with Die Sets


- For use with modular plugs
- Cuts, strips, and terminates cable
- All plug sizes, except 10-position are accommodated using interchangeable die sets

MOUSER STOCK NO.	Fig.	Description	Price Each
571-22316521	O	8-position line	121.50
571-22316523	O	4-position handset	107.08
571-2-231652-6	O	6-position offset-latch	117.40
571-22316527	O	6-position long body	117.40
571-22316528	O	4, 6-position line	121.50

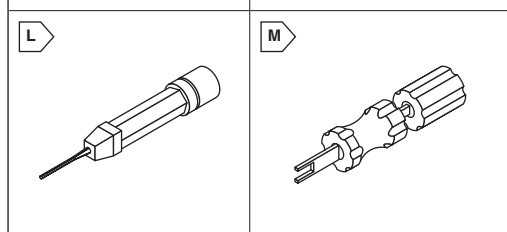

Die Set Only for Professional Hand Tool

MOUSER STOCK NO.	Fig.	Description	Price Each
571-8534001	-	8-position line	46.99
571-8534003	-	4-position handset	46.99
571-8534006	-	6-position offset-latch	46.99
571-8534007	-	6-position long body	46.99
571-8534008	-	4,6-position line	46.99

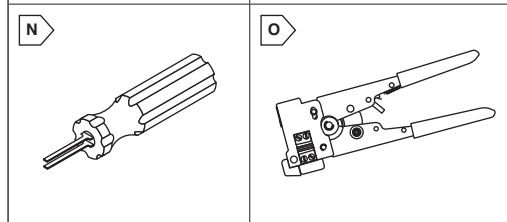

Professional Hand Tool Kits

MOUSER STOCK NO.	Fig.	Description	Price Each
571-12316661	-	4-position handset, 4, 6, and 8-position die sets, set of replacement strip blades and small screwdriver	241.12
571-2316625	-	(1) set of strip blades	4.78

AMP

Hand Tools