


CHICAGO MINIATURE Incandescent Replacements

Chicago Miniature Lighting, LLC
Lighting the world since 1910

RoHS Compliant **This product is RoHS compliant.**

LED Indication

Chicago Miniature

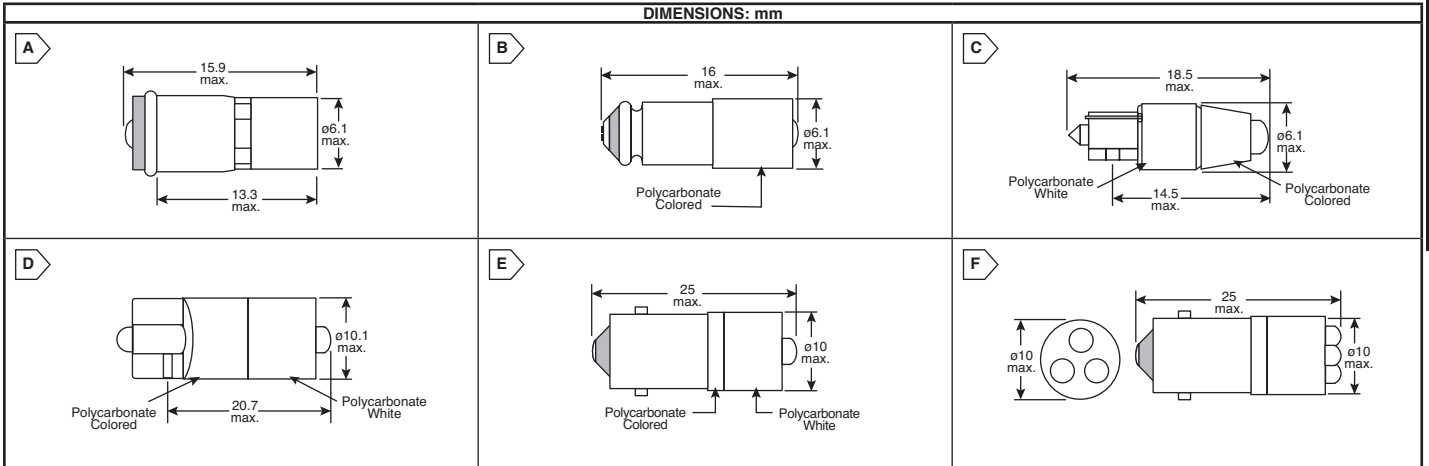

INCANDESCENT REPLACEMENTS

Features:

- Extremely High Brightness with Low Current Draw
- Low Heat Generation
- Shock and Vibration Proof
- Five Standard Colors

Specification:

- Long Life: 100K Hours vs. 10K Hours
- Storage Temperature: -25°C to +80°C
- Ambient Temperature: -20°C to +60°C

For quantities of 1000 or more, call for quote.

MOUSER STOCK NO.	Chicago Miniature Part No.	Fig.	Color	Voltage	Current (mA)	Luminous Intensity (mcd)	Wavelength (nm)	Replaces Incandescent No.	Price Each			
									1	10	100	500
15101 Series												
606-1510125UR3	1510125UR3	A	Red	12DC	14	330	630		8.04	5.63	4.82	4.27
606-1510125UG3	1510125UG3	A	Green	12DC	14	910	525	394,	12.01	8.40	7.21	6.38
606-1510125W3	1510125W3	A	White Clear	12DC	14	700	—	330, 382	12.01	8.40	7.21	6.38
606-1510125W3D	1510125W3D	A	White Diffused	12DC	14	350	—		12.01	8.40	7.21	6.38
606-1510135UR3	1510135UR3	A	Red	24DC	14	330	630		7.99	5.60	4.80	4.25
606-1510135UG3	1510135UG3	A	Green	24DC	14	910	525	327, 376,	12.01	8.40	7.21	6.38
606-1510135W3	1510135W3	A	White Clear	24DC	14	700	—	385, 387	12.01	8.40	7.21	6.38
606-1510135W3D	1510135W3D	A	White Diffused	24DC	14	350	—		12.01	8.40	7.21	6.38
15121 Series												
606-1512125W3	1512125W3	B	White Clear	12DC	7/14	700	—	336, 386,	10.31	7.21	6.19	5.53
606-1512125W3D	1512125W3D	B	White Diffused	12DC	7/14	350	—	393	10.31	7.21	6.19	5.53
606-1512135UG3	1512135UG3	B	Green	24DC	7/14	910	525	276,	10.32	7.22	6.19	5.54
606-1512135W3	1512135W3	B	White Clear	24DC	7/14	700	—	334,	10.32	7.22	6.19	5.54
606-1512135W3D	1512135W3D	B	White Diffused	24DC	7/14	350	—	388	10.32	7.22	6.19	5.54
1511A Series												
606-1511A25B3	1511A25B3	C	Blue	12AC/DC	6/12	300	470		11.46	8.02	6.88	6.09
606-1511A25W3	1511A25W3	C	White Clear	12AC/DC	6/12	600	—	18, 37, 70,	11.46	8.02	6.88	6.09
606-1511A25W3D	1511A25W3D	C	White Diffused	12AC/DC	6/12	300	—	73, 74	11.46	8.02	6.88	6.09
1511B Series												
606-1511B25W3	1511B25W3	D	White Clear	12AC/DC	7/14	700	—	192, 124, 158	11.46	8.02	6.88	6.09
606-1511B25W3D	1511B25W3D	D	White Diffused	12AC/DC	7/14	350	—	161, 168, 184	11.46	8.02	6.88	6.09
606-1511B35W3	1511B35W3	D	White Clear	24AC/DC	7/14	700	—	585, 655, 656,	11.46	8.02	6.88	6.09
606-1511B35W3D	1511B35W3D	D	White Diffused	24AC/DC	7/14	350	—	657	11.46	8.02	6.88	6.09
18602 Series												
606-18602250	18602250	E	Red	12AC/DC	15	350	630	12MB, 181,	8.16	5.70	4.90	4.33
606-18602251	18602251	E	Green	12AC/DC	15	1000	525	756, 1488,	11.15	7.81	6.69	5.99
606-18602252	18602252	E	Yellow	12AC/DC	15	300	587	1815, 1894,	9.01	6.30	5.41	4.79
606-18602257	18602257	E	Blue	12AC/DC	15	400	470	1889, 7191,	11.15	7.81	6.69	5.99
606-1860225W3	1860225W3	E	White Clear	12AC/DC	15	750	—	1893, 1898	11.15	7.81	6.69	5.99
606-18602350	18602350	E	Red	24AC/DC	15	350	630		8.16	5.70	4.90	4.33
606-18602351	18602351	E	Green	24AC/DC	15	1000	525	24MB,	11.15	7.81	6.69	5.99
606-1860235W3	1860235W3	E	White Clear	24AC/DC	15	750	—	1437,	11.15	7.81	6.69	5.99
606-1860235W3D	1860235W3D	E	White Diffused	24AC/DC	15	375	—	1818	11.15	7.81	6.69	5.99
606-18602450	18602450	E	Red	28AC/DC	15	350	630	313, 757	8.16	5.70	4.90	4.33
606-18602451	18602451	E	Green	28AC/DC	15	1000	525	1437, 1819,	11.15	7.81	6.69	5.99
606-1860245W3	1860245W3	E	White Clear	28AC/DC	15	750	—	1820, 1929,	11.15	7.81	6.69	5.99
606-1860245W3D	1860245W3D	E	White Diffused	28AC/DC	15	375	—	1843, 1864, 1873	11.15	7.81	6.69	5.99
18620 Series												
606-1862035W3	1862035W3	F	White Clear	24AC/DC	9/17	3 x 850	—	24MB, 1437	25.53	17.87	15.32	13.71
606-1862045W3	1862045W3	F	White Clear	28AC/DC	9/17	3 x 850	—	1843, 1864	25.53	17.87	15.32	13.71
606-1862045W3D	1862045W3D	F	White Diffused	28AC/DC	9/17	3 x 425	—	1873	25.53	17.87	15.32	13.71