


CHICAGO MINIATURE Incandescent Lamps

Products may be RoHS compliant.
Check mouser.com for RoHS status.

LED Indication

Chicago Miniature

DIMENSIONS: in.

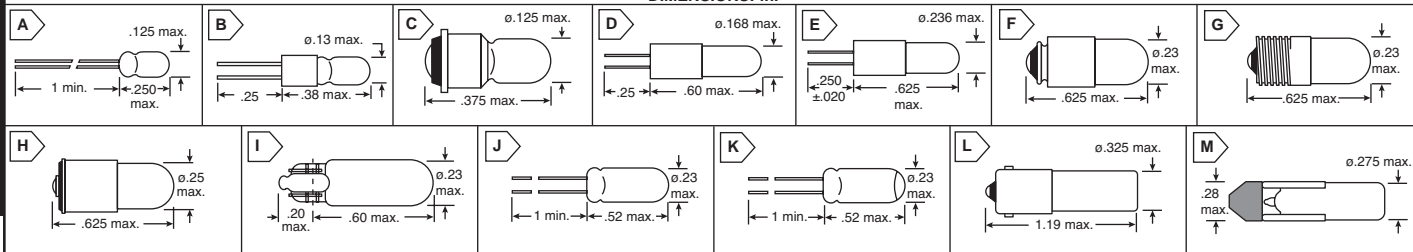

T-3/4 Wire Terminal Lamps

For quantities greater than listed, call for quote.

Type	MOUSER STOCK NO.	Fig.	Volts	Amps	M.S.C.P.	(Hrs.) Life	Price Each		
							1	10	100
6833	606-CM6833	A	5.0	.060	.050	25,000	1.46	1.27	1.22
7153	606-CM7153	A	5.0	.115	.150	40,000	1.51	1.31	1.26
7153AS15	606-CM7153AS15	A	5.0	.115	.150	40,000	1.58	1.37	1.31

T-1 Bi-Pin Base (.05" Spacing)

For quantities greater than listed, call for quote.

Type	MOUSER STOCK NO.	Fig.	Volts	Amps	M.S.C.P.	(Hrs.) Life	Price Each		
							1	10	100
7265	606-CM7265	B	5.0	.060	.150	5,000	1.99	1.73	1.66
7680	606-CM7680	B	5.0	.060	.030	60,000	1.90	1.64	1.58
7715	606-CM7715	B	5.0	.115	.150	40,000	1.83	1.59	1.53
7839	606-CM7839	B	28.0	.024	.150	4,000	2.17	1.88	1.81

T-1 Bi-Pin Base (.100" Spacing)

For quantities greater than listed, call for quote.

Type	MOUSER STOCK NO.	Fig.	Volts	Amps	M.S.C.P.	(Hrs.) Life	1	10	100
8-2402	606-CM8-2402	B	28.0	.024	.150	4,000	6.28	5.44	5.24

T-1 Sub-Midget Flange Base

For quantities greater than listed, call for quote.

Type	MOUSER STOCK NO.	Fig.	Volts	Amps	M.S.C.P.	(Hrs.) Life	Price Each		
							1	10	100
682	606-CM682	C	5.0	.060	.030	60,000	1.93	1.67	1.61
685	606-CM685	C	5.0	.060	.050	25,000	2.22	1.92	1.85
718	606-CM718	C	5.0	.115	.150	40,000	2.03	1.76	1.69
6839	606-CM6839	C	28.0	.024	.130	4,000	2.10	1.82	1.75

T-1 Wire Terminal (.145" Height)

For quantities greater than listed, call for quote.

Type	MOUSER STOCK NO.	Fig.	Volts	Amps	M.S.C.P.	(Hrs.) Life	Price Each		
							1	10	100
7152	606-CM7152	A	5.0	.115	.150	40,000	1.22	1.06	1.02

T-1 Wire Terminal (.25" Height)

For quantities greater than listed, call for quote.

Type	MOUSER STOCK NO.	Fig.	Volts	Amps	M.S.C.P.	(Hrs.) Life	Price Each		
							1	10	100
680	606-CM680	A	5.0	.060	.030	60,000	1.11	.96	.92
683	606-CM683	A	5.0	.060	.050	25,000	1.08	.93	.90
715	606-CM715	A	5.0	.115	.150	40,000	1.19	1.03	.99
715AS15	606-CM715AS15	A	5.0	.115	.150	40,000	1.27	1.10	1.06
7219	606-CM7219	A	12.0	.060	.150	10,000	.35	.29	.27
7220	606-CM7220	A	18.0	.026	.150	10,000	.55	.48	.46
6838	606-CM6838	A	28.0	.024	.150	4,000	1.70	1.48	1.42

T-1 1/4 Bi-Pin Base (.100" Spacing)

For quantities greater than listed, call for quote.

Type	MOUSER STOCK NO.	Fig.	Volts	Amps	M.S.C.P.	(Hrs.) Life	1	10	100
7646	606-CM7646	D	14.0	.080	.500	1,000	2.49	2.16	2.08
7632	606-CM7632	D	28.0	.040	.320	1,000	2.49	2.16	2.08

T-1 3/4 Bi-Pin Base (.125" Spacing)

For quantities greater than listed, call for quote.

Type	MOUSER STOCK NO.	Fig.	Volts	Amps	M.S.C.P.	(Hrs.) Life	Price Each		
							1	10	100
7361	606-CM7361	E	5.0	.060	.050	25,000	1.54	1.33	1.28
7328	606-CM7328	E	6.0	.200	.600	1,000	1.21	1.05	1.01
7377	606-CM7377	E	6.3	.075	.230	1,000	1.21	1.05	1.01
7381	606-CM7381	E	6.3	.200	.400	20,000	1.08	.93	.90
7371	606-CM7371	E	12.0	.040	.120	10,000	1.14	.99	.95
7373	606-CM7373	E	14.0	.100	.500	10,000	1.08	.94	.90
7382	606-CM7382	E	14.0	.080	.300	15,000	1.09	.95	.91
7327	606-CM7327	E	28.0	.040	.340	4,000	.95	.82	.79
7374	606-CM7374	E	28.0	.040	.150	10,000	1.22	1.06	1.02
7387	606-CM7387	E	28.0	.040	.300	7,000	.96	.84	.80
7876	606-CM7876	E	28.0	.060	.340	25,000	1.11	.96	.92

T-1 3/4 Midget Groove Base

For quantities greater than listed, call for quote.

Type	MOUSER STOCK NO.	Fig.	Volts	Amps	M.S.C.P.	(Hrs.) Life	Price Each		
							1	10	100
379	606-CM379	F	6.3	.200	.400	20,000	1.16	1.00	.96
336	606-CM336	F	14.0	.080	.500	1,500	1.11	.96	.92
386	606-CM386	F	14.0	.080	.300	15,000	1.11	.96	.92
334	606-CM334	F	28.0	.040	.340	4,000	.95	.82	.79
388	606-CM388	F	28.0	.040	.300	7,000	1.14	.99	.95

T-1 3/4 Midget Screw Base

For quantities greater than listed, call for quote.

Type	MOUSER STOCK NO.	Fig.	Volts	Amps	M.S.C.P.	(Hrs.) Life	Price Each		
							1	10	100
1769	606-CM1769	G	2.5	.200	.200	5,000	1.09	.95	.91
373	606-CM373	G	14.0	.080	.500	1,500	1.19	1.03	.99
8362	606-CM8362	G	14.0	.080	.300	15,000	1.09	.95	.91
335	606-CM335	G	28.0	.040	.340	4,000	.98	.85	.82
399	606-CM399	G	28.0	.040	.300	7,000	1.06	.92	.88

T-1 3/4 Midget Flange Base

For quantities greater than listed, call for quote.

Type	MOUSER STOCK NO.	Fig.	Volts	Amps	M.S.C.P.	(Hrs.) Life	Price Each		
							1	10	100
338	606-CM338	H	2.7	.060	.040	6,000	1.01	.88	.84
3150	606-CM3150	H	5.0	.060	.150	5,000	.92	.73	.54
7333	606-CM7333	H	5.0	.060	.050	25,000	.93	.81	.78
7335	606-CM7335	H	5.0	.115	.150	40,000	.93	.81	.78
328	606-CM328	H	6.0	.200	.600	1,000	.93	.81	.78
345	606-CM345	H	6.0	.040	.030	1,000	.98	.85	.82
381	606-CM381	H	6.3	.200	.400	20,000	1.27	1.10	1.06
344	606-CM344	H	10.0	.014	.002	50,000	1.32	1.14	1.10
367	606-CM367	H	10.0	.040	.080	5,000	1.13	.98	.94
394	606-CM394	H	12.0	.040	.120	10,000	1.01	.88	.84
330	606-CM330	H	14.0	.080	.500	1,500	.95	.82	.79
382	606-CM382	H	14.0	.080	.300	15,000	.91	.79	.76
8918	606-CM8918	H	14.0	.100	.500	10,000	1.06	.92	.88
370	606-CM370	H	18.0	.040	.150	10,000	1.19	1.03	.99
327	606-CM327	H	28.0	.040	.340	4,000	.60	.52	.51
376	606-CM376	H	28.0	.060	.340	25,000	.79	.68	.66
385	606-CM385	H	28.0	.040	.150	10,000	.90	.78	.75
387	606-CM387	H	28.0	.040	.300	7,000	.42	.36	.35
7341	606-CM7341	H	28.0	.065	.650	5,000	.95	.82	.79

T-1 3/4 Wedge Base

For quantities greater than listed, call for quote.

Type	MOUSER STOCK NO.	Fig.	Volts	Amps	M.S.C.P.	(Hrs.) Life	Price Each		
							1	10	100
86	606-CM86	I	6.3	.200	.400	20,000	.74	.64	.62
73	606-CM73	I	14.0	.080	.300	15,000	.61	.53	.51
85	606-CM85	I	28.0	.040	.300	7,000	.58	.50	.48

T-1 3/4 Wire Terminal

For quantities greater than listed, call for quote.

Type	MOUSER STOCK NO.	Fig.	Volts	Amps	M.S.C.P.	(Hrs.) Life	Price Each		
							1	10	100
2182	606-CM2182	J	14.0	.080	.300	40,000	.42	.372	.356
1764	606-CM1764	J	28.0	.040	.340	4,000	.61	.53	.51
2187	606-CM2187	J	28.0	.040	.300	7,000	.56	.49	.47

TL-1 3/4 Wire Terminal, Lens End

For quantities greater than listed, call for quote.

Type	MOUSER STOCK NO.	Fig.	Volts	Amps	(Hrs.) Life	Price Each		
						1	10	100
8-374	606-CM8-374	K	2.5	.350	3,000	1.99	1.73	1.66

T-2 Miniature Bayonet Base

For quantities greater than listed, call for quote.

Type	MOUSER STOCK NO.	Fig.	Volts	Amps	End Foot Candles	(Hrs.) Life	Price Each		
							1	10	100
24MB	606-CM24MB	L	24.0	.073	3000	1,000	1.41	1.23	1.18
28MB	606-CM28MB	L	28.0	.040	1600	5,000	1.41	1.23	1.18
60MB	606-CM60MB	L	60.0	.050	2200	7,500	1.51	1.31	1.26
120MB	606-CM120MB	L	120.0	.025	1200	5,000	1.14	.99	.95
8-967	606-CM8-967	L	120.0	.025	1200	5,000	6.92	6.00	5.77

T-2 Telephone Slide Base-Type 5 (.915" Height)

For quantities greater than listed, call for quote.

Type	MOUSER STOCK NO.
------	------------------