

# 3M™ Wire Management and Marking Products

 
RoHS Compliant This product is RoHS compliant.



## WIRE MANAGEMENT

### Cable Ties

- Easy Insertion
- Long Life
- Material: Type 6/6 Nylon (UL94V2)



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Tensile Strength (lbs.)	Length (in.)	Max. Bundle Dia. (in.)	Width (in.)	Color	Price Each			
						1	100	1000	10000
<b>Nylon</b>									
517-PB4NT18-M	18	4	0.70	0.10	Natural	.06	.05	.04	.03
517-PB6NT40-M	40	6	1.25	0.14	Natural	.08	.06	.05	.04
517-PB8NT50-M	50	8	1.90	0.18	Natural	.10	.08	.06	.05
517-PB15NT50-D	50	15	4.10	0.19	Natural	.14	.12	.08	.06
<b>Nylon Weather (UV) Resistant - For Outdoor Use</b>									
517-PB4BK18-M	18	4	0.70	0.10	Black	.08	.06	.05	.04
517-PB6BK40-M	40	6	1.25	0.14	Black	.10	.08	.06	.05
517-PB8BK50-M	50	8	1.90	0.18	Black	.10	.08	.06	.05
517-PB15BK50-D	50	15	4.10	0.19	Black	.18	.14	.09	.08
517-PB15BK120-D	120	15	4.00	0.30	Black	.35	.29	.17	.14

### Fasteners



#### 3M™ Scotchmate™ Fastener Hook and Loop

- Provide excellent moisture resistance
- For static loads temperature should not exceed 49°C / 120°F
- Temperature range: -29°C / -20°F to 49°C / 120°F continuous, to 70°C / 158°F intermittent

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Description	Price Each	
		1	5
517-3526/REEL	1" wide, black adhesive, 4.9 yards	41.70	38.83
517-3526W/REEL	1" wide, white adhesive, 4.9 yards	41.70	38.83

#### 3M™ Dual Lock™ Reclosable Fastener

- High temperature and solvent resistant
- Black polypropylene reclosable fastener with rubber based pressure sensitive adhesive
- Tensile strength can replace mechanical fasteners when mushroom shaped stems interlock


For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Description	Price Each	
		1	5
517-3541/REEL	1" wide, black adhesive	60.13	54.11
517-3551/REEL	1" wide, black adhesive, UV resistant	87.36	81.24
517-3560/REEL	1" wide, clear adhesive	92.23	85.77

## WIRE MARKING AND LABELING

### ScotchCode™ Wire Marker Tape Dispensers

Dispenser with ten refillable compartments for the easy-to-cut colored, lettered, or numbered tape.

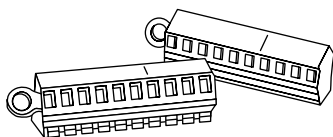

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Description	Price Each		
		1	10	25
517-STD09	1 roll each # 0-9	49.85	47.36	44.98
517-STDC	Dispenser, 1 roll each color: black, blue, brown, green, gray, orange, red, violet, white, and yellow	43.40	41.01	38.55


### Numbered and Colored Tape Refills

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Description	Price Each		
		1	10	25
517-SDR-0	Numbered Refill - 0	3.12	2.89	2.60
517-SDR-1	Numbered Refill - 1	3.12	2.89	2.60
517-SDR-2	Numbered Refill - 2	3.12	2.89	2.60
517-SDR-3	Numbered Refill - 3	3.12	2.89	2.60
517-SDR-4	Numbered Refill - 4	3.12	2.89	2.60
517-SDR-5	Numbered Refill - 5	3.12	2.89	2.60
517-SDR-6	Numbered Refill - 6	3.12	2.89	2.60
517-SDR-7	Numbered Refill - 7	3.12	2.89	2.60
517-SDR-8	Numbered Refill - 8	3.12	2.89	2.60
517-SDR-9	Numbered Refill - 9	3.12	2.89	2.60
517-SDR-BK	Color Refill - Black	3.12	2.89	2.60
517-SDR-BL	Color Refill - Blue	3.12	2.89	2.60
517-SDR-BN	Color Refill - Brown	3.12	2.89	2.60
517-SDR-GN	Color Refill - Green	3.12	2.89	2.60
517-SDR-OR	Color Refill - Orange	3.12	2.89	2.60
517-SDR-RD	Color Refill - Red	3.12	2.89	2.60
517-SDR-VL	Color Refill - Violet	3.12	2.89	2.60
517-SDR-WH	Color Refill - White	3.12	2.89	2.60
517-SDR-YL	Color Refill - Yellow	3.12	2.89	2.60

### ScotchCode™ Write-On Wire Marker Tape Dispensers and Refills

- SWD comes with the pen and 250 markers
- Used for cable, motor panels, control panels or sub-assemblies
- Provides a smooth, stable writing surface

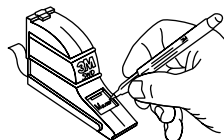

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Description	Price Each		
		1	10	25
517-SWD	Dispenser for write-on markers, size 3/4" x 1-3/8"	39.14	36.25	32.62
517-SWD-R	Write-on marker refills, size 3/4" x 1-3/8"	30.26	28.03	25.22

### SPB Pre-Printed Wire Marker Books

- To mark electrical wires and terminal strips
- Material: Vinyl impregnated cloth film with natural rubber adhesive
- Clearly printed
- Wide Variety
- Legible, Neat
- Convenient




For quantities greater than listed, call for quote.


MOUSER STOCK NO.	Contents	Price Each
517-SPB-01	45 ea. 0-9; 15 ea. L1-L3, T1-T3	18.20
517-SPB-02	10 ea. A-Z, 0-15, +, -, /	18.20
517-SPB-03	10 ea. 1-45	17.85
517-SPB-04	150 ea. 1, 2, 3	17.85
517-SPB-05	150 ea. A, B, C	17.85
517-SPB-08	6 ea. 1-15; 4 ea. 16-90; 2 ea. A-Z, +, -, /, O	17.85
517-SPB-09	45 ea. 1, 2, 3, A, B, C; 30 ea. L1-L3, T1-T3	18.21
517-SPB-11	15 ea. 1-30	18.20
517-SPB-12	15 ea. A-Z; 8 ea. +; 7 ea. -; 21 ea. Write-On Markers	18.56
517-SPB-13	45 ea. +, -, AC, DC; 33 ea. POS, NEG, GND; 27 ea. NEUT, SPARE; 21 ea. Write-On Markers	18.21
517-SPB-14	46-90	18.21

### SWB Write-On Wire Marker Books

The 3M SWB Write-on Wire Marker Book contains self laminating, write-on markers designed for small volume applications involving special or complex legends that are hand written at the job site.

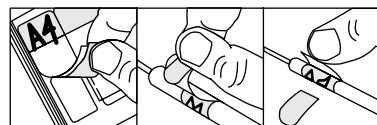

1. Grasp marker and liner tab at bottom and remove by peeling upward.
2. Apply printed end of marker to wire and wrap, bending marker to lift tab.
3. Wrap tail of marker over legend as tab separates from marker.

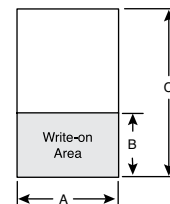

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Labels per Book	Write-on Area (in.)		Marker size (in.)		Recommended Wire O.D.	Price Each
		A	B	A	C		
517-SWB-01	180	0.50	0.50	0.50	1.50	0.16 x 0.31	19.33
517-SWB-02	120	0.75	0.75	0.75	1.75	0.24 x 0.31	20.11
517-SWB-03	60	1.00	1.00	1.00	2.85	0.32 x 0.58	19.72
517-SWB-04	30	1.00	1.00	1.00	5.00	0.32 x 1.55	19.52