

CHICAGO MINIATURE Incandescent and Neon Lamps




Chicago Miniature Lighting, LLC
Lighting the world since 1910

Products may be RoHS compliant.
Check mouser.com for RoHS status.

Chicago Miniature Lighting, LLC
Lighting the world since 1910

INCANDESCENT LAMPS

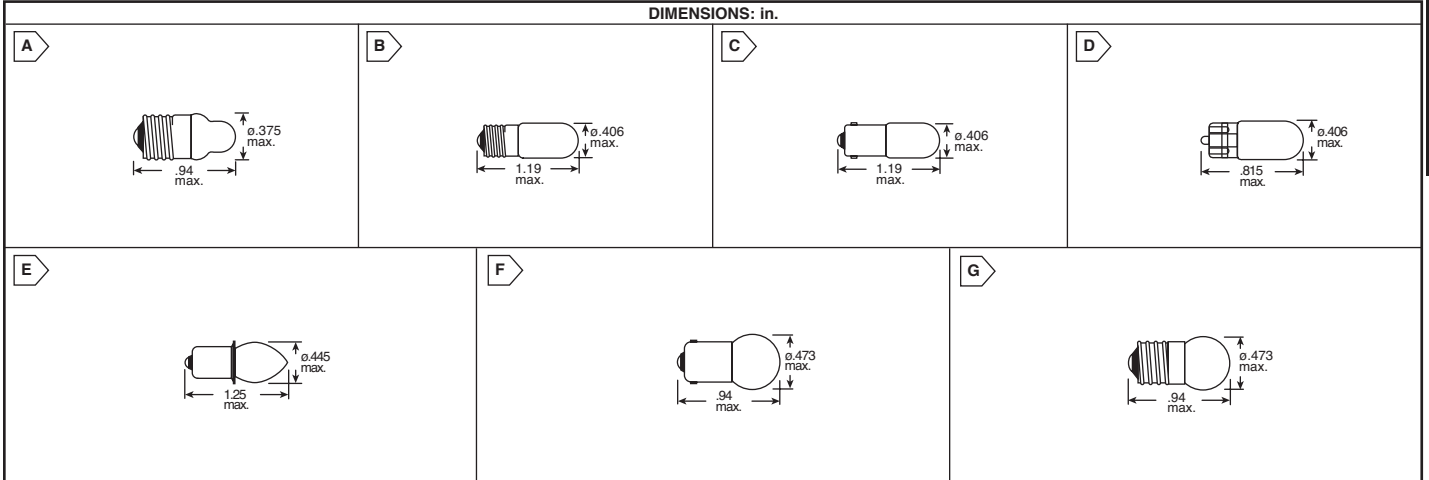

For quantities of 500 and up, call for quote.


Type	MOUSER STOCK NO.	Fig.	Volts	Amps	M.S.C.P.	(Hrs.) Life	Price Each		
							1	10	100
GTL-3 Miniature Screw Base, Lens End									
222	606-CM222	A	2.25	.250	-	5	.76	.66	.63
T-3 1/4 Miniature Screw Base									
40	606-CM40	B	6.3	.150	.500	3,000	.71	.61	.59
46	606-CM46	B	6.3	.250	.900	3,000	.87	.75	.72
1821	606-CM1821	B	28.0	.170	3.400	500	2.22	1.92	1.85
T-3 1/4 Miniature Bayonet Base									
43	606-CM43	C	2.5	.500	.500	3,000	1.13	.98	.95
1850	606-CM1850	C	5.0	.090	.250	1,500	.57	.50	.476
44	606-CM44	C	6.3	.250	.900	3,000	.41	.35	.34
47	606-CM47	C	6.3	.150	.500	3,000	.72	.64	.57
755	606-CM755	C	6.3	.150	.330	20,000	.88	.77	.74
1847	606-CM1847	C	6.3	.150	.380	5,000	.80	.74	.67
1866	606-CM1866	C	6.3	.250	.650	5,000	.76	.66	.63
1816	606-CM1816	C	13.0	.330	3.00	1,000	1.06	.93	.88
756	606-CM756	C	14.0	.080	.310	15,000	1.04	.90	.87
1815	606-CM1815	C	14.0	.200	1.40	3,000	.98	.85	.82
1891	606-CM1891	C	14.0	.240	2.000	500	.76	.69	.66
1893	606-CM1893	C	14.0	.330	2.000	7,500	.60	.52	.50
1813	606-CM1813	C	14.4	.100	.860	1,000	.88	.76	.73
1892	606-CM1892	C	14.4	.120	.750	1,000	.98	.85	.81
1818	606-CM1818	C	24.0	.170	3.300	250	2.17	1.88	1.81
313	606-CM313	C	28.0	.170	3.500	500	.87	.75	.72
757	606-CM757	C	28.0	.080	.620	7,500	.88	.77	.74
1819	606-CM1819	C	28.0	.040	.3400	2,500	.99	.85	.83
1820	606-CM1820	C	28.0	.100	1.60	1,000	.79	.68	.66
1829	606-CM1829	C	28.0	.070	1.00	1,000	.88	.76	.74

For quantities of 500 and up, call for quote.

Type	MOUSER STOCK NO.	Fig.	Volts	Amps	M.S.C.P.	(Hrs.) Life	Price Each		
							1	10	100
T-3 1/4 Miniature Bayonet Base (Cont.)									
1864	606-CM1864	C	28.0	.170	3.000	1,500	.87	.75	.72
1822	606-CM1822	C	36.0	.100	2.100	1,000	1.29	1.12	1.07
1828	606-CM1828	C	37.5	.050	.650	3,000	2.09	1.81	1.74
1835	606-CM1835	C	55.0	.050	1.100	5,000	2.38	2.06	1.98
8-3995	606-CM8-3995	C	130.0	.020	.200	2,000	1.04	.94	.86
T-3 1/4 Wedge Base									
259	606-CM259	D	6.30	.250	.650	5,000	.60	.53	.50
161	606-CM161	D	14.0	.190	1.000	1,500	.71	.61	.59
168	606-CM168	D	14.0	.350	3.000	1,500	.64	.56	.54
194	606-CM194	D	14.0	.270	2.000	1,500	.50	.43	.42
656	606-CM656	D	28.0	.060	.620	2,500	.66	.57	.55
B-3 1/2 Miniature Bayonet Base									
PR4	606-PR4	E	2.33	.270	.400	10	.66	.57	.55
PR2	606-PR2	E	2.38	.500	.800	15	.64	.56	.54
PR6	606-PR6	E	2.47	.300	.450	30	.66	.57	.55
PR3	606-PR3	E	3.57	.500	1.500	15	.66	.57	.55
PR7	606-PR7	E	3.70	.300	.900	30	.79	.68	.66
G-3 1/2 Miniature Bayonet Base									
219	606-CM219	F	6.3	.250	.500	5,000	.84	.65	.53
51	606-CM51	F	7.5	.220	1.000	1,000	.97	.85	.81
53	606-CM53	F	14.4	.120	1.000	1,000	.80	.69	.67
1450	606-CM1450	F	24.0	.035	.230	3,000	1.30	1.13	1.08
G-3 1/2 Miniature Screw Base									
14	606-CM14	G	2.47	.300	.500	15	1.83	1.59	1.53
13	606-CM13	G	3.70	.300	.980	15	1.35	1.16	1.12
50	606-CM50	G	7.50	.220	1.000	1,000	.95	.83	.794

Chicago Miniature Lighting, LLC
Lighting the world since 1910

NEON LAMPS

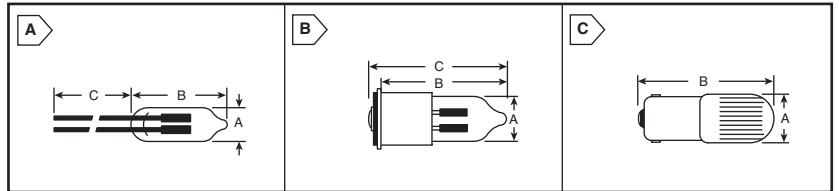

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Fig.	Type	Lamp Size	Breakdown Voltage (max.) AC/DC	Design Current (mA)	Dimensions: in.			Price Each		
						A (max.)	B (max.)	C (min.)	1	10	100
606-2ML	A	NE-38S	T-1 1/4	65/90	.300	.156	.395	1.000	.90	.78	.75
606-A1B	A	----	T-2	65/90	.300	.244	.500	1.000	.36	.31	.30
606-A2B	A	NE-2V	T-2	65/90	.700	.244	.750	1.000	.50	.43	.41
606-A9A	A	NE-2E	T-2	65/90	.700	.244	.750	2.000	.32	.28	.275
606-A1C	A	----	T-2	95/135	1.200	.244	.500	1.000	.40	.35	.33
606-A2A	A	----	T-2	65/90	.700	.244	.750	2.000	.50	.43	.41
606-C2A	A	NE-2H	T-2	95/135	1.900	.244	.750	2.000	.40	.344	.335
606-C2A-T	A	NE-2HT	T-2	95/135	1.900	.244	.750	2.000	.50	.43	.41
606-A1G	B	----	T-2	65/90	.300	.250	.525	.625	2.84	2.46	2.34
606-B1A	C	NE-51	T-3 1/4	65/90	.300	.430	1.188	-----	.99	.86	.83
606-B2A	C	NE-51H	T-3 1/4	95/135	1.200	.430	1.188	-----	.99	.86	.83
606-B2A-R	C	NE-51HR	T-3 1/4	95/135	1.200	.430	1.188	-----	3.42	2.96	2.85