


CHICAGO MINIATURE INDICATORS and Lamp Holders

Chicago Miniature Lighting, LLC
Lighting the world since 1910

Products may be RoHS compliant.
Check mouser.com for RoHS status.

Chicago Miniature LED Indication

ASTROLITE LED INDICATOR

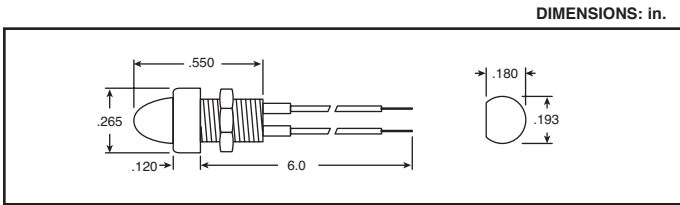


Specifications:

- Mounting hole: .193"
- Mounting centers: .334" min.
- Panel thickness: .188"
- Bezel/Shank: chrome plated brass
- Hex nut: nickel plated brass
- Wire leads: 26AWG stranded, 105°C PVC insulation

For quantities of 500 or more, call for quote.

MOUSER STOCK NO.	Color		Forward Voltage @ I _F =20mA		Luminous Intensity @ 10mA(mcd)		Peak Wave-Length	Price Each		
	LED	Lens	Typ.	Max.	Min.	Typ.		1	10	100
606-6039-004-304Y	Yellow	Yel diff	2.1	3.0	1.5	8.0	585	5.29	4.58	4.40

GEMLITE SUBMIDGET INDICATORS

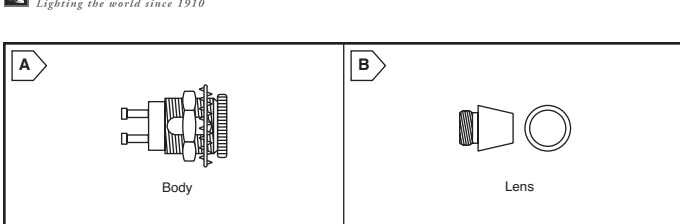


Specifications:

- Mounting hole: .313"
- Mounting centers: .469" min.
- Panel thickness: .218" max.
- Lock washer: nickel plated bronze
- Hex nut: nickel plated brass
- Lens: high temperature lexan
- Lens shank: nickel plated brass
- Housing material: black nickel plated brass
- Electrical rating: up to 30V, up to 1W

For quantities of 500 or more, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each		
			1	10	100
606-5160-458	A	T-1 sub-midget flange base indicator, body	9.99	8.66	8.33
606-160A-604R	B	Translucent red lens for 5160-48, lens	1.49	1.29	1.24
606-160A-604G	B	Translucent green lens for 5160-48, lens	1.49	1.29	1.24
606-160A-604Y	B	Translucent yellow lens for 5160-48, lens	2.14	1.85	1.78
606-160A-604W	B	Translucent white lens for 5160-48, lens	1.49	1.29	1.24

MIDGET FLANGE RELAMPABLE INDICATORS

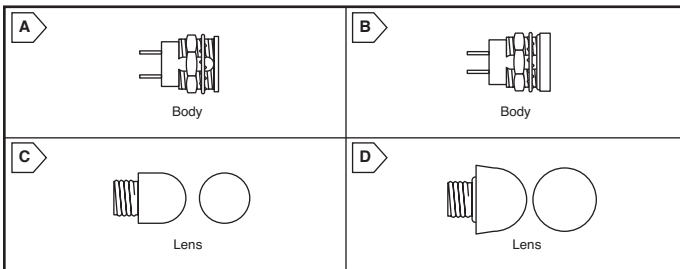


Specifications:

- Mounting hole: .484"
- Mounting centers: .750" min.
- Panel thickness: standard=.265" waterlight=.188"
- Terminals: tin plated brass
- Housing material: black anodized aluminum
- Hex nut/lock washer: chrome treated steel
- O-rings (5139 only): neoprene
- Electrical rating: up to 30V, up to 2W
- Lens: high temperature lexan

For quantities of 500 or more, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each		
			1	10	100
606-5131-038	A	T-1 3/4 midget flange standard indicator	4.52	3.97	3.85
606-5139-038	B	T-1 3/4 midget flange watertight indicator	6.17	5.35	5.14
606-131A-303R	C	Transparent red lens for 5131-038	3.15	2.73	2.63
606-131A-303A	C	Transparent amber lens for 5131-038	3.15	2.73	2.63
606-131A-303G	C	Transparent green lens for 5131-038	3.15	2.73	2.63
606-131A-304R	C	Translucent red lens for 5131-038	3.15	2.73	2.63
606-131A-304G	C	Translucent green lens for 5131-038	3.15	2.73	2.63
606-131A-304Y	C	Translucent yellow lens for 5131-038	3.15	2.73	2.63
606-139A-404G	D	Translucent green lens for 5139-038	5.78	5.02	4.84
606-139A-404R	D	Translucent red lens for 5139-038	5.78	5.02	4.84
606-139A-404Y	D	Translucent yellow lens for 5139-038	5.78	5.02	4.84

GLO-LITE NEON INDICATORS

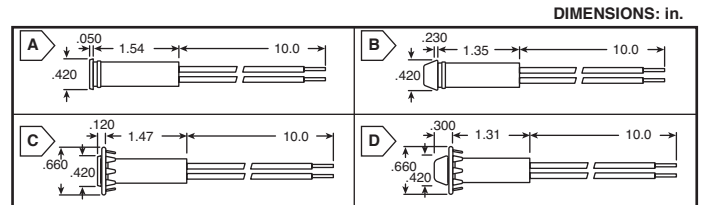

Specifications:


- Mounting hole: 6063 Series - .375" / 6073 Series - .500"
- Mounting centers: 6063 Series - .500" / 6073 Series - .688"
- Panel thickness: 6063 Series - 1.25" / 6073 Series - .078"
- Bezel (6073 only): chrome plated brass
- Wire leads: 22AWG stranded black 105°C PVC
- Electrical: 125VAC, built-in 30KΩ 1/4W resistor
- UL Recognized, CSA Certified

For quantities of 500 or more, call for quote.

MOUSER STOCK NO.	Fig.	Color	Description	Price Each		
				1	10	100
606-6063-001-534R	A	Red	Flat face with no bezel	2.91	2.52	2.43
606-6063-001-634R	B	Red	Conical face with no bezel	2.91	2.52	2.43
606-6073-001-534R	C	Red	Flat face with chrome bezel	4.03	3.49	3.36
606-6073-001-634R	D	Red	Conical face with chrome bezel	4.03	3.49	3.36
606-6073-001-634W	D	White	Conical face with chrome bezel	4.03	3.49	3.36

T-2 AND T-3 1/4 MINIATURE RELAMPABLE INDICATORS

(For use with Bayonet Incandescent and Neon Lamps)

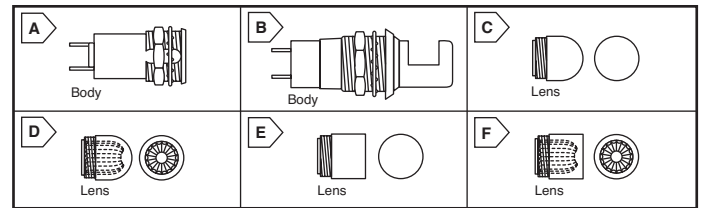

Specifications:

- Mounting hole: .688"
- Mounting centers: .969" min.
- Panel thickness: .406" max.
- Lock washer: chromate treated steel
- Housing material: 5100 Series - glass filled polyester 5200 Series - phenolic 900-200 Series - black anodized aluminum
- Hex nut: zinc plated steel
- Lens (5100 and 5200 Series): high temperature lexan

Body

For quantities of 500 or more, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each		
			1	10	100
606-5100-822	A	Solder lug terminals, no resistor	6.76	6.09	5.41
606-5100-823	A	Screw type terminals, no resistor	5.64	4.92	4.73
606-5100-824	A	.250" quick connect terminals, no resistor	5.41	4.68	4.50
606-900-200	B	Instrument lite, solder lug terminals	28.30	22.80	20.50

Lenses (for 606-5100 and 606-5200 series, shown above)

For quantities of 500 or more, call for quote.

606-25P-306R	C	Transparent red dome	.87	.67	.48
606-25P-306A	C	Transparent amber dome	.87	.67	.48
606-25P-306G	C	Transparent green dome	.87	.67	.48
606-25P-306C	C	Transparent clear dome	.87	.67	.48
606-25P-307R	C	Translucent red dome	.87	.67	.48
606-25P-307G	C	Translucent green dome	.87	.67	.48
606-25P-307Y	C	Translucent yellow dome	.87	.67	.48
606-25P-307W	C	Translucent white dome	.87	.67	.48
606-25P-326R	D	Transparent red fluted dome	.87	.67	.48
606-25P-326A	D	Transparent amber fluted dome	.87	.67	.48
606-25P-326G	D	Transparent green fluted dome	.87	.67	.48
606-25P-326C	D	Transparent clear fluted dome	.87	.67	.48
606-25P-606A	E	Transparent amber cylindrical	.87	.67	.48
606-25P-606R	E	Transparent red cylindrical	.87	.67	.48
606-25P-606G	E	Transparent green cylindrical	.87	.67	.48
606-25P-606C	E	Transparent clear cylindrical	.87	.67	.48
606-25P-607R	E	Translucent red cylindrical	.87	.67	.48
606-25P-607G	E	Translucent green cylindrical	.87	.67	.48
606-25P-607Y	E	Translucent yellow cylindrical	.87	.67	.48
606-25P-607W	E	Translucent white cylindrical	.87	.67	.48
606-25P-626R	F	Transparent red fluted cylindrical	.87	.67	.48
606-25P-626A	F	Transparent amber fluted cylindrical	.87	.67	.48
606-25P-626G	F	Transparent green fluted cylindrical	.87	.67	.48
606-25P-626C	F	Transparent clear fluted cylindrical	.87	.67	.48

RELAMPABLE INDICATOR HOLDERS



For quantities of 500 or more, call for quote.

MOUSER STOCK NO.	Description	Price Each		
		1	10	100
606-CM21-2	T-1 3/4 bi-pin base lamp socket	6.83	5.91	5.69