

DIALIGHT IP67 / NEMA 4X Panel Mount LED Indicators



RoHS Compliant This product is RoHS compliant.

657 SERIES PANEL MOUNT INDICATORS

Features / Benefits:



- IP67 / NEMA 4X
- Cool-to-the-touch Operation
- Daylight Viewable
- Resistant to shock and vibration
- Anti-Capillary Wire
- LED Technology engineered for up to 100k hours of operation



Flat Lens



Domed Lens

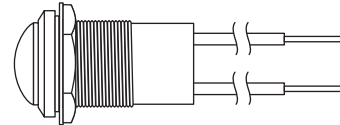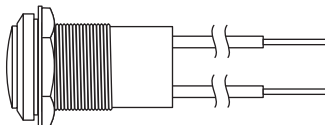

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Dialight Part No.	Fig.	Color	Lens Color	Intensity (fL)	Voltage (V) Typical	Current (mA)	Price Each			
								1	25	100	250
645-657-1502-103F	657-1502-103F	A	Red	Tinted Diffused	100fL	5V	19	14.27	12.68	11.10	10.15
645-657-1502-303F	657-1502-303F	A	Red	White Diffused	100fL	5V	19	14.27	12.68	11.10	10.15
645-657-1503-103F	657-1503-103F	A	Red	Tinted Diffused	100fL	12V	20	14.27	12.68	11.10	10.15
645-657-1503-303F	657-1503-303F	A	Red	White Diffused	100fL	12V	20	14.27	12.68	11.10	10.15
645-657-1504-103F	657-1504-103F	A	Red	Tinted Diffused	100fL	24V	19	14.27	12.68	11.10	10.15
645-657-1504-303F	657-1504-303F	A	Red	White Diffused	100fL	24V	19	14.27	12.68	11.10	10.15
645-657-1902-103F	657-1902-103F	A	Orange	Tinted Diffused	150fL	5V	19	14.27	12.68	11.10	10.15
645-657-1902-303F	657-1902-303F	A	Orange	White Diffused	150fL	5V	19	14.27	12.68	11.10	10.15
645-657-1903-103F	657-1903-103F	A	Orange	Tinted Diffused	150fL	12V	20	14.27	12.68	11.10	10.15
645-657-1903-303F	657-1903-303F	A	Orange	White Diffused	150fL	12V	20	14.27	12.68	11.10	10.15
645-657-1904-103F	657-1904-103F	A	Orange	Tinted Diffused	150fL	24V	19	14.27	12.68	11.10	10.15
645-657-1904-303F	657-1904-303F	A	Orange	White Diffused	150fL	24V	19	14.27	12.68	11.10	10.15
645-657-1702-103F	657-1702-103F	A	Yellow	Tinted Diffused	90fL	5V	19	14.27	12.68	11.10	10.15
645-657-1702-303F	657-1702-303F	A	Yellow	White Diffused	90fL	5V	19	14.27	12.68	11.10	10.15
645-657-1703-103F	657-1703-103F	A	Yellow	Tinted Diffused	90fL	12V	20	14.27	12.68	11.10	10.15
645-657-1703-303F	657-1703-303F	A	Yellow	White Diffused	90fL	12V	20	14.27	12.68	11.10	10.15
645-657-1704-103F	657-1704-103F	A	Yellow	Tinted Diffused	90fL	24V	19	14.27	12.68	11.10	10.15
645-657-1704-303F	657-1704-303F	A	Yellow	White Diffused	90fL	24V	19	14.27	12.68	11.10	10.15
645-657-1602-103F	657-1602-103F	A	Green	Tinted Diffused	70fL	5V	18	14.03	12.63	11.93	11.22
645-657-1602-303F	657-1602-303F	A	Green	White Diffused	70fL	5V	18	14.03	12.63	11.93	11.22
645-657-1603-103F	657-1603-103F	A	Green	Tinted Diffused	70fL	12V	20	14.03	12.63	11.93	11.22
645-657-1603-303F	657-1603-303F	A	Green	White Diffused	70fL	12V	20	14.03	12.63	11.93	11.22
645-657-1604-103F	657-1604-103F	A	Green	Tinted Diffused	70fL	24V	20	14.03	12.63	11.93	11.22
645-657-1604-303F	657-1604-303F	A	Green	White Diffused	70fL	24V	20	14.03	12.63	11.93	11.22
645-657-1802-103F	657-1802-103F	A	Blue	Tinted Diffused	25fL	5V	18	14.03	12.63	11.93	11.22
645-657-1802-303F	657-1802-303F	A	Blue	White Diffused	25fL	5V	18	14.03	12.63	11.93	11.22
645-657-1803-103F	657-1803-103F	A	Blue	Tinted Diffused	25fL	12V	20	14.03	12.63	11.93	11.22
645-657-1803-303F	657-1803-303F	A	Blue	White Diffused	25fL	12V	20	14.03	12.63	11.93	11.22
645-657-1804-103F	657-1804-103F	A	Blue	Tinted Diffused	25fL	24V	20	14.03	12.63	11.93	11.22
645-657-1804-303F	657-1804-303F	A	Blue	White Diffused	25fL	24V	20	14.03	12.63	11.93	11.22
645-657-1002-303F	657-1002-303F	A	White	White Diffused	90fL	5V	18	14.03	12.63	11.93	11.22
645-657-1003-303F	657-1003-303F	A	White	White Diffused	90fL	12V	20	14.03	12.63	11.93	11.22
645-657-1004-303F	657-1004-303F	A	White	White Diffused	90fL	24V	20	14.03	12.63	11.93	11.22
645-657-2502-103F	657-2502-103F	B	Red	Tinted Diffused	100fL	5V	19	14.27	12.68	11.10	10.15
645-657-2502-303F	657-2502-303F	B	Red	White Diffused	100fL	5V	19	14.27	12.68	11.10	10.15
645-657-2503-103F	657-2503-103F	B	Red	Tinted Diffused	100fL	12V	20	14.27	12.68	11.10	10.15
645-657-2503-303F	657-2503-303F	B	Red	White Diffused	100fL	12V	20	14.27	12.68	11.10	10.15
645-657-2504-103F	657-2504-103F	B	Red	Tinted Diffused	100fL	24V	19	14.27	12.68	11.10	10.15
645-657-2504-303F	657-2504-303F	B	Red	White Diffused	100fL	24V	19	14.27	12.68	11.10	10.15
645-657-2902-103F	657-2902-103F	B	Orange	Tinted Diffused	150fL	5V	19	14.27	12.68	11.10	10.15
645-657-2902-303F	657-2902-303F	B	Orange	White Diffused	150fL	5V	19	14.27	12.68	11.10	10.15
645-657-2903-103F	657-2903-103F	B	Orange	Tinted Diffused	150fL	12V	20	14.27	12.68	11.10	10.15
645-657-2903-303F	657-2903-303F	B	Orange	White Diffused	150fL	12V	20	14.27	12.68	11.10	10.15
645-657-2904-103F	657-2904-103F	B	Orange	Tinted Diffused	150fL	24V	19	14.27	12.68	11.10	10.15
645-657-2904-303F	657-2904-303F	B	Orange	White Diffused	150fL	24V	19	14.27	12.68	11.10	10.15
645-657-2702-103F	657-2702-103F	B	Yellow	Tinted Diffused	90fL	5V	19	14.27	12.68	11.10	10.15
645-657-2702-303F	657-2702-303F	B	Yellow	White Diffused	90fL	5V	19	14.27	12.68	11.10	10.15
645-657-2703-103F	657-2703-103F	B	Yellow	Tinted Diffused	90fL	12V	20	14.27	12.68	11.10	10.15
645-657-2703-303F	657-2703-303F	B	Yellow	White Diffused	90fL	12V	20	14.27	12.68	11.10	10.15
645-657-2704-103F	657-2704-103F	B	Yellow	Tinted Diffused	90fL	24V	19	14.27	12.68	11.10	10.15
645-657-2704-303F	657-2704-303F	B	Yellow	White Diffused	90fL	24V	19	14.27	12.68	11.10	10.15
645-657-2602-103F	657-2602-103F	B	Green	Tinted Diffused	70fL	5V	18	14.03	12.63	11.93	11.22
645-657-2602-303F	657-2602-303F	B	Green	White Diffused	70fL	5V	18	14.03	12.63	11.93	11.22
645-657-2603-103F	657-2603-103F	B	Green	Tinted Diffused	70fL	12V	20	14.03	12.63	11.93	11.22
645-657-2603-303F	657-2603-303F	B	Green	White Diffused	70fL	12V	20	14.03	12.63	11.93	11.22
645-657-2604-103F	657-2604-103F	B	Green	Tinted Diffused	70fL	24V	20	14.03	12.63	11.93	11.22
645-657-2604-303F	657-2604-303F	B	Green	White Diffused	70fL	24V	20	14.03	12.63	11.93	11.22
645-657-2802-103F	657-2802-103F	B	Blue	Tinted Diffused	25fL	5V	18	14.03	12.63	11.93	11.22
645-657-2802-303F	657-2802-303F	B	Blue	White Diffused	25fL	5V	18	14.03	12.63	11.93	11.22
645-657-2803-103F	657-2803-103F	B	Blue	Tinted Diffused	25fL	12V	20	14.03	12.63	11.93	11.22
645-657-2803-303F	657-2803-303F	B	Blue	White Diffused	25fL	12V	20	14.03	12.63	11.93	11.22
645-657-2804-103F	657-2804-103F	B	Blue	Tinted Diffused	25fL	24V	20	14.03	12.63	11.93	11.22
645-657-2804-303F	657-2804-303F	B	Blue	White Diffused	25fL	24V	20	14.03	12.63	11.93	11.22
645-657-2002-303F	657-2002-303F	B	White	White Diffused	90fL	5V	18	14.03	12.63	11.93	11.22
645-657-2003-303F	657-2003-303F	B	White	White Diffused	90fL	12V	20	14.03	12.63	11.93	11.22
645-657-2004-303F	657-2004-303F	B	White	White Diffused	90fL	24V	20	14.03	12.63	11.93	11.22