


# MEDER Reed Switches



This product is RoHS compliant.

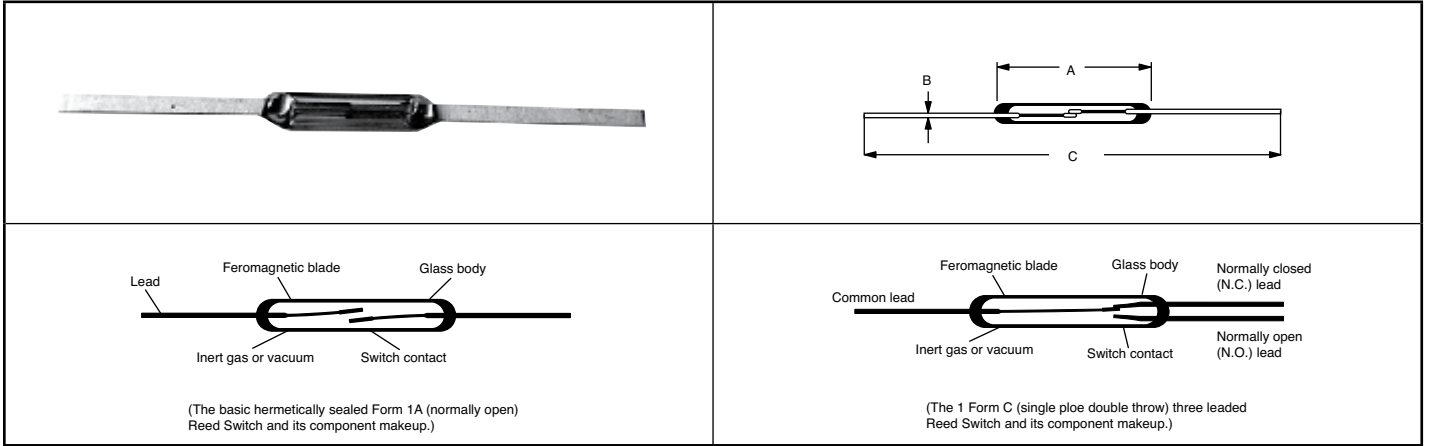

## MEDER REED SWITCHES

### Features:

- High breakdown voltage
- Super ultra-miniature
- Super ultra-miniature SMD
- High power
- Miniature high-performance
- Miniature offset -type
- Long life
- Miniature wide differential
- Miniature offset-type long reed
- Form A = normal open contact (N.O.)
- Form C = change over contact (S.P.D.T.)
- AT = Ampere Turns; Paramet that describes magnetic sensitivity.



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	MEDER Part No.	Dimensions (mm)			Switched Power (W)	Description	Price Each			
		A	B	C			1	10	25	100
876-KSK-1A04-1015	KSK-1A04-1015	4.1	0.15	34.5	30	1 Form A, 4.1mm AT 1015	5.34	5.34	3.91	3.31
876-KSK-1A35-1015	KSK-1A35-1015	10.5	0.71	34.5	20	1 Form A, 10.5mm AT 1015	.88	.88	.73	.66
876-KSK-1A35-1520	KSK-1A35-1520	10.5	0.71	34.5	20	1 Form A, 10.5mm AT 1520	.88	.88	.73	.66
876-KSK-1A46-1020	KSK-1A46-1020	12.0	2.0	44.3	10	1 Form A, SPST-NO, 12mm AT 1020	1.02	1.02	.848	.766
876-KSK-1A52-2025	KSK-1A52-2025	21.0	0.108	55.2	50	1 Form A, 21mm AT 2025	1.68	1.68	1.34	1.21
876-KSK-1A52-2530	KSK-1A52-2530	21.0	2.8	55.4	30	1 Form A, SPST-NO, 21mm AT 2025	1.29	1.29	1.15	1.10
876-KSK-1A52-3040	KSK-1A52-3040	21.0	0.108	55.2	50	1 Form A, 21mm AT 3040	1.29	1.29	1.15	1.10
876-KSK-1A66-1015	KSK-1A66-1015	14.0	0.087	44.1	10	1 Form A, 14mm AT 1015	.73	.73	.66	.594
876-KSK-1A66/3-1015	KSK-1A66/3-1015	14.0	2.2	44.1	10	1 Form A, SPST-NO, 14mm, Iridium Contact, AT 1015	.80	.80	.58	.49
876-KSK-1A66-1520	KSK-1A66-1520	14.0	0.087	44.1	10	1 Form A, 14mm AT 1520	.94	.94	.79	.71
876-KSK-1A66/3-1520	KSK-1A66/3-1520	14.0	2.2	44.3	20	1 Form A, SPST-NO, 14mm, Iridium Contact, AT 1520	.80	.80	.58	.49
876-KSK-1A66-2030	KSK-1A66-2030	14.0	0.087	44.1	10	1 Form A, 14mm AT 2030	.76	.76	.68	.64
876-KSK-1A66/3-2030	KSK-1A66/3-2030	14.0	0.5	44.3	10	1 Form A, SPST-NO, 14mm, Iridium Contact, AT 2030	.80	.80	.58	.49
876-KSK-1A80-1015	KSK-1A80-1015	7.0	0.071	35.6	10	1 Form A, 7mm AT 1015	1.43	1.43	.97	.87
876-KSK-1A80-1520	KSK-1A80-1520	7.0	0.071	35.6	10	1 Form A, 7mm AT 1520	1.43	1.43	.97	.87
876-KSK-1A80-2030	KSK-1A80-2030	7.0	0.071	35.6	10	1 Form A, 7mm AT 2030	1.54	1.54	1.24	1.11
876-KSK-1A85-2025	KSK-1A85-2025	21.0	0.108	55.5	100	1 Form A, 21mm AT 2025	1.58	1.58	1.36	1.18
876-KSK-1A85-2030	KSK-1A85-2030	21.0	0.108	55.5	100	1 Form A, 21mm AT 2030	1.58	1.58	1.36	1.18
876-KSK-1A85-2530	KSK-1A85-2530	21.0	0.108	55.5	100	1 Form A, 21mm AT 2530	1.64	1.64	1.41	1.22
876-KSK-1A85-3040	KSK-1A85-3040	21.0	0.108	55.5	100	1 Form A, 21mm AT 3040	1.58	1.58	1.36	1.18
876-KSK-1A87-1015	KSK-1A87-1015	10.0	0.079	35.5	10	1 Form A, 10mm AT 1015	.92	.92	.84	.76
876-KSK-1A87-1520	KSK-1A87-1520	10.0	0.079	35.5	10	1 Form A, 10mm AT 1520	.92	.92	.84	.76
876-KSK-1A87-2030	KSK-1A87-2030	10.0	0.079	35.5	10	1 Form A, 10mm AT 2030	.92	.92	.84	.76
876-KSK-1C90U-1015	KSK-1C90U-1015	14.0	0.100	56.1	20	1 Form C, 14mm AT 1015 Straight Lead	2.72	2.72	2.44	2.31
876-KSK-1C90U-1520	KSK-1C90U-1520	14.0	0.100	56.1	20	1 Form C, 14mm AT 1520 Straight Lead	2.72	2.72	2.44	2.31
876-KSK-1C90U-2034	KSK-1C90U-2034	14.0	0.5	56.1	10	1 Form C, SPST-NC, 14mm AT 2034 Straight Lead	3.95	3.95	3.52	2.99
876-KSK-1C90F-1015	KSK-1C90F-1015	14.0	0.100	54.5	20	1 Form C, 14mm AT 1015 Formed Lead	2.97	2.97	2.37	1.94
876-KSK-1C90F-1520	KSK-1C90F-1520	14.0	0.100	54.5	20	1 Form C, 14mm AT 1520 Formed Lead	2.97	2.97	2.37	1.94
876-KSK-1C90F-2025	KSK-1C90F-2025	14.0	0.100	54.5	20	1 Form C, 14mm AT 2025 Formed Lead	2.97	2.97	2.37	1.94
876-ORD211-1015	ORD211-1015	10.0	0.6	44.1	24	1 Form A, 10mm AT 1015 OKI	.67	.67	.55	.52
876-ORD211-1520	ORD211-1520	10.0	0.6	44.1	24	1 Form A, 10mm AT 1520 OKI	.67	.67	.55	.52
876-ORD211-2030	ORD211-2030	10.0	0.6	44.1	24	1 Form A, 10mm AT 2030 OKI	.67	.67	.55	.52
876-ORD213-1015	ORD213-1015	7.0	0.3	35.8	24	1 Form A, 7mm AT 1015 OKI	.99	.99	.82	.77
876-ORD213-1520	ORD213-1520	7.0	0.3	35.8	24	1 Form A, 7mm AT 1520 OKI	.99	.99	.82	.77
876-ORD213-2030	ORD213-2030	7.0	0.3	35.8	24	1 Form A, 7mm AT 2030 OKI	.99	.99	.82	.77
876-ORD213S-1-1015	ORD213S-1-1015	10.2	0.5	1.8	24	1 Form A, Surface Mount 10.2mm AT 1015 OKI	1.28	1.28	1.05	.99
876-ORD213S-1T-1015	ORD213S-1T-1015	10.2	0.5	1.8	24	1 Form A, Surface Mount 10.2mm AT 1015 T/R OKI	1.36	1.36	1.18	1.05
876-ORD219-1015	ORD219-1015	12.0	0.5	44.3	100	1 Form A, 12mm AT 1015 OKI	.61	.61	.50	.48
876-ORD2210V-2025	ORD2210V-2025	21.0	0.6	55.4	100	1 Form A, 21mm AT 2025 OKI	1.13	1.13	.93	.87
876-ORD2210V-2530	ORD2210V-2530	21.0	0.6	55.4	100	1 Form A, 21mm AT 2530 OKI	1.13	1.13	.93	.87
876-ORD2211-2030	ORD2211-2030	16.5	0.6	44.1	100	1 Form A, 16.5mm AT 2030 OKI	1.14	1.14	.938	.883
876-ORD2220-2030	ORD2220-2030	14.0	0.5	56.7	40	1 Form A, 14mm AT 2030 OKI	.95	.95	.78	.73
876-ORD2221-2030	ORD2221-2030	13.0	0.21	44.2	100	1 Form A, 13mm AT 2030 OKI	1.31	1.31	1.07	1.01
876-ORD228S-1-1015	ORD228S-1-1015	14.0	0.5	19.6	100	1 Form A, Surface Mount 14mm AT 1015 OKI	.71	.71	.58	.55
876-ORD228S-1T-1015	ORD228S-1T-1015	14.0	0.5	19.6	100	1 Form A, Surface Mount 14mm AT 1015 T/R OKI	.83	.83	.68	.64
876-ORD228VL-1015	ORD228VL-1015	14.0	0.5	44.3	100	1 Form A, 14mm AT 1015 OKI	.57	.57	.47	.44
876-ORD228VL-1520	ORD228VL-1520	14.0	0.5	44.3	100	1 Form A, 14mm AT 1520 OKI	.57	.57	.47	.44
876-ORD228VL-2030	ORD228VL-2030	14.0	0.5	44.3	100	1 Form A, 14mm AT 2030 OKI	.57	.57	.47	.44
876-ORD229-2025	ORD229-2025	21.0	0.6	55.4	50	1 Form A, 21mm AT 2025 OKI	1.00	1.00	.82	.77
876-ORD229-2530	ORD229-2530	21.0	0.6	55.4	50	1 Form A, 21mm AT 2530 OKI	1.00	1.00	.82	.77
876-ORD311-1015	ORD311-1015	7.0	0.33	35.8	10	1 Form A, 7mm AT 1015 OKI	.98	.98	.80	.76
876-ORD312-1015	ORD312-1015	12.0	0.5	44.3	30	1 Form A, 12mm AT 1015 OKI	.99	.99	.81	.77
876-ORD9215-1015	ORD9215-1015	17.0	0.5	44.1	10	1 Form A, 17mm AT 1015 OKI	.56	.56	.46	.44
876-ORD324-1015	ORD324-1015	14.0	0.5	44.3	10	1 Form A, 14.0mm AT 1015	.47	.47	.39	.37
876-ORD324-1520	ORD324-1520	14.0	0.5	44.3	10	1 Form A, SPST-NO, 14mm, Iridium Contacts, AT 1520 OKI	.47	.47	.39	.37
876-ORD9215-1520	ORD9215-1520	17.0	0.5	44.1	10	1 Form A, 17mm AT 1520 OKI	.56	.56	.46	.44
876-ORD324-1015	ORD324-1015	14.0	0.5	44.3	10	1 Form A, 14mm AT 1015 OKI	.47	.47	.39	.37
876-ORT551-1015	ORT551-1015	14.0	0.5	56.1	3	1 Form C, 14mm AT 1015 OKI	2.00	2.00	1.64	1.55
876-ORT551-1-1015	ORT551-1-1015	14.0	0.5	56.1	3	1 Form C, 14mm, AT 1015 Formed Leads OKI	2.30	2.30	1.88	1.77