

# POMONA Test Clips and Enclosures

## Pomona TEST LEAD HOLDERS AND PATCH CORDS KITS

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. |               | Fig. | Description                                  | Max Cable Dia. (in.) | Price Each |       |       |
|------------------|---------------|------|--|----------------------|------------|-------|-------|
| Mfr.             | Mfr. Part No. |      |  |                      | 1          | 25    | 50    |
| 565—1508         |               | A    | Test lead holder, orange                     | 0.210                | 11.83      | 10.93 | 10.38 |
| 565—2708         |               | A    | Test lead holder, blue                       | 0.450                | 11.73      | 10.93 | 10.39 |
| 565—4408         |               | A    | Test lead holder, black                      | 0.320                | 9.30       | 8.94  | 8.54  |
| 565—5523         |               | B    | Patch cord Kit: 10pcs, 1 ea. Standard color. | -                    | 39.87      | 37.88 | 35.98 |

## Pomona GRABBERS AND TEST CLIPS

Replace blank with 0 for Black, 2 for Red

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. |               | Fig. | Description                                 | Max Cable Dia. (in.) | Price Each |      |      |
|------------------|---------------|------|---|----------------------|------------|------|------|
| Mfr.             | Mfr. Part No. |      |   |                      | 1          | 25   | 50   |
| 565—3925         |               | C    | Do-it-yourself Minigrabber test clip .09Ga  | 0.09                 | 1.82       | 1.72 | 1.65 |
| 565—4555         |               | C    | Do-it-yourself Minigrabber test clip .144Ga | 0.14                 | 2.13       | 2.01 | 1.97 |
| 565—4233         |               | D    | Do-it-yourself Micrograbber test clip       | 0.10                 | 2.02       | 1.91 | 1.82 |
| 565—5243         |               | E    | Do-it-yourself SMD Grabber test clip        | 0.05                 | 2.39       | 2.19 | 2.08 |
| 565—4723         |               | F    | Minigrabber test clip with banana Jack      | 0.15                 | 5.41       | 4.95 | 4.69 |

## Pomona TEST CLIPS

Replace blank with 0 for Black, 2 for Red

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. |               | Fig. | Description   | Max Cable Dia. (in.) | Price Each |       |       |
|------------------|---------------|------|---|----------------------|------------|-------|-------|
| Mfr.             | Mfr. Part No. |      |   |                      | 1          | 25    | 50    |
| 565—5788         |               | G    | Miniature alligator to 2mm banana jack                | 0.24                 | 2.20       | 2.02  | 1.92  |
| 565—6041B        |               | G    | XL pair (red/black) alligator clip to 4mm banana jack | 0.80                 | 11.34      | 10.77 | 10.23 |
| 565—2240         |               | H    | Alligator test clip to banana jack, with insulator    | 0.30                 | .81        | .74   | .71   |

## Pomona MICRO SMD GRABBER TEST CLIPS

Replace blank with 0 for Black, 2 for Red

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. |               | Fig. | Description                                     | Max Cable Dia. (in.) | Price Each |       |       |
|------------------|---------------|------|---|----------------------|------------|-------|-------|
| Mfr.             | Mfr. Part No. |      |   |                      | 1          | 25    | 50    |
| 565—6490         |               | I    | Micro SMD Grabber Test Clip for 0.05 to 0.02in. | -                    | 28.99      | 28.16 | 27.55 |
| 565—4771-36      |               | J    | Order to attach SMD Grabber Test Clip to DMM.   | -                    | 6.74       | 6.42  | 6.10  |

## Pomona TELECOM PRODUCTS (BANTAM PLUGS)

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. |               | Fig. | Description                                      | Length (in.) | Price Each |       |       |
|------------------|---------------|------|--|--------------|------------|-------|-------|
| Mfr.             | Mfr. Part No. |      |  |              | 1          | 25    | 50    |
| 565—4279-12      |               | K    | Bantam plug patch cable                          | 12           | 29.49      | 28.64 | 27.21 |
| 565—4279-24      |               | K    | Bantam plug patch cable                          | 24           | 30.07      | 28.61 | 27.21 |
| 565—4279-36      |               | K    | Bantam plug patch cable                          | 36           | 30.07      | 28.64 | 27.21 |
| 565—4279-48      |               | K    | Bantam plug patch cable                          | 48           | 32.11      | 30.59 | 29.06 |
| 565—4279-60      |               | K    | Bantam plug patch cable                          | 60           | 32.11      | 30.59 | 29.06 |
| 565—5026-36      |               | L    | Bantam plug to 2 alligator clips patch cable     | 36           | 35.18      | 33.50 | 31.82 |
| 565—5026-60      |               | L    | Bantam plug to 2 alligator clips patch cable     | 60           | 35.92      | 34.87 | 33.13 |
| 565—4281-60      |               | M    | Bantam plug to double banana plug, balanced line | 60           | 47.49      | 46.11 | 43.80 |

## Pomona BOXES AND ENCLOSURES

### Miniature Size Die Cast Aluminum Boxes (1.5"x1.13"x.88")

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. |               | Fig. | Description                                    | Price Each |       |       |
|------------------|---------------|------|--|------------|-------|-------|
| Mfr.             | Mfr. Part No. |      |  | 1          | 25    | 50    |
| 565—3752         |               | N    | Blue Bake Enamel Finish BNC (FML) to BNC(Male) | 29.12      | 26.91 | 26.34 |
| 565—3753         |               | N    | Blue Bake Enamel Finish                        | 8.19       | 7.71  | 7.47  |
| 565—3754         |               | N    | Unfinished                                     | 5.77       | 5.48  | 5.21  |
| 565—4742         |               | -    | Replacement Cover                              | 3.77       | 3.60  | 3.41  |
| 565—4864         |               | -    | Cover Screws, 100/Package                      | 18.34      | 17.48 | 16.60 |

### 'A' Size Die Cast Aluminum Boxes (2.25"x1.13"x.88")

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. |               | Fig. | Description                                    | Price Each |       |       |
|------------------|---------------|------|--|------------|-------|-------|
| Mfr.             | Mfr. Part No. |      |  | 1          | 25    | 50    |
| 565—2400         |               | O    | Unfinished                                     | 7.28       | 6.93  | 6.58  |
| 565—2397         |               | O    | Blue Bake Enamel Finish                        | 8.99       | 8.47  | 8.21  |
| 565—2390         |               | O    | Blue Bake Enamel Finish BNC (FML) to BNC(FML)  | 27.02      | 24.97 | 24.44 |
| 565—2391         |               | O    | Blue Bake Enamel Finish BNC (Male) to BNC(FML) | 29.50      | 27.80 | 26.91 |
| 565—4245         |               | -    | Replacement Cover                              | 3.77       | 3.60  | 3.41  |
| 565—3728         |               | -    | Flange Mounting Cover                          | 9.65       | 8.44  | 8.19  |
| 565—4864         |               | -    | Cover Screws, 100/Package                      | 18.34      | 17.48 | 16.60 |

### 'B' Size Die Cast Aluminum Boxes (2.25"x1.38"x1.13")

For quantities greater than listed, call for quote.


| MOUSER STOCK NO. |               | Fig. | Description                                   | Price Each |       |       |
|------------------|---------------|------|---|------------|-------|-------|
| Mfr.             | Mfr. Part No. |      |   | 1          | 25    | 50    |
| 565—2417         |               | O    | Blue Bake Enamel Finish                       | 8.60       | 7.95  | 7.78  |
| 565—2428         |               | O    | Unfinished                                    | 8.06       | 7.47  | 7.30  |
| 565—3230         |               | O    | Blue Bake Enamel Finish BNC (FML) to BNC(FML) | 25.98      | 24.75 | 23.51 |
| 565—4246         |               | -    | Replacement Cover                             | 3.63       | 3.46  | 3.29  |
| 565—3719         |               | -    | Flange Mounting Cover                         | 5.13       | 4.89  | 4.65  |
| 565—4864         |               | -    | Cover Screws, 100/Package                     | 18.34      | 17.48 | 16.60 |

### 'C' Size Die Cast Aluminum Boxes With Cover (4.25"x2.64"x1.71")

| MOUSER STOCK NO. |               | Fig. | Description                                       | Price Each |       |       |
|------------------|---------------|------|---|------------|-------|-------|
| Mfr.             | Mfr. Part No. |      |   | 1          | 25    | 50    |
| 565—2901         |               | P    | Blue Bake Enamel Finish                           | 20.31      | 19.14 | 18.53 |
| 565—2906         |               | P    | Unfinished  | 17.20      | 15.87 | 15.05 |
| 565—2902         |               | P    | Blue Bake Enamel Finish BNC (FML) to BNC(FML)     | 40.34      | 39.10 | 37.16 |
| 565—4248         |               | -    | Replacement Cover                                 | 5.99       | 5.70  | 5.42  |
| 565—2352         |               | -    | Connector Screws with Solder Turret for all Boxes | 61.22      | 59.33 | 57.44 |

### 'D' Size Die Cast Aluminum Boxes With Cover (3.00"x2.63"x1.65")

| MOUSER STOCK NO. |               | Fig. | Description                         | Price Each |       |       |
|------------------|---------------|------|-------------------------------------|------------|-------|-------|
| Mfr.             | Mfr. Part No. |      |                                     | 1          | 25    | 50    |
| 565—3606         |               | O    | Shielded Box, Unfinished with Cover | 14.49      | 13.66 | 13.21 |

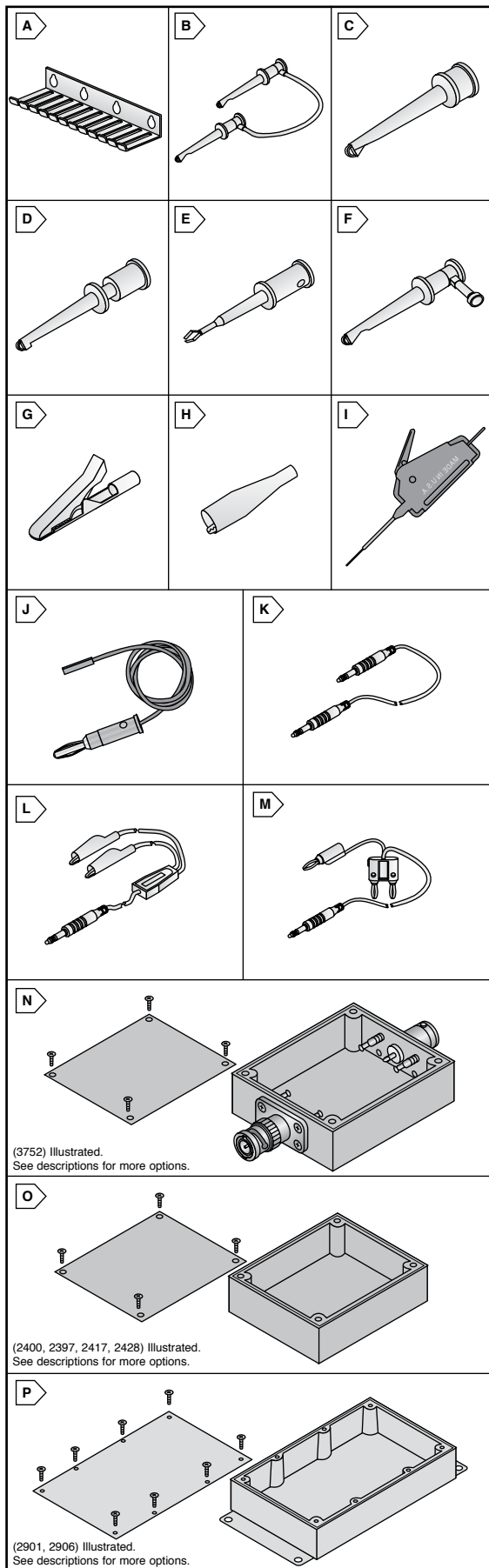

(3752) Illustrated. See descriptions for more options.

(2400, 2397, 2417, 2428) Illustrated. See descriptions for more options.

(2901, 2906) Illustrated. See descriptions for more options.