

HIROSE Circular Connectors


RoHS Compliant This product is RoHS compliant.



HIROSE ELECTRIC CO., LTD.

JR SERIES - HIGH PERFORMANCE

These JR Series connectors are designed to meet the Japanese JIS C 5432 specification standard. These connectors offer excellent performance both electrically and mechanically. They have five keys in the fitting section to assure smooth coupling.

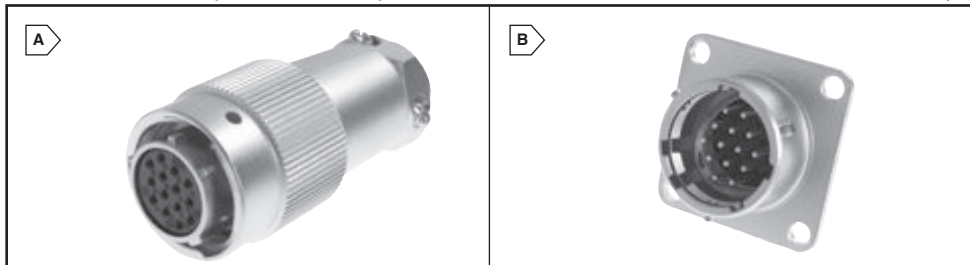

Plugs: Bayonet Lock Type

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Hirose Part No.	Fig.	No. of Contacts	Shell Size	Price Each		
					1	10	50
Pin Contacts							
798-JRC16BP7P71	JRC16BP-7P(71)	A	7	16	18.30	17.69	16.47
798-JRC16BP10P71	JRC16BP-10P(71)	A	10	16	18.60	17.98	16.74
Socket Contacts							
798-JRC16BP14S71	JRC16BP-14S(71)	A	14	16	25.20	24.36	22.68
798-JRC21BP26S71	JRC21BP-26S(71)	A	26	21	28.95	27.98	26.05

Receptacles: Bayonet Lock Type

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Hirose Part No.	Fig.	No. of Contacts	Shell Size	Price Each		
					1	10	50
Pin Contacts							
798-JRC16BR14P71	JRC16BR-14P(71)	B	14	16	11.41	9.92	8.92
798-JRC21BR26P71	JRC21BR-26P(71)	B	26	21	14.48	13.39	12.01
Socket Contacts							
798-JRC16BR7S71	JRC16BR-7S(71)	B	7	16	12.30	11.37	10.20
798-JRC16BR10S71	JRC16BR-10S(71)	B	10	16	12.96	11.98	10.75

JR SERIES - HIGH PERFORMANCE, WATERPROOF

These JR Series connectors are designed to meet the Japanese JIS C 5432 specification standard. These connectors offer excellent performance both electrically and mechanically. They have five keys in the fitting section to assure smooth coupling.

- Smooth connection
- Waterproof structure
- Versatile
- Outstanding corrosion resistance

Plugs: Soldering Type

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Hirose Part No.	Fig.	No. of Contacts	Shell Size	Price Each		
					1	10	50
Male							
798-JR13WP-3P71	JR13WP-3P(71)	A	3	13	16.32	15.36	13.92
798-JR13WP-5P71	JR13WP-5P(71)	A	5	13	16.49	15.52	14.06
798-JR16WP7P71	JR16WP-7P(71)	A	7	16	16.65	16.09	14.98
798-JR16WP10P71	JR16WP-10P(71)	A	10	16	16.95	16.38	15.25
798-JR21WP16P71	JR21WP-16P(71)	A	16	21	19.20	18.56	17.28
798-JR25WP8P71	JR25WP-8P(71)	A	8	25	27.00	26.10	24.30
798-JR25WP24P71	JR25WP-24P(71)	A	24	25	24.45	23.63	22.00
Female							
798-JR13WP3S71	JR13WP-3S(71)	A	3	13	15.00	14.50	13.50
798-JR16WP7S71	JR16WP-7S(71)	A	7	16	17.10	16.53	15.39
798-JR16WP10S71	JR16WP-10S(71)	A	10	16	16.95	16.38	15.25
798-JR21WP10S71	JR21WP-10S(71)	A	10	21	19.20	18.56	17.28
798-JR21WP16S71	JR21WP-16S(71)	A	16	21	19.80	19.14	17.82
798-JR25WP4S71	JR25WP-4S(71)	A	4	25	30.45	29.43	27.40
798-JR25WP16S71	JR25WP-16S(71)	A	16	25	24.45	23.63	22.00
798-JR25WP24S71	JR25WP-24S(71)	A	24	25	25.35	24.50	22.81

Receptacles: Soldering Type


For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Hirose Part No.	Fig.	No. of Contacts	Shell Size	Price Each		
					1	10	50
Male							
798-JR13WR3P71	JR13WR-3P(71)	B	3	13	8.44	7.34	6.60
798-JR13WR5P71	JR13WR-5P(71)	B	5	13	8.74	7.60	6.84
798-JR16WR7P71	JR16WR-7P(71)	B	7	16	9.43	8.20	7.38
798-JR16WRA7P71	JR16WRA-7P(71)	C	7	16	12.32	11.39	10.22
798-JR16WR10P71	JR16WR-10P(71)	B	10	16	9.89	8.60	7.74
798-JR25WR4P71	JR25WR-4P(71)	B	4	25	15.13	14.24	12.90
98-JR25WR16P71	JR25WR-16P(71)	B	16	25	12.24	11.32	10.15
798-JR25WR24P71	JR25WR-24P(71)	B	24	25	13.30	12.30	11.03
Female							
798-JR13WR3S71	JR13WR-3S(71)	B	3	13	9.41	8.18	7.36
798-JR13WR-5S71	JR13WR-5S(71)	B	5	13	9.73	8.46	7.61
798-JR16WR7S71	JR16WR-7S(71)	B	7	16	10.12	8.80	7.92
798-JR21WR16S71	JR21WR-16S(71)	B	16	21	11.82	10.93	9.81
798-JR25WR16S71	JR25WR-16S(71)	B	16	25	13.38	12.37	11.10
798-JR25WR24S71	JR25WR-24S(71)	B	24	25	14.56	13.46	12.08

Cord Clamp

For quantities of 100 and up, call for quote.

MOUSER STOCK NO.	Hirose Part No.	Fig.	Dimensions		Price Each		
			A	B	1	10	50
Standard Type							
798-JR13WCC471	JR13WCC-4(71)	D	4	20	11.20	9.74	8.76
798-JR13WCC571	JR13WCC-5(71)	D	5	20	11.20	9.74	8.76
798-JR13WCC671	JR13WCC-6(71)	D	6	20	11.20	9.74	8.76
798-JR16WCC671	JR16WCC-6(71)	D	6	20	10.64	9.84	8.83
798-JR16WCC871	JR16WCC-8(71)	D	8	20	10.64	9.84	8.83
798-JR16WCC1071	JR16WCC-10(71)	D	10	20	10.64	9.84	8.83
798-JR21WCC1271	JR21WCC-12(71)	D	12	27	13.43	12.64	11.45
798-JR25WCC1071	JR25WCC-10(71)	D	10	31	13.53	12.73	11.54
Simple Type							
798-JR16WCCA671	JR16WCCA-6(71)	E	6	23	7.36	6.22	5.23
798-JR16WCCA1071	JR16WCCA-10(71)	E	10	23	7.36	6.22	5.23

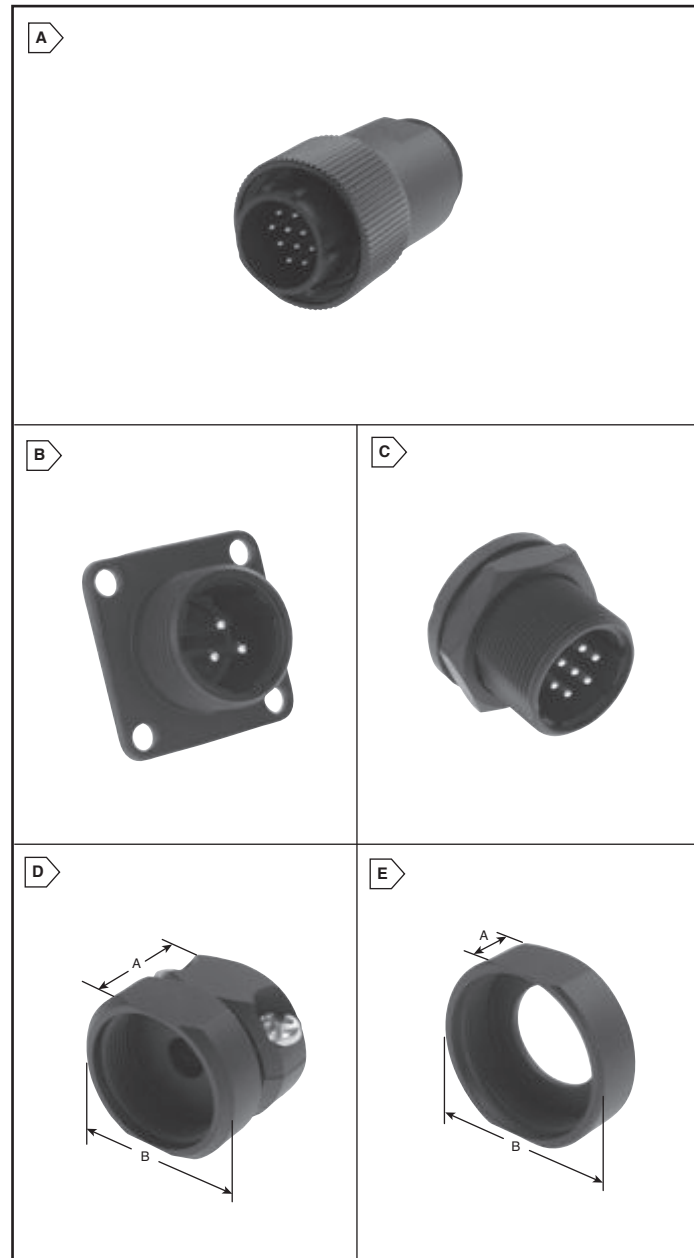

NEW FROM HIROSE

Circular Connectors

NEW FROM HIROSE

NEW FROM HIROSE