


# CENTRAL Diodes and Rectifiers

Products may be RoHS compliant. Check mouser.com for RoHS status.

**Central**  
Semiconductor Corp.

Diodes & Rectifiers

Central

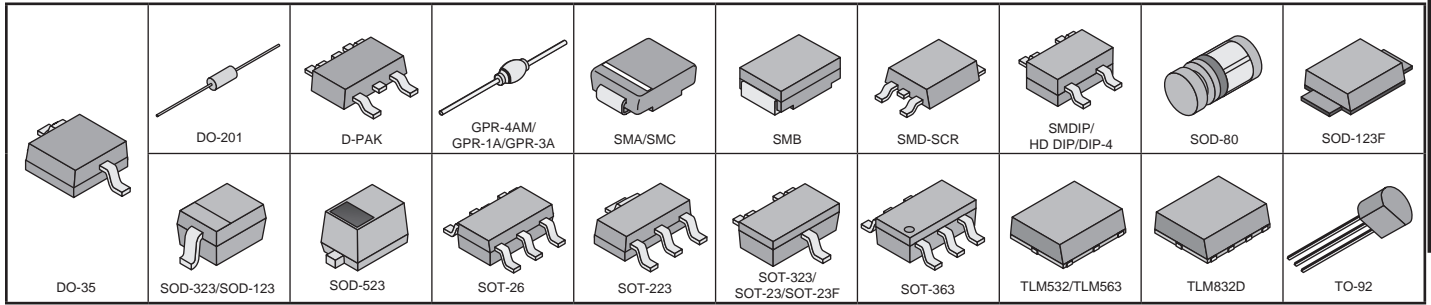

## CENTRAL ZENER DIODES

**NEW**  
PRODUCT

◆ Surface Mount Device

## CENTRAL ZENER DIODES (CONT.)

◆ Surface Mount Device

MOUSER STOCK NO.	Central Part No.	Package	If (mA)	VRRM (V)	PD (mW)	Price Each			
						1	25	100	250
610-CMPZ4614	CMPZ4614	SOT-23	120	1.8	350	.64	.56	.56	.40
610-CMPZ4617	CMPZ4617	SOT-23	95	2.4	350	.64	.56	.56	.40
610-CMOZ2V4	CMOZ2V4	SOD-523	5	2.4	250	.46	.327	.30	.272
610-CMOZ3V0	CMOZ3V0	SOD-523	5	3	250	.46	.409	.381	.327
610-CMOZ3L3	CMOZ3L3	SOD-523	0.25	3.3	250	.46	.327	.30	.272
610-CMDZ5226B	CMDZ5226B	SOD-323	20	3.3	250	.21	.171	.142	.128
610-1N4622	1N4622	DO-35	0.25	3.9	250	.46	.43	.41	.39
610-CMOZ4L3	CMOZ4L3	SOD-523	0.25	4.3	250	.46	.327	.30	.272
610-CMDZ5230B	CMDZ5230B	SOD-323	20	4.7	250	.21	.171	.142	.128
610-CMPZ4624	CMPZ4624	SOT-23	60	4.7	350	.64	.56	.56	.40
610-1N4625	1N4625	DO-35	0.25	5.1	250	.97	.937	.791	.687
610-CMOZ5L1	CMOZ5L1	SOD-523	0.25	5.1	250	.46	.327	.30	.272
610-CMDZ5L1	CMDZ5L1	SOD-323	0.5	5.1	250	.29	.27	.25	.23
610-CMDZ5231B	CMDZ5231B	SOD-323	20	5.1	250	.30	.257	.225	.20
610-1N4626	1N4626	DO-35	0.25	5.6	250	.97	.937	.791	.687
610-CMOZ6L2	CMOZ6L2	SOD-523	0.25	6.2	250	.45	.42	.375	.345
610-CMOZ6L8	CMOZ6L8	SOD-523	0.25	6.8	250	.46	.327	.30	.272
610-CMDZ5235B	CMDZ5235B	SOD-323	20	6.8	250	.30	.257	.225	.20
610-CMDZ5236B	CMDZ5236B	SOD-323	20	7.5	250	.30	.257	.225	.20
610-CMOZ9L1	CMOZ9L1	SOD-523	0.25	9.1	250	.46	.327	.30	.272
610-CMOZ9V1	CMOZ9V1	SOD-523	5	9.1	250	.46	.409	.381	.327
610-CMOZ10L	CMOZ10L	SOD-523	0.25	10	250	.45	.42	.375	.345
610-CMDZ10L	CMDZ10L	SOD-323	0.5	10	250	.45	.32	.28	.25
610-CMDZ5240B	CMDZ5240B	SOD-323	20	10	250	.30	.257	.225	.20
610-CMDZ5241B	CMDZ5241B	SOD-323	20	11	250	.21	.171	.142	.128
610-CMOZ12L	CMOZ12L	SOD-523	0.25	12	250	.46	.327	.30	.272
610-CMDZ5242B	CMDZ5242B	SOD-323	20	12	250	.21	.171	.142	.128
610-1N4109	1N4109	DO-35	0.25	15	250	.83	.74	.66	.61
610-CMOZ15L	CMOZ15L	SOD-523	0.25	15	250	.30	.28	.25	.23
610-CMDZ15L	CMDZ15L	SOD-323	0.5	15	250	.29	.27	.25	.23
610-1N4110	1N4110	DO-35	0.25	16	250	.32	.30	.28	.26
610-CMOZ16L	CMOZ16L	SOD-523	0.25	16	250	.45	.42	.375	.345
610-CMDZ16L	CMDZ16L	SOD-323	0.5	16	250	.29	.27	.25	.23
610-CMDZ5248B	CMDZ5248B	SOD-323	20	18	250	.21	.171	.142	.128
610-CMZ5359B	CMZ5359B	SMC	50	18.2	10	.46	.77	.69	.65
610-CMDZ5250B	CMDZ5250B	SOD-323	20	20	250	.30	.257	.225	.20
610-CMOZ22L	CMOZ22L	SOD-523	0.25	22	250	.46	.327	.30	.272
610-CMDZ24L	CMDZ24L	SOD-323	0.5	24	250	.29	.27	.25	.23
610-CMOZ24V	CMOZ24V	SOD-523	5	24	250	.46	.409	.381	.327
610-CMDZ30L	CMDZ30L	SOD-323	0.5	30	250	.29	.27	.25	.23
610-CMDZ5256B	CMDZ5256B	SOD-323	20	30	250	.30	.257	.225	.20
610-CMOZ36V	CMOZ36V	SOD-523	0.25	36	500	.33	.292	.253	.233
610-CMOZ43V	CMOZ43V	SOD-523	5	43	250	.46	.327	.30	.272
610-CMSZDA2V4	CMSZDA2V4	SOT-323	5	2.4	275	.25	.228	.197	.167
610-CMSZDA2V7	CMSZDA2V7	SOT-323	5	2.7	275	.25	.228	.197	.167
610-CMSZDA3V3	CMSZDA3V3	SOT-323	5	3.3	275	.25	.228	.197	.167
610-CMSZ5234B	CMSZ5234B	SOT-323	20	6.2	275	.15	.14	.12	.12
610-CMSZDA10V	CMSZDA10V	SOT-323	5	10	275	.34	.319	.288	.258
610-CMSZ5240B	CMSZ5240B	SOT-323	20	10	275	.15	.14	.13	.12
610-CMSZDA15V	CMSZDA15V	SOT-323	5	15	275	.34	.319	.288	.258
610-CMSZDA16V	CMSZDA16V	SOT-323	5	16	275	.34	.319	.288	.258
610-CMSZDA18V	CMSZDA18V	SOT-323	5	16.8	275	.34	.319	.288	.258
610-CMSZ5261B	CMSZ5261B	SOT-323	2.7	47	275	.15	.14	.12	.114
610-CMKTC825A	CMKTC825A	SOT-363	7.5	6.2	325	1.03	.94	.854	.769
610-1N746A	1N746A	DO-35	20	3.3	500	.13	.12	.10	.09
610-1N747A	1N747A	DO-35	20	3.6	500	.13	.12	.10	.09
610-1N748A	1N748A	DO-35	20	3.9	500	.13	.12	.10	.09
610-1N749A	1N749A	DO-35	20	4.3	500	.50	.388	.277	.213
610-1N750A	1N750A	DO-35	20	4.7	500	.50	.388	.277	.213
610-1N751A	1N751A	DO-35	20	5.1	500	.50	.388	.277	.213
610-1N752A	1N752A	DO-35	20	5.6	500	.50	.388	.277	.213
610-1N753A	1N753A	DO-35	20	6.2	500	.50	.388	.277	.213
610-CLL5234B	CLL5234B	SOD-80	20	6.2	500	.12	.108	.09	.078
610-1N754A	1N754A	DO-35	20	6.8	500	.13	.12	.10	.09
610-CLL5235B	CLL5235B	SOD-80	20	6.8	500	.13	.12	.10	.09
610-1N756A	1N756A	DO-35	20	8.2	500	.50	.388	.277	.213
610-1N758A	1N758A	DO-35	20	10	500	.50	.388	.277	.213
610-1N759A	1N759A	DO-35	20	12	500	.13	.12	.10	.09
610-CZ5342B	CZ5342B	DO-201	175	6.8	5000	.52	.47	.42	.38
610-CZ5343B	CZ5343B	DO-201	175	7.5	5000	.52	.47	.42	.38
610-CZ5344B	CZ5344B	DO-201	150	8.2	5000	.52	.47	.42	.38
610-CZ5347B	CZ5347B	DO-201	125	10	5000	.52	.47	.42	.38
610-CZ5348B	CZ5348B	DO-201	125	11	5000	.52	.47	.42	.38
610-CZ5349B	CZ5349B	DO-201	100	12	5000	.52	.47	.42	.38