

ALPS Metal Shaft Potentiometers


ALPS

ALPS 9MM SIZE METAL SHAFT SNAP-IN POTENTIOMETERS

RK09L Series

Features:

- Shaft Type: Flat

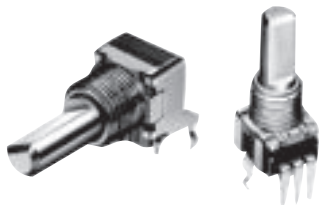


For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Length of Shaft	Total Resistance	Resistance Taper	Price Each			
Mfr.	Mfr. Part No.				1	25	50	100
Single-Unit Horizontal								
688—RK09L1120A2S		15mm	10kΩ	15A	.90	.83	.75	.60
Single-Unit Vertical								
688—RK09L1140A5P		15mm	50kΩ	1B	3.10	2.55	2.35	2.00
688—RK09L114001T		20mm	10kΩ	1B	1.07	.98	.89	.71
688—RK09L1140A65		25mm	5kΩ	1B	.98	.90	.83	.66
Dual-Unit Horizontal								
688—RK09L12B0A31		15mm	50kΩ	15A	1.60	1.45	1.25	1.10
Dual-Unit Vertical								
688—RK09L12D0A1T		20mm	10kΩ	15A	1.12	1.02	.93	.74

ALPS 9MM SIZE METAL SHAFT MULTI-GANGED POTENTIOMETERS

RK097/RK098 Series

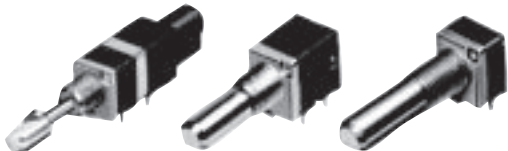

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Length of Shaft	Total Resistance	Resistance Taper	Price Each			
Mfr.	Mfr. Part No.				1	25	50	100
Single-Unit Horizontal								
688—RK097111080J		15mm	10kΩ	15A	1.74	1.48	1.29	1.21
688—RK0971110909		15mm	20kΩ	1B	1.26	1.16	1.05	.84
688—RK097111050B		15mm	50kΩ	15A	1.26	1.16	1.05	.84
688—RK0971110D7Z		15mm	50kΩ	1B	1.33	1.22	1.11	.89
688—RK097111020N		15mm	50kΩ	1B	1.26	1.16	1.05	.84
688—RK0971110D88		20mm	10kΩ	1B	1.77	1.51	1.31	1.23
688—RK097111091M		25mm	10kΩ	15A	1.92	1.63	1.42	1.34
688—RK0971110D57		25mm	10kΩ	1B	1.93	1.64	1.43	1.34
688—RK0971111Z0P		15mm	20kΩ	15A	2.16	1.98	1.80	1.44
688—RK09711110AL		20mm	10kΩ	15A	2.39	2.03	1.77	1.66
688—RK09711110EL		20mm	10kΩ	1B	2.39	2.03	1.77	1.66
688—RK097111202P		25mm	10kΩ	15A	3.37	2.87	2.50	2.35
688—RK097111202Q		25mm	10kΩ	1B	3.37	2.87	2.50	2.35
688—RK0971114D0B		15mm	10kΩ	3B	2.46	2.09	1.82	1.71
688—RK0971214Z06		20mm	10kΩ	1B	3.63	3.09	2.69	2.52
688—RK0971224Z01		20mm	10kΩ	15A	3.30	2.80	2.44	2.35
688—RK0971114Z07		20mm	10kΩ	1B	3.13	2.67	2.32	2.18
688—RK0971114Z04		25mm	10kΩ	1B	2.45	2.24	2.04	1.63
688—RK097111T065		25mm	10kΩ	1B	2.52	2.15	1.87	1.76
688—RK097111T064		25mm	100kΩ	15A	2.51	2.14	1.86	1.75
688—RK097111TD2M		25mm	10kΩ	1B	2.27	1.94	1.68	1.58
Dual-Unit Horizontal								
688—RK09712200MC		15mm	10kΩ	15A	1.80	1.65	1.50	1.20
688—RK09712200MY		15mm	10kΩ	3B	1.80	1.65	1.50	1.20
688—RK0971221Z05		15mm	10kΩ	3B	2.80	2.57	2.33	1.87
688—RK097121TD57		25mm	10kΩ	1B	4.76	4.12	3.47	3.05
688—RK097122T017		25mm	10kΩ	15A	2.68	2.28	1.98	1.86

© Copyright 2011 Mouser Electronics


© Copyright 2011 Mouser Electronics

ALPS 27MM SIZE METAL SHAFT POTENTIOMETERS

RK27 Series

Features:

- Shaft Types: Flat and Slotted

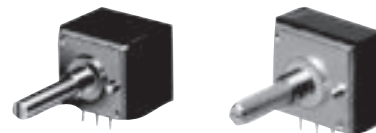

For quantities greater than listed, call for quote.


MOUSER STOCK NO.		Length of Shaft	Total Resistance	Resistance Taper	Price Each			
Mfr.	Mfr. Part No.				1	25	50	100
Single-Unit Horizontal								
688—RK271111001T		25mm	100kΩ	15A	6.92	6.30	5.67	5.04
688—RK2711120026		25mm	100kΩ	15A	7.33	6.66	5.99	5.33
Dual-Unit Horizontal								
688—RK27112A00AK		20mm	100kΩ	15A	11.71	10.64	9.58	8.51
688—RK27112A00CC		25mm	100kΩ	15A	11.71	10.64	9.58	8.51
688—RK27112A0A16		20mm	100kΩ	15A	11.71	10.64	9.58	8.51

ALPS 16MM SIZE METAL SHAFT POTENTIOMETERS

RK163 Series

Features:

- Shaft Types: Flat and Knurled

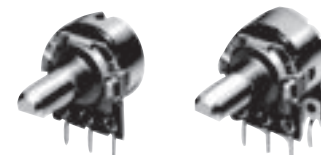

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Length of Shaft	Total Resistance	Resistance Taper	Price Each			
Mfr.	Mfr. Part No.				1	25	50	100
Single-Unit Horizontal								
688—RK1631110TBK		15mm	10kΩ	1B	1.62	1.49	1.35	1.08
688—RK1631110TT3		20mm	10kΩ	15A	1.62	1.49	1.35	1.08
688—RK1631110TNP		20mm	10kΩ	1B	1.62	1.49	1.35	1.08
Dual-Unit Horizontal								
688—RK1631210AX9		15mm	10kΩ	1B	2.59	2.37	2.16	1.73
688—RK16312A0B85		20mm	10kΩ	15A	2.66	2.44	2.22	1.77

ALPS 9MM SIZE INSULATED SHAFT LONG-LIFE POTENTIOMETER

Features:

- Shaft Types: Flat



For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Length of Shaft	Total Resistance	Resistance Taper	Price Each			
Mfr.	Mfr. Part No.				1	25	50	100
Single-Unit Horizontal								
688—RK09Y11L0001		15mm	10kΩ	15A	.61	.56	.51	.41

ALPS 16MM/27MM SIZE MOTOR-DRIVEN POTENTIOMETERS

Features:

- Shaft Types: Flat



For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Length of Shaft	Total Resistance	Resistance Taper	Price Each			
Mfr.	Mfr. Part No.				1	25	50	100
Single-Unit								
688—RK16812MG099		25mm	100k	3B	8.00	7.00	6.25	5.65
688—RK16814MG02R		25mm	20k	15A	6.88	6.26	5.63	5.01
Dual-Unit								
688—RK27112MC030		25mm	100k	15A	18.00	16.37	14.73	13.09
6 Ganged-Unit								
688—RK16816MGA04		25mm	100k	3B	9.91	9.01	8.11	7.21

© Copyright 2011 Mouser Electronics

© Copyright 2011 Mouser Electronics