


# BOMAR Between Series Adapters

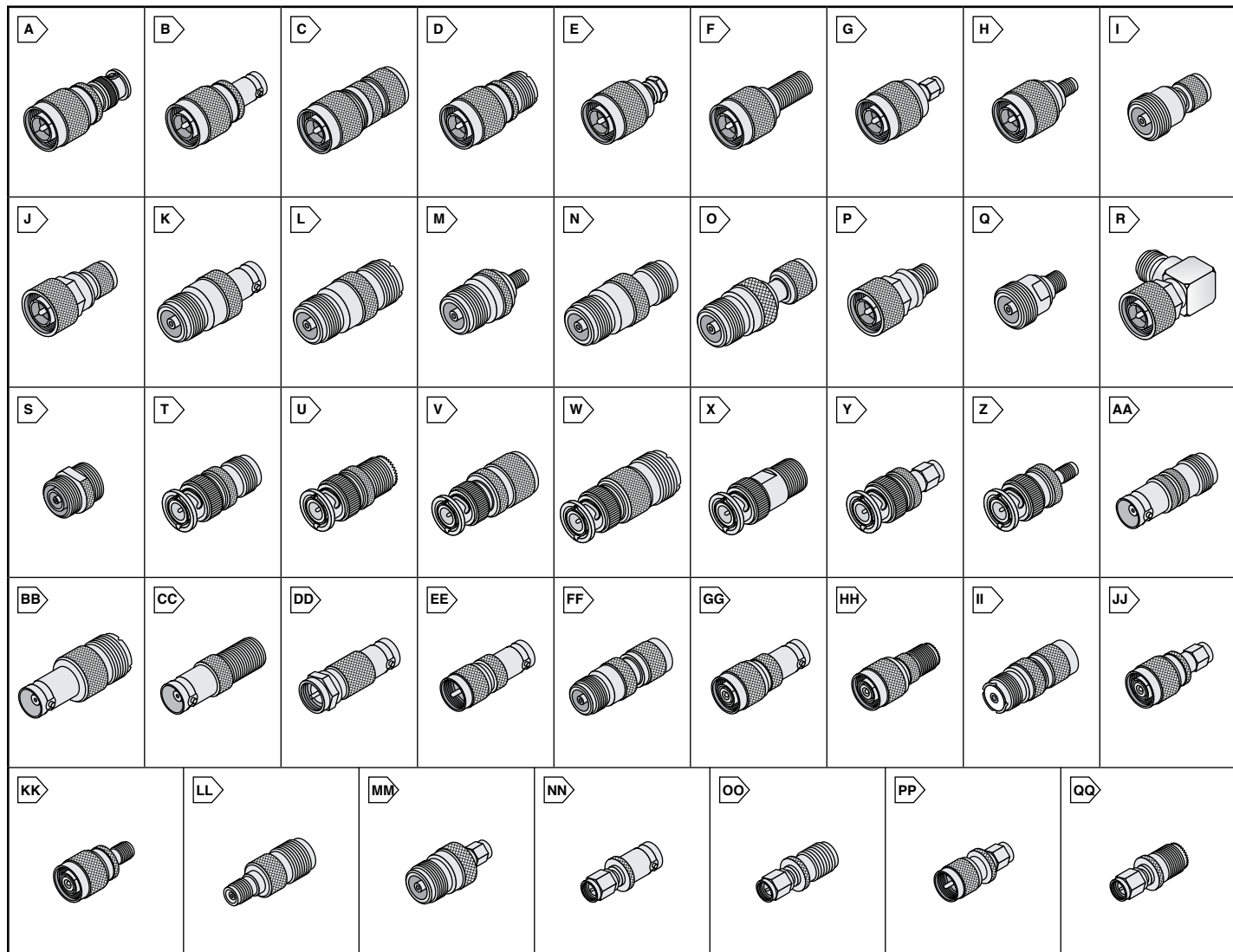

RF Connectors

Bomar

Between series adapters solve a variety of connection problems where connectors of different types could ordinarily not be mated together. Each adapter has a different type coupling at each end allowing for a wide variety of interconnections to fit almost all interconnection situations. All adapters are constructed of machined brass and are nickel plated.

• RoHS Compliant per Bomar documentation



RoHS Compliant



RoHS Compliant

\*Plating: Tri-plate, a copper alloy composed of three components: 55% copper, 25% tin, and 20% zinc

For quantities of 100 and up, call for quote.

| MOUSER STOCK NO.          | Bomar Part No. | Fig. | Description                | Price Each |       |       |       |
|---------------------------|----------------|------|----------------------------|------------|-------|-------|-------|
|                           |                |      |                            | 1          | 10    | 25    | 50    |
| <b>Type N Adapters</b>    |                |      |                            |            |       |       |       |
| 678-1303505               | 1303505        | A    | N Plug to BNC Plug         | 22.56      | 21.80 | 20.50 | 19.80 |
| 678-1313505               | 1313505        | B    | N Plug to BNC Jack         | 15.15      | 14.26 | 13.86 | 12.91 |
| 678-1307505               | 1307505        | C    | N Plug to UHF Plug         | 24.54      | 23.72 | 22.90 | 22.27 |
| 678-1317505               | 1317505        | D    | N Plug to UHF Jack         | 16.52      | 15.02 | 14.50 | 13.32 |
| 678-1308505               | 1308505        | E    | N Plug to F Plug           | 8.54       | 7.77  | 7.28  | 6.69  |
| 678-1318505               | 1318505        | F    | N Plug to F Jack           | 13.19      | 12.42 | 11.82 | 11.30 |
| 678-1309505               | 1309505        | G    | N Plug to SMA Plug         | 31.97      | 29.07 | 28.05 | 26.07 |
| 678-1319505               | 1319505        | H    | N Plug to SMA Jack         | 13.06      | 12.08 | 11.58 | 10.90 |
| * 678-131150011           | 131150011      | I    | N Plug to 7/16 Jack        | 28.92      | 27.96 | 26.29 | 25.86 |
| * 678-153115011           | 153115011      | J    | N Plug to 7/16 Plug        | 31.20      | 30.16 | 28.36 | 27.80 |
| 678-1323505               | 1323505        | K    | N Jack to BNC Jack         | 15.57      | 14.66 | 13.80 | 13.20 |
| 678-1327505               | 1327505        | L    | N Jack to UHF Jack         | 13.89      | 13.07 | 12.58 | 11.97 |
| 678-1329505               | 1329505        | M    | N Jack to SMA Jack         | 64.35      | 60.94 | 57.68 | 55.68 |
| 678-1325505               | 1325505        | N    | N Jack to TNC Jack         | 20.21      | 18.37 | 18.18 | 16.81 |
| 678-6311505               | 6311505        | O    | N Jack to Mini-UHF Plug    | 18.00      | 16.64 | 15.30 | 14.23 |
| * 678-153155011           | 153155011      | P    | N Jack to 7/16 Plug        | 26.03      | 25.16 | 23.66 | 22.97 |
| * 678-153215011           | 153215011      | Q    | N Jack to 7/16 Jack        | 25.86      | 25.00 | 23.51 | 23.27 |
| <b>Type 7/16 Adapters</b> |                |      |                            |            |       |       |       |
| * 678-1513A5011           | 1513A5011      | R    | 7/16 Plug to 7/16 Jack R/A | 45.49      | 43.86 | 42.23 | 41.87 |
| * 678-1532A5011           | 1532A5011      | S    | 7/16 Jack to 7/16 Jack     | 28.92      | 27.96 | 26.29 | 25.80 |
| <b>Type BNC Adapters</b>  |                |      |                            |            |       |       |       |
| 678-3315505               | 3315505        | T    | BNC Plug to TNC Jack       | 6.38       | 5.80  | 5.61  | 5.16  |
| 678-3316505               | 3316505        | U    | BNC Plug to Mini-UHF Jack  | 11.00      | 10.17 | 9.69  | 9.21  |
| 678-3307505               | 3307505        | V    | BNC Plug to UHF Plug       | 16.75      | 15.76 | 13.82 | 13.81 |

For quantities of 100 and up, call for quote.

| MOUSER STOCK NO.               | Bomar Part No. | Fig. | Description               | Price Each |       |       |       |
|--------------------------------|----------------|------|---------------------------|------------|-------|-------|-------|
|                                |                |      |                           | 1          | 10    | 25    | 50    |
| <b>Type BNC Adapters Cont.</b> |                |      |                           |            |       |       |       |
| 678-3317505                    | 3317505        | W    | BNC Plug to UHF Jack      | 10.16      | 9.39  | 8.61  | 7.92  |
| 678-3318505                    | 3318505        | X    | BNC Plug to F Jack        | 4.92       | 4.48  | 4.32  | 3.97  |
| 678-3309505                    | 3309505        | Y    | BNC Plug to SMA Plug      | 21.56      | 20.84 | 20.33 | 18.97 |
| 678-3319505                    | 3319505        | Z    | BNC Plug to SMA Jack      | 8.52       | 7.78  | 7.27  | 7.01  |
| 678-3325505                    | 3325505        | AA   | BNC Jack to TNC Jack      | 15.30      | 13.90 | 13.70 | 12.72 |
| 678-3327505                    | 3327505        | BB   | BNC Jack to UHF Jack      | 15.02      | 14.16 | 13.93 | 12.96 |
| 678-3328505                    | 3328505        | CC   | BNC Jack to F Jack        | 5.73       | 5.22  | 5.03  | 4.63  |
| 678-8313505                    | 8313505        | DD   | BNC Jack to F Plug        | 4.61       | 4.20  | 4.05  | 3.72  |
| 678-6313505                    | 6313505        | EE   | BNC Jack to Mini-UHF Plug | 14.62      | 13.28 | 12.82 | 11.79 |
| <b>Type TNC Adapters</b>       |                |      |                           |            |       |       |       |
| 678-5311505                    | 5311505        | FF   | TNC Plug to N Jack        | 10.42      | 9.63  | 8.84  | 8.45  |
| 678-5313505                    | 5313505        | GG   | TNC Plug to BNC Jack      | 5.58       | 5.07  | 4.89  | 4.49  |
| 678-5316505                    | 5316505        | HH   | TNC Plug to Mini-UHF Jack | 10.12      | 9.19  | 8.86  | 8.14  |
| 678-5317505                    | 5317505        | II   | TNC Plug to UHF Jack      | 13.96      | 13.14 | 12.94 | 12.85 |
| 678-5309505                    | 5309505        | JJ   | TNC Plug to SMA Plug      | 12.86      | 11.89 | 10.95 | 10.06 |
| 678-5319505                    | 5319505        | KK   | TNC Plug to SMA Jack      | 21.50      | 20.78 | 20.15 | 19.86 |
| 678-5329505                    | 5329505        | LL   | TNC Jack to SMA Jack      | 40.43      | 38.99 | 37.54 | 36.80 |
| <b>Type SMA Adapters</b>       |                |      |                           |            |       |       |       |
| 678-9311505                    | 9311505        | MM   | SMA Plug to N Jack        | 19.50      | 18.85 | 18.15 | 17.45 |
| 678-9313505                    | 9313505        | NN   | SMA Plug to BNC Jack      | 11.92      | 11.02 | 10.57 | 9.98  |
| 678-9315505                    | 9315505        | OO   | SMA Plug to TNC Jack      | 21.71      | 20.98 | 19.95 | 19.02 |
| 678-9306505                    | 9306505        | PP   | SMA Plug to Mini-UHF Plug | 6.66       | 6.06  | 5.84  | 5.37  |
| 678-9316505                    | 9316505        | QQ   | SMA Plug to Mini-UHF Jack | 23.88      | 23.08 | 22.08 | 21.08 |