


EVERLIGHT LED Circuit Board Indicators

EVERLIGHT

RoHS Compliant This product is RoHS compliant.

DIMENSIONS: in.

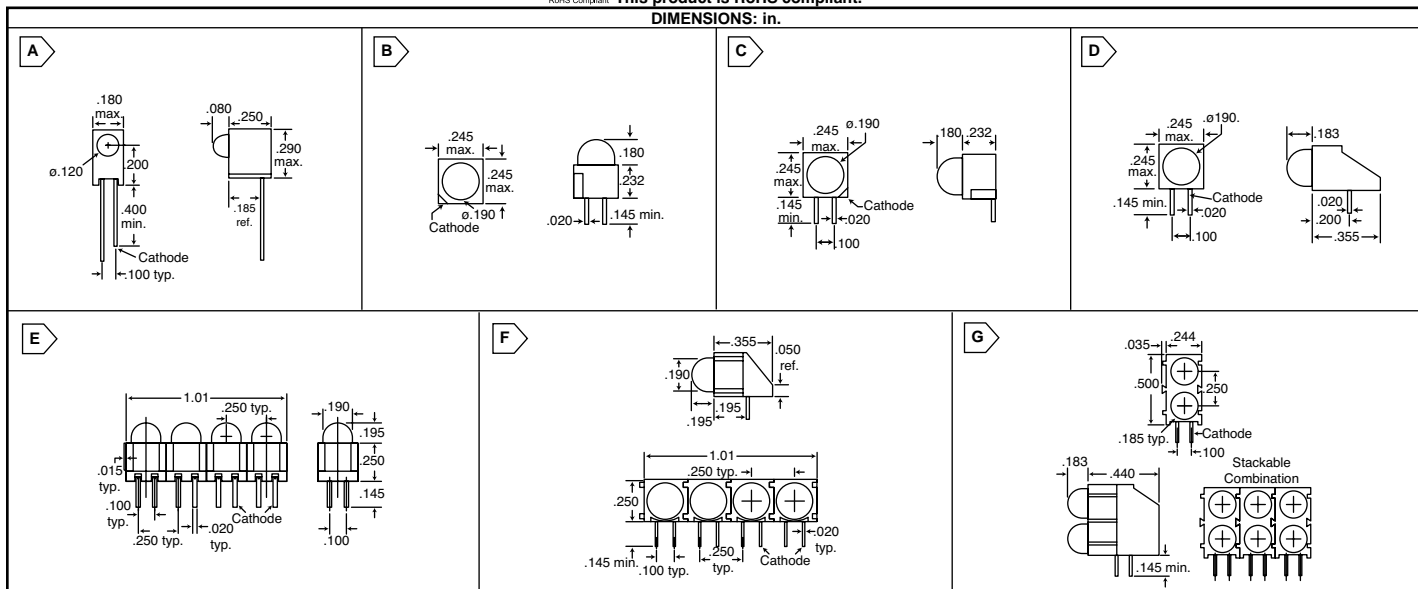

LED Indication
Everlight

PCB INDICATORS

T-1 PCB Indicators

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. | Everlight Part No. | Fig. | Color | Description | Vf | mcd | mA | Price Each | | |
|------------------|--------------------|------|------------|-------------|-----|-----|----|------------|-----|-----|
| | | | | | | | | 1 | 100 | 500 |
| 638-MV5764.MP4B | MV5764MP4B | A | Hi-Eff.Red | Right Angle | 2 | 2 | 10 | .31 | .18 | .13 |
| 638-MV5064.MP4B | MV5064MP4B | A | Red | Right Angle | 1.6 | 1.5 | 20 | .31 | .18 | .13 |
| 638-MV5364.MP4B | MV5364MP4B | A | Yellow | Right Angle | 2.1 | 2 | 10 | .40 | .25 | .19 |
| 638-MV5464.MP4B | MV5464MP4B | A | Green | Right Angle | 2.2 | 5 | 20 | .39 | .24 | .18 |

T-1 3/4 PCB Indicators

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. | Everlight Part No. | Fig. | Color | Description | Vf | mcd | mA | Price Each | | |
|------------------|--------------------|------|------------|-------------|-----|-----|----|------------|-----|-----|
| | | | | | | | | 1 | 100 | 500 |
| 638-MV67539.MP5 | MV67539MP5 | B | Hi-Eff.Red | Straight | 2.1 | 15 | 20 | .40 | .25 | .19 |
| 638-MV60539.MP5 | MV60539MP5 | B | Red | Straight | 1.7 | 3.2 | 20 | .40 | .25 | .19 |
| 638-MV63539.MP5 | MV63539MP5 | B | Yellow | Straight | 2.1 | 20 | 20 | .40 | .25 | .19 |
| 638-MV64539.MP5 | MV64539MP5 | B | Green | Straight | 2.2 | 28 | 20 | .40 | .25 | .19 |
| 638-MV67539.MP6 | MV67539MP6 | C | Hi-Eff.Red | Right Angle | 2.1 | 15 | 20 | .39 | .23 | .17 |
| 638-MV60539.MP6 | MV60539MP6 | C | Red | Right Angle | 1.7 | 3.2 | 20 | .40 | .25 | .19 |
| 638-MV63539.MP6 | MV63539MP6 | C | Yellow | Right Angle | 2.1 | 20 | 20 | .40 | .25 | .19 |
| 638-MV64539.MP6 | MV64539MP6 | C | Green | Right Angle | 2.2 | 28 | 20 | .40 | .25 | .19 |
| 638-MV67539.MP7 | MV67539MP7 | D | Hi-Eff.Red | Right Angle | 2.1 | 15 | 20 | .35 | .20 | .15 |
| 638-MV60539.MP7 | MV60539MP7 | D | Red | Right Angle | 1.7 | 3.2 | 20 | .40 | .25 | .19 |
| 638-MV63539.MP7 | MV63539MP7 | D | Yellow | Right Angle | 2.1 | 20 | 20 | .40 | .25 | .19 |
| 638-MV64539.MP7 | MV64539MP7 | D | Green | Right Angle | 2.2 | 28 | 20 | .40 | .25 | .19 |

T-1 3/4 Bi-Color PCB Indicators

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. | Everlight Part No. | Fig. | Color | Description | Vf | mcd | mA | Price Each | | |
|------------------|--------------------|------|-----------|-------------|-----|-----|----|------------|-----|-----|
| | | | | | | | | 1 | 100 | 500 |
| 638-MV54919.MP5 | MV54919MP5 | B | Red/Green | Straight | 2.3 | 6 | 20 | .43 | .29 | .22 |
| 638-MV54919.MP6 | MV54919MP6 | C | Red/Green | Right Angle | 2.3 | 6 | 20 | .46 | .32 | .24 |
| 638-MV54919.MP7 | MV54919MP7 | D | Red/Green | Right Angle | 2.3 | 6 | 20 | .43 | .30 | .23 |

T-1 3/4 Unit PCB Indicators

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. | Everlight Part No. | Fig. | Color | Description | Vf | mcd | mA | Price Each | | |
|------------------|--------------------|------|------------|--------------------|-----|-----|----|------------|------|-----|
| | | | | | | | | 1 | 100 | 500 |
| 638-MV64539.MP8 | MV64539MP8 | E | Green | 4 Lamp Straight | 2.2 | 28 | 20 | 1.37 | .94 | .68 |
| 638-MV67539.MP8B | MV67539MP8B | F | Hi-Eff.Red | 4 Lamp Right Angle | 2.1 | 15 | 20 | 1.37 | .94 | .68 |
| 638-MV60539.MP8B | MV60539MP8B | F | Red | 4 Lamp Right Angle | 1.7 | 3.2 | 20 | 1.54 | 1.06 | .77 |

T-1 3/4 Bi-Level PCB Indicators

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. | Everlight Part No. | Fig. | Color | Description | Vf | mcd | mA | Price Each | | |
|------------------|--------------------|------|------------|-------------|-----|-----|----|------------|-----|-----|
| | | | | | | | | 1 | 100 | 500 |
| 638-MV60539.MP90 | MV60539MP90 | G | Red | Bi-Level | 1.7 | 3.2 | 20 | .73 | .51 | .38 |
| 638-MV63539.MP93 | MV63539MP93 | G | Yellow | Bi-Level | 2.1 | 20 | 20 | .73 | .51 | .38 |
| 638-MV64539.MP94 | MV64539MP94 | G | Green | Bi-Level | 2.2 | 28 | 20 | .82 | .58 | .43 |
| 638-MV67539.MP97 | MV67539MP97 | G | Hi-Eff.Red | Bi-Level | 2.1 | 15 | 20 | .82 | .58 | .43 |