

# WURTH ELECTRONICS I/O Connectors & Modular Jacks



NEW AT MOUSER

Data/Network/Telecom

Wurth Electronics

NEW AT MOUSER

NEW AT MOUSER


## USB 3.0 CONNECTORS



This product is RoHS compliant.

Midcom

MOUSER STOCK NO.	Wurth Electronics Part No.	Fig.	Description	Price Each			
				1	25	100	250
<a href="#">710-692121030100</a>	692121030100	A	Horizontal Type A Thru-Hole	3.77	2.90	2.40	2.30
<a href="#">710-692121230100</a>	692121230100	B	Horizontal Type A, Offset 1.04mm Thru-Hole	3.77	2.90	2.40	2.30
<a href="#">710-692121130100</a>	692121130100	C	Reverse Horizontal Type A, Offset 0.14mm Thru-Hole	4.10	3.15	2.60	2.49
<a href="#">710-692121330100</a>	692121330100	C	Reverse Horizontal Type A, Offset 1.75mm Thru-Hole	4.10	3.15	2.60	2.49
<a href="#">710-692122030100</a>	692122030100	D	Horizontal Type A SMD	4.10	3.15	2.60	2.49
<a href="#">710-692141030100</a>	692141030100	E	Horizontal Type A Dual, Thru-Hole	7.67	5.90	4.87	4.48
<a href="#">710-692112030100</a>	692112030100	F	Horizontal Type A SMD with Clip	4.10	3.15	2.60	2.49
<a href="#">710-692221030100</a>	692221030100	G	Horizontal Type B Thru-Hole	5.67	4.36	3.60	3.45
<a href="#">710-7497110616</a>	7497110616	H	WE-RJ45 LAN with dual USB 3.0	25.17	19.36	16.00	15.36

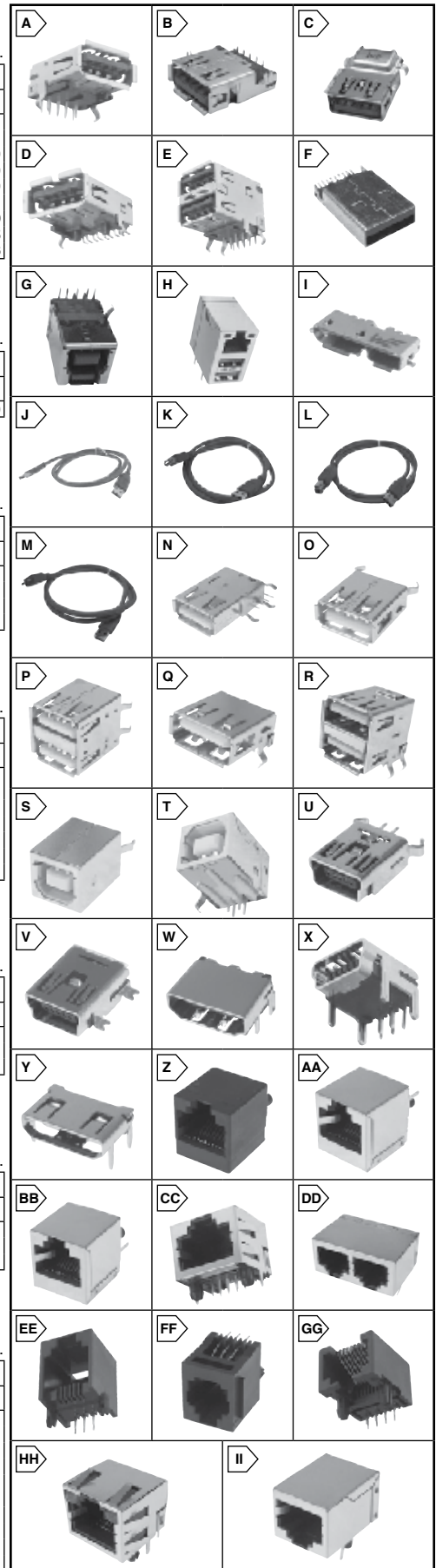

## MICRO USB 3.0



RoHS Compliant

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Wurth Electronics Part No.	Fig.	Description	Price Each			
				1	25	100	250
<a href="#">710-692622030100</a>	692622030100	I	Micro Horizontal B SMT	4.10	3.15	2.60	2.49

## USB 3.0 CABLE ASSEMBLIES



RoHS Compliant

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Wurth Electronics Part No.	Fig.	Description	Price Each			
				1	25	100	250
<a href="#">710-692901100000</a>	692901100000	J	USB 3.0 Type A Male to Type A Male	18.88	14.52	12.00	11.52
<a href="#">710-692902100000</a>	692902100000	K	USB 3.0 Type A Male to Type A Female	19.83	15.25	12.60	12.09
<a href="#">710-692903100000</a>	692903100000	L	USB 3.0 Type A Male to Type B Male	19.83	15.25	12.60	12.09
<a href="#">710-692904100000</a>	692904100000	M	USB 3.0 Type A Male to Micro B Male	22.02	16.94	14.00	13.44

## USB CONNECTORS



RoHS Compliant

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Wurth Electronics Part No.	Fig.	Description	Price Each			
				1	25	100	250
<a href="#">710-614004134726</a>	614004134726	N	USB Type A Up Right	3.36	2.80	2.48	2.20
<a href="#">710-614004135023</a>	614004135023	O	USB Type A Vertical	2.31	1.93	1.70	1.51
<a href="#">710-614008235023</a>	614008235023	P	USB Type A Vertical Dual	3.36	2.80	2.48	2.20
<a href="#">710-61400416021</a>	61400416021	Q	USB Type A Horizontal	1.89	1.58	1.39	1.23
<a href="#">710-61400826021</a>	61400826021	R	USB Type A Horizontal Dual Stacked	3.99	3.33	2.94	2.61
<a href="#">710-61400413321</a>	61400413321	S	USB Type B Vertical	1.68	1.40	1.24	1.10
<a href="#">710-61400416121</a>	61400416121	T	USB Type B Horizontal	2.60	2.17	1.92	1.70

## MINI USB CONNECTORS



RoHS Compliant

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Wurth Electronics Part No.	Fig.	Description	Price Each			
				1	25	100	250
<a href="#">710-651005136421</a>	651005136421	U	Mini USB Type B Vertical 5 Contacts	3.78	3.15	2.79	2.47
<a href="#">710-651005136521</a>	651005136521	V	Mini USB Type B Horizontal 5 Contacts	2.73	2.28	2.01	1.78
<a href="#">710-65100516121</a>	65100516121	W	Mini USB Type B SMT Horizontal 5 Contacts	2.60	2.17	1.92	1.70

## HDMI CONNECTORS



RoHS Compliant

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Wurth Electronics Part No.	Fig.	Description	Price Each			
				1	25	100	250
<a href="#">710-685119134923</a>	685119134923	X	SMT Horizontal HDMI	3.90	3.25	2.76	1.78
<a href="#">710-685119135725</a>	685119135725	X	SMT Horizontal HDMI with UNC 4-40 SCREW	4.62	3.85	3.41	3.02
<a href="#">710-685119136923</a>	685119136923	Y	SMT Horizontal Mini HDMI	5.40	4.50	3.82	3.37

## MODULAR JACKS



RoHS Compliant

For quantities of 500 and up, call for quote.

MOUSER STOCK NO.	Wurth Electronics Part No.	Fig.	Description	Price Each			
				1	25	100	250
<a href="#">710-615008138021</a>	615008138021	Z	Vertical Plastic 8P8C	2.52	2.10	1.86	1.65
<a href="#">710-615008138221</a>	615008138221	AA	Vertical Shielded 8P8C Front Post	3.57	2.98	2.63	2.33
<a href="#">710-615008140421</a>	615008140421	BB	Vertical Shielded 8P8C Rear Post	3.78	3.15	2.79	2.47
<a href="#">710-615008140621</a>	615008140621	CC	Horizontal Shielded w. EMI Panel Finger 8P8C Tab Up	3.57	2.98	2.63	2.33
<a href="#">710-615016137621</a>	615016137621	DD	Horizontal Shielded Dual Port 8P8C Tab Down	5.46	4.55	4.03	3.57
<a href="#">710-615006138421</a>	615006138421	EE	Horizontal Plastic 6PxC Tab Up	1.26	1.05	.93	.825
<a href="#">710-615006138521</a>	615006138521	FF	Vertical Plastic 6P6c with Ears	1.64	1.37	1.20	1.07
<a href="#">710-615008137121</a>	615008137121	GG	Horizontal Plastic 8P8C Thru-Hole Tab Down	3.36	2.80	2.48	2.20
<a href="#">710-615008137421</a>	615008137421	HH	Horizontal Shielded w. LED and EMI Panel Finger 8P8C Tab Up	5.88	4.90	4.34	3.85
<a href="#">710-61500814221</a>	61500814221	II	Horizontal Shielded 8P8C Tab Down	4.83	4.03	3.56	3.16