



CONEC IP67 Connector Systems

RoHS Compliant This page of product is compliant.

IP67 FIBER OPTIC LC-DUPLEX SYSTEM FOR HARSH ENVIRONMENTS







MOUSER STOCK NO.	CONEC Part No.	Fig.	Description	Price Each			
				1	10	25	50
Receptacle Assembly Kits							
706-17-300010	17-300010	A	Plastic, Single Mode	20.38	18.34	16.67	15.28
706-17-300060	17-300060	A	Die-Cast Single Mode	36.18	32.56	29.60	27.13
706-17-300070	17-300070	A	Die-Cast Multi Mode	32.60	29.34	26.67	24.45
Plug Kits							
706-17-300030	17-300030	B	Plastic, Single Mode	29.80	26.82	24.38	22.35
706-17-300110	17-300110	B	Plastic, APC Single Mode	38.24	34.42	31.29	28.68
706-17-300080	17-300080	B	Die-Cast, Single Mode	43.09	38.78	35.25	32.32
706-17-300090	17-300090	B	Die-Cast, Multi Mode	43.09	38.78	35.25	32.32
706-17-300120	17-300120	B	Die-Cast, APC Single Mode	51.60	46.44	42.22	38.70
Accessories							
706-17-300050	17-300050	-	Protective cover receptacle	7.00	6.30	5.73	5.25

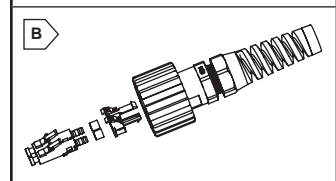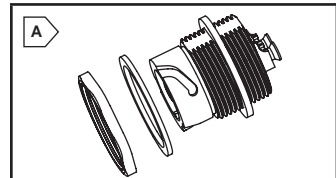

SEALED INDUSTRIAL ETHERNET CIRCULAR IP67 RJ45 CONNECTOR SYSTEM


RJ45 Receptacles

MOUSER STOCK NO.	CONEC Part No.	Fig.	Description	Price Each			
				1	10	25	50
Inline Coupler Kits							
631-17-10000	17-10000	C	Plastic with shielded inline coupler + protective cover	16.95	14.38	13.77	12.63
631-17-10020	17-10020	C	Plastic unshielded inline coupler + protective cover	13.93	12.38	11.14	10.13
706-17-10009	17-10009	C	Plastic with shielded inline coupler	18.20	14.15	12.84	12.26
631-17-10011	17-10011	C	Metalized plastic with shielded inline coupler + protective cover	19.67	16.18	15.58	14.63
706-17-101754	17-101754	C	Zinc Die-Cast Version with Shielded RJ45 Inline Coupler	28.11	21.08	20.07	19.16
706-17-101764	17-101764	C	Zinc Die-Cast Version with Unshielded RJ45 Inline Coupler	26.68	20.01	19.06	18.19
706-17-101814	17-101814	C	Zinc Die-Cast Version with Shielded RJ45 Coupler + Cover	42.15	31.61	30.11	28.74
706-17-101824	17-101824	C	Zinc Die-Cast Version with Unshielded RJ45 Coupler + Cover	40.73	30.55	29.09	27.77
IDC Kits							
631-17-10021	17-10021	D	Plastic with shielded IDC jack + protective cover	18.38	16.95	14.38	13.01
631-17-10038	17-10038	D	Potted metalized plastic with shielded IDC jack + protective cover	24.09	19.44	18.78	17.87
631-17-10037	17-10037	D	Potted plastic with shielded IDC jack + protective cover	18.76	14.92	14.23	13.26
706-17-10033	17-10033	D	Potted plastic version with shielded inline coupler, with IDC Jack	22.21	17.27	15.67	14.95
PCB Kits							
631-17-10023	17-10023	E	Plastic with shielded PCB jack + protective cover	18.51	16.66	15.15	14.12
631-17-10024	17-10024	E	Metalized plastic with shielded PCB jack + protective cover	21.40	18.72	17.46	14.96
631-17-10039	17-10039	E	Potted plastic with shielded PCB jack + protective cover	18.76	15.03	14.45	13.16
631-17-10040	17-10040	E	Potted metalized plastic with shielded PCB jack + protective cover	21.09	17.41	16.81	15.93
706-17-10017	17-10017	E	Plastic version with shielded inline coupler, with PCB Jack	20.70	16.10	14.60	13.94
706-17-10035	17-10035	E	Potted plastic version with shielded inline coupler, with PCB Jack	22.39	15.92	14.14	13.73
Installation Housing Kits							
706-17-100934	17-100934	F	Metal version w/shielded Cat 5e In-line coupler, M28 thread screw	29.32	26.98	24.98	23.25
706-17-101494	17-101494	F	Metal version w/unshielded Cat 5e In-line coupler, M28 thread screw	20.96	16.76	16.63	15.88
706-17-101604	17-101604	F	Metal version w/shielded Cat 5e In-line coupler + Protective cover (M28)	33.38	26.70	26.49	25.29
706-17-101614	17-101614	F	Metal version w/unshielded Cat 5e In-line coupler + Protective cover (M28)	31.86	25.48	25.29	24.14

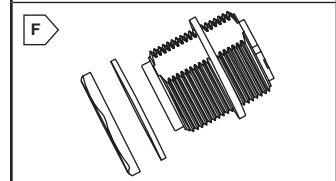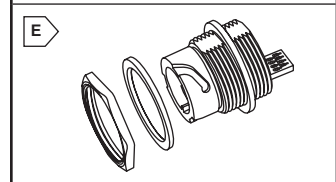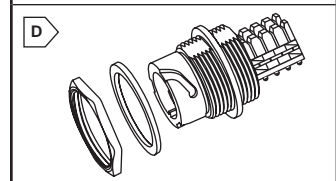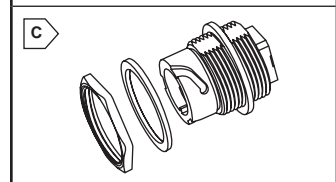


RJ45 Plugs

MOUSER STOCK NO.	CONEC Part No.	Fig.	Description	Price Each			
				1	10	25	50
Plug Kit							
631-17-10001	17-10001	G	Plug Kit-plastic version-quick bayonet style locking	7.08	5.23	5.01	4.67
631-17-10013	17-10013	G	Plug Kit-metalized plastic version-quick bayonet style locking	11.63	8.60	7.98	7.13
631-17-10044	17-10044	G	Plug Kit-die cast coupling ring, version-quick bayonet style locking	14.41	11.52	9.78	9.22
706-17-101794	17-101794	G	Plug Kit-die cast, version-quick bayonet style locking	18.98	14.69	13.76	13.13
Plugs with Strain Relief							
631-17-100464	17-100464	G	Plug with strain relief kit plastic version with M28 thread locking style	9.50	7.03	6.88	6.34
631-17-100474	17-100474	G	Plug w/ strain relief kit metalized version with M28 thread locking style	11.63	8.60	8.01	7.63

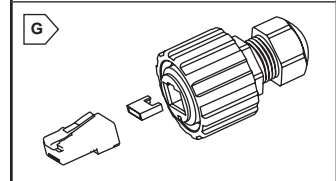



Protective Covers

MOUSER STOCK NO.	CONEC Part No.	Fig.	Description	Price Each			
				1	10	25	50
631-17-10002	17-10002	-	Protective cover assembly plastic version	4.70	4.18	3.76	3.42
631-17-10014	17-10014	-	Protective cover assembly metalized plastic version	4.78	4.24	3.82	3.47

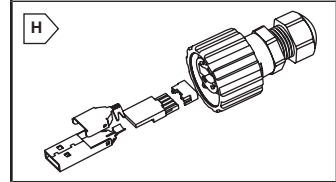

USB 2.0 IP67 WATER RESISTANT CONNECTOR SYSTEM

MOUSER STOCK NO.	CONEC Part No.	Fig.	Description	Price Each			
				1	10	25	50
Plastic							
706-17-200121	17-200121	H	USB Type A Plug Kit bayonet type	4.58	5.09	4.71	4.58
706-17-200151	17-200151	H	USB Strain Relief Assembly w/Type A Plug M28 Thread	4.63	4.95	4.77	4.63
706-17-200001	17-200001	C	USB Type A/A Female Adapter, Plastic bayonet type	5.69	6.09	5.87	5.69
706-17-200161	17-200161	C	USB Receptacle and Cover bayonet Type A/A Female Adapter	7.66	8.58	8.12	7.66
Metal							
706-17-200591	17-200591	H	USB Type A Plug Kit, Die Cast	9.77	10.44	10.07	9.77
706-17-200331	17-200331	I	USB Type A Plug Assembly Kit, Metal M28 Thread	10.96	11.63	11.18	10.96
706-17-200321	17-200321	F	USB Type A/A Female Adapter, Metal M28 Thread	12.96	14.02	13.47	12.96
706-17-200601	17-200601	C	USB Type A/A Female Adapter, Die Cast, bayonet type	16.19	16.77	16.44	16.19
706-17-200611	17-200611	C	USB Type A/A Female Adapter, Die Cast, bayonet type with cover	24.05	25.29	24.54	24.05
Covers							
631-17-10002	17-10002	-	Protective cover assembly plastic version	3.42	4.18	3.76	3.42
706-17-101710	17-101710	-	Protective cover assembly bayonet type, with metal ball chain	4.52	5.06	4.80	4.52
706-17-100950	17-100950	-	Protective cover assembly metal M28 thread	8.59	9.19	8.86	8.59
706-17-101800	17-101800	-	Protective cover die cast - bayonet	8.91	10.17	9.33	8.91
Patch Cords							
706-17-200231	17-200231	J	USB Patch Cord 2M Type A Plug (Bayonet) to Type A Plug (Standard)	8.54	9.67	9.13	8.54
706-17-200181	17-200181	J	USB Patch Cord 2M Type A Plug (Bayonet) to Type B Plug (Standard)	8.54	9.67	9.13	8.54

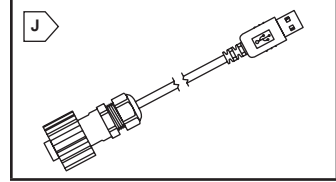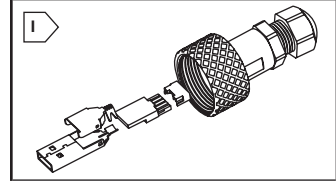

TOOLS

MOUSER STOCK NO.	CONEC Part No.	Description	Price Each	
			1	5
631-360X30049X	360X30049X	Punch-Down Tool	5.23	4.64
631-360X30029X	360X30029X	RJ45 Plug Terminator	37.87	33.14