


KOBICONN Insulated / Uninsulated Terminals

KOBICONN

Terminals

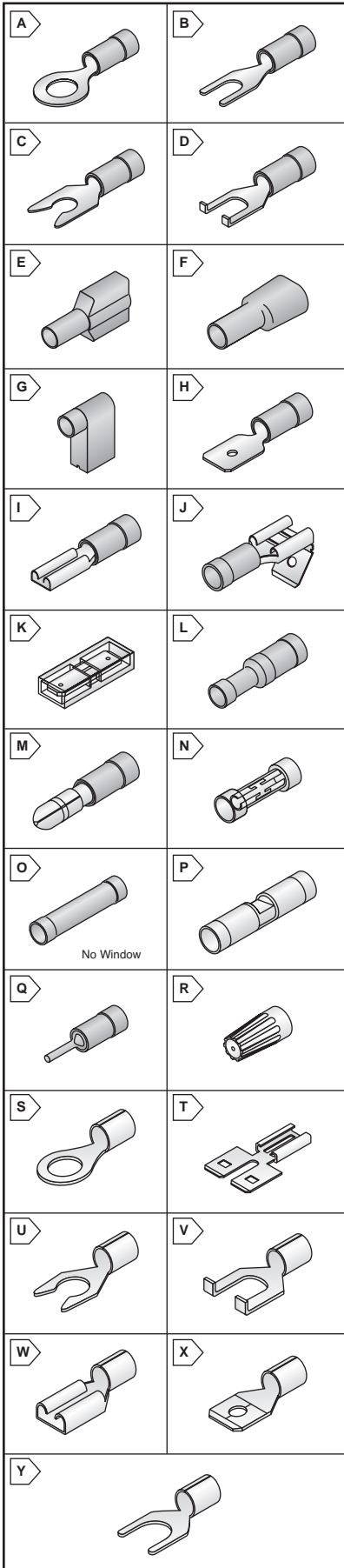

INSULATED SOLDERLESS TERMINALS

Ring Terminals Vinyl Insulated

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Color	Stud Size	Wire Size (AWG)	Price Each			
					1	100	1000	5000
159-2201	A	Red	1/4"	22-16	.18	.13	.10	.09
159-2202	A	Red	5/16"	22-16	.18	.12	.10	.08
159-2204	A	Red	#4	22-16	.15	.10	.09	.08
159-2206	A	Red	#6	22-16	.15	.10	.08	.07
159-2208	A	Red	#8	22-16	.16	.10	.09	.07
159-2210	A	Red	#10	22-16	.15	.09	.08	.07
159-1601	A	Blue	#4	16-14	.15	.10	.09	.07
159-1602	A	Blue	1/4"	16-14	.16	.13	.11	.09
159-1603	A	Blue	5/16"	16-14	.18	.14	.13	.12
159-1606	A	Blue	#6	16-14	.15	.10	.08	.07
159-1608	A	Blue	#8	16-14	.14	.10	.08	.071
159-1610	A	Blue	#10	16-14	.15	.09	.08	.07
159-1201	A	Yellow	#6	12/10	.16	.12	.10	.08
159-1202	A	Yellow	#8	12/10	.22	.18	.13	.11
159-1203	A	Yellow	#10	12/10	.20	.15	.12	.10
159-1204	A	Yellow	1/4"	12/10	.19	.16	.14	.12
159-1205	A	Yellow	5/16"	12/10	.35	.21	.19	.16
159-1206	A	Yellow	3/8"	12/10	.20	.14	.13	.117

Spade Terminals Vinyl Insulated

159-2226	B	Red	#6	22-16	.15	.09	.08	.07
159-2228	B	Red	#8	22-16	.15	.09	.08	.07
159-2220	B	Red	#10	22-16	.13	.09	.08	.07
159-1626	B	Blue	#6	16-14	.16	.10	.09	.07
159-1628	B	Blue	#8	16-14	.15	.09	.08	.06
159-1620	B	Blue	#10	16-14	.15	.10	.09	.07
159-1207	B	Yellow	#8	12/10	.21	.15	.13	.10
159-1208	B	Yellow	#10	12/10	.20	.15	.12	.11

Locking Spade Terminals Vinyl Insulated

159-2203	C	Red	#6	22-16	.15	.11	.09	.07
159-2207	C	Red	#8	22-16	.15	.09	.08	.07
159-1605	C	Blue	#6	16-14	.15	.09	.07	.06
159-1607	C	Blue	#8	16-14	.16	.10	.08	.07

Flanged Spade Terminals Vinyl Insulated

159-2236	D	Red	#6	22-16	.15	.10	.09	.07
159-2238	D	Red	#8	22-16	.18	.10	.09	.07
159-2230	D	Red	#10	22-16	.18	.12	.11	.10
159-1636	D	Blue	#6	16-14	.15	.09	.08	.06
159-1638	D	Blue	#8	16-14	.19	.13	.12	.11
159-1630	D	Blue	#10	16-14	.15	.09	.08	.07

Couplers (Male) Nylon Insulated

MOUSER STOCK NO.	Fig.	Color	Stud Size	Wire Size (AWG)	Price Each			
					1	100	1000	5000
159-3251	E	Red	22-16	.250x.032	.26	.21	.16	.11
159-7251	E	Blue	16-14	.250x.032	.26	.21	.19	.14

Couplers (Female) Vinyl Insulated

159-2215	F	Red	22-16	.250x.032	.19	.13	.11	.09
159-1618	F	Blue	16-14	.250x.032	.19	.13	.11	.09

Couplers (Female) Nylon Insulated

159-3250	F	Red	22-16	.250x.032	.26	.21	.17	.11
159-7250	F	Blue	16-14	.250x.032	.31	.24	.22	.15

Flag Disconnects (Female) Nylon Insulated

159-2225	G	Red	22-16	.250x.032	.27	.22	.20	.15
159-1625	G	Blue	16-14	.250x.032	.24	.16	.14	.13

Disconnects Vinyl Insulated

MOUSER STOCK NO.	Fig.	Color	Stud Size	Wire Size (AWG)	Price Each			
					1	100	1000	5000
159-2250	H	Red	.250x.032	22-16	.18	.10	.09	.07
159-6250	H	Blue	.250x.032	16-14	.16	.10	.09	.07
159-1210	H	Yellow	.250x.032	22-10	.12	.10	.09	.08
159-2211	I	Red	.11x.020	22-16	.16	.10	.09	.07
159-2187	I	Red	.187x.020	22-16	.19	.10	.09	.08
159-2205	I	Red	.20x.020	22-16	.15	.09	.08	.07
159-2251	I	Red	.250x.032	22-16	.18	.10	.09	.08
159-1604	I	Blue	.110x.020	16-14	.13	.10	.08	.07
159-6187	I	Blue	.187x.020	16-14	.13	.10	.08	.07
159-6205	I	Blue	.20x.020	16-14	.15	.10	.09	.07
159-6251	I	Blue	.250x.032	16-14	.18	.10	.09	.08
159-1209	I	Yellow	.250x.032	12/10	.17	.12	.11	.07
159-2212	J	Red	.250x.032	22-16	.24	.14	.13	.12
159-1611	J	Blue	.250x.032	16-14	.18	.11	.10	.09

Adapter- Male to Male Disconnect Vinyl Insulated

159-1502	K	Clear	.250x.032	----	.24	.16	.14	.13
----------	---	-------	-----------	------	-----	-----	-----	-----

Bullet Connectors Vinyl Insulated

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Color	Stud Size	Wire Size (AWG)	Price Each			
					1	100	1000	5000
159-2156	L	Red	0.157	22-16	.18	.13	.11	.09
159-3156	L	Red	0.157	22-16	.18	.11	.10	.09
159-1612	L	Blue	0.157	16-14	.21	.12	.11	.10
159-1613	L	Blue	0.195	16-14	.18	.12	.10	.08
159-1615	M	Blue	0.157	16-14	.18	.11	.09	.08
159-1616	M	Blue	0.195	16-14	.16	.10	.09	.07

Adapter- Bullet to Bullet Connector Vinyl Insulated

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Color	Wire Size (AWG)	Tab Width (In.)	Price Each			
					1	100	1000	5000
159-1501	N	Yellow	0.156	----	.28	.17	.16	.12

Butt Connectors Vinyl Insulated

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Color	Wire Size (AWG)	Tab Width (In.)	Price Each			
					1	100	1000	5000
159-1622	O	Red	22-16	----	.19	.10	.09	.07
159-1614	O	Blue	16-14	----	.18	.10	.09	.07
159-1213	O	Yellow	12/10	----	.30	.18	.16	.14
159-2252	P	Red	22-16	----	.42	.28	.25	.23

Pin Terminals Vinyl Insulated

For quantities greater than listed, call for quote.

159-2213	Q	Red	0.074	22-16	.18	.15	.10	.09
159-1617	Q	Blue	0.074	16-14	.16	.11	.09	.08
159-1211	Q	Yellow	0.11	12/10	.29	.20	.15	.14

Wire Nuts

For quantities greater than listed, call for quote.

159-2216	R	Gray	----	22-16	.16	.10	.09	.076
159-2214	R	Orange	----	22-14	.13	.09	.08	.07
159-1803	R	Yellow	----	18-12	.15	.10	.09	.08
159-1804	R	Red	----	18-10	.15	.10	.09	.08

UNINSULATED SOLDERLESS TERMINALS

Brazed Seam Except Where Noted

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Stud Size	Wire Size (AWG)	Price Each			
				1	100	1000	5000

Ring Terminals Non-Insulated

159-2222	S	#4	22-16	.10	.08	.07	.06
159-2223	S	#6	22-16	.11	.07	.06	.05
159-2224	S	#8	22-16	.15	.08	.06	.05
159-2227	S	#10	22-16	.15	.09	.08	.07
159-2229	S	1/4"	22-16	.11	.08	.07	.06
159-2231	S	5/16"	22-16	.11	.09	.08	.07
159-1627	S	#4	16-14	.11	.08	.06	.05
159-1629	S	#6	16-14	.15	.09	.08	.06
159-1632	S	#10	16-14	.12	.09	.08	.07
159-1218	S	#10	12/10	.17	.13	.10	.09
159-1219	S	1/4"	12/10	.19	.13	.11	.10
159-1220	S	5/16"	12/10	.17	.12	.11	.10
159-1221	S	3/8"	12/10	.18	.13	.11	.09

Double Male/Female Adapter

159-1226	T	.250 x .032	----	.22	.14	.13	.10
----------	---	-------------	------	-----	-----	-----	-----

Locking Spade Terminals Non-Insulated

159-2241	U	#6	22-16	.10	.06	.05	.04
159-2242	U	#8	22-16	.09	.06	.05	.04
159-1644	U	#6	16-14	.10	.08	.07	.05

Flange Spade Terminals Non-Insulated Butted Seam

159-2244A	V	#6	22-16	.08	.06	.05	.04
159-2245	V	#8	22-16	.10	.06	.05	.04

Disconnects Non-Insulated Butted Seam

159-2235	W	.110 x .020	22-16	.07	.05	.04	.03
159-2237	W	.187 x .020	22-16	.09	.06	.05	.04
159-2239A	W	.205 x .020	22-16	.10	.06	.05	.04
159-2240	W	.250 x .032	22-16	.11	.08	.06	.05
159-1640	W	.110 x .020	16-14	.08	.06	.05	.04
159-1641	W	.187 x .020	16-14	.10	.06	.05	.04
159-1642	W	.205 x .020	16-14	.10	.07	.06	.05
159-1643	W	.250 x .032	16-14	.11	.08	.07	.06
159-1224	W	.250 x .032	12/10	.14	.09	.08	.06
159-1650	X	.250 x .032	16-14	.10	.08	.07	.06
159-1225	X	.250 x .032	12/10	.13	.08	.07	.06


Spade Terminals Non-Insulated

159-2232	Y	#6	22-16	.09	.07	.06	.05
159-2233	Y	#8	22-16	.13	.08	.07	.06
159-2234	Y	#10	22-16	.11	.08	.07	.06
159-1635	Y	#6	16-14	.11	.09	.07	.06
159-1637	Y	#8	16-14	.09	.08	.06	.05
159-1222	Y	#8	12/10	.19	.13	.11	.09

CRIMP TOOL FOR SOLDERLESS TERMINALS

Heavy duty or small task tool designed with crimper, cutter, and stripper all in one.

 - * Use with fig. A,B,C,D,E,H,J,P
- ** Use with fig. F,L,M
- *** Use with fig. S,U,Y



MOUSER STOCK NO.	Description	Price Each
159-32800		